




Reinforced PVC - Potable Water Hose



HydroMode™ reinforced PVC hose incorporates a polyester spiraled yarn which allows use in higher pressure applications. Hose provides good chemical resistance and is flexible and lightweight. It is Phthalate free and NSF 61® certified for use in potable water and food beverage applications.

Features

- NSF-61 certified
- Shore A 73 PVC
- Clear blue in color
- Flexible and lightweight
- Phthalate free

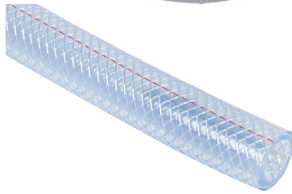

Reinforced Construction

Reinforced PVC - Potable Water Hose								
Temp. Range		+15°F to +150°F (-9.4°C to +65.6°C)						
Hardness		Shore A 73 PVC						
Part Number	Price	Hose I.D. (inch)	Hose O.D. (inch)	Working Pressure (psi) @ 70°F	Working Pressure (psi) @ 125°F	Wall Thickness (inch)	PKG Length	Package Weight (lbs)
HBV316-100CBL	\$21.00	0.187	0.375	250	145	0.094	100 ft	4.4
HBV316-300CBL	\$63.00	0.187	0.375	250	145	0.094	300 ft	13.2
HBV14-100CBL	\$25.00	0.250	0.438	250	145	0.094	100 ft	5.8
HBV14-300CBL	\$76.00	0.250	0.438	250	145	0.094	300 ft	17.5
HBV516-100CBL	\$33.00	0.313	0.531	250	130	0.109	100 ft	7.4
HBV516-300CBL	\$99.00	0.313	0.531	250	130	0.109	300 ft	22.2
HBV38-100CBL	\$40.00	0.375	0.594	225	120	0.110	100 ft	9.0
HBV38-300CBL	\$119.00	0.375	0.594	225	120	0.110	300 ft	27.1
HBV12-100CBL	\$58.00	0.500	0.750	200	95	0.125	100 ft	13.3
HBV12-300CBL	\$175.00	0.500	0.750	200	95	0.125	300 ft	40.0
HBV58-100CBL	\$70.00	0.625	0.891	200	95	0.133	100 ft	15.9
HBV58-300CBL	\$209.00	0.625	0.891	200	95	0.133	300 ft	47.8
HBV34-100CBL	\$91.00	0.750	1.030	150	80	0.140	100 ft	20.7
HBV34-300CBL	\$273.00	0.750	1.030	150	80	0.140	300 ft	62.2
HBV1-100CBL	\$131.00	1.000	1.300	125	70	0.150	100 ft	29.1
HBV1-200CBL	\$261.00	1.000	1.300	125	70	0.150	200 ft	58.2