



# HydroMode™ Potable Water Push-to-Connect Fittings

HydroMode push-to-connect union hand valve fitting with acetel body and synthetic rubber o-ring. For use with polyethylene and other flexible tubing. Five fittings per package.

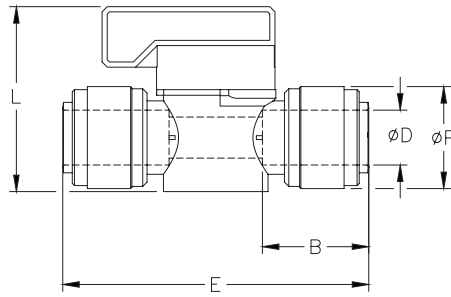

| HydroMode™ Union Hand Valve  |         |                     |           |      |      |      |      |                      |               |
|--|---------|---------------------|-----------|------|------|------|------|----------------------|---------------|
| Inch Sizes - dimensions in millimeters (mm) unless otherwise noted |         |                     |           |      |      |      |      |                      |               |
| Part No.   | Price   | Size (inch)         | ØD (inch) | B    | ØP   | L    | E    | Package Weight (lbs) | Qty. per pack |
| HVU14-P  | \$12.00 | 1/4 in. x 1/4 in.   | 1/4       | 16.1 | 15.5 | 34.5 | 51.7 | 0.1                  | 2             |
| HVU516-P   | \$12.00 | 5/16 in. x 5/16 in. | 5/16      | 17.5 | 17.6 | 34.5 | 53.5 | 0.1                  | 2             |
| HVU38-P  | \$12.50 | 3/8 in. x 3/8 in.   | 3/8       | 20.2 | 20.0 | 42.3 | 63.2 | 0.1                  | 2             |
| HVU12-P  | \$13.00 | 1/2 in. x 1/2 in.   | 1/2       | 23.9 | 23.0 | 42.3 | 70.8 | 0.2                  | 2             |

HydroMode push-to-connect polyoxymethylene (acetel) locking clip. For use with HydroMode fittings. Twenty five fittings per package.

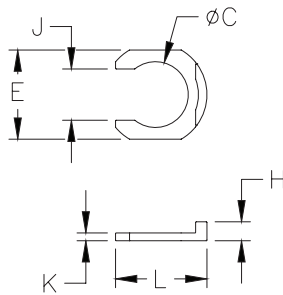


| HydroMode™ Locking Clip  |        |             |           |      |      |      |     |      |     |                      |               |
|--|--------|-------------|-----------|------|------|------|-----|------|-----|----------------------|---------------|
| Inch Sizes - dimensions in millimeters (mm) unless otherwise noted |        |             |           |      |      |      |     |      |     |                      |               |
| Part No.   | Price  | Size (inch) | ØD (inch) | ØC   | E    | L    | H   | J    | K   | Package Weight (lbs) | Qty. per pack |
| LC532-P  | \$2.75 | 5/32 in.    | 5/32      | 6.2  | 10.2 | 11.0 | 2.8 | 4.3  | 1.1 | 0.1                  | 25            |
| LC14-P   | \$2.75 | 1/4 in.     | 1/4       | 8.0  | 11.6 | 11.6 | 3.1 | 6.4  | 1.3 | 0.1                  | 25            |
| LC516-P  | \$3.00 | 5/16 in.    | 5/16      | 9.6  | 13.5 | 13.9 | 3.3 | 7.3  | 1.4 | 0.1                  | 25            |
| LC38-P   | \$3.00 | 3/8 in.     | 3/8       | 11.8 | 16.0 | 16.4 | 3.4 | 9.2  | 1.4 | 0.1                  | 25            |
| LC12-P   | \$3.00 | 1/2 in.     | 1/2       | 14.4 | 19.0 | 19.0 | 3.6 | 11.1 | 1.4 | 0.1                  | 25            |

# HydroMode™ Potable Water Push-to-Connect Fittings

HydroMode push-to-connect fittings are designed to work with potable water and beverages. Installing or removing flexible tubing is quick and easy. All fittings are made of NSF approved materials with NSF-51® and NSF-61® certifications. The body and collet of the fittings are made from polyoxymethylene (POM) also known as acetal, while the o-rings are made from ethylene propylene diene monomer (EPDM) which is a type of synthetic rubber.

## Features

- Designed for potable water and beverages
- NSF-51 and NSF-61 certified
- Easy tubing installation and removal
- Optional retaining clips prevent accidental tube removal
- Fittings rated for up to 145psi at 70°C (158°F)

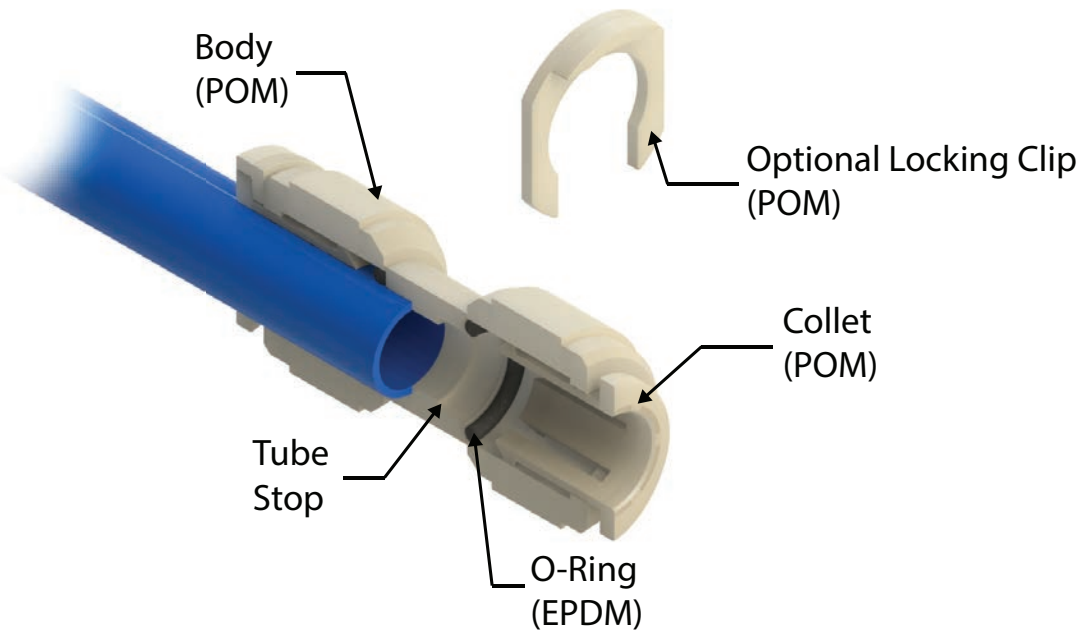

*Push-to-Connect Fitting  
Cut-away Diagram*