

# Polycarbonate Enclosures – Premium Series

## Subpanels and Swing-Out Panels



### Construction

- Subpanels available in aluminum, PVC, and steel with white powder coat finish.
- Swing-Out panels available in aluminum.
- Mounting hardware included.
- Use the Adjustable Depth Subpanel Mounting Kit with any subpanel to create a dead-front panel with adjustable depth.
- Mounting screw torque - 10 to 15 lb-in.
- Aluminum panels are 0.063-in thick.
- Painted steel panels are 0.075-in thick.
- PVC panels are 0.187-in thick.



Premium Series Polycarbonate Enclosures - Subpanels								
Aluminum	Price	PVC	Price	Aluminum & PVC Dimensions HxW	Painted Steel	Price	Painted Steel Dimensions HxW	For Use With
<b>ABP66-P10</b>	\$9.00	<b>PVCBP66-P10</b>	\$10.00	4.88 x 4.88 [124 x 124]	<b>SBP66-P10</b>	\$9.50	4.88 x 4.88 [124 x 124]	H606 enclosures
<b>ABP86-P10</b>	\$9.50	<b>PVCBP86-P10</b>	\$11.00	6.75 x 4.88 [171 x 124]	<b>SBP86-P10</b>	\$10.50	6.88 x 4.88 [175 x 124]	H806 enclosures
<b>ABP88-P10</b>	\$10.50	<b>PVCBP88-P10</b>	\$12.75	6.75 x 6.88 [174 x 175]	<b>SBP88-P10</b>	\$11.00	6.88 x 6.88 [175 x 175]	H808 enclosures
<b>ABP108-P10</b>	\$11.50	<b>PVCBP108-P10</b>	\$15.25	8.75 x 6.88 [222 x 175]	<b>SBP108-P10</b>	\$12.75	8.88 x 6.88 [226 x 175]	H1008 enclosures
<b>ABP1210-P10</b>	\$13.25	<b>PVCBP1210-P10</b>	\$18.00	10.75 x 8.88 [273 x 226]	<b>SBP1210-P10</b>	\$14.25	10.88 x 8.88 [276 x 226]	H1210 enclosures

*Note: Dimensions in inches [millimeters].*

Premium Series Polycarbonate Enclosures - Swing-Out Panels			
Aluminum	Price	Dimension HxW	For Use With
<b>ABP-66USOPK-P10</b>	\$24.00	4.92 x 4.92 [125 x 125]	H606 enclosures
<b>ABP-86USOPK-P10</b>	\$24.50	6.75 x 4.87 [171 x 124]	H806 enclosures
<b>ABP-88USOPK-P10</b>	\$25.50	6.75 x 6.87 [171 x 174]	H808 enclosures
<b>ABP-108USOPK-P10</b>	\$26.50	8.75 x 6.88 [222 x 175]	H1008 and P1008 enclosures
<b>ABP-1210USPK-P10</b>	\$27.50	10.88 x 8.88 [276 x 226]	H1210 enclosures

*Note: Dimensions in inches [millimeters].*





Premium Series Polycarbonate Enclosures Adjustable Depth Subpanel Mounting Kit		
Part Number	Price	Includes
<b>BPAKG-P10</b>	\$14.75	4 brackets with set screws
<b>UBPAKG-P10</b>	\$17.00	4 brackets with thumb screws

*Note: Also fits P1008 Impact series enclosures.*



# Polycarbonate Enclosures – Premium Series

## Dimensions

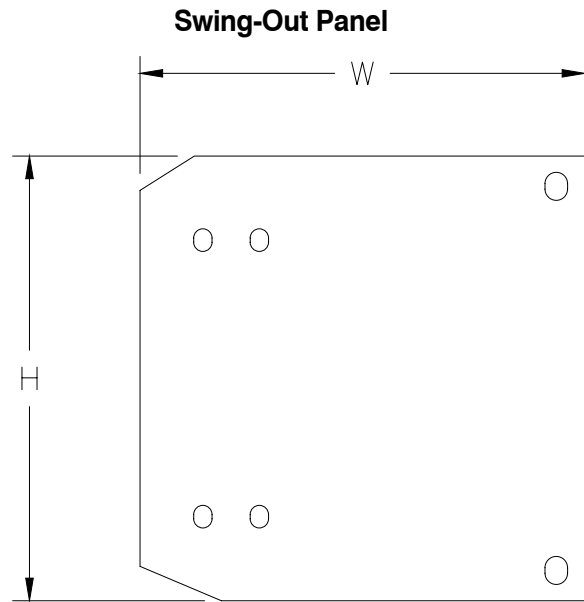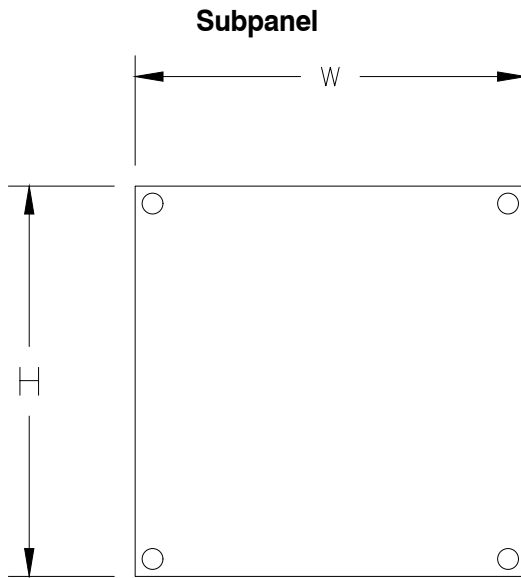

*See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete Engineering Drawings.*

# Polycarbonate Enclosures Pole-Mounting Kits



## Construction

- All kits include galvanized steel strut rails and plated steel fasteners, except PMKG-12-IMP-P10, which does not have strut rails.
- Kits for 9-1/2 to 12 in diameter poles include galvanized steel band clamps and brackets. All other kits include galvanized steel pipe clamps.



Pole Mounting Kits				
Part Number	Price	Pole Diameter	Kit Includes	For Use With
<b>PMKG-26-P10</b>	\$35.00	2in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	6in wide Premium series enclosures
<b>PMKG-36-P10</b>	\$42.00	3in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	6in wide Premium series enclosures
<b>PMKG-46-P10</b>	\$44.00	4in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	6in wide Premium series enclosures
<b>PMKG-126-P10</b>	\$54.00	9-1/2 in to 12 in	Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners	6in wide Premium series enclosures
<b>PMKG-28-P10</b>	\$37.00	2in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	8in wide Premium series enclosures
<b>PMKG-38-P10</b>	\$42.00	3in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	8in wide Premium series enclosures
<b>PMKG-48-P10</b>	\$44.00	4in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	8in wide Premium series enclosures
<b>PMKG-128-P10</b>	\$55.00	9-1/2 in to 12 in	Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners	8in wide Premium series enclosures
<b>PMKG-210-P10</b>	\$37.00	2in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	10in wide Premium series enclosure
<b>PMKG-310-P10</b>	\$43.00	3in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	10in wide Premium series enclosures
<b>PMKG-410-P10</b>	\$45.50	4in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	10in wide Premium series enclosures
<b>PMKG-1210-P10</b>	\$57.00	9-1/2 in to 12 in	Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners	10in wide Premium series enclosures
<b>PMKG-12-IMP-P10</b>	\$23.00	2in to 12in	Plastic tie wrap and mount adapter; plated steel fasteners	4in wide Impact series enclosures
<b>PMKG-26-IMP-P604</b>	\$35.00	2in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	6in wide Impact series enclosures
<b>PMKG-36-IMP-P604</b>	\$42.00	3in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	6in wide Impact series enclosures
<b>PMKG-46-IMP-P604</b>	\$44.00	4in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	6in wide Impact series enclosures
<b>PMKG-126-IMP-P604</b>	\$54.00	9-1/2 in to 12 in	Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners	6in wide Impact series enclosures
<b>PMKG-28-IMP-P604</b>	\$37.00	2in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	8in wide Impact series enclosures
<b>PMKG-38-IMP-P604</b>	\$42.00	3in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	8in wide Impact series enclosures
<b>PMKG-48-IMP-P604</b>	\$44.00	4in	Galvanized steel strut rails, pipe clamps, and brackets; plated steel fasteners	8in wide Impact series enclosures
<b>PMKG-128-IMP-P604</b>	\$55.00	9-1/2 in to 12 in	Galvanized steel strut rails, band clamps, and brackets; plated steel fasteners	8in wide Impact series enclosures

# Polycarbonate Enclosures – Accessories



Slotted DIN Rail 35mm x 7mm Plated Steel			
Part Number	Price	Length	For Use With
<b>DIN4-IMP-P10</b>	\$11.50	3.82 [97]	4in wide Impact series enclosures
<b>DIN6-IMP-P604</b>	\$11.50	4.88 [124]	6in wide Impact series enclosures
<b>DIN8-IMP-P604</b>	\$14.75	6.75 [171]	8in wide Impact series enclosures
<b>DIN6-P10</b>	\$11.50	4.88 [124]	6in wide Premium series enclosures
<b>DIN8-P10</b>	\$14.75	6.75 [171]	8in wide Premium series enclosures
<b>DIN10-P10</b>	\$15.75	8.88 [225]	10in wide Premium series enclosures

*Notes: Dimensions in inches [millimeters].  
Each item includes (2) DIN rails and mounting hardware.*



Mounting Feet Kits			
Part Number	Price	Material	For Use With
<b>MFKG-P10</b>	\$9.75	polycarbonate	Premium series enclosures
<b>MFKSS-P10</b>	\$28.00	304 stainless steel	Premium series enclosures

*Note: Each kit includes (4) mounting feet and mounting hardware.*



Screw Packs (10 Pcs)					
Part Number	Price	Screw Type	Size	Screw Head	For Use With
<b>SP-8-P604</b>	\$7.00	25-thread cutting	#8-32 x 3/8 in	Phillips pan head	4in and 6in wide Impact series enclosures
<b>SP-10I-P604</b>	\$7.75	25-thread cutting	#10-32 x 3/8 in	Phillips pan head	8in wide Impact series and all Premium series enclosures



Outdoor Labyrinth Vent				
Part Number	Price	Material	Dimension HxWxD	For Use With
<b>VENT-2-P604</b>	\$9.25	polypropylene	2.72 x 2.03 x 0.88 [69 x 52 x 22]	Impact and Premium series enclosures

*Notes: Dimensions in inches [millimeters].  
Installation of vent de-rates enclosure to NEMA 3R.*



Replacement Quick-Release Latches			
Part Number	Price	Latch Material	For Use With
<b>SLL-KIT-P10</b>	\$15.75	304 stainless steel	Premium series enclosures

