

## Overview

### Cable Entry System KDP/X and KDP/R Series

The KDP/X and KDP/R cable entry systems are one-piece systems that allow for a high density of cables to pass through a small area of an enclosure or other bulkhead surfaces. The robust frame designs give better mechanical stability while achieving a high degree of environmental protection.

The KDP/X series is a fourth-generation cable entry frame with improved tool-free clip-in mounting and one instead of two elastomer layers. This is a great alternative to cable fittings when having many cables and space is an issue. These frames use standard cutouts with tool-free clip-in mounting or screw mounting options. The KDP/X series enables the quick and simple installation of up to 29 cables in a single frame.

The KDP/R series is a round type cable entry frame in 2 sizes, M50 x 1.5 mm or M63 x 1.5 mm. Designed to easily snap into 1.5 to 2.0 mm wall thickness or can be secured into place using the optional lock nut. The KDP/R series enables the quick and simple installation of up to 46 cables in a single frame.



## Features


- Available in 2 frame types
- Quick and easy to install
- Mounting options:  
Snap-in (both) or bolt-in (KDP/X) or lock nut (KDP/R)
- Integrated strain relief
- Fits standard cut-out dimensions
- High protection class IP65
- UL Type rating:  
KDP/X - UL Type 1, 12 KDP/R - UL Type 1
- Operating temperature:  
KDP/X -22 to 158°F [-30 to 70°C]  
KDP/R -22 to 194°F [-30 to 90°C]
- Flammability: V0 - UL94 (frame)
- Halogen-free
- 2-year warranty

## Agency Approvals

- cURus, meets UL508A underFile E481225


### Two Ways to Mount

Bolt-In Snap-In

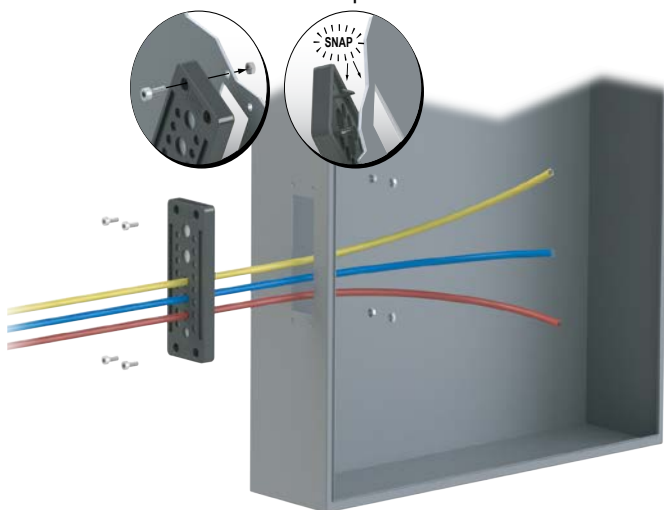

### Two Ways to Mount

Snap-In Optional lock nut

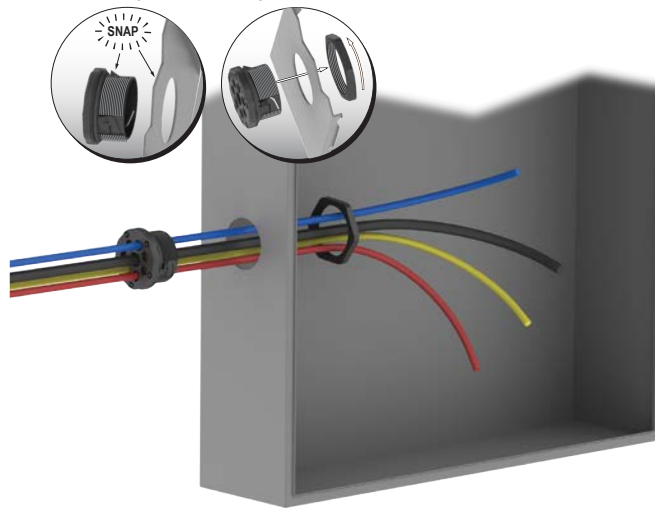

Screw mounting hardware not included with frames. Recommended screw: 4 x M5 (0.8 to 1.2 N•m)  
Tool-free clip-in mounting, frame thickness of 0.06 to 0.08 inches (1.5 to 2.0 mm) is required.

## Frames - KDP/X Series

The KDP/X series is a fourth generation cable entry frame with improved tool-free clip-in mounting and one instead of two elastomer layers. This is a great alternative to cable fittings when having a large number of cables and space is an issue. These frames use standard cutouts with tool-free clip-in mounting for wall thickness 1.5 to 2mm or screw mounting options.

Frames - KDP/X Series						
Part Number	Price	Qty	Number of Openings	Type	Drawing Link	Material
<b>Frame Size 24</b>						
<a href="#">567305</a>	\$47.50	1	(2) 3 to 6.5 mm (1) 5 to 9.2 mm (5) 9 to 14 mm (2) 14 to 20 mm	KDP/X 24/10	<a href="#">PDF</a>	Frame: Polyamide 6.6  Seal: TPU/ EPDM Thermoplastic polyurethane/ [ethylene propylene diene monomer]
<a href="#">567315</a>	\$47.50	1	(4) 3 to 6.5 mm (4) 5 to 9.2 mm (3) 14 to 20 mm	KDP/X 24/11	<a href="#">PDF</a>	
<a href="#">567325</a>	\$47.50	1	(12) 8 to 12 mm	KDP/X 24/12	<a href="#">PDF</a>	
<a href="#">567335</a>	\$47.50	1	(2) 3 to 5.5 mm (6) 4.1 to 8.1 mm (4) 9 to 14 mm (1) 14 to 20 mm	KDP/X 24/13	<a href="#">PDF</a>	
<a href="#">567345</a>	\$47.50	1	(6) 3 to 6.5 mm (4) 5 to 9.2 mm (4) 9.6 to 15.9 mm	KDP/X 24/14	<a href="#">PDF</a>	
<a href="#">567355</a>	\$47.50	1	(17) 5 to 9.2 mm	KDP/X 27/17	<a href="#">PDF</a>	
<a href="#">567356</a>	\$47.50	1	(11) 3 to 6.5 mm (1) 4.1 to 8.1 mm (5) 8 to 12.5 mm	KDP/X 24/17-1	<a href="#">PDF</a>	
<a href="#">567398</a>	\$47.50	1	(2) 3.5 to 6.5 mm (14) 5 to 9.2 mm (3) 7.5 to 11.5 mm	KDP/X 24/19	<a href="#">PDF</a>	
<a href="#">567365</a>	\$47.50	1	(16) 3 to 6.5 mm (4) 5 to 9.2 mm (2) 8 to 12.5 mm	KDP/X 24/22	<a href="#">PDF</a>	
<a href="#">567399</a>	\$47.50	1	(16) 3.5 to 6.5 mm (4) 7.5 to 11.5 mm (2) 9 to 14 mm	KDP/X 24/22-1	<a href="#">PDF</a>	
<a href="#">567375</a>	\$47.50	1	(23) 4.1 to 8.1 mm	KDP/X 24/23	<a href="#">PDF</a>	
<a href="#">567385</a>	\$47.50	1	(29) 3 to 6.5 mm	KDP/X 24/29	<a href="#">PDF</a>	

Notes: Screw mounting hardware not included with frames. Recommended screw: 4 x M5 (0.8 to 1.2 N•m)  
 Tool-free clip-in mounting, frame thickness of 0.06 to 0.08 inches (1.5 to 2.0 mm) is required.

[567345](#)[567305](#)[567315](#)[567325](#)[567335](#)[567355](#)[567356](#)[567375](#)[567365](#)[567385](#)[567399](#)[567398](#)

## Frames - KDP/R Series Round

The KDP/R series is a round type cable entry frame in 2 sizes, M50 x 1.5 mm or M63 x 1.5 mm. Designed to easily snap into 1.5 to 2.0 mm wall thickness or can be secure into place using the optional lock nut. The KDP/R series enables the quick and simple installation of up to 46 cables in a single frame.

Frames - KDP/R Series Round *						
Part Number	Price	Qty	Number of Openings	Type	Drawing Link	Material
Frame Size M50 x 1.5 mm						Frame: Polyamide 6.6  Seal: EPDM [ethylene propylene diene monomer]
<a href="#">565201</a>	\$48.00	1	(3) 6 to 10 mm (1) 9.6 to 15.9 mm	KDP/R M50/4	<a href="#">PDF</a>	
<a href="#">565203</a>	\$48.00	1	(1) 3 to 5.5 mm (5) 5 to 9.2 mm	KDP/R M50/6	<a href="#">PDF</a>	
<a href="#">565205</a>	\$48.00	1	(7) 3.5 to 6.5 mm (1) 6 to 10 mm	KDP/R M50/8	<a href="#">PDF</a>	
<a href="#">565207</a>	\$48.00	1	(31) 1.5 to 3.1 mm	KDP/R M50/31	<a href="#">PDF</a>	
Frame Size M63 x 1.5 mm						
<a href="#">565209</a>	\$49.00	1	(2) 3 to 6.5 mm (4) 5 to 9.2 mm (2) 9.6 to 15.9 mm	KDP/R M63/8	<a href="#">PDF</a>	
<a href="#">565211</a>	\$49.00	1	(6) 3 to 5.5 mm (6) 3.5 to 6.5 mm (1) 6 to 10 mm	KDP/R M63/13	<a href="#">PDF</a>	
<a href="#">565213</a>	\$49.00	1	(19) 3 to 5 mm	KDP/R M63/19	<a href="#">PDF</a>	
<a href="#">565215</a>	\$49.00	1	(46) 1.5 to 3.1 mm	KDP/R M63/46	<a href="#">PDF</a>	

Note: UL rating not supported when nut is used to secure frame.  
Hex nut not included, see table below.

[565201](#)[565203](#)[565205](#)[565207](#)[565209](#)[565211](#)[565213](#)[565215](#)

## Hex Nuts for KDP/R Series Round Frames

- -22 to 212°F [-30 to 100°C]
- UL94 VO self-extinguishing
- Polyamide PA 6

Hex Nuts For KDP/R Series Round Frames			
Part Number	Price	Description	Drawing Link
<a href="#">565250</a>	\$16.00	Murrplastik hex nut, M50 x 1.5 mm thread type, polyamide, black. Package of 5.	<a href="#">PDF</a>
<a href="#">565252</a>	\$18.50	Murrplastik hex nut, M63 x 1.5 mm thread type, polyamide, black. Package of 5.	<a href="#">PDF</a>

[565250](#)



# Cable Entry System

## Frames - KDP/Z Series

The KDP/Z series is an entry and fastening system for cables and pneumatic hoses used in control cabinets and machine construction. These frames use standard cutouts with tool-free clip-in mounting for wall thickness 1.5 to 2 mm or screw mounting options. Wherever quick assembly, cable protection, and high packing density are required, this frame can be used.

## Features

- Quick and easy to install
- Mounting options:
  - Assemble with clips or M5 screws
- Integrated strain relief
- Fits standard cut-out dimensions
- High protection class IP65, IP66, IP67, IP69K
- UL Type rating:
  - UL Type rating 4X, 12
- Operating temperature:
  - -22 to 158°F [-30 to 70°C]
- Flammability: HB - UL94 (frame)
- 2-year warranty


[567415](#)

[567419](#)

[567417](#)

[567421](#)

Frames - KDP/Z Series						
Part Number	Price	Qty	Number of Openings	Type	Drawing Link	Material
Frame Size 24						Frame: Polypropylene (PP)  Seal: Thermoplastic Elastomer (TPE)
<a href="#">567415</a>	\$72.00	1	(3) 22-33mm	KDP/Z 24/3	<a href="#">PDF</a>	
<a href="#">567417</a>	\$72.00	1	(14) 7.5-12mm	KDP/Z 24/14	<a href="#">PDF</a>	
<a href="#">567419</a>	\$72.00	1	(2) 3-6mm (4) 5-9mm (3) 7.5-12mm (3) 10-16mm (2) 14-20mm	KDP/Z 24/14	<a href="#">PDF</a>	
<a href="#">567421</a>	\$72.00	1	(23) 5-9mm	KDP/Z 24/23	<a href="#">PDF</a>	
Frame Size 16						
<a href="#">567405</a>	\$69.00	1	(10) 7.5-12mm	KDP/Z 16/10	<a href="#">PDF</a>	
<a href="#">567407</a>	\$69.00	1	(2) 3-5mm (4) 5-9mm (2) 7.5-12mm (2) 10-16mm (2) 14-20mm	KDP/Z 16/12	<a href="#">PDF</a>	
<a href="#">567409</a>	\$69.00	1	(17) 5-9mm	KDP/Z 16/17	<a href="#">PDF</a>	
<a href="#">567411</a>	\$69.00	1	(16) 3-6mm (6) 5-9mm (2) 7.5-12mm	KDP/Z 16/24	<a href="#">PDF</a>	
<a href="#">567413</a>	\$69.00	1	(20) 2-4mm (20) 3-6mm	KDP/Z 16/40	<a href="#">PDF</a>	
Frame Size 10						
<a href="#">567401</a>	\$73.00	1	(14) 5-9mm	KDP/Z 10/14	<a href="#">PDF</a>	
<a href="#">567403</a>	\$74.00	1	(8) 3-8mm (3) 5-9mm (4) 7.5-12mm	KDP/Z 10/15	<a href="#">PDF</a>	


[567405](#)

[567407](#)

[567409](#)

Notes: Screw mounting hardware not included with frames. Recommended screw: 4 x M5 (0.8 to 1.2 N•m)


[567403](#)

[567401](#)

[567413](#)

[567411](#)