

# KILLARK XCS Series Control Station Cover Assemblies - Pilot Lights

## Listings



Pilot Light



Double Pilot Light



Pilot Light / Pushbutton



Pilot Light / Two Mini Pushbutton

- UL Listed; File E53360
- Class I, Div. 1 & 2, Groups C, D
- Class II, Div. 1 & 2, Groups E, F, G
- Class III
- NEMA 3, 7 (C, D) 9 (E, F, G)
- CSA Certified; File LR11714
- Class I, Zones 1 & 2, Groups IIB, IIA



XCS Pilot Light						
Part Number (Includes cover with device)	Price	Description	Diagram	LED Voltage	Lens Color	Legend Plate Marking
<b>XCS-0B24ALD</b>	\$172.00	Single pilot light		110 VAC/VDC	Amber	Blank plate
<b>XCS-0B24CLD</b>	\$172.00	Single pilot light		110 VAC/VDC	Clear	Blank plate
<b>XCS-0B24GLD</b>	\$172.00	Single pilot light		110 VAC/VDC	Green	Blank plate
<b>XCS-0B24RLD</b>	\$172.00	Single pilot light		110 VAC/VDC	Red	Blank plate

XCS Double Pilot Light						
Part Number (Includes cover with device)	Price	Description	Diagram	LED Voltage	Lens Colors	Legend Plate Marking
<b>XCS-0B30ALD</b>	\$259.00	Two pilot lights		110 VAC/VDC	Amber Amber	Two blank plates
<b>XCS-0B30CLD</b>	\$253.00	Two pilot lights		110 VAC/VDC	Clear Clear	Two blank plates
<b>XCS-0B30GLD</b>	\$253.00	Two pilot lights		110 VAC/VDC	Green Green	Two blank plates
<b>XCS-0B30RLD</b>	\$253.00	Two pilot lights		110 VAC/VDC	Red Red	Two blank plates
<b>XCS-0B30RLD-GLD</b>	\$253.00	Two pilot lights		110 VAC/VDC	Red Green	Two blank plates

XCS Momentary Contact Pushbutton and Pilot Light							
Part Number (Includes cover with device)	Price	Description	Diagram	LED Voltage	Pushbutton Color	Lens Color	Legend Plate Marking
<b>XCS-0B13-CD</b>	\$179.00	1 N.C. momentary operator and pilot light		110 VAC/VDC	Red	Clear	Pushbutton: "STOP" Pilot light: Blank plate
<b>XCS-0B13-OD</b>	\$179.00	1 N.O. momentary operator and pilot light		110 VAC/VDC	Green	Red	Pushbutton: "START" Pilot light: Blank plate
<b>XCS-0B13-UD</b>	\$224.00	1 N.O. / 1 N.C. momentary and pilot light		110 VAC/VDC	Black	Red	Two blank plates

XCS Two Mini Momentary Contact Pushbuttons and Pilot Light							
Part Number (Includes cover with device)	Price	Description	Diagram	LED Voltage	Pushbutton Colors	Lens Color	Legend Plate Marking
<b>XCS-0A15D</b>	\$283.00	Mini red operator with 1 N.C. momentary contact and mini green operator with 1 N.O. momentary contact, and pilot light		110 VAC/VDC	Green Red	Red	N.O. Pushbutton: "START" N.C. Pushbutton: "STOP" Pilot light: Blank plate


\* We also offer a large selection of optional legend plates. See accessories later in this section.

# KILLARK Hazardous Location Controls - Dimensions


## XCS Series Cover Assemblies

Dimensions in inches [mm]


### XCS-0B24ALD, -0B24CLD, -0B24RLD

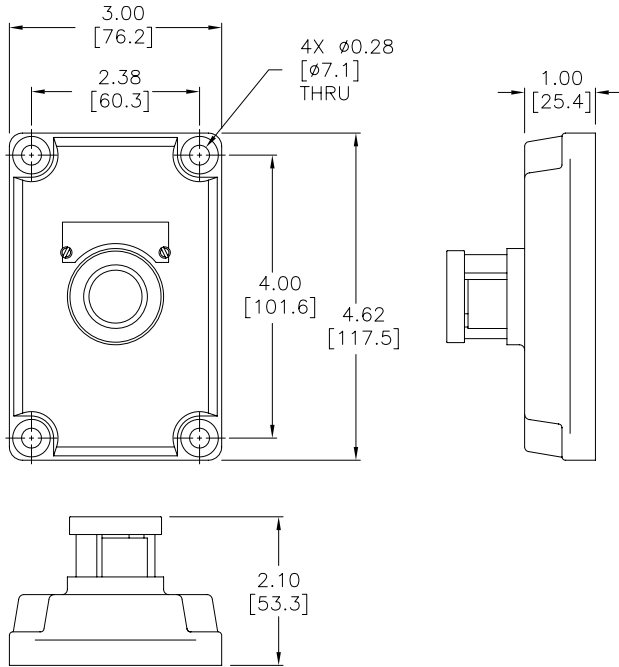


### XCS-0B30ALD, -0B30CLD, -0B30GLD, -0B30RLD, -0B30RLD-GLD

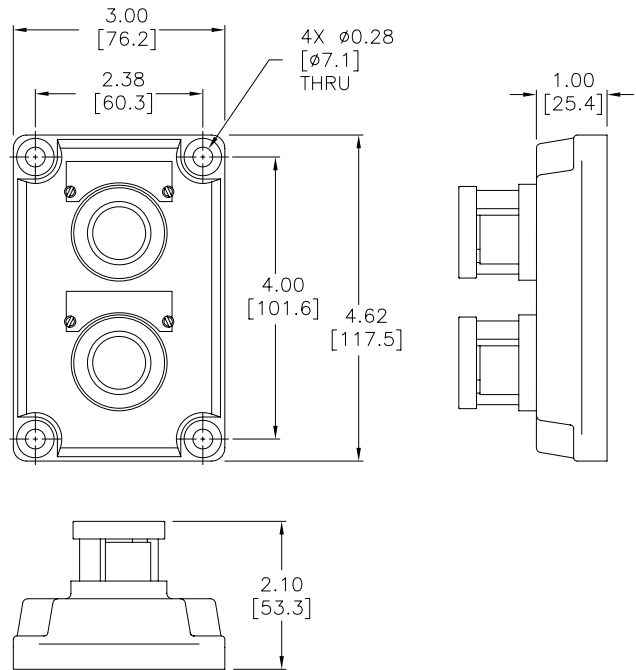

### XCS-0B13-CD, -0B13-OD, -0B13-UD

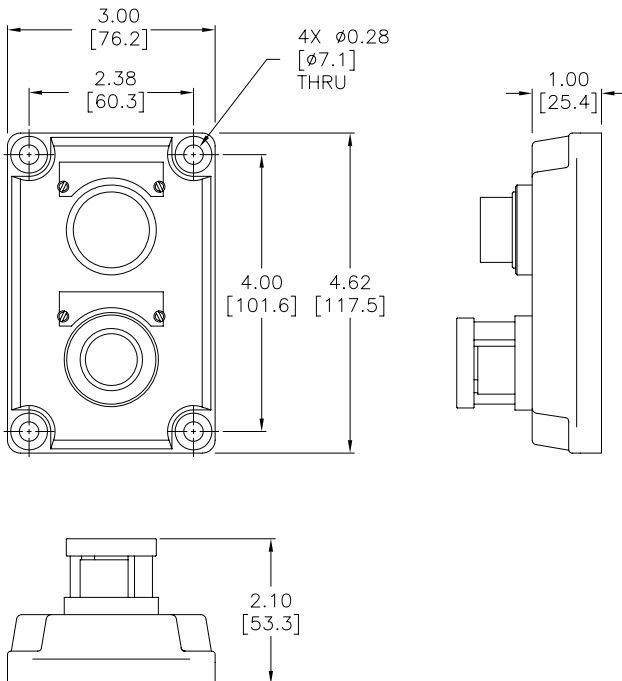

### XCS-0A15D

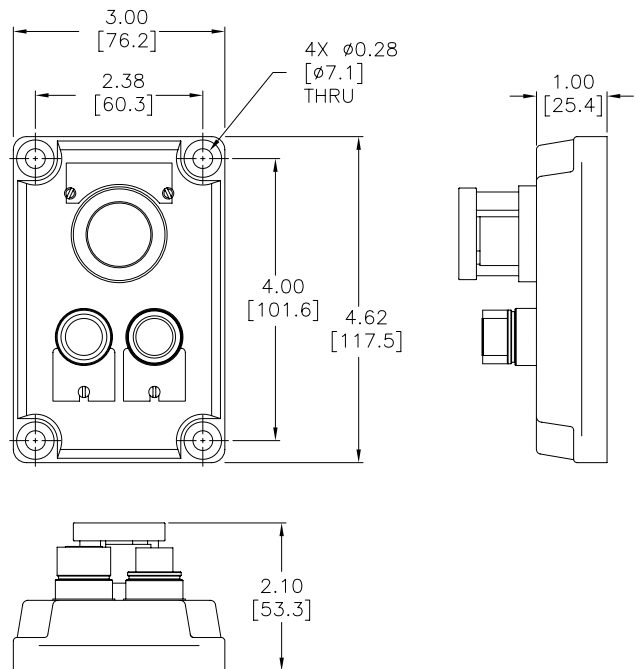

# KILLARK SWB Series Splice/Device Boxes For Use With XCS Cover Assemblies



**SWB-2**



**SWB-5**



**SWB-8**



**SWB-11**



**SWB-42**

## Listings

- UL Listed; File E53360
- Class I, Div. 1 & 2, Groups C, D
- Class II, Div. 1 & 2, Groups E, F, G
- Class III
- NEMA 3, 7 (C, D) 9 (E, F, G)
- CSA Certified; File LR11712
- Class I, Zones 1 & 2, Groups IIB, IIA




SWB Device Bodies			
Part Number	Price	Description	Hub Size (inches)
<b>SWB-2</b>	\$41.50	Single gang / Dead-end	3/4
<b>SWB-5</b>	\$42.50	Single gang / Feed-through	3/4
<b>SWB-8</b>	\$81.00	Double gang / Dead-end	3/4
<b>SWB-11</b>	\$82.00	Double gang / Feed-through	3/4
<b>SWB-42</b>	\$107.00	Single gang / Dead-end / Deep style	3/4
<b>SWB-45</b>	\$132.00	Single gang / Feed-through / Deep style	3/4

# KILLARK Hazardous Location Controls - Dimensions


## SWB Series Splice/Device Boxes

Dimensions in inches [mm]


### SWB-2

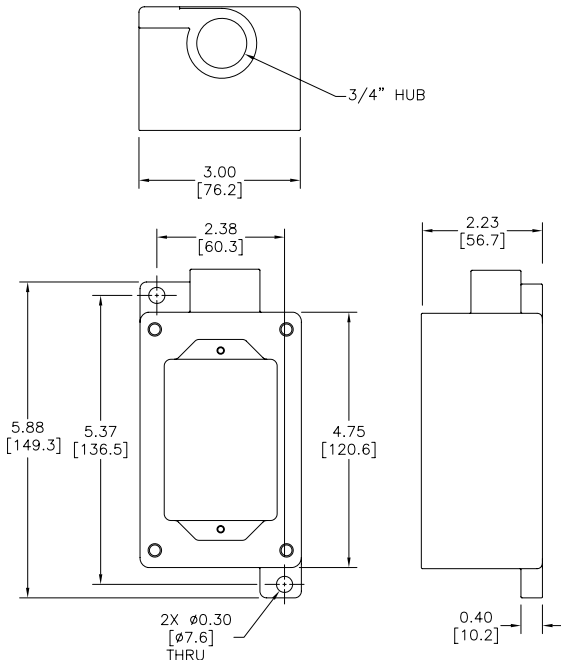


### SWB-5

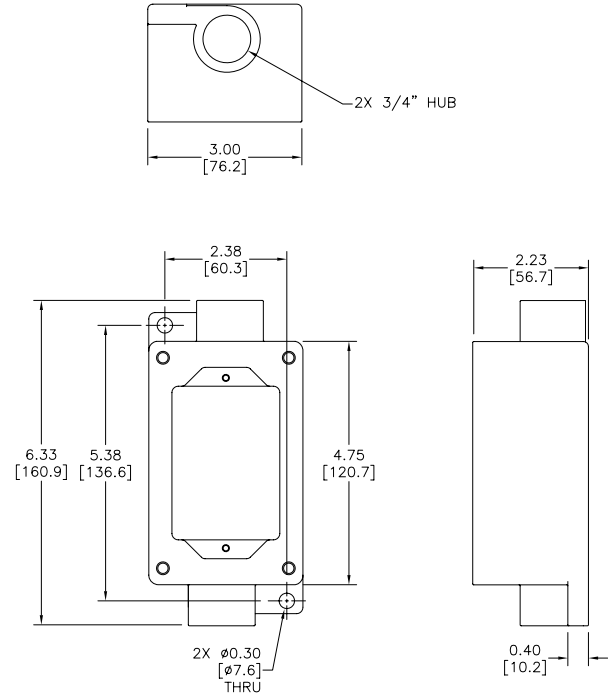

### SWB-42

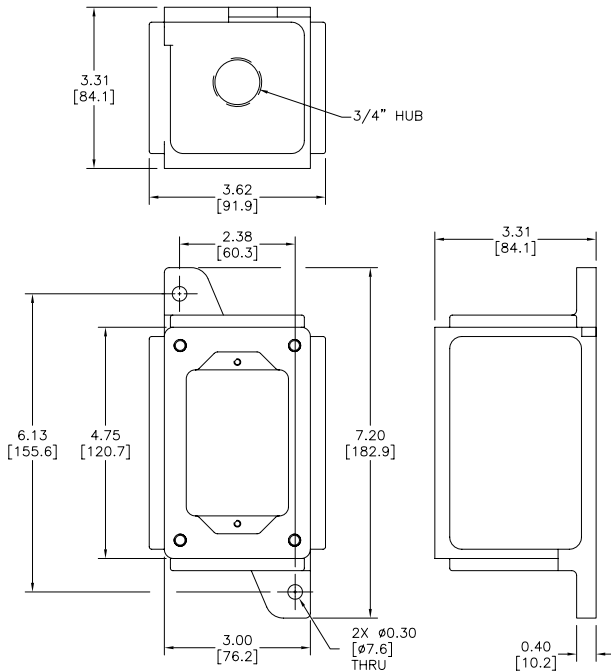

### SWB-45

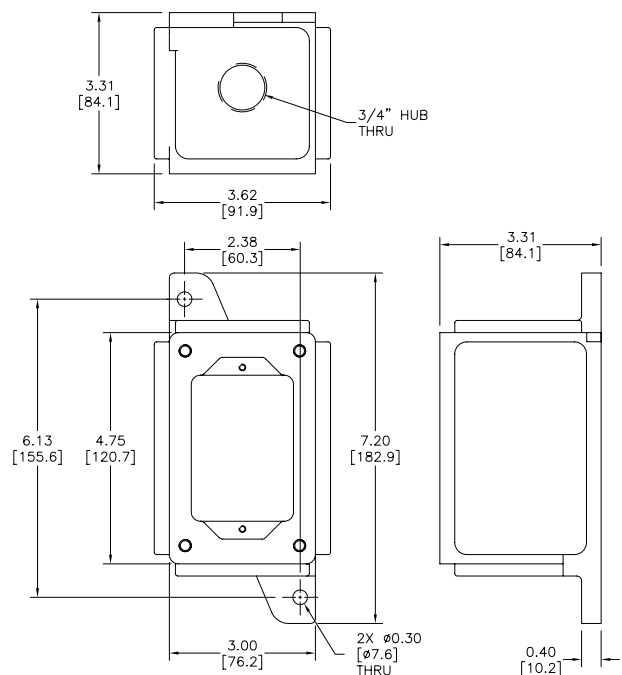


# KILLARK Hazardous Location Controls - Dimensions

## SWB Series Splice/Device Boxes

Dimensions in inches [mm]

### SWB-8

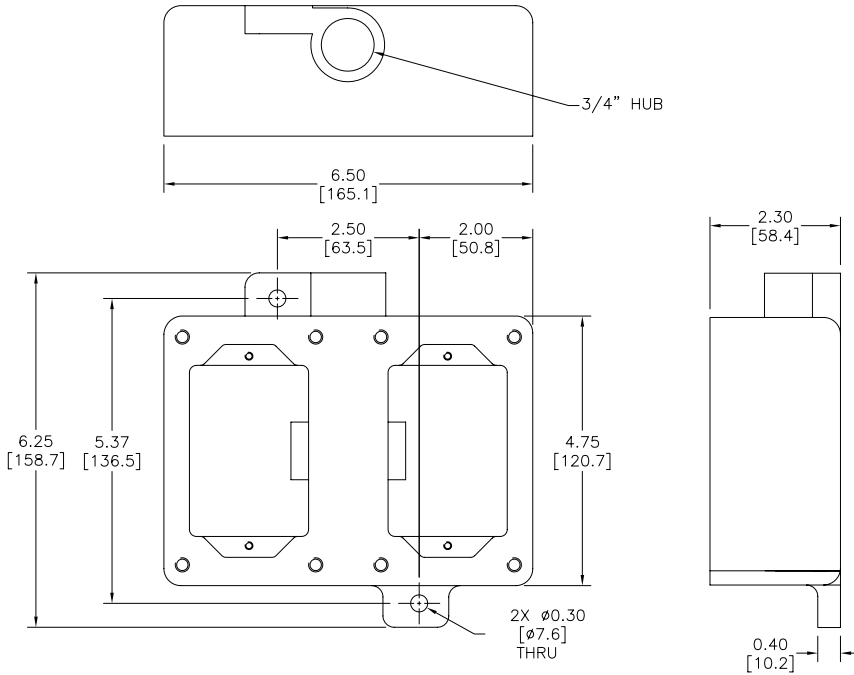

### SWB-11

