

# KNIPEX® Water Pump Pliers

## Pliers Wrench

### Features

- Adjustable screwing tool replaces a full set of inch and metric open end wrenches
- Designed for gripping, holding, pressing, and bending workpieces
- Zero backlash jaw surface pressure prevents damage to edges of sensitive components
- Adjustment at the touch of a button
- Parallel jaws allow for gripping of all widths to the specified maximum size



8603150SBA



8603250SBA



8603300SBA

| Pliers Wrench |   |                   |                 |                      |                  |         |         |
|---------------|---|-------------------|-----------------|----------------------|------------------|---------|---------|
| Part Number   | Description   | Pliers Length     | Max Jaw Opening | Adjustment Positions | Weight           | Pcs/Pkg | Price   |
| 8603150SBA    | Nickel-plated mini adjustable Pliers Wrench with plastic-coated handles for precision mechanics | 5.91 in [150 mm]  | 1.06 in [27 mm] | 14                   | 6.17 oz [175 g]  | 1       | \$48.00 |
| 8603250SBA    | Nickel-plated adjustable Pliers Wrench with plastic-coated handles                              | 9.84 in [250 mm]  | 1.81 in [46 mm] | 17                   | 18.91 oz [536 g] | 1       | \$54.00 |
| 8603300SBA    | Nickel-plated adjustable Pliers Wrench with plastic-coated handles                              | 11.81 in [300 mm] | 2.36 in [60 mm] | 22                   | 25.71 oz [729 g] | 1       | \$68.00 |

Inch dimensions are rounded to the nearest hundredth.

## Cobra® Pump Pliers

### Features

- Self-locking on pipes and nuts, no slipping
- Pushbutton adjustment
- Low hand force required
- Hardness of 61 HRC
- Guard prevents finger pinching
- Chrome vanadium electric steel, oil-hardened and tempered



8701125SBA



8701180SBA



8701250SBA



8701300SBA

| Cobra® Pump Pliers |  |                   |                  |                 |                      |                  |         |         |
|--------------------|--|-------------------|------------------|-----------------|----------------------|------------------|---------|---------|
| Part Number        | Description  | Pliers Length     | Max Jaw Capacity |                 | Adjustment Positions | Weight           | Pcs/Pkg | Price   |
|                    |  |                   | Pipe             | Nut             |                      |                  |         |         |
| 8701125SBA         | Mini Cobra® pliers with non-slip plastic-coated handles for use in precision mechanics and hobbies | 4.92 in [125 mm]  | 1.06 in [27 mm]  | 1.06 in [27 mm] | 13                   | 3.00 oz [85 g]   | 1       | \$28.50 |
| 8701180SBA         | Cobra® pliers with non-slip plastic-coated handles   | 7.09 in [180 mm]  | 1.65 in [42 mm]  | 1.42 in [36 mm] | 18                   | 6.00 oz [170 g]  | 1       | \$30.50 |
| 8701250SBA         | Cobra® pliers with non-slip plastic-coated handles   | 9.84 in [250 mm]  | 1.97 in [50 mm]  | 1.81 in [46 mm] | 25                   | 11.08 oz [314 g] | 1       | \$32.50 |
| 8701300SBA         | Cobra® pliers with non-slip plastic-coated handles   | 11.81 in [300 mm] | 2.76 in [70 mm]  | 2.36 in [60 mm] | 30                   | 18.70 oz [530 g] | 1       | \$45.00 |
| 8702180SBA         | Cobra® pliers with multi-component comfort grip handles  | 7.09 in [180 mm]  | 1.65 in [42 mm]  | 1.42 in [36 mm] | 18                   | 6.91 oz [196 g]  | 1       | \$33.50 |

Inch dimensions are rounded to the nearest hundredth. HRC refers to Rockwell C Scale.



8702180SBA



# KNIPEX® Water Pump Pliers

## Alligator® Pliers

### Features

- Can be used for outdoor work environments
- High stability box joint design
- Self-locking on pipes and nuts, no slipping
- Guard prevent finger pinching
- Thin V-jaw profile
- Chrome vanadium electric steel; oil-hardened and tempered
- Hardness of 61 approximately HRC



8801300SBA



8802250SBA



8808250SBA



8801180SBA



8801250SBA

| Alligator® Pliers |  |                   |                  |                 |                      |                  |         |         |
|-------------------|--|-------------------|------------------|-----------------|----------------------|------------------|---------|---------|
| Part Number       | Description  | Pliers Length     | Max Jaw Capacity |                 | Adjustment Positions | Weight           | Pcs/Pkg | Price   |
|                   |  |                   | Pipe             | Nut             |                      |                  |         |         |
| 8801180SBA        | Alligator® pliers with non-slip plastic-coated handles                                       | 7.09 in [180 mm]  | 1.26 in [32 mm]  | 1.18 in [30 mm] | 7                    | 6.35 oz [180 g]  | 1       | \$22.00 |
| 8801250SBA        | Alligator® pliers with non-slip plastic-coated handles                                       | 9.84 in [250 mm]  | 1.97 in [50 mm]  | 1.81 in [46 mm] | 9                    | 11.25 oz [319 g] | 1       | \$24.50 |
| 8801300SBA        | Alligator® pliers with non-slip plastic-coated handles                                       | 11.81 in [300 mm] | 2.76 in [70 mm]  | 2.36 in [60 mm] | 9                    | 18.02 oz [511 g] | 1       | \$37.00 |
| 8802250SBA        | Alligator® pliers with multi-component comfort grip handles                                  | 9.84 in [250 mm]  | 1.97 in [50 mm]  | 1.81 in [46 mm] | 9                    | 12.59 oz [357 g] | 1       | \$28.50 |
|                   | Alligator® pliers, VDE tested, insulated to 1,000V with multi-component comfort grip handles | 9.84 in [250 mm]  | 1.97 in [50 mm]  | 1.81 in [46 mm] | 9                    | 13.97 oz [396 g] | 1       | \$37.00 |

Inch dimensions are rounded to the nearest hundredth. HRC refers to Rockwell C Scale.



| Wire Classes |                              |                    |                   |
|--------------|------------------------------|--------------------|-------------------|
| Wire Type    | Examples                     | Tensile Strength   |                   |
|              |                              | lb/in <sup>2</sup> | N/mm <sup>2</sup> |
| Soft wire    | Copper, plastics             | 31,908             | 220               |
| Medium-hard  | Nail, wire pin               | 108,778            | 750               |
| Hard         | Wire rope strand, steel wire | 261,067            | 1800              |
| Piano wire   | Spring steel wire            | 333,586            | 2300              |

# KNIPEX® Water Pump Pliers

## Raptor™ Pliers - Multiple Slip Joint Spanner

### Features

- Smooth parrot jaw design for metric and imperial nuts and screws
- Self-locking from 17 mm to 32 mm
- Zero backlash gripping of metric or imperial hexagonal head screws
- Secure and tight grabbing of bolt heads, even those with rounded edges, rusted nuts or heavily coated workpieces
- Chrome vanadium electric steel, oil-hardened and tempered

| Multiple Slip Joint Spanner |   |                  |                         |                      |                  |         |         |
|-----------------------------|---|------------------|-------------------------|----------------------|------------------|---------|---------|
| Part Number                 | Description   | Pliers Length    | Jaw Opening             | Adjustment Positions | Weight           | Pcs/Pkg | Price   |
| 8741250SBA                  | Raptor™ pliers - multiple slip joint spanner with non-slip plastic-coated handles | 9.84 in [250 mm] | 0.39-1.26 in [10-32 mm] | 15                   | 11.57 oz [328 g] | 1       | \$36.00 |

Inch dimensions are rounded to the nearest hundredth.



8741250SBA



## Cobra® Extra Slim Pump Pliers

### Features

- Thin head allows for powerful gripping in confined work spaces
- Long narrow jaws
- Three-point rest provides a firm grip on flat material
- Adjustment at the touch of a button directly on the workpiece
- Self-locking on pipes and nuts, no slipping
- High stability box joint design
- Guard prevents finger pinching
- Chrome vanadium electric steel, forged, oil-hardened



8751250SBA

| Extra Slim Cobra® Pliers |  |                  |                  |                 |                      |                  |         |         |
|--------------------------|--|------------------|------------------|-----------------|----------------------|------------------|---------|---------|
| Part Number              | Description  | Pliers Length    | Max Jaw Capacity |                 | Adjustment Positions | Weight           | Pcs/Pkg | Price   |
|                          |  |                  | Pipe             | Nut             |                      |                  |         |         |
| 8751250SBA               | Cobra® extra slim pump pliers with non-slip plastic-coated handles | 9.84 in [250 mm] | 1.26 in [32 mm]  | 1.34 in [34 mm] | 19                   | 11.57 oz [328 g] | 1       | \$39.00 |

Inch dimensions are rounded to the nearest hundredth.

# KNIPEX® Pliers Sets and Accessories

## KNIPEX® Pliers Sets and Accessories

| Pliers Sets and Accessories |  |                  |         |          |
|-----------------------------|--|------------------|---------|----------|
| Part Number                 | Description  | Weight           | Pcs/Pkg | Price    |
| <b>002005US</b>             | Set of 3 high-leverage diagonal cutters: 6¼" diagonal cutter (p/n 7401160SBA), 10" diagonal cutter (p/n 7401250SBA), and 8" angled diagonal cutter (p/n 7421200SBA)  | 2.15 lb [975 g]  | 3       | \$93.00  |
| <b>002006US1</b>            | Set of 3 Cobra® pliers, non-slip, plastic-coated handles, push-button adjustment, thin jaw profile, self-gripping; 7" (p/n 8701180SBA), 10" (p/n 8701250SBA), and 12" (p/n 8701300SBA) lengths.  | 2.6 lb [1179 g]  | 3       | \$102.00 |
| <b>002006US2</b>            | Set of 3 Pliers Wrenches, push-button adjustment, box joint, self-ratcheting, non-slip plastic-coated handles, chrome vanadium steel; 7" (p/n 8603180SBA), 10" (p/n 8603250SBA), 12" (p/n 8603300SBA) lengths  | 2.34 lb [1061 g] | 3       | \$159.00 |
| <b>002007US1</b>            | Set of 3 Alligator® pliers, chrome vanadium steel, self-gripping, thin jaw profile, non-slip plastic-coated handles; 7" (p/n 8801180SBA), 10" (p/n 8801250SBA), and 12" (p/n 8801300SBA) lengths   | 2.15 lb [975 g]  | 3       | \$77.00  |
| <b>002072V01</b>            | 2-Piece mini pliers set in practical belt pouch. Includes (1) 6" Wrench Pliers (p/n 8603150SBA and (1) 5" (p/n 8701125SBA) mini Cobra® pliers  | 0.77 lb [349 g]  | 2       | \$95.00  |
| <b>001101</b>               | Twin universal control cabinet key. Two 4-way wheel wrenches connected in a space-saving way with magnets. Includes lock profiles: square (5-6, 7-8, 9-10, 11mm), triangular (7, 8-9, 10-11, 12mm), double-bit (3-5mm), half-moon (6mm), stepped square (6-9mm), reversing bit (slot 1x7mm, cross-recess PH2). Die-cast zinc material. | 0.31 lb [140 g]  | 1       | \$42.50  |



002005US



002006US1




002006US2



002007US1



002072V01

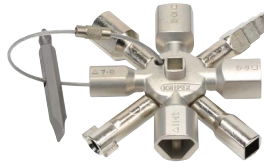

001101