



Screwless Terminal Blocks

At A Glance KN-P Series

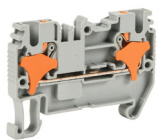
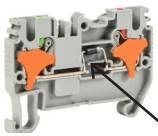
Overview

The KONNECT-IT screwless terminal blocks with push-in technology reduce connection time by not needing any tools when installing solid, ferrule-ended, and some stranded wires.

 
 
Wires can also be connected by simply pressing the orange button to open the terminal. To release the wire simply press the orange button to open the terminal. These terminal blocks come in single-, double-, and triple-level configurations including diode configurations, indication, multiple terminals on each side, and grounding blocks. These terminal blocks come with the highest UL94 V0 flammability rating, allowing a wider range of applications where they can be used. The single-level terminal blocks come in 52-, 65-, 78-, and 91-mm lengths which allows greater flexibility when searching for the right terminal block for your application.

Single-Level Feed-Through, with Diode(s), or with LED Indication

 
 
 
 
52.50 mm length

**KN-P25****KN-P25DA** Diode

 
 
65.40 mm length

**KN-P25E****KN-P25-1-2**

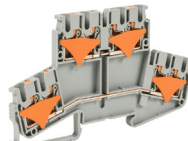
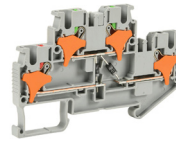
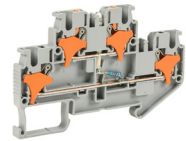
78.40 mm length

**KN-P25-2-2****KN-P25E-1-2****KN-P25E****KN-P25CLD110** LED Indicator

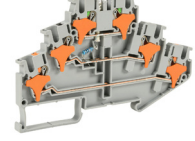
91.50 mm length

**KN-P25C-2-2****KN-P25CDA-2-2** Diode

Double-Level Feed-Through, with Diode(s), or with LED Indication

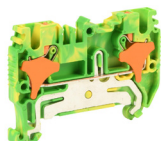
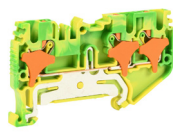
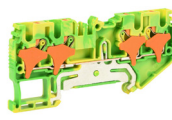
**KN-PD25****KN-PD25-2-2****KN-PD25DA2****KN-PD25LD24**

Triple-Level Feed-Through, with NPN/PNP, or with LED Indication

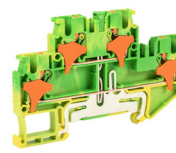
**KN-PT25****KN-PT25-1-1S-1S****KN-PT25-NPN****KN-PT25LD110**

Ground Terminal Blocks

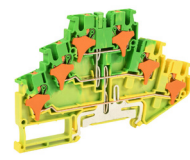
Single-Level

**KN-PG25****KN-PG25E-1-2****KN-PG25-2-2**

Double-Level

**KN-PDG25**

Triple-Level

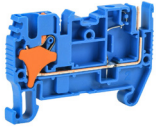
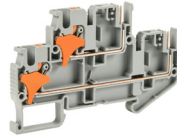
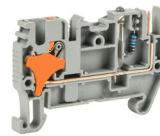
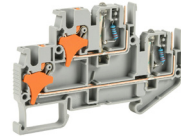
**KN-PTG25**



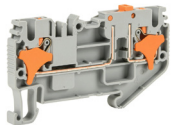
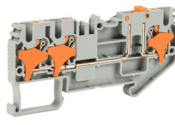
 
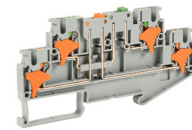
Screwless Terminal Blocks

At A Glance KN-P Series

Plug-in Terminal Blocks

**KN-P25-1-PNBLU****KN-PD25-1-PN****KN-P25LD24-1-PN****KN-PD25-1-PNLD24**

Disconnect Terminal Blocks

**KN-P25EDIS****KN-P25EDIS-1-2****KN-P25CDIS-2-2****KN-PD25DIS**

Accessories

End Brackets

**KN-EB3V0****KN-EM8V0**

Jumpers

**KN-P3J25****KN-P4J25**

Separators

**KN-PS25-10**

End Covers

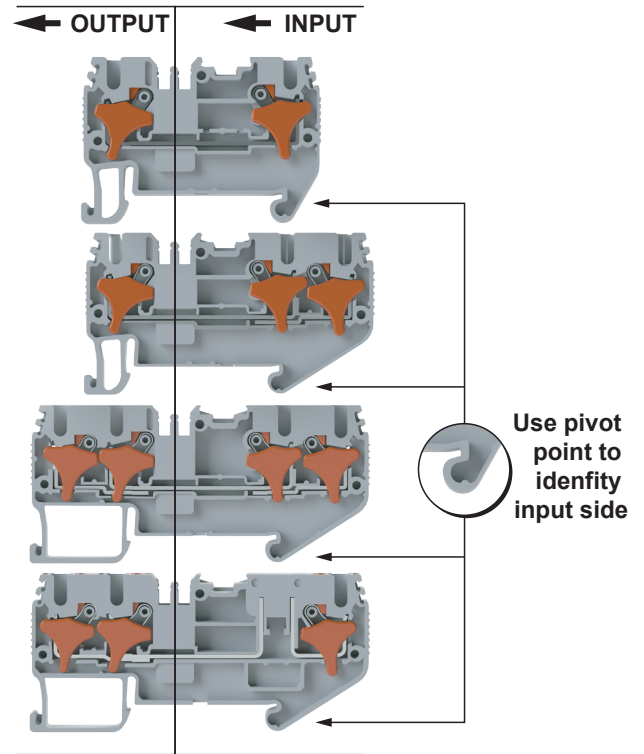
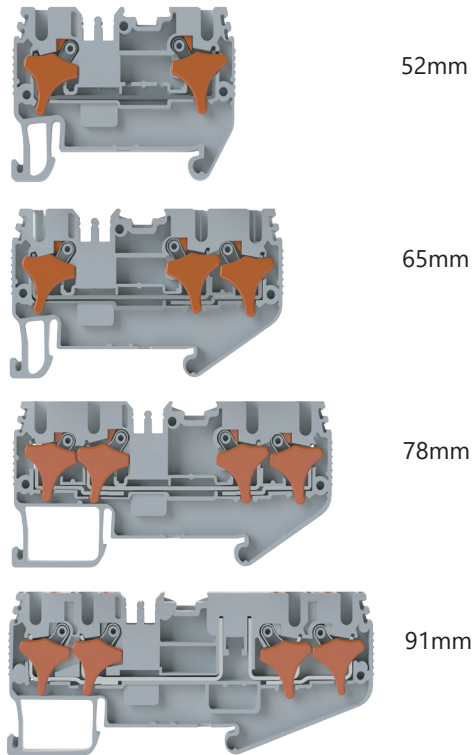
**KN-PEC25-17**



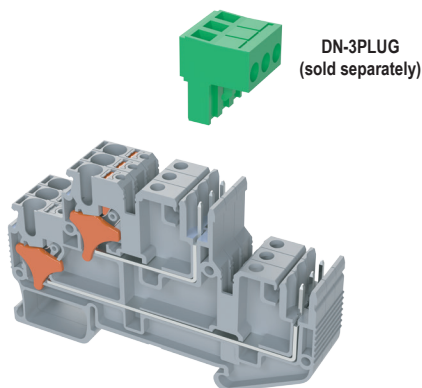
Screwless Terminal Blocks

At A Glance KN-P Series

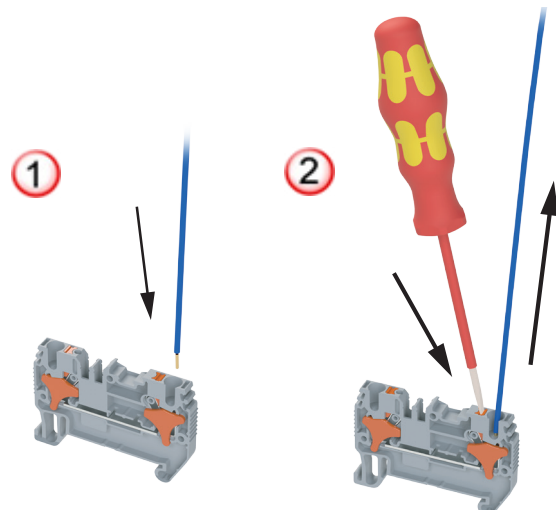
Single-level terminal blocks are available in four lengths, allowing users to select the correct terminal blocks for the application while keeping a clean and uniform look.



Plug-in terminal blocks allow for quick installation of field devices and reduce the chance for incorrect wiring.

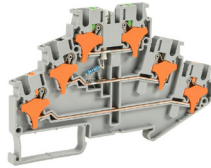


1. Push-in solid or ferrule-terminated wire (for stranded wire press orange button).
2. Press orange button to release wire.





Screwless Triple-Level Feed-Through With Indication Terminal Blocks KN-P Series

**KN-PT25LD110**

Screwless Triple-Level Feed-Through With Indication Terminal Blocks KN-P Series									
Part Number	Qty	Price	Feature	Internal Connection	Number of Outputs	Number of Inputs	Voltage	Color	Drawing Link
KN-PT25LD110	50	\$359.00	Triple-level, power indicator between levels 2 and 3		3	3	110 VAC/VDC	Gray	PDF
KN-PT25LD110-25	25	\$201.00			3	3	220 VAC/VDC		PDF
KN-PT25LD220	50	\$359.00			3	3	24 VAC/VDC		PDF
KN-PT25LD220-25	25	\$201.00			3	3	48 VAC/VDC		PDF
KN-PT25LD24	50	\$359.00			3	3	110 VAC/VDC		PDF
KN-PT25LD24-25	25	\$201.00			3	3	220 VAC/VDC		PDF
KN-PT25LD48	50	\$359.00			3	3	24 VAC/VDC		PDF
KN-PT25LD48-25	25	\$201.00			3	3	48 VAC/VDC		PDF

Specifications						
Part Number	Width mm [in]	Length mm[in]	Nominal Current IN (UL)	Nominal Voltage UN (UL)	Nominal Current IN (CE)	Nominal Voltage UN (CE)
KN-PT25LD110	5.2 [0.20]	101.0 [3.98]	20A	110 VAC/VDC	24A	110 VAC
KN-PT25LD220				220 VAC/VDC		220 VAC
KN-PT25LD24				24 VAC/VDC		24 VAC/VDC
KN-PT25LD48				48 VAC/VDC		48 VDC



Screwless Triple-Level Feed-Through With Indication Terminal Blocks KN-P Series

General Specifications	
Connection	Screwless
Stripping Length	8 - 10mm [0.31 - 0.39 in]
UL Approval (mm ² /AWG/kcmil)	28-12 AWG
CE Conformity (mm ² /AWG/kcmil)	2.5 mm ²
Density (approximate)	192 per meter
SCCR Rating	10kA
Operating Temperature	-60 to 130°C [-76 to 266°F]
Relative Humidity	50% max at 104°F [40°C] and 90% max at 68°F [20°C]
Inflammability Class (according to UL 94)	V0
Conductor (material/per terminal/type)	For Copper (CU) only. Single conductor in terminal, can use stranded/solid/ferrule wire types.
Material	Polyamide (PA)
Mounting	35mm DIN rail
Agecny Approval	CE, cURus File Number E179129

Accessories				
Part Number	End Covers	Separators	Jumpers	Marking Tags
KN-PT25LD110	KN-PEC25-20	—	KN-P2J25 KN-P3J25 KN-P4J25 KN-P5J25 KN-P10J25 KN-P20J25	KN-L5 Series
KN-PT25LD220	KN-PEC25-20	—		
KN-PT25LD24	KN-PEC25-20	—		
KN-PT25LD48	KN-PEC25-20	—		



Screwless Accessories KN-P Series

End Covers

End covers are used to cover the open side of sectional DIN rail mount terminal blocks. They should be used at the end of an assembly of identical terminal blocks or whenever there is a change in the physical size of the terminal block.

Material: Polyamide 66



KN-PEC25-17

End Covers KN-P Series									
Part Number	Qty	Price	Drawing Link	Part Number	Qty	Price	Drawing Link	Color	Works With
KN-PEC25-10	50	\$35.00	PDF	KN-PEC25-10-25	25	\$20.00	PDF	Gray	KN-PD25DIS series blocks
KN-PEC25-11	50	\$25.50	PDF	KN-PEC25-11-25	25	\$14.50	PDF	Gray	KN-PD25-2-2 series blocks
KN-PEC25-12	50	\$45.00	PDF	KN-PEC25-12-25	25	\$25.50	PDF	Gray	KN-PD25-1-PN series blocks
KN-PEC25-13	50	\$28.50	PDF	KN-PEC25-13-25	25	\$15.50	PDF	Gray	KN-PMD25 series blocks
KN-PEC25-14	50	\$18.50	PDF	KN-PEC25-14-25	25	\$10.00	PDF	Gray	KN-P25-1-PN series blocks
KN-PEC25-15	50	\$11.00	PDF	KN-PEC25-15-25	25	\$6.50	PDF	Gray	KN-P25 series blocks
KN-PEC25-16	50	\$11.00	PDF	KN-PEC25-16-25	25	\$6.50	PDF	Yellow/Green	KN-PG25 series blocks
KN-PEC25-17	25	\$14.50	PDF	—	—	—	—	Gray	KN-PD25 series blocks
KN-PEC25-18	25	\$14.50	PDF	—	—	—	—	Yellow/Green	KN-PDG25 series blocks
KN-PEC25-19	50	\$29.50	PDF	KN-PEC25-19-25	25	\$16.50	PDF	Yellow/Green	KN-PTG25 series blocks
KN-PEC25-20	50	\$29.50	PDF	KN-PEC25-20-25	25	\$16.50	PDF	Gray	KN-PT25 series blocks
KN-PEC25-21	50	\$18.50	PDF	KN-PEC25-21-25	25	\$10.00	PDF	Yellow/Green	KN-PG25E-1-2 series blocks
KN-PEC25-22	50	\$18.50	PDF	KN-PEC25-22-25	25	\$10.00	PDF	Gray	KN-P25-1-2 series blocks
KN-PEC25-23	50	\$24.00	PDF	KN-PEC25-23-25	25	\$14.50	PDF	Gray	KN-P25CDIS-2-2 series blocks
KN-PEC25-24	50	\$32.00	PDF	KN-PEC25-24-25	25	\$17.50	PDF	Gray	KN-PT25-1-1S-1S series blocks
KN-PEC25-25	50	\$22.00	PDF	KN-PEC25-25-25	25	\$12.00	PDF	Yellow/Green	KN-PG25-2-2 series blocks
KN-PEC25-26	50	\$22.00	PDF	KN-PEC25-26-25	25	\$12.00	PDF	Gray	KN-P25-2-2 series blocks

Separators

Separators are used to segment banks of terminal blocks. Allows you to maintain a single row of terminal blocks, but have separate power source clusters.



KN-PS25-10

Separators KN-P Series									
Part Number	Qty	Price	Drawing Link	Part Number	Qty	Price	Drawing Link	Color	Works With
KN-PS25-10	50	\$26.50	PDF	KN-PS25-10-25	25	\$15.50	PDF	Gray	KN-P25 series blocks
KN-PS25-11	25	\$26.50	PDF	—	—	—	—	Gray	KN-PD25 series blocks
KN-PS25-12	50	\$36.00	PDF	KN-PS25-12-25	25	\$21.00	PDF	Gray	KN-P25-1-2 series blocks
KN-PS25-13	50	\$44.00	PDF	KN-PS25-13-25	25	\$25.50	PDF	Gray	KN-P25CDIS-2-2 series blocks
KN-PS25-14	50	\$51.00	PDF	KN-PS25-14-25	25	\$28.50	PDF	Gray	KN-PT25-1-1S-1S series blocks
KN-PS25-15	50	\$44.00	PDF	KN-PS25-15-25	25	\$25.50	PDF	Gray	KN-P25-2-2 series blocks



Screwless Accessories KN-P Series

Multi-Pole Jumper Bars

Multi-pole jumper bars provide terminal block connection flexibility, and can be installed quickly without the use of tools. The multi-pole jumpers feature all metal construction with a finger safe insulating cover that has UL94: V0 flammability rating.

**KN-P3J25****KN-P4J25**

Multi-Pole Jumper Bars KN-P Series

Part Number	Qty	Price	Number of Poles	Rating	Type	Works With	Color	Drawing Links
KN-P2J25	25	\$9.00	10	24A	Push-in	KN-P25, KN-PD25 or KN-PT25 series blocks	Yellow	PDF
KN-P3J25	20	\$9.00	20					PDF
KN-P4J25	10	\$6.50	2					PDF
KN-P5J25	10	\$6.50	3					PDF
KN-P10J25	5	\$5.50	4					PDF
KN-P20J25	10	\$22.00	5					PDF

End Brackets

End brackets prevent terminal blocks and other DIN rail mount components and devices from moving laterally on the rail. They are constructed from polyamide and available in configurations for 35mm DIN rails. Rated for inflammability class according to UL 94: V0.

**KN-EB3V0****KN-EM8V0**

End Brackets KN-P Series

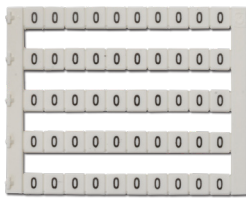
Part Number	Qty	Price	Type	Bracket Width	Mounting	Tightening Torque	Color	Works With	Drawing Link		
KN-EB3V0	100	\$63.00	Screw-down end bracket	8mm	35mm DIN rail	0.6-0.8 Nm	Gray	Konnect-It KN-P25 series	PDF		
KN-EB3V0-10	10	\$6.50		8mm					PDF		
KN-EB7V0	50	\$61.00		10mm					PDF		
KN-EB7V0-10	10	\$13.00		10mm					PDF		
KN-EB4V0	100	\$66.00	Snap-on end bracket	8mm		—					PDF
KN-EB4V0-10	10	\$7.50		8mm							PDF
KN-EM8V0	125	\$26.50		5mm							PDF
KN-EM8V0-25	25	\$5.50		5mm							PDF



KONNECT-IT® Accessories

Marking Tags 5 x 5mm

Use with any KONNECT-IT series terminal blocks.



5 x 5mm Marking Tags Ordering Information

250 Pieces per Package						500 Pieces per Package					
Part Number	Imprint	Price	Part Number	Imprint	Price	Part Number	Imprint	Price	Part Number	Imprint	Price
KN-L5-BLANK-250	Blank	\$13.00	KN-L5-A-250	A	\$13.00	KN-L5-BLANK	Blank	\$20.00	KN-L5-A	A	\$24.00
KN-L5-0-250	0	\$13.00	KN-L5-B-250	B	\$13.00	KN-L5-0	0	\$24.00	KN-L5-B	B	\$24.00
KN-L5-1-250	1	\$13.00	KN-L5-C-250	C	\$13.00	KN-L5-1	1	\$24.00	KN-L5-C	C	\$24.00
KN-L5-2-250	2	\$13.00	KN-L5-D-250	D	\$13.00	KN-L5-2	2	\$24.00	KN-L5-D	D	\$24.00
KN-L5-3-250	3	\$13.00	KN-L5-E-250	E	\$13.00	KN-L5-3	3	\$24.00	KN-L5-E	E	\$24.00
KN-L5-4-250	4	\$13.00	KN-L5-F-250	F	\$13.00	KN-L5-4	4	\$24.00	KN-L5-F	F	\$24.00
KN-L5-5-250	5	\$13.00	KN-L5-G-250	G	\$13.00	KN-L5-5	5	\$24.00	KN-L5-G	G	\$24.00
KN-L5-6-250	6	\$13.00	KN-L5-H-250	H	\$13.00	KN-L5-6	6	\$24.00	KN-L5-H	H	\$24.00
KN-L5-7-250	7	\$13.00	KN-L5-I-250	I	\$13.00	KN-L5-7	7	\$24.00	KN-L5-I	I	\$24.00
KN-L5-8-250	8	\$13.00	KN-L5-J-250	J	\$13.00	KN-L5-8	8	\$24.00	KN-L5-J	J	\$25.00
KN-L5-9-250	9	\$13.00	KN-L5-K-250	K	\$13.00	KN-L5-9	9	\$24.00	KN-L5-K	K	\$25.00
KN-L5-10-250	10	\$13.00	KN-L5-L-250	L	\$12.50	KN-L5-10	10	\$24.00	KN-L5-L	L	\$24.00
KN-L5-1-10-250	1-10	\$13.00	KN-L5-M-250	M	\$13.00	KN-L5-1-10	1-10	\$24.00	KN-L5-M	M	\$25.00
KN-L5-11-20-250	11-20	\$13.00	KN-L5-N-250	N	\$12.50	KN-L5-11-20	11-20	\$24.00	KN-L5-N	N	\$24.00
KN-L5-21-30-250	21-30	\$13.00	KN-L5-O-250	O	\$12.50	KN-L5-21-30	21-30	\$24.00	KN-L5-O	O	\$24.00
KN-L5-31-40-250	31-40	\$13.00	KN-L5-P-250	P	\$13.00	KN-L5-31-40	31-40	\$24.00	KN-L5-P	P	\$25.00
KN-L5-41-50-250	41-50	\$13.00	KN-L5-Q-250	Q	\$13.00	KN-L5-41-50	41-50	\$24.00	KN-L5-Q	Q	\$25.00
KN-L5-1-50-250	1-50	\$13.00	KN-L5-R-250	R	\$12.50	KN-L5-1-50	1-50	\$24.00	KN-L5-R	R	\$24.00
KN-L5-51-100-250	51-100	\$13.00	KN-L5-S-250	S	\$12.50	KN-L5-51-100	51-100	\$24.00	KN-L5-S	S	\$24.00
KN-L5-101-150-250	101-150	\$13.00	KN-L5-T-250	T	\$12.50	KN-L5-101-150	101-150	\$24.00	KN-L5-T	T	\$24.00
KN-L5-151-200-250	151-200	\$13.00	KN-L5-U-250	U	\$13.00	KN-L5-151-200	151-200	\$24.00	KN-L5-U	U	\$25.00
KN-L5-201-250-250	201-250	\$13.00	KN-L5-V-250	V	\$12.50	KN-L5-201-250	201-250	\$24.00	KN-L5-V	V	\$24.00
KN-L5-251-300-250	251-300	\$13.00	KN-L5-W-250	W	\$13.00	KN-L5-251-300	251-300	\$24.00	KN-L5-W	W	\$25.00
KN-L5-301-350-250	301-350	\$13.00	KN-L5-X-250	X	\$12.50	KN-L5-301-350	301-350	\$24.00	KN-L5-X	X	\$24.00
KN-L5-351-400-250	351-400	\$13.00	KN-L5-Y-250	Y	\$12.50	KN-L5-351-400	351-400	\$24.00	KN-L5-Y	Y	\$24.00
KN-L5-401-450-250	401-450	\$13.00	KN-L5-Z-250	Z	\$13.00	KN-L5-401-450	401-450	\$24.00	KN-L5-Z	Z	\$25.00
KN-L5-451-500-250	451-500	\$13.00	KN-L5-POS-250	+	\$12.50	KN-L5-451-500	451-500	\$24.00	KN-L5-POS	+	\$24.00
KN-L5-L1-250	L1	\$12.50	KN-L5-NEG-250	-	\$12.50	KN-L5-L1	L1	\$24.00	KN-L5-NEG	-	\$24.00
KN-L5-L2-250	L2	\$12.50	KN-L5-GND-250	GND	\$13.00	KN-L5-L2	L2	\$24.00	KN-L5-GND	GND	\$24.00
KN-L5-L3-250	L3	\$12.50				KN-L5-L3	L3	\$24.00			