

Shielded RJ45 to RJ45 Bulkhead Connectors

Features

- Cat5e or Cat6a models available
- Mounting hardware included
- 5-year warranty



492075

492076


Shielded RJ45 to RJ45 Bulkhead Connectors						
Part Number	Price	Number of Wires	Connector Type		Connection	Drawing Link
			Exterior	Interior		
492075	\$38.00	8	RJ45 female 8-wire/8-pin	RJ45 female 8-wire/8-pin	Cat5e	PDF
492076	\$41.00		RJ45 female 8-wire/8-pin	RJ45 female 8-wire/8-pin	Cat6a	PDF

Shielded RJ45 to RJ45 Bulkhead Connectors Specifications		
Model	492075	492076
Type	RJ45:8-Wire, 8-Pin	
Rated Voltage	24V AC/DC	
Maximum Operating Voltage	50V	
Rated Current	1.5 A	
Transmission Type	Cat5e	Cat6a
Transfer Rate	1 Gbit/s	10 Gbit/s
Bandwidth	500 MHz	
Operating Temperature Range	-25 to 70°C [-13 to 158°F]	
Protection Degree	IP65 UL508E Type 2, 3R, 4, 4X, 12, 13 (cover closed), IP20 (cable inserted)	
Housing Mounting	Front installation	
Housing Mounting Hole Size	22.5 mm	
Housing Mounting Panel Thickness	1.0 to 5.0 mm [0.04in to 0.20 in]	
Housing Mounting Tightening Torque	1.2 to 2 N•m [10.6 to 17.7 in-lb]	
Housing Material	Polyamide/thermoplastic (PA) / Polybutylene terephthalate (PBT)	
Cover Material	Thermoplastic polyurethane (TPU)	
Contact Material	Copper Tin Alloy (CuSn) gold plated	
Approvals*	cULus File E326112	


*To obtain the most current agency approval information, see the Agency Compliance & Certifications Checklist section on the specific part number's web page.

Wiring Diagrams

492075

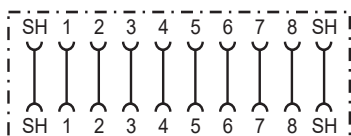


492076

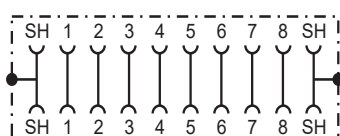

Pin Assignment

RJ45 Female

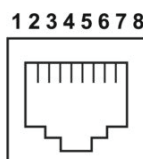

Mounting Diagram

