


P2-550 CPU Module

Port Specifications

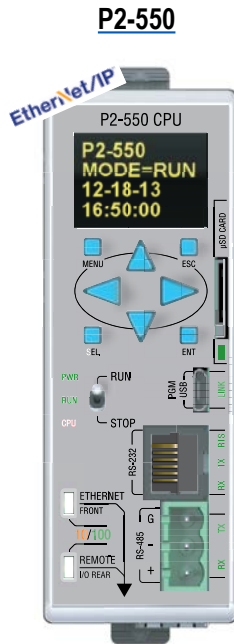

MICRO USB Programming Port

Used exclusively for connecting to a PC running the Productivity Suite programming software.

Micro USB Input Specifications	
Port Name	MICRO USB
Description	Standard Micro USB Slave input for programming and on-line monitoring, with built-in surge protection. Not compatible with older full speed USB devices.
Transfer Rate	480 Mbps
Port Status LED	Green LED is illuminated when LINK is established to programming software.
Cables	USB Type A to Micro USB Type B: 6ft cable part # USB-CBL-AMICB6 15ft cable part # USB-CBL-AMICB15

