

Enclosure Accessories - Fasteners and Miscellaneous



Print pockets



WAPPL0810

Print Pockets	Price	Description	Wt. [lb]
WAPPL0606	\$12.00	6"x6" plastic print pocket can be placed anywhere within enclosure using 2-way adhesive tape flanges. Color: white	0.5
WAPPL0810	\$19.00	8"x10" plastic print pocket can be placed anywhere within enclosure using 2-way adhesive tape flanges. Color: white	

Clamp Nuts



Clamp nuts for enclosure unistrut are available for special purposes and spares, but are not required for standard enclosure accessories.

Clamp Nuts	Price	Description	Wt. [lb]
WAPS1420CN	\$17.00	1/4-20 clamp nut with 1/4-20 x 1/2in-long pan head screw. Package of 2.	1
WAPS3816CN	\$16.00	3/8-16 clamp nut with 3/8-16 x 1in-long hex bolt. Package of 1.	

Touch-up paint



WAGSE

Touch-Up Paint	Price	Description	Wt. [lb]
WAGSE	\$16.00	ANSI-61 gray satin enamel in 12 oz. spray can. Use on existing enclosure and sub-panel finishes.	1.5

Stainless Steel Screws



HW-2PKSS

Stainless Steel Screws	Price	Description	Wt. [oz]
HW-2PKSS	\$1.75	Stainless steel screws #10-24 x 5/8in long, with o-rings- pkg of 2	1
HW-4PKSS	\$1.75	Stainless steel screws #10-24 x 5/8in long, with o-rings - pkg of 4	

Encapsulated Screws



HW-2PKENCAP

Encapsulated Screws	Price	Description	Wt. [oz]
HW-2PKENCAP	\$1.75	PVC-encapsulated screws - pkg of 2	1
HW-4PKENCAP	\$3.50	PVC-encapsulated screws - pkg of 4	

Spring Nut



Spring Nut Package	Price	Description	Wt. [lb]
HFWSHC	No Match!	Grid fasteners for mounting equipment to grid straps. Package of 20 spring nuts with 1/4-20 pan head	0.1
W1032N	\$28.00	Plated #10-32 spring nuts will fit all rack mounting angles with 7/32 diameter holes. Package of 20.	

Enclosure Shipping Schedule

Same day	1 -10 days
----------	------------

Color indicates shipping lead time in business days.

Enclosure Accessories - Miscellaneous



Vapor Capsule

Carrying Handle



Carrying Handle	Price	Description	Wt.
HW-CARRYINGHANDLE	\$16.50	Non-metallic black handle, for use on Hubbell-Wiegmann non-metallic enclosures.	2 oz.




Vapor Capsule	Price	Description	Wt.
HW-C12	\$13.50	Non-toxic vapor emitted from the capsule passivates the metal surfaces on the interior of the enclosure against atmospheric corrosion for up to one year by reducing the electro-chemical activity of the metal surfaces. Installs easily with a self-adhesive strip.	1 oz.

Enclosure Shipping Schedule	
Same day	1 - 14 days
Color indicates shipping lead time in business days.	




Locking Protective Cover

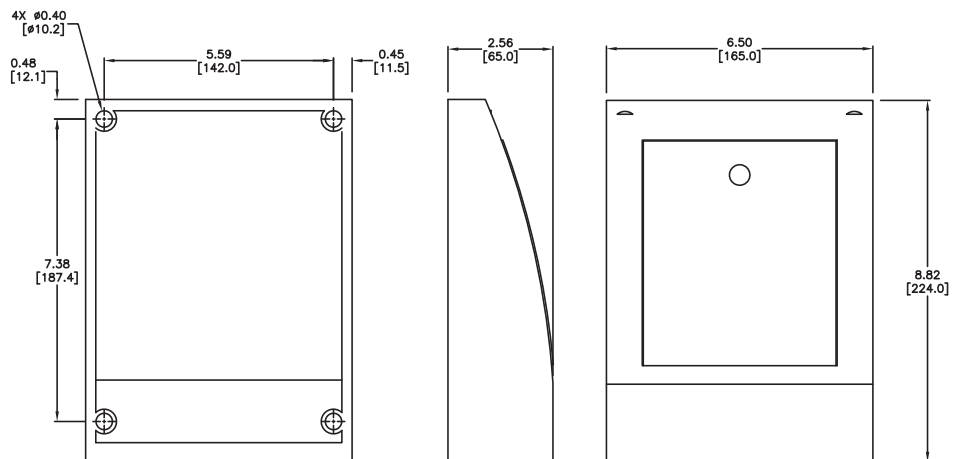

Features

- Packaged multi-purpose protective cover
- Locking door
- Weather and UV resistant (UL 94-HB)
- IP 20 Protection Class
- Includes mounting screws

Locking Protective Cover	Description	Price
086110-00	Stego multi-purpose protective cover with locking door, weather and UV resistant (UL 94-HB), IP20 protection class. Includes mounting screws and keys.	\$37.00

 

- Company Information
- Systems Overview
- Programmable Controllers
- Field I/O
- Software
- C-more & other HMI
- Drives
- Soft Starters
- Motors & Gearbox
- Steppers/ Servos
- Motor Controls
- Proximity Sensors
- Photo Sensors
- Limit Switches
- Encoders
- Current Sensors
- Pressure Sensors
- Temperature Sensors
- Pushbuttons/ Lights
- Process
- Relays/ Timers
- Comm.
- Terminal Blocks & Wiring
- Power
- Circuit Protection
- Enclosures
- Tools
- Pneumatics
- Safety
- Appendix
- Product Index
- Part # Index