

# BRYANT®

Quick Selection Guide

# Manual Motor Controllers / Disconnects




Toggle Switch AC Motor Controllers / Disconnects						
Part Number	Description	Amperage	Phase	Poles	Wired	Price
<b>30002D</b>	Switch only, 30A, 2-pole, 15 HP @ 600 VAC - Standard Toggle	30	1	2	Back and Side	\$24.50
<b>30003D</b>	Switch only, 30A, 3-pole, 20 HP @ 600 VAC - Standard Toggle	30	3	3	Back and Side	\$52.00
<b>4002*</b>	Switch only, 40A, 2-pole, 5 HP @ 600 VAC - Standard Toggle	40	1	2	Side	\$28.00
<b>40002D</b>	Switch only, 40A, 2-pole, 15 HP @ 600 VAC - Standard Toggle	40	1	2	Side	\$42.50
<b>40003D</b>	Switch only, 40A, 3-pole, 20 HP @ 600 VAC - Standard Toggle	40	3	3	Side	\$69.00
<b>60002D</b>	Switch only, 60A, 2-pole, 20 HP @ 600 VAC - Standard Toggle	60	1	2	Back	\$74.00
<b>60003D</b>	Switch only, 60A, 3-pole, 30 HP @ 600 VAC - Standard Toggle	60	3	3	Back	\$90.00

*\*Motor controller only ("Not suitable as disconnect")*

Toggle Switch AC Motor Controller Accessories		
Part Number	Description	Price
<b>30003FG</b>	Finger Guards; red; for use with 30A and 40A Switches (Set of 2)	\$6.25
<b>30100</b>	NEMA 1 Enclosure without switch, use with 30002D and 30003D	\$17.00

**Example**  
Back and Side Wired

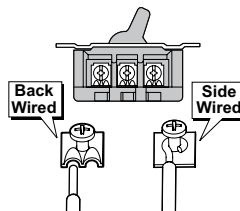

Enclosed Toggle Switch AC Motor Controllers / Disconnects							
Part Number	Description	Included Switch	Amperage	Phase	Poles	Enclosure	Price
<b>30102D</b>	Enclosed, 30A, 2-pole, NEMA 1	30002D Standard Toggle	30	1	2	NEMA 1 Metal	\$31.50
<b>30103D</b>	Enclosed, 30A, 3-pole, NEMA 1	30003D Standard Toggle	30	3	3		\$68.00
<b>30302D</b>	Enclosed, 30A, 2-pole, Aluminum	30002D Standard Toggle	30	1	2	NEMA 3R Metal	\$46.50
<b>30303D</b>	Enclosed, 30A, 3-pole, Aluminum	30003D Standard Toggle	30	3	3		\$84.00
<b>30322D*</b>	Enclosed, 30A, 2-pole, Plastic	30002DS Short Toggle	30	1	2	NEMA 3R Thermo-plastic	\$55.00
<b>30323D*</b>	Enclosed, 30A, 3-pole, Plastic	30003DS Short Toggle	30	3	3		\$58.00
<b>60302D*</b>	Enclosed, 60A, 2-pole, Aluminum	60002FWD Standard Toggle	60	1	2	NEMA 3R Metal	\$108.00
<b>60303D*</b>	Enclosed, 60A, 3-pole, Aluminum	60003FWD Standard Toggle	60	3	3		\$127.00

*\*Switch is not available as a separate item*

NEMA 4X Enclosed Rotary Switch AC Motor Controllers / Disconnects							
Part Number	Description	Included Switch	Amperage	Phase	Poles	Enclosure	Price
<b>664X33D*</b>	Enclosed, 30A, 3-pole, NEMA 4X	66033D Rotary	30	3	3	NEMA 4X Thermoplastic	\$114.00
<b>664X63D*</b>	Enclosed, 60A, 3-pole, NEMA 4X	66033D Rotary	60	3	3		\$143.00

*\*Switch is not available as a separate item*



NEMA 4X Enclosed Rotary Switch AC Motor Controller Accessories		
Part Number	Description	Price
<b>30003FG</b>	Finger Guards; red; for use with 30A and 40A Switches (Set of 2)	\$6.25
<b>660AC*</b>	SPDT Auxiliary contact NO / NC; includes one contact for use with push-on terminals; use with 664X33D and 664X63D	\$16.00
<b>6610MK</b>	Rotary handle replacement kit, use with 664X33D and 664X63D. (Nema 1 rating) Must use gasket replacement kit 664XWP for NEMA 4X rating.	\$12.50
<b>664XWP</b>	NEMA 4X enclosure gasket replacement kit; includes 4 seals, neoprene bushing and 3 o-rings; use with 664X33D and 664X63D	\$8.50
<b>664XFT</b>	NEMA 4X enclosure mounting feet	\$7.50
<b>6603N</b>	NEMA 4X enclosure neutral buss connector	\$38.50

*\*660AC Terminal is a quick connect terminal #250*