



# MVDY - 10mm Miniature Solenoid Valve Manifolds and Accessories

The MVDY manifolds and accessories are designed to work specifically with the MVDY miniature solenoid valves. They are made of aluminum and have a maximum operating pressure of 145 psi.



Part No. [103310081010001](#)




Part No. [103310092041005](#)

10mm Miniature Solenoid Valve Manifolds and Accessories									
Part No.	Mfg. Part No.	Number of Stations	Inlet Port Size	Outlet Port Size	Exhaust Port Size	Manufacturer Technical Specifications	Drawing Link	Price	Weight (lb)
<a href="#">103310081010001</a>	MVDY-100-3B1	1	M5 x 0.8 female ISO	M5 x 0.8 female ISO	M5 x 0.8 female ISO	PDF	<a href="#">PDF</a>	\$8.50	0.02
<a href="#">103310092021002</a>	MVDY-100-3M2	2	(2) M5 x 0.8 female ISO	(2) M5 x 0.8 female ISO	(2) M5 x 0.8 female ISO		<a href="#">PDF</a>	\$20.50	0.09
<a href="#">103310092041005</a>	MVDY-100-3M4	4	(2) M5 x 0.8 female ISO	(4) M5 x 0.8 female ISO	(2) M5 x 0.8 female ISO		<a href="#">PDF</a>	\$31.00	0.13
<a href="#">103310092061002</a>	MVDY-100-3M6	6	(2) M5 x 0.8 female ISO	(6) M5 x 0.8 female ISO	(2) M5 x 0.8 female ISO		<a href="#">PDF</a>	\$41.00	0.18
<a href="#">103310092081002</a>	MVDY-100-3M8	8	(2) M5 x 0.8 female ISO	(8) M5 x 0.8 female ISO	(2) M5 x 0.8 female ISO		<a href="#">PDF</a>	\$51.00	0.21



Part No. [103310091000001](#)

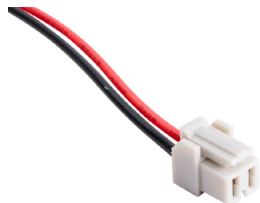

Part No. [203300000000011](#)

10mm Miniature Solenoid Valve Accessories						
Part No.	Mfg. Part No.	Description	Manufacturer Technical Specifications	Drawing Link	Price	Weight (lb)
<a href="#">103310091000001</a>	MVDY-100-3P	Mindman blanking plate, plated steel. For use with MVDY-100 series manifolds. Mounting screws included.	PDF	<a href="#">PDF</a>	\$4.00	0.01
<a href="#">203300000000011</a>	MVDY-100-WDR3	Mindman solenoid valve cable, JAM RMH male to pigtail, straight cable entry, 24 VDC, 24 AWG, 9.8ft/3m cable length. For use with MVDY-100 series miniature solenoid valves.		<a href="#">PDF</a>	\$3.50	0.06