

NEMA 12 and 13 Handy Screw Cover Wall Mount



Applications

Designed for use where protection from dirt, dust, oil and water is needed. Particularly suitable for use with liquid-tight flexible conduit.

Construction

- Bodies and doors fabricated from 14 gauge steel
- Drawn lid that features no welded seams or sharp corners
- No holes or conduit knockouts
- Lids are sealed with closed cell oil resistant neoprene gasket
- Cover screws thread into neoprene gasket for maximum seal
- External mounting plates, top and bottom of enclosure
- Screw holes for cover match conventional outlet mounting criteria

Finish

- ANSI-61 gray polyester powder light texture inside and out over phosphatized surfaces

Listings

- UL 508, Types 12 & 13 [UL File E64791]
- CSA Certified, Type 12 [CSA File LL66078]
- NEMA/EEMAC Types 12 & 13
- JIC EL-1-71




Enclosure Shipping Schedule	
Same day	1 - 7 days
Color indicates shipping lead time in business days.	

NEMA 12 and 13 Handy Screw Cover Wall Mount		
Part Number	Price	Size HxWxD
JIC040202	\$22.50	4x2x2 [102x51x51]
JIC0403025	\$27.00	4.25x2.88x2.63 [108x73x67]
JIC040403	\$31.00	4x4x3 [102x102x76]

Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawings.

Dimensions in [mm]

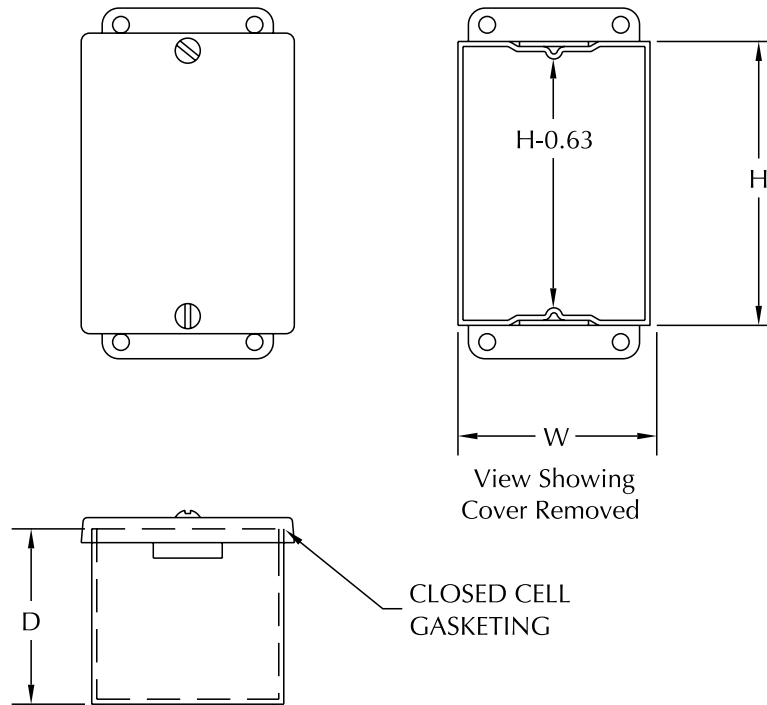

See our website: www.AutomationDirect.com for complete engineering drawings.