

NEMA 12 and 13 Handy Screw Cover Wall Mount



Applications

Designed for use where protection from dirt, dust, oil and water is needed. Particularly suitable for use with liquid-tight flexible conduit.

Construction

- Bodies and doors fabricated from 14 gauge steel
- Drawn lid that features no welded seams or sharp corners
- No holes or conduit knockouts
- Lids are sealed with closed cell oil resistant neoprene gasket
- Cover screws thread into neoprene gasket for maximum seal
- External mounting plates, top and bottom of enclosure
- Screw holes for cover match conventional outlet mounting criteria

Finish

- ANSI-61 gray polyester powder light texture inside and out over phosphatized surfaces

Listings


- UL 508, Types 12 & 13 [UL File E64791]
- CSA Certified, Type 12 [CSA File LL66078]
- NEMA/EEMAC Types 12 & 13
- JIC EL-1-71



NEMA 12 and 13 Handy Screw Cover Wall Mount		
Part Number	Price	Size HxWxD
JIC040202	\$23.00	4.30 x 2.30 x 2.26 [109 x 58 x 57]
JIC0403025	\$27.00	4.55 x 3.17 x 2.89 [116 x 81 x 73]
JIC040403	\$31.50	4.25 x 4.25 x 3.26 [108 x 108 x 83]
Notes: Dimensions in inches [millimeters] Letters in table correspond to letters on dimensional drawings.		

Enclosure Shipping Schedule				
Same day	1 - 7 days	1 -10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

Dimensions in [mm]

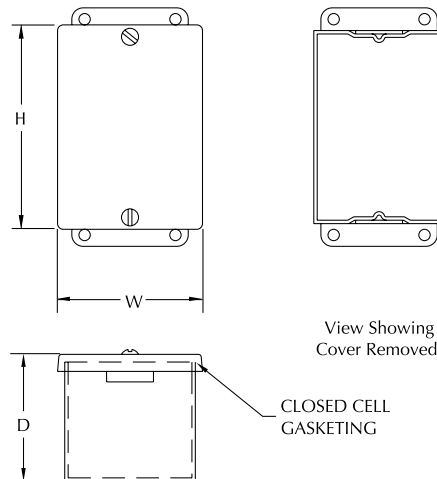

See our website: www.AutomationDirect.com for complete engineering drawings.