

30mm Pushbutton NEMA 12 and 13 Slim Line Wall Mount



Applications

Designed to hold all standard 30mm brands of pushbuttons, switches and pilot lights. Provides protection from dirt, dust, oil and water. This slimline model is designed for conditions where enclosures must fit within very limited areas.



Construction

- Fabricated from 14 gauge steel
- Closed cell oil-resistant neoprene gasket
- Continuously welded seams ground smooth
- External mounting feet, top and bottom of enclosure
- Captivated cover screws thread into sealed wells
- Standard "4-way" pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights
- Grounding provisions provided

Finish


- ANSI 61 gray polyester powder inside and out over phosphatized surfaces

Listings

- UL 508, Types 12 & 13 [UL File E64791]
- CSA Certified Types 12 & 13 [CSA File LL66078]
- NEMA/EEMAC Types 12 & 13



Dimensions

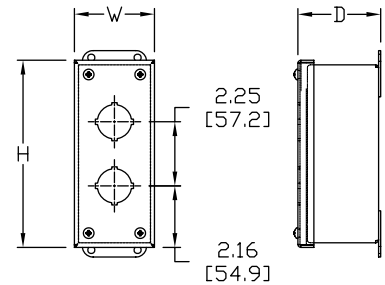


| Enclosure Shipping Schedule | | |
|-----------------------------|------------|------------|
| Same day | 1 - 7 days | 1 -10 days |

Color indicates shipping lead time in business days.


| 30mm Pushbutton NEMA 12 and 13 Slim Line Wall Mount | | | |
|---|---------|---------|-------------------------------------|
| Part Number | Price | # Holes | Size HxWxD |
| PSL1 | \$43.50 | 1 | 4.32 x 2.81 x 2.83 [110 x 71 x 72] |
| PSL2 | \$48.50 | 2 | 6.57 x 2.81 x 2.83 [167 x 71 x 72] |
| PSL3 | \$55.00 | 3 | 8.82 x 2.81 x 2.83 [224 x 71 x 72] |
| PSL4 | \$61.00 | 4 | 11.07 x 2.81 x 2.83 [281 x 71 x 72] |

Notes: Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.

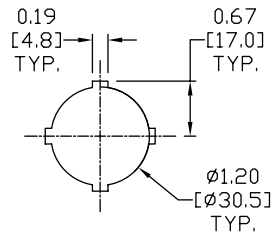

STANDARD 4-WAY PUSHBUTTON

PB HOLE ARRANGEMENTS

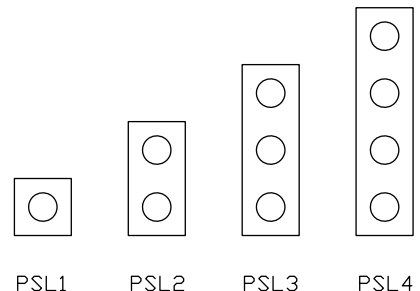

See our website: www.AutomationDirect.com for complete engineering drawings.