

# 30mm Pushbutton Extra Deep Wall Mount



## Applications

Designed to hold 30mm oil-tight pushbuttons, switches and pilot lights. Provides protection from dirt, dust, oil and water. Extra deep design accommodates additional contact blocks for pushbuttons.

## Construction

- Bodies and doors fabricated from 14 gauge steel
- Closed cell oil-resistant neoprene gasket
- Continuously welded seams ground smooth
- External mounting feet, top and bottom of enclosure
- Captivated cover screws thread into sealed wells
- Standard "4-way" pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights
- Enclosures with 2 or more holes have internal detachable hinges to hold cover open during wiring, yet permit quick removal
- Grounding provisions provided

## Finish

- Painted Steel: ANSI 61 gray polyester powder inside and out over phosphatized surfaces
- Stainless steel: #3 intermediate polished finish

## Listings

- UL 508, Types 4, 12 & 13 (stainless steel enclosures also 4X) [UL File E64791]
- CSA Certified, Types 12 & 13 (stainless steel enclosures also 4, 4X) [CSA File LL66078]
- NEMA/EEMAC Types 4, 12 & 13 (stainless steel enclosures also 4X)



### Enclosure Shipping Schedule

Same day	1 - 7 days	1 -10 days
----------	------------	------------

Color indicates shipping lead time in business days.

### 30mm Pushbutton Extra Deep Wall Mount

Painted Steel	Price	Enclosure Size HxWxD	304 Stainless Steel	Price	Enclosure Size HxWxD	# Holes
<b>PBXD1</b>	\$60.00	4.32 x 4.38 x 5.14 [110 x 111 x 131]	<b>PBXD1SS</b>	\$154.00	4.25 x 4.34 x 5.01 [108 x 110 x 127]	1
<b>PBXD2</b>	\$69.00	6.31 x 4.38 x 5.14 [160 x 111 x 131]	<b>PBXD2SS</b>	\$141.00	6.25 x 4.34 x 5.01 [159 x 110 x 127]	2
<b>PBXD3</b>	\$78.00	8.26 x 4.38 x 5.14 [210 x 111 x 131]	<b>PBXD3SS</b>	\$145.00	8.25 x 4.34 x 5.01 [210 x 110 x 127]	3
<b>PBXD4</b>	\$87.00	10.31 x 4.38 x 5.14 [262 x 111 x 131]	<b>PBXD4SS</b>	\$146.00	10.25 x 4.34 x 5.01 [260 x 110 x 127]	4
<b>PBXD4S</b>	\$89.00	7.57 x 6.63 x 5.14 [192 x 168 x 131]	—			4
<b>PBXD6</b>	\$101.00	9.82 x 6.63 x 5.14 [249 x 168 x 131]	—			6
<b>PBXD9</b>	\$116.00	9.82 x 8.88 x 5.14 [249 x 226 x 131]	—			9
<b>PBXD10</b>	\$124.00	14.32 x 6.63 x 5.14 [364 x 168 x 131]	—			10
<b>PBXD12</b>	\$133.00	12.07 x 8.88 x 5.14 [307 x 226 x 131]	—			12
<b>PBXD16</b>	\$149.00	12.07 x 11.13 x 5.14 [307 x 283 x 131]	<b>PBXD16SS</b>	\$189.00	12.00 x 11.09 x 5.01 [305 x 282 x 127]	16
<b>PBXD16V</b>	\$166.00	21.07 x 6.63 x 5.14 [535 x 168 x 131]	—			16
<b>PBXD20</b>	\$166.00	14.32 x 11.13 x 5.14 [364 x 283 x 131]	—			20
<b>PBXD25</b>	\$188.00	14.32 x 13.38 x 5.14 [364 x 340 x 131]	—			25


Notes: Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

# 30mm Pushbutton Extra Deep Wall Mount





Enclosures for Electrical/Electronic Equipment

## Dimensions

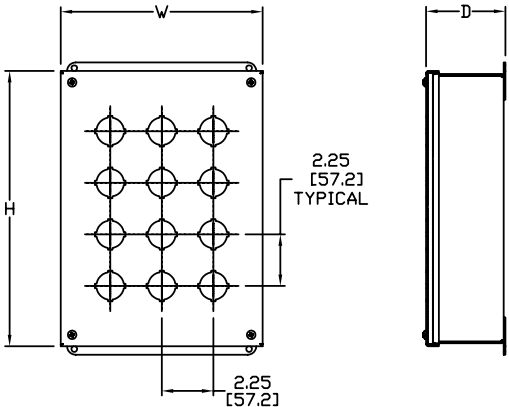

### PBXD HOLE ARRANGEMENTS

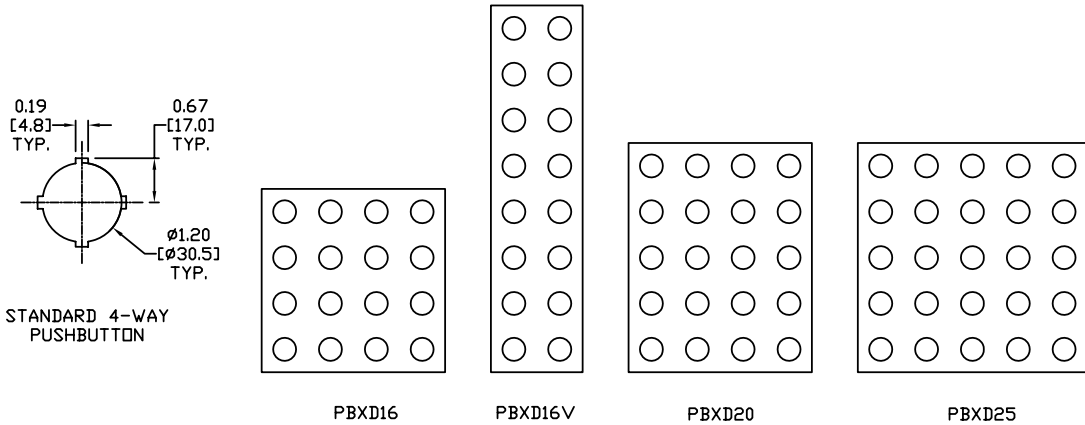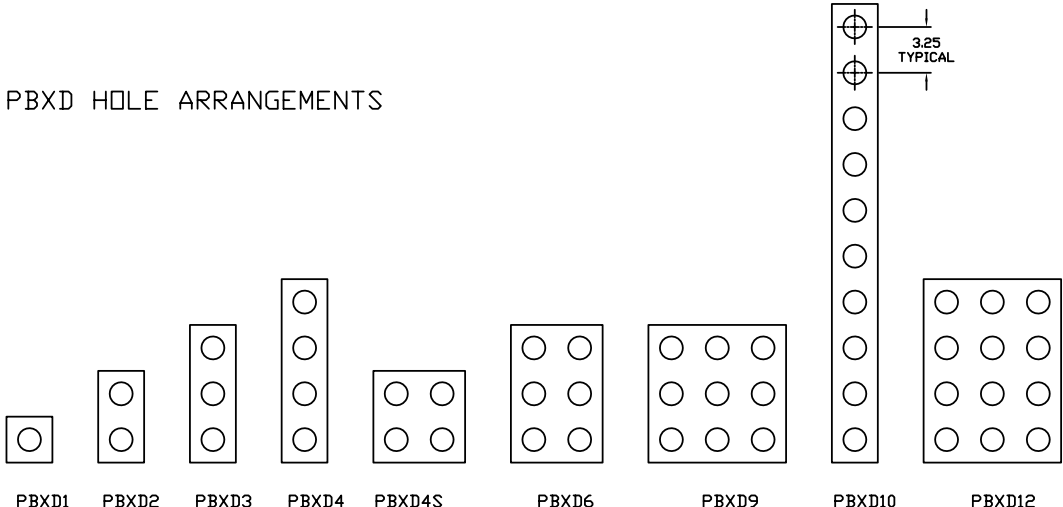

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.