

30mm Pushbutton Extra-Deep Wall-Mount



Applications

Designed to hold 30mm oil-tight pushbuttons, switches and pilot lights. Provides protection from dirt, dust, oil and water. Extra deep design accommodates additional contact blocks for pushbuttons.

Construction

- Bodies and doors fabricated from 14 gauge steel
- Closed cell oil-resistant neoprene gasket
- Continuously welded seams ground smooth
- External mounting feet, top and bottom of enclosure
- Captivated cover screws thread into sealed wells
- Standard "4-way" pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights
- Enclosures with 2 or more holes have internal detachable hinges to hold cover open during wiring, yet permit quick removal
- Grounding provisions provided

Finish

- Painted Steel: ANSI 61 gray polyester powder inside and out over phosphatized surfaces
- Stainless steel: #3 intermediate polished finish

Listings

- UL 508, Types 4, 12 &13 (stainless steel enclosures also 4X) [UL File E64791]
- NEMA/EEMAC Types 4, 12 &13 (stainless steel enclosures also 4X)



Shipping Schedule

Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------

Color indicates shipping lead time in business days.

30mm Pushbutton Extra-Deep Wall-Mount Painted Steel

Painted Steel	Price	Enclosure Size HxWxD	# Holes	Drawing Link
PBXD1	\$83.00	4.32 x 4.38 x 5.14 [110 x 111 x 131]	1	PDF
PBXD2	\$120.00	6.31 x 4.38 x 5.14 [160 x 111 x 131]	2	PDF
PBXD3	\$107.00	8.26 x 4.38 x 5.14 [210 x 111 x 131]	3	PDF
PBXD4S	\$121.00	7.57 x 6.63 x 5.14 [192 x 168 x 131]	4	PDF
PBXD4	\$129.00	10.31 x 4.38 x 5.14 [262 x 111 x 131]	4	PDF
PBXD6	\$139.00	9.82 x 6.63 x 5.14 [249 x 168 x 131]	6	PDF
PBXD9	\$159.00	9.82 x 8.88 x 5.14 [249 x 226 x 131]	9	PDF
PBXD10	\$173.00	14.32 x 6.63 x 5.14 [364 x 168 x 131]	10	PDF
PBXD12	\$182.00	12.07 x 8.88 x 5.14 [307 x 226 x 131]	12	PDF
PBXD16	\$204.00	12.07 x 11.13 x 5.14 [307 x 283 x 131]	16	PDF
PBXD16V	\$225.00	21.07 x 6.63 x 5.14 [535 x 168 x 131]	16	PDF
PBXD20	\$228.00	14.32 x 11.13 x 5.14 [364 x 283 x 131]	20	PDF
PBXD25	\$257.00	14.32 x 13.38 x 5.14 [364 x 340 x 131]	25	PDF

Note: Dimensions in inches [millimeters].

30mm Pushbutton Extra-Deep Wall-Mount Stainless Steel


Stainless Steel	Price	Enclosure Size HxWxD	# Holes	Drawing Link
PBXD1SS	\$159.00	4.25 x 4.34 x 5.01 [108 x 110 x 127]	1	PDF
PBXD2SS	\$191.00	6.25 x 4.34 x 5.01 [159 x 110 x 127]	2	PDF
PBXD4SS	\$249.00	10.25 x 4.34 x 5.01 [260 x 110 x 127]	4	PDF
PBXD3SS	\$321.00	8.25 x 4.34 x 5.01 [210 x 110 x 127]	3	PDF
PBXD16SS	\$570.00	12.00 x 11.09 x 5.01 [305 x 282 x 127]	16	PDF

Note: Dimensions in inches [millimeters].

30mm Pushbutton Extra-Deep Wall-Mount



Dimensions

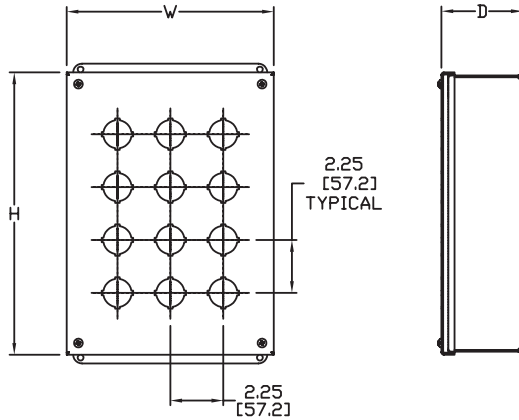

PBXD HOLE ARRANGEMENTS

