

# WC12 NEMA 12 and 13 Operator Consoles



## Applications

Designed to hold electrical and electronic controls and instruments. Pushbuttons, pilot lights, meters, switches, etc. can be mounted on sloping control surfaces. Interior components can be mounted on subpanel and terminal straps. Heavy duty construction provides protection from dirt, dust, oil and water.



## Construction

### Base

- Bodies and doors fabricated from 14 gauge steel
- Seams are continuously welded and ground smooth
- 3-point keylocking handle is provided on front main door
- Double overlapping doors are provided on two door consoles
- Main hinged doors are flush
- Large sloping control panels are hinged along bottom edge
- Control panels have captivated screws threaded into sealed wells
- Door stops provided to hold control panel open
- Closed cell neoprene gasket
- Removable subpanel is included with console
- Grounding provisions provided
- Studs are welded to inside of console for mounting subpanel
- An inclined body rail is welded to each side of 24" wide and 36" wide consoles for support of terminal straps
- [Uses WAL2 series handles and WAL2KEY replacement key](#)

## Top

- Fabricated from 14 gauge steel
- Top has a sloped front surface
- Four holes are provided for mounting to body
- Seams are continuously welded and ground smooth
- Instrument and access panels have captivated screws which thread into sealed wells
- Closed cell neoprene gasket
- Instrument panels and access panels are removable

## Writing desk

- Fabricated from 14 gauge steel
- Seams are continuously welded and ground smooth
- Desks are removable and attach easily to console front

## Finish

- ANSI 61 gray polyester powder inside and out over phosphatized surfaces
- Included painted steel subpanel is white polyester powder over phosphatized surfaces

## Listings

- UL 508, Types 12 & 13 [UL File E64791]
- CSA Certified, Types 12 & 13 [CSA File LL66078]
- NEMA/EEMAC Types 12 & 13



### Enclosure Shipping Schedule

Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
----------	------------	-------------	-------------	-------------

Color indicates shipping lead time in business days.

### WC12 NEMA 12 and 13 Operator Consoles


Console Base	Price	Console Base HxWxD	Subpanel Size	Console Top	Price	Writing Desk	Price	Caster Kit
<b>WC1224B (Single Door)</b>	\$1,292.00	36.13 x 24.13 x 24.06 [918 x 613 x 611]	32.00 x 18.00 [813 x 457]	<b>WC1224T</b>	\$380.00	<b>WC1224W</b>	\$119.00	<b>WC12C</b>
<b>WC12B (Single Door)</b>	\$1,488.00	36.13 x 36.13 x 24.06 [918 x 918 x 611]	32.00 x 30.00 [813 x 762]	<b>WC12T</b>	\$436.00	<b>WC12W</b>	\$152.00	<b>WC12C</b>
<b>WC1248BD (Double Door)</b>	\$1,803.00	36.13 x 48.13 x 24.06 [918 x 1223 x 611]	32.00 x 42.00 [813 x 1067]	<b>WC1248T</b>	\$514.00	<b>WC1248W</b>	\$186.00	<b>WC12C</b>

Notes: Dimensions in inches [millimeters]. Letters in table correspond to letters on dimensional drawings. Subpanels included. Tops, writing desk, etc. must be ordered separately.

# WC12 NEMA 12 and 13 Operator Consoles

## Dimensions

In [mm]

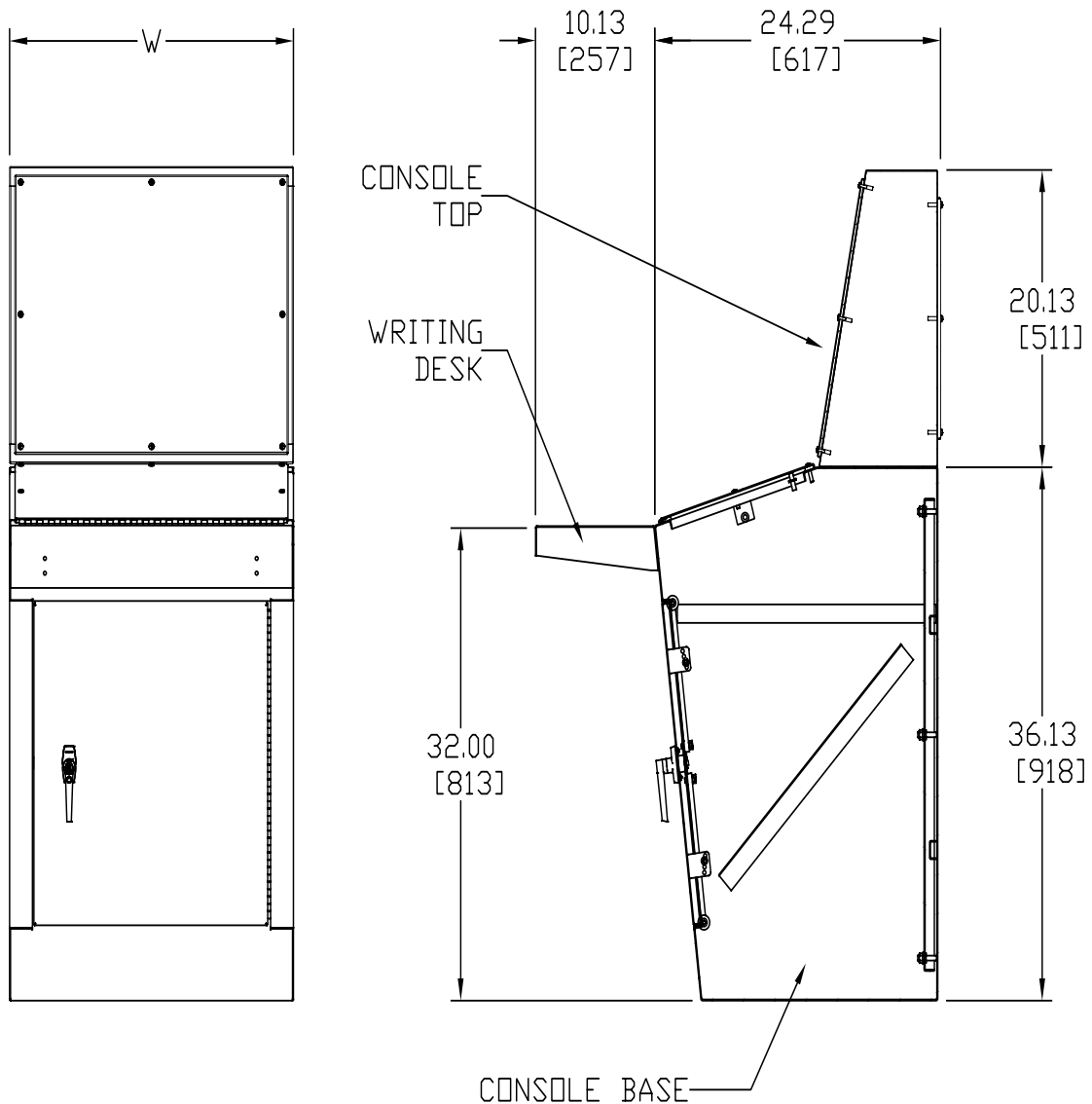

### NOTES:

1. ACCESS DOORS OPEN 180 DEGREES.
2. 3-POINT KEY LOCKING HANDLES ARE PROVIDED ON MAIN DOORS
3. WRITING DESK IS PROVIDED WITH MOUNTING HARDWARE.
4. 48" WIDE CONSOLE HAS TWO DOORS.

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Enclosure Accessories - Mounting Feet and Casters

## Mounting Feet for Freedom, Commander, and Centurion Series Enclosures



Mounting Foot Kit	Price	Description	Wt. [oz]
<b>FRMGFTKIT</b>	\$10.75	AttaBox mounting feet kit, fiber-glass-reinforced polyester, for use on Freedom series enclosures. Includes (4) mounting feet and mounting hardware.	1
<b>COMTGFTKIT</b>	\$22.00	AttaBox mounting feet kit, fiber-glass-reinforced polyester, for use on Commander series fiberglass, in-line, pushbutton enclosures. Does not fit C0763, C0963, COxPBW series, and COPCxxx series, COPCxB series, and COPCxB22 series enclosures. Includes (2) mounting feet, mounting hardware and silicone adhesive/sealant.	1
<b>CEMTGFTKIT</b>	\$22.50	AttaBox mounting feet kit, fiber-glass-reinforced polyester, for use on Centurion series enclosures. Includes (4) mounting feet and mounting hardware.	1



Enclosure Shipping Schedule			
Same day	1 - 5 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

## Mounting Feet for Ultimate Series Enclosures



Mounting Feet	Price	Description	Wt. [lb]
<b>N412MFK</b>	\$17.50	Hubbell-Wiegmann mounting feet kit, plated finish. For use on NEMA 412 Ultimate series enclosures. Includes (4) mounting feet, mounting hardware and sealing washers.	4
<b>N412MFKSS</b>	\$48.50	Hubbell-Wiegmann mounting feet kit, 304 stainless steel. For use on NEMA 412 Ultimate series enclosures. Includes (4) mounting feet, mounting hardware and sealing washers.	4



## Casters

Casters can be used on any enclosure to provide mobility. Caster kits include mounting plates designed to fit Hubbell-Wiegmann WC10 and WC12 consoles, but can be adapted to fit other enclosures.

Caster Kit	Price	Description	Wt. [lb]	Capacity [lb]
<b>WC10C</b>	\$175.00	Hubbell-Wiegmann caster kit, for WC10 consoles. Includes 4 zinc-plated steel casters (2 swivel, 2 stationary), 2 ANSI 61 gray mounting plates and hardware.	4	200
<b>WC12C</b>	\$175.00	Hubbell-Wiegmann caster kit, for WC12 consoles. Includes 4 zinc-plated steel casters (2 swivel, 2 stationary), 2 ANSI 61 gray mounting plates and hardware.	4	200



WC12C

Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.