

# Operator Consolets



## Applications

Designed to house a variety of electronic control or instrumentation devices. Consolets provide protection from dirt, dust, oil and water. Flexible design allows for mounting on either of two sides, creating control surfaces of 30° or 60°. Consolets can be mounted on desktops, pedestals, or other flat surfaces.

## Construction

- Bodies and doors fabricated from 14-gauge steel
- Seams are Continuously-welded and ground smooth, less knockouts or holes
- Captivated cover screws threaded into sealed wells
- Control panel is continuously hinged along bottom edge
- Closed-cell neoprene gasket
- Grounding provisions provided

## Finish

- Painted Steel: ANSI 61 gray polyester powder inside and out over phosphatized surfaces
- Stainless Steel: #3 intermediate polished finish

## Listings

- UL 508 12 and 13 (stainless steel also 4 and 4X) [UL File E64791]




Operator Consolets				
<i>Painted Steel</i>	<i>Price</i>	<i>Stainless Steel</i>	<i>Price</i>	<i>Enclosure SizeHxD</i>
<b>WC08C08</b>	\$180.00	<b>WC08C08SS</b>	\$309.00	8.31 x 8.31 x 7.10 [211 x 211 x 180]
<b>WC08C12</b>	\$199.00	<b>WC08C12SS</b>	\$342.00	8.31 x 12.31 x 7.10 [211 x 315 x 180]
<b>WC08C16</b>	\$218.00	<b>WC08C16SS</b>	\$375.00	8.31 x 16.31 x 7.10 [211 x 414 x 180]
–	–	<b>WC08C20SS</b>	\$408.00	8.31 x 20.31 x 7.10 [211 x 516 x 180]
<b>WC12C12</b>	\$232.00	<b>WC12C12SS</b>	\$398.00	12.31 x 12.31 x 9.10 [313 x 313 x 231]
<b>WC12C16</b>	\$258.00	<b>WC12C16SS</b>	\$443.00	12.31 x 16.31 x 9.10 [313 x 414 x 231]
<b>WC12C20</b>	\$293.00	<b>WC12C20SS</b>	\$490.00	12.31 x 20.31 x 9.10 [313 x 516 x 231]
<b>WC12C24</b>	\$319.00	<b>WC12C24SS</b>	\$534.00	12.31 x 24.31 x 9.10 [513 x 617 x 231]
<b>WC16C16</b>	\$300.00	<b>WC16C16SS</b>	\$516.00	16.31 x 16.31 x 11.10 [414 x 414 x 282]
<b>WC16C20</b>	\$333.00	<b>WC16C20SS</b>	\$574.00	16.31 x 20.31 x 11.10 [414 x 516 x 282]
<b>WC16C24</b>	\$367.00	<b>WC16C24SS</b>	\$632.00	16.31 x 24.31 x 11.10 [414 x 617 x 282]
<b>WC16C30</b>	\$429.00	–	–	16.31 x 30.31 x 11.10 [414 x 770 x 282]
<b>WC16C36</b>	\$483.00	<b>WC16C36SS</b>	\$918.00	16.31 x 36.31 x 11.10 [414 x 922 x 282]
<b>WC20C20</b>	\$396.00	<b>WC20C20SS</b>	\$662.00	20.31 x 20.31 x 13.10 [516 x 516 x 333]
<b>WC20C24</b>	\$438.00	<b>WC20C24SS</b>	\$733.00	20.31 x 24.31 x 13.10 [516 x 617 x 333]
<b>WC20C30</b>	\$489.00	<b>WC20C30SS</b>	\$843.00	20.31 x 30.31 x 13.10 [516 x 770 x 333]

Notes: Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawings.  
 Letters in table correspond to letters on dimensional drawings.

# Operator Consolets



## Dimensions

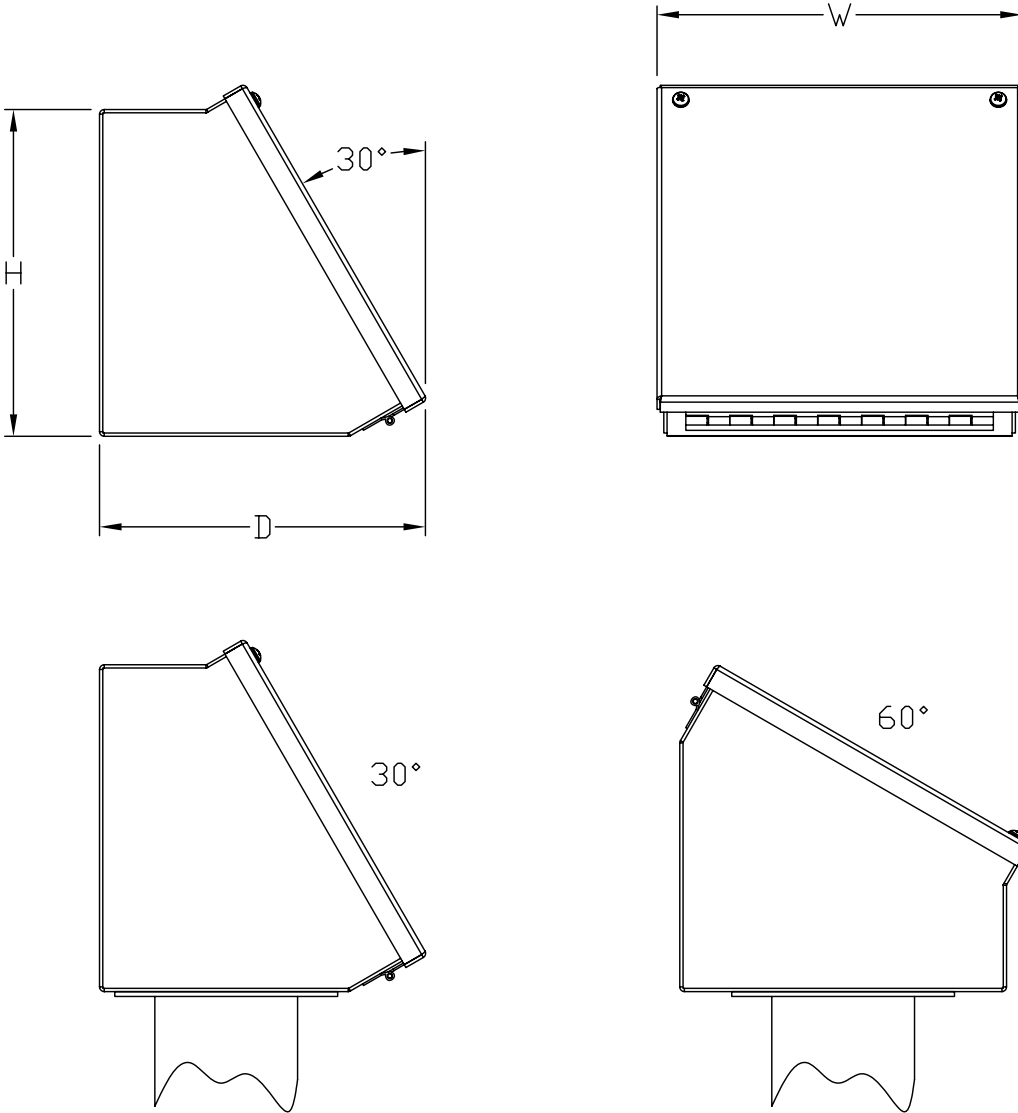

CONSOLET CAN BE POSITIONED AT 30° OR 60° ANGLE