


Operator Consolets

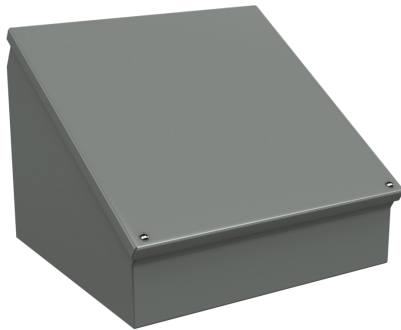

Applications

Designed to house a variety of electronic control or instrumentation devices. Consolets provide protection from dirt, dust, oil and water. Flexible design allows for mounting on either of two sides, creating control surfaces of 30° or 60°. Consolets can be mounted on desktops, pedestals, or other flat surfaces.

Finish

- Painted Steel: ANSI 61 gray polyester powder inside and out over phosphatized surfaces
- Stainless Steel: #3 intermediate polished finish

Listings

- UL 508, Types 12 & 13 (stainless steel also Types 4 & 4X) [UL File E64791]



Construction

- Bodies and doors fabricated from 14 gauge steel
- Seams are continuously welded and ground smooth, less knockouts or holes
- Captivated cover screws threaded into sealed wells
- Control panel is continuously hinged along bottom edge
- Closed cell neoprene gasket
- Grounding provisions provided

Shipping Schedule

Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------

Color indicates shipping lead time in business days.

Operator Consolets


Painted Steel	Price	Stainless Steel	Price	Enclosure SizeHxD
WC08C08	\$158.00	WC08C08SS	\$271.00	8.31 x 8.31 x 7.10 [211 x 211 x 180]
WC08C12	\$175.00	WC08C12SS	\$300.00	8.31 x 12.31 x 7.10 [211 x 315 x 180]
WC08C16	\$192.00	WC08C16SS	\$330.00	8.31 x 16.31 x 7.10 [211 x 414 x 180]
WC08C20	\$214.00	WC08C20SS	\$358.00	8.31 x 20.31 x 7.10 [211 x 516 x 180]
WC12C12	\$203.00	WC12C12SS	\$350.00	12.31 x 12.31 x 9.10 [313 x 313 x 231]
WC12C16	\$226.00	WC12C16SS	\$389.00	12.31 x 16.31 x 9.10 [313 x 414 x 231]
WC12C20	\$258.00	WC12C20SS	\$430.00	12.31 x 20.31 x 9.10 [313 x 516 x 231]
WC12C24	\$280.00	WC12C24SS	\$469.00	12.31 x 24.31 x 9.10 [513 x 617 x 231]
WC16C16	\$263.00	WC16C16SS	\$453.00	16.31 x 16.31 x 11.10 [414 x 414 x 282]
WC16C20	\$293.00	WC16C20SS	\$504.00	16.31 x 20.31 x 11.10 [414 x 516 x 282]
WC16C24	\$323.00	WC16C24SS	\$555.00	16.31 x 24.31 x 11.10 [414 x 617 x 282]
WC16C30	\$377.00	WC16C30SS	\$631.00	16.31 x 30.31 x 11.10 [414 x 770 x 282]
WC16C36	\$425.00	WC16C36SS	\$806.00	16.31 x 36.31 x 11.10 [414 x 922 x 282]
WC20C20	\$348.00	WC20C20SS	\$582.00	20.31 x 20.31 x 13.10 [516 x 516 x 333]
WC20C24	\$385.00	WC20C24SS	\$644.00	20.31 x 24.31 x 13.10 [516 x 617 x 333]
WC20C30	\$430.00	WC20C30SS	\$741.00	20.31 x 30.31 x 13.10 [516 x 770 x 333]

Notes: Dimensions in inches [millimeters].
 Letters in table correspond to letters on dimensional drawings.
 Letters in table correspond to letters on dimensional drawings.

Operator Consolets



Dimensions

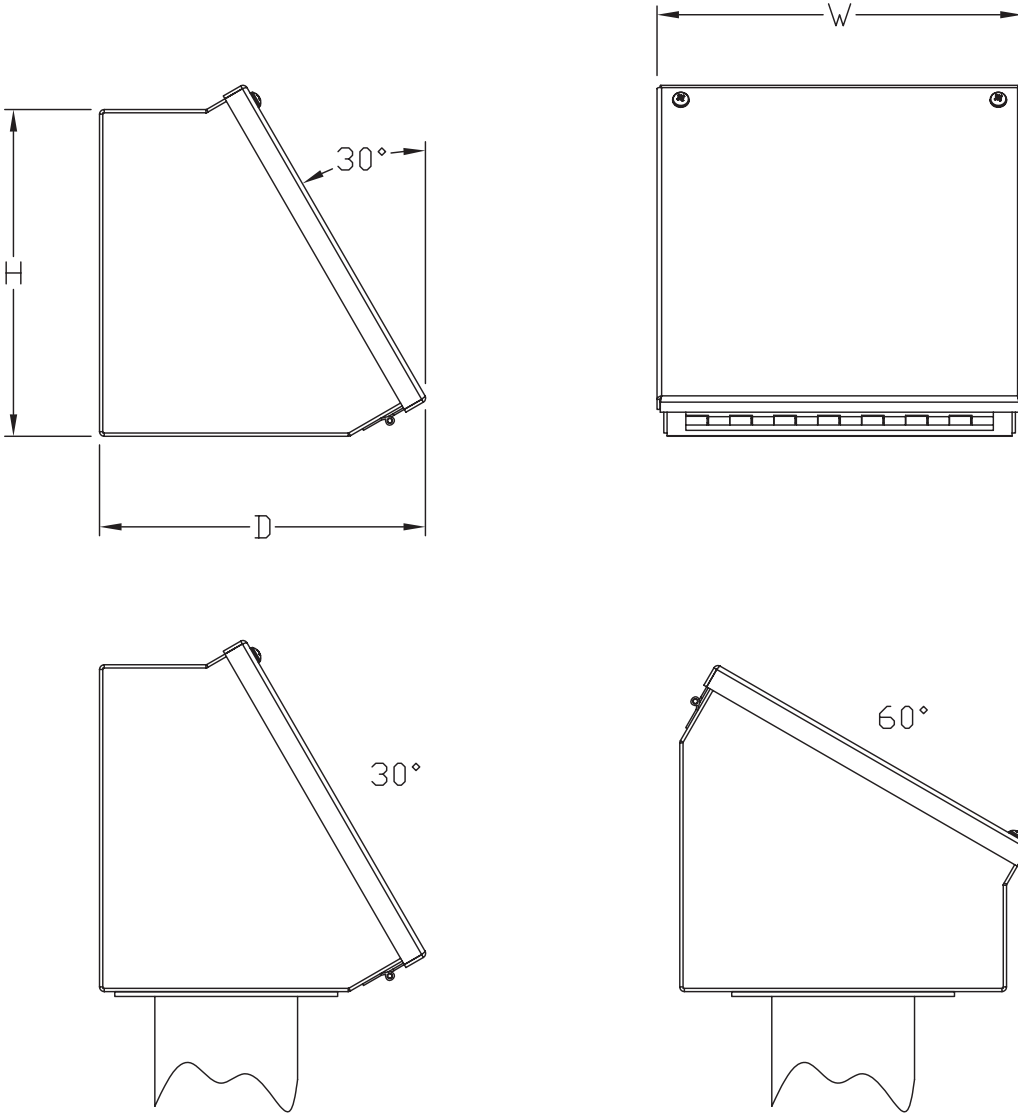

CONSOLET CAN BE POSITIONED AT 30° OR 60° ANGLE