

# NEMA 3, 4, 4X and 12 Stainless Steel Freestanding Single-Door



## Application

Designed to house electrical and electronic controls, terminals, and instruments in areas that are regularly hosed down or are otherwise very wet. Also suitable for outdoor applications.

## Construction

- Bodies and doors fabricated from 12 gauge 304 and 316L stainless steel
- Continuously welded seams ground smooth
- “Uni-strut” mounting channels are welded horizontally to interior body sides [top, bottom and center]
- Optional swing, half, full and rack panels can be mounted anywhere along “uni-strut” channel
- Rolled lip around three sides of door and along top of enclosure’s opening excludes liquids and contaminants from entering
- Quick and easy to operate stainless steel door clamps around three sides of doors

- Heavy gauge continuous hinge with stainless steel hinge pin
- Doors are removable by pulling stainless steel continuous hinge pin
- Hasp and staple are provided for padlocking
- Print pocket is provided
- Heavy duty removable lifting eyes
- Doors are sealed with poured-in-place polyurethane gasket
- Grounding provisions provided
- [Uses WAN4XRA clamp](#)

## Finish

- Smooth grain finish

## Listings

- UL 508, Types 3, 4, 4X & 12 [UL File E64791]
- CSA Certified, Type 3, 4 & 12 [CSA File LL66078]
- NEMA/EEMAC Types 3, 4, 4X & 12



FOR CURRENT LISTINGS, PLEASE SEE [WWW.AUTOMATIONDIRECT.COM](http://WWW.AUTOMATIONDIRECT.COM)

### Enclosure Shipping Schedule

Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
----------	------------	-------------	-------------	-------------

Color indicates shipping lead time in business days.

### NEMA 3, 4, 4x and 12 Stainless Steel Freestanding Single-Door

304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD
<b>N4S722518FSSS</b>	\$5,496.00	<b>N4S722518FSSSA</b>	\$6,787.00	72.12 x 25.12 x 18.12 [1832 x 638 x 460]
<b>N4S723124FSSS</b>	\$5,877.00	<b>N4S723124FSSSA</b>	\$8,286.00	72.12 x 31.12 x 24.12 [1832 x 790 x 613]
<b>N4S723724FSSS</b>	\$6,932.00	<b>N4S723724FSSSA</b>	\$9,037.00	72.12 x 37.12 x 24.12 [1832 x 943 x 613]

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

### Standard Subpanels

Enclosures	Full Height		Half Height	
	Painted Steel	Galvanized	Painted Steel	Galvanized
<b>N4S722518FSSS</b>	<b>WA72P24F1</b>	<b>WA72P24F1G</b>	<b>WA72P24F2</b>	<b>WA72P24F2G</b>
<b>N4S723124FSSS</b>	<b>WA72P30F1</b>	<b>WA72P30F1G</b>	<b>WA72P30F2</b>	<b>WA72P30F2G</b>
<b>N4S723724FSSS</b>	<b>WA72P36F1</b>	<b>WA72P36F1G</b>	<b>WA72P36F2</b>	<b>WA72P36F2G</b>
<b>N4S722518FSSSA</b>	<b>WA72P24F1</b>	<b>WA72P24F1G</b>	<b>WA72P24F2</b>	<b>WA72P24F2G</b>
<b>N4S723124FSSSA</b>	<b>WA72P30F1</b>	<b>WA72P30F1G</b>	<b>WA72P30F2</b>	<b>WA72P30F2G</b>
<b>N4S723724FSSSA</b>	<b>WA72P36F1</b>	<b>WA72P36F1G</b>	<b>WA72P36F2</b>	<b>WA72P36F2G</b>

# NEMA 3, 4, 4X and 12 Stainless Steel Freestanding Single-Door

Enclosure Shipping Schedule				
Same day	1 - 7 days	1 -10 days	1 - 15 days	1 - 20 days


Color indicates shipping lead time in business days.

Swing-Out Panels				
Enclosures	Full Height		Half Height	
	Painted Steel	Galvanized	Painted Steel	Galvanized
N4S722518FSSS	WA72SP24F3	WA72SP24F3G	WA72SP24F4	WA72SP24F4G
N4S723124FSSS	WA72SP30F3	WA72SP30F3G	WA72SP30F4	WA72SP30F4G
N4S723724FSSS	WA72SP36F3	WA72SP36F3G	WA72SP36F4	WA72SP36F4G
N4S722518FSSSA	WA72SP24F3	WA72SP24F3G	WA72SP24F4	WA72SP24F4G
N4S723124FSSSA	WA72SP30F3	WA72SP30F3G	WA72SP30F4	WA72SP30F4G
N4S723724FSSSA	WA72SP36F3	WA72SP36F3G	WA72SP36F4	WA72SP36F4G

Side Mount Panels			Swing-Out Rack
Enclosures	Painted Steel	Galvanized	
N4S722518FSSS	WA72SMP14	WA72SMP14G	-
N4S723124FSSS	WA72SMP14, WA72SMP20	WA72SMP14G, WA72SMP20G	WA7230SOF19
N4S723724FSSS	WA72SMP14, WA72SMP20	WA72SMP14G, WA72SMP20G	WA7236SOF19
N4S722518FSSSA	WA72SMP14	WA72SMP14G	-
N4S723124FSSSA	WA72SMP14, WA72SMP20	WA72SMP14G, WA72SMP20G	WA7230SOF19
N4S723724FSSSA	WA72SMP14, WA72SMP20	WA72SMP14G, WA72SMP20G	WA7236SOF19

# NEMA 3, 4, 4X and 12 Stainless Steel Freestanding Single-Door

## Dimensions in [mm]

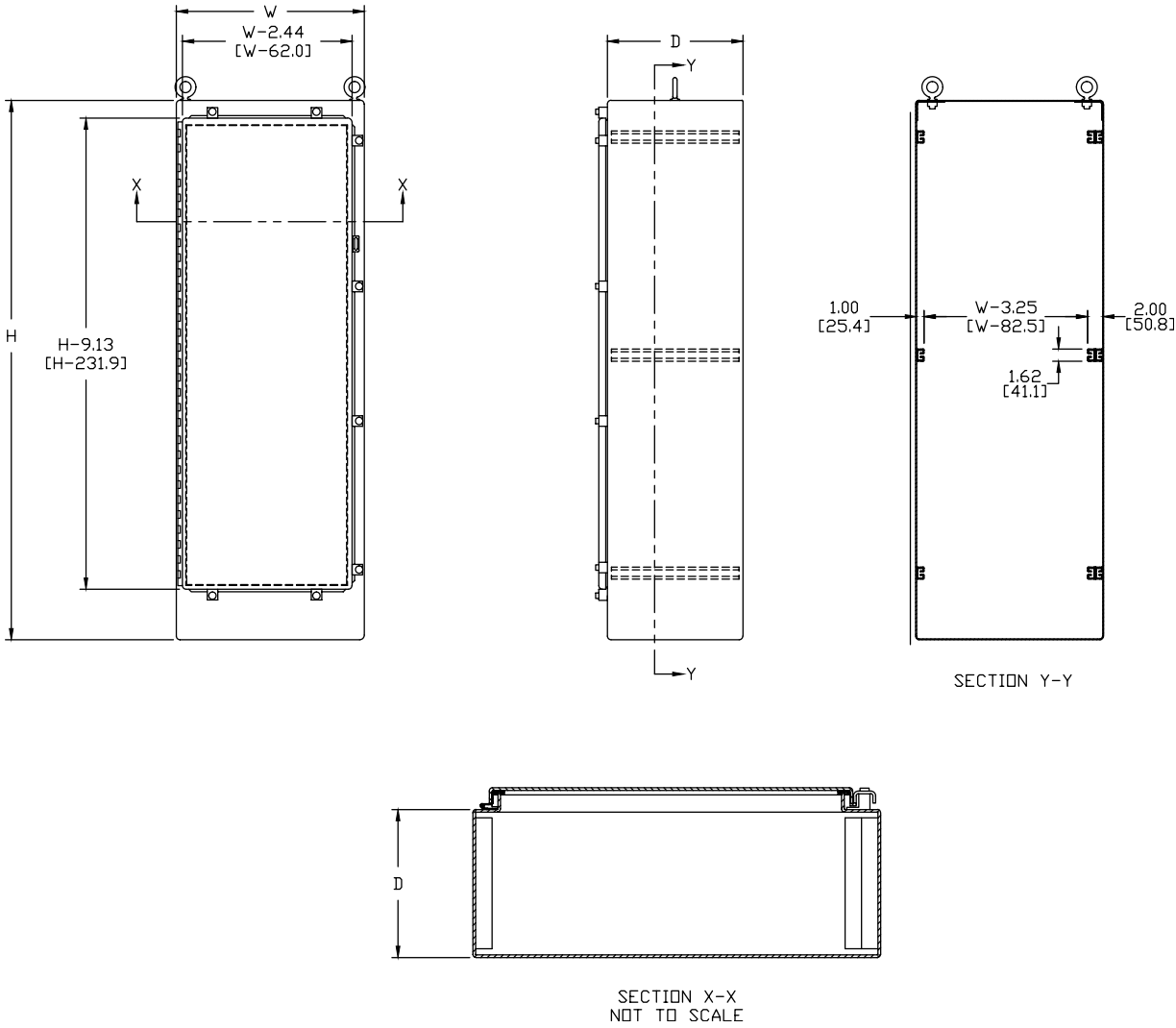


See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# WA-F1/F2 Panels for Single-Door Freestanding Enclosures



## Description

- Panels for single-door single-access and single-door dual-access, freestanding NEMA 12, and freestanding NEMA 4 enclosures
- Can be positioned anywhere along horizontal depth-wise mounting channels
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- May be used in two-door enclosures along with other freestanding accessories

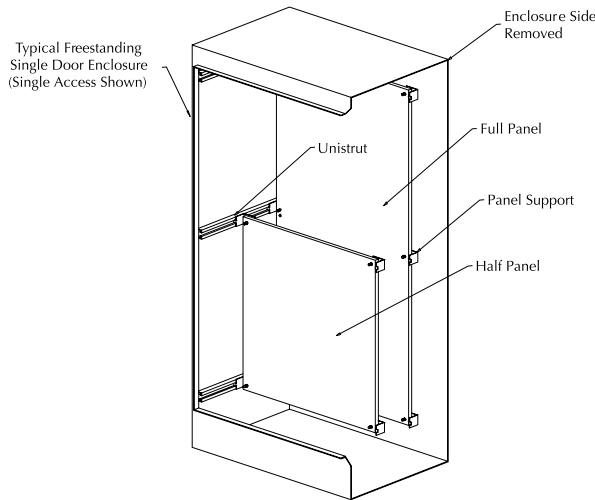

Painted Steel	Price	Galvanized	Price	Steel Gauge	Panel Size AxB	Subpanel Type
WA60P24F1	\$223.00	WA60P24F1G	\$223.00	12	48.00 x 20.00 [1219 x 508]	Full
WA60P24F2	\$149.00	WA60P24F2G	\$149.00	10	24.88 x 20.00 [632 x 508]	Half
WA60P36F1	\$288.00	WA60P36F1G	\$288.00	12	48.00 x 32.00 [1219 x 813]	Full
WA60P36F2	\$181.00	WA60P36F2G	\$181.00	12	24.88 x 32.00 [632 x 813]	Half
WA72P24F1	\$249.00	WA72P24F1G	\$249.00	12	60.00 x 20.00 [1524 x 508]	Full
WA72P24F2	\$160.00	WA72P24F2G	\$160.00	12	30.88 x 20.00 [784 x 508]	Half
WA72P30F1	\$290.00	WA72P30F1G	\$290.00	12	60.00 x 26.00 [1524 x 660]	Full
WA72P30F2	\$181.00	WA72P30F2G	\$181.00	10	30.88 x 26.00 [784 x 660]	Half
WA72P36F1	\$331.00	WA72P36F1G	\$331.00	12	60.00 x 32.00 [1524 x 813]	Full
WA72P36F2	\$202.00	WA72P36F2G	\$202.00	12	30.88 x 32.00 [784 x 813]	Half
WA90P24F1	\$290.00	WA90P24F1G	\$290.00	12	78.00 x 20.00 [1981 x 508]	Full
WA90P24F2	\$181.00	WA90P24F2G	\$181.00	10	39.88 x 20.00 [1013 x 508]	Half
WA90P36F1	\$389.00	WA90P36F1G	\$389.00	12	78.00 x 32.00 [1981 x 813]	Full
WA90P36F2	\$235.00	WA90P36F2G	\$235.00	10	39.88 x 32.00 [1013 x 813]	Half

Notes: Dimensions in inches [millimeters].  
If used in a two-door enclosure, a center panel support must be ordered.  
Suffix F1= full panel, F2 = half panel


## Dimensions

in [mm]


Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

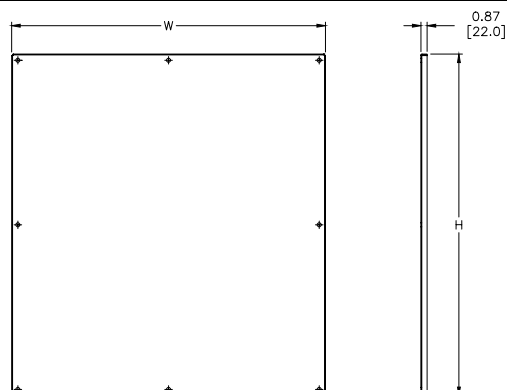

# WA-SMP Series Side-Mount Panels for Freestanding Enclosures

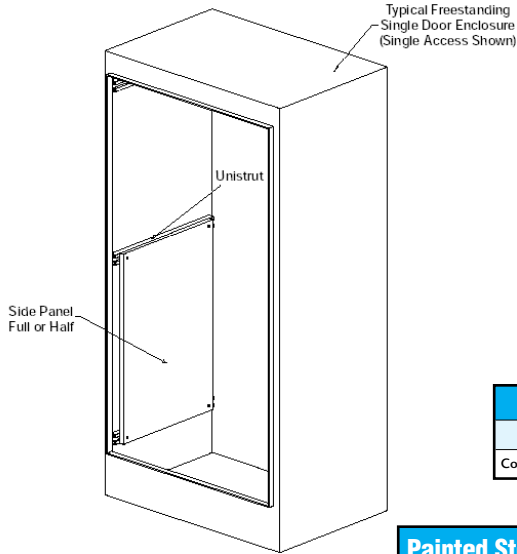

## Description

- Panels for freestanding NEMA 4 and freestanding NEMA 12 enclosures
- Panels are fabricated from 12 gauge steel
- They provide extra mounting space on the sides of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels attach securely to mounting channels

Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days


Color indicates shipping lead time in business days.

Painted Steel	Price	Galvanized	Price	Panel Size AxB
<b>WA60SMP14</b>	\$135.00	<b>WA60SMP14G</b>	\$135.00	48.00 x 14.00 [1219 x 356]
<b>WA72SMP14</b>	\$153.00	<b>WA72SMP14G</b>	\$153.00	60.00 x 14.00 [1524 x 356]
<b>WA72SMP20</b>	\$188.00	<b>WA72SMP20G</b>	\$188.00	60.00 x 20.00 [1524 x 508]
<b>WA90SMP14</b>	\$220.00	<b>WA90SMP14G</b>	\$220.00	78.00 x 14.00 [1981 x 356]
<b>WA90SMP20</b>	\$231.00	<b>WA90SMP20G</b>	\$231.00	78.00 x 20.00 [1981 x 508]

*Note: Dimensions in inches (millimeters)*


## Dimensions

in [mm]

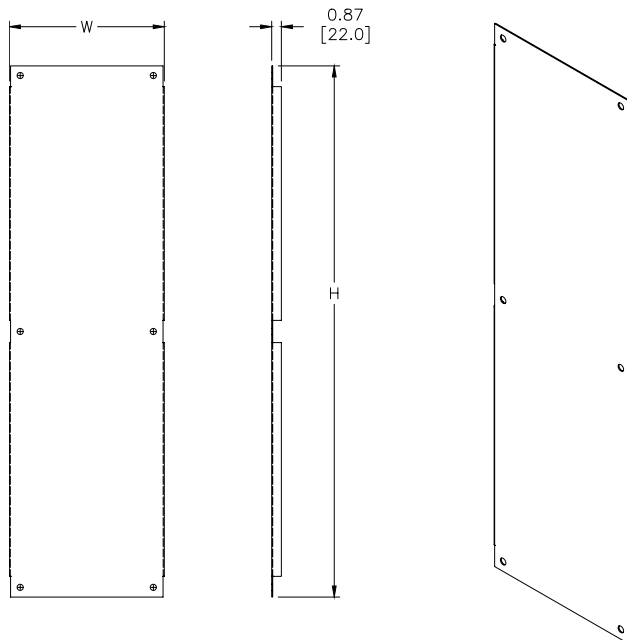

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# WASP-F3/F4 Series Accessory Swing-Out Panels For Freestanding Enclosures

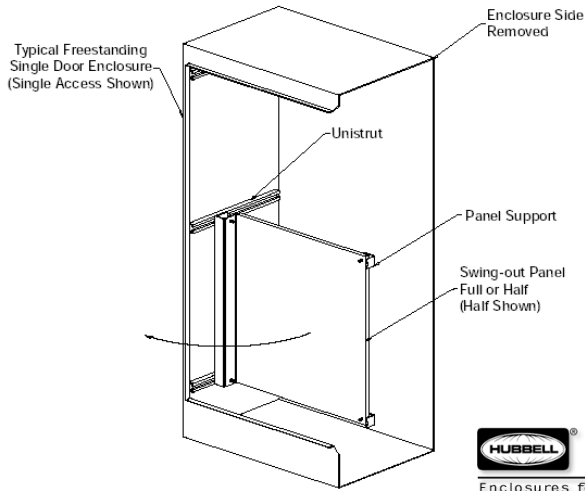

## Description

- Panels for freestanding NEMA 12 enclosures and freestanding NEMA 4 enclosures
- Full-height and half-height swing-out panels are available
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting can be on either side of the enclosure
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- May be used in two-door enclosures along with other freestanding accessories
- Fabricated from 12 gauge steel
- Mounting hardware is furnished with each panel



Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days


Color indicates shipping lead time in business days.

Painted Steel	Price	Galvanized	Price	Panel Size AxB	Subpanel Type
<b>WA60SP24F3</b>	\$360.00	<b>WA60SP24F3G</b>	\$360.00	48.00 x 19.00 [1219 x 483]	Full
<b>WA60SP24F4</b>	\$253.00	<b>WA60SP24F4G</b>	\$253.00	24.88 x 19.00 [632 x 483]	Half
<b>WA60SP36F3</b>	\$444.00	<b>WA60SP36F3G</b>	\$444.00	48.00 x 31.00 [1219 x 787]	Full
<b>WA60SP36F4</b>	\$294.00	<b>WA60SP36F4G</b>	\$294.00	24.88 x 31.00 [632 x 787]	Half
<b>WA72SP24F3</b>	\$437.00	<b>WA72SP24F3G</b>	\$437.00	60.00 x 19.00 [1524 x 483]	Full
<b>WA72SP24F4</b>	\$296.00	<b>WA72SP24F4G</b>	\$296.00	30.88 x 19.00 [784 x 483]	Half
<b>WA72SP30F3</b>	\$506.00	<b>WA72SP30F3G</b>	\$506.00	60.00 x 25.00 [1524 x 635]	Full
<b>WA72SP30F4</b>	\$335.00	<b>WA72SP30F4G</b>	\$335.00	30.88 x 25.00 [784 x 635]	Half
<b>WA72SP36F3</b>	\$576.00	<b>WA72SP36F3G</b>	\$576.00	60.00 x 31.00 [1524 x 787]	Full
<b>WA72SP36F4</b>	\$373.00	<b>WA72SP36F4G</b>	\$373.00	30.88 x 31.00 [784 x 787]	Half
<b>WA90SP36F3</b>	\$684.00	<b>WA90SP36F3G</b>	\$684.00	78.00 x 31.00 [1981 x 787]	Full
<b>WA90SP36F4</b>	\$432.00	<b>WA90SP36F4G</b>	\$432.00	39.88 x 31.00 [1013 x 787]	Half

Notes: Dimensions in inches [millimeters].  
 Note 1: If used in a two-door enclosure, a center panel support must be ordered.  
 Note 2: Suffix F3 =full panel, F4 =half panel

## Dimensions


in [mm]

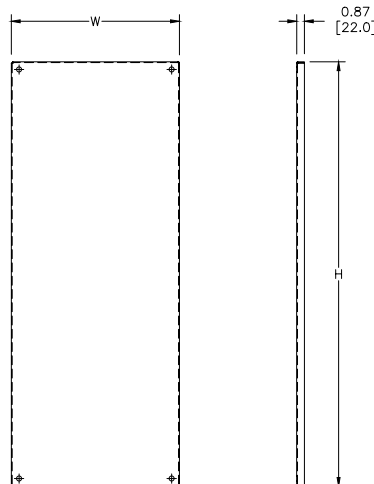

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Enclosure Accessories - Rack Mounting

## Swing-Out Rack Mounting Frames For Freestanding Enclosures

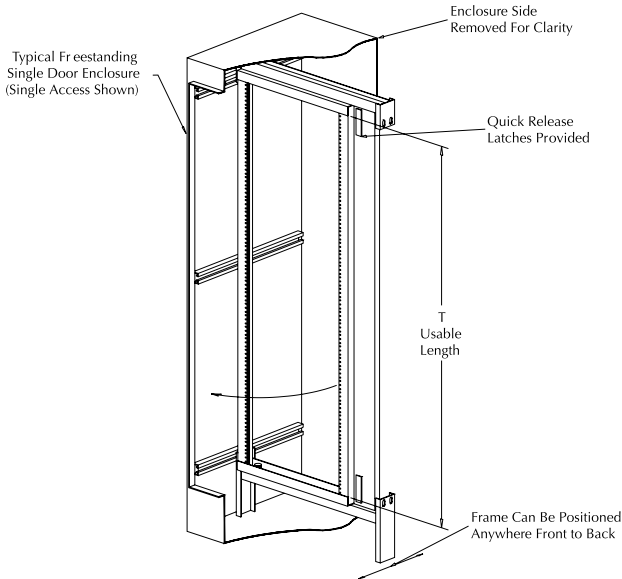

Fabricated from 10-gauge steel, these swing-out rack mounting frames are available for mounting 19-inch rack-mounted equipment. Mounting holes are tapped with #10-32 threads spaced per E.I.A. standard.

Frames are painted with white polyester powder.

Note: If used in a two-door enclosure, a center panel support must be ordered.

Mounting Frames	Price	Fits Enclosure HxW	Usable Angle Length "T"	Wt. [lb]
<b>WA7230SOF19</b>	\$450.00	72 x 30 [1829 x 762]	57.88 [1470]	61
<b>WA7236SOF19</b>	\$486.00	72x36 [1829x914]	57.88 [1470]	73
<b>WA9036SOF19</b>	\$513.00	90x36 [2286x914]	75.38 [1915]	87

**Note: Dimensions in inches [millimeters]**

## Rack Mounting Angles for Ultimate Series

Rack mounting angles allow the installation of 19-inch rack equipment in 24-inch wide NEMA 412 enclosures. "L" shaped thru-hole angles may be fixed to the enclosure flange, or used in combination with the Adjustable Depth Mounting Kits. Thru-hole diameters are 0.281in. Brackets are fabricated from 14 ga. galvanized steel. Mounting hardware and two angles are provided.

**Note: W1032N clip nuts must be purchased separately.**



Rack Mounting Angles	Price	For Enclosure Height in [mm]	Wt. [lb]
<b>HFWRA20C</b>	\$74.00	20 [508]	3
<b>HFWRA24C</b>	\$78.00	24 [609]	
<b>HFWRA30C</b>	\$94.00	30 [762]	4
<b>HFWRA36C</b>	\$105.00	36 [914]	
<b>HFWRA48C</b>	\$124.00	48 [1219]	7

## Console Rack Angles

Angle brackets for mounting 19-inch rack equipment in the WC14B console.



Console Rack Angle	Price	Description	Wt. [lb]
<b>WC14R</b>	\$153.00	Hubbell-Wiegmann enclosure rack angle, white polyester powder finish, for WC14B enclosure. For use on WC series consoles but provides standard rack hole spacing for only WC14B. Includes mounting hardware. Package of 2.	11

## Rack Mounting Angle For Wall Mounts

Designed for mounting 19-inch rack mounted equipment in 24-inch wide NEMA 12, NEMA 4 and NEMA 412 wall mount enclosures. Small holes are tapped # 10-32. Sealing washers are also provided to maintain original NEMA rating after installation.

Rack Mounting Angle	Price	For Enclosure Height in [mm]	Description	Wt. [lb]
<b>WARAK24</b>	\$80.00	24 [609]	Enclosure rack mounting angle, white polyester powder finish. Includes mounting hardware. Package of 2.	8
<b>WARAK30</b>	\$100.00	30 [762]		10
<b>WARAK36</b>	\$121.00	36 [914]		12

Enclosure Shipping Schedule	
1 - 10 days	1 - 15 days

Color indicates shipping lead time in business days.

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.