

# NEMA 3 and 4 Gasketed Screw Cover



## Application

Designed for use as a wiring box, junction box, pull box and terminal box in many indoor or outdoor applications where dust or moisture is a problem.

## Construction

- Bodies and covers fabricated from 14 or 12 gauge carbon steel
- Seams are continuously welded and ground smooth
- Cover contains closed cell oil resistant neoprene gasket
- Enclosure comes with stainless steel cover screws which thread into sealed wells to prevent liquid, dust, etc., from entering into the enclosure through the screw holes
- Ground stud located in door
- No holes, knockouts, or rear mounting holes

## Finish

- ANSI 61 gray polyester powder inside and out

## Listings

- UL50, Types 3 & 4 [UL File E23553]
- NFMA/FFMAC Types 3 & 4



FOR CURRENT LISTINGS, PLEASE SEE [WWW.AUTOMATIONDIRECT.COM](http://WWW.AUTOMATIONDIRECT.COM)

### Enclosure Shipping Schedule

Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------	-------------

Color indicates shipping lead time in business days.

### NEMA 3 and 4 Gasketed Screw Cover

ANSI 61 Gray Light-Textured	Price	Body/Door Steel Gauge	Enclosure Size HxWxD
WA060604GSC	\$55.00	14/14	6.13 x 6.13 x 4.36 [156 x 156 x 111]
WA060606GSC	\$56.00		6.13 x 6.13 x 6.36 [156 x 156 x 162]
WA060804GSC	\$58.00		6.13 x 8.13 x 4.36 [156 x 207 x 111]
WA060806GSC	\$61.00		6.13 x 8.13 x 6.36 [156 x 207 x 162]
WA080804GSC	\$67.00		8.13 x 8.13 x 4.36 [207 x 207 x 111]
WA080806GSC	\$70.00		8.13 x 8.13 x 6.36 [207 x 207 x 162]
WA081004GSC	\$73.00		8.13 x 10.13 x 4.36 [207 x 257 x 111]
WA101004GSC	\$80.00		10.13 x 10.13 x 4.36 [257 x 257 x 111]
WA101006GSC	\$89.00		10.13 x 10.13 x 6.36 [257 x 257 x 162]
WA101206GSC	\$101.00		10.13 x 12.13 x 6.36 [257 x 308 x 162]
WA121204GSC	\$106.00		12.13 x 12.13 x 4.36 [308 x 308 x 111]
WA121206GSC	\$110.00		12.13 x 12.13 x 6.36 [308 x 308 x 162]
WA121606GSC	\$115.00		12.13 x 16.13 x 6.36 [308 x 410 x 162]
WA121608GSC	\$119.00		12.13 x 16.13 x 8.36 [308 x 410 x 212]
WA161606GSC	\$124.00		16.13 x 16.13 x 6.36 [410 x 410 x 162]
WA161608GSC	\$129.00		16.13 x 16.13 x 8.36 [410 x 410 x 212]
WA181806GSC	\$130.00		18.13 x 18.13 x 6.36 [461 x 461 x 162]
WA202008GSC	\$202.00		20.13 x 20.13 x 8.36 [511 x 511 x 212]
WA202408GSC	\$229.00	20.13 x 24.13 x 8.36 [511 x 613 x 212]	
WA242408GSC	\$259.00	24.13 x 24.13 x 8.36 [613 x 613 x 212]	
WA303012GSC	\$614.00	12/12	30.25 x 30.25 x 12.41 [768 x 768 x 315]
WA363612GSC	\$633.00		36.25 x 36.25 x 12.41 [921 x 921 x 315]

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].

# NEMA 3 and 4 Gasketed Screw Cover Galvanized Steel



## Application

Designed for use as a wiring box, junction box, pull box and terminal box in many indoor or outdoor applications where dust or moisture is a problem.

## Construction

- Bodies and covers fabricated from G-90 grade galvanized steel.
- Seams are continuously welded and ground smooth
- Cover contains closed cell oil resistant neoprene gasket
- Enclosure comes with stainless steel cover screws which thread into sealed wells to prevent liquid, dust, etc., from entering into the enclosure through the screw holes
- Ground stud located in door
- Galvanized box welded corners protected by zinc-rich coating
- No holes, knockouts, or rear mounting holes

## Finish

- G-90 pregalvanized steel

## Listings

- UL50, Types 3 & 4 [UL File E23553]
- NEMA/EEMAC Types 3 & 4
- CSA Certified Types 3 & 4 [CSA File LL66078]



FOR CURRENT LISTINGS, PLEASE SEE [WWW.AUTOMATIONDIRECT.COM](http://WWW.AUTOMATIONDIRECT.COM)

Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

NEMA 3 and 4 Gasketed Screw Cover - Galvanized Steel			
Galvanized	Price	Body/Door Steel Gauge	Enclosure Size HxWxD
WA060604GSCG	\$55.00	14/14	6.13 x 6.13 x 4.40 [156 x 156 x 112]
WA060606GSCG	\$56.00		6.13 x 6.13 x 6.40 [156 x 156 x 163]
WA060804GSCG	\$58.00		6.13 x 8.13 x 4.40 [156 x 207 x 112]
WA060806GSCG	\$61.00		6.13 x 8.13 x 6.40 [156 x 207 x 163]
WA080804GSCG	\$67.00		8.13 x 8.13 x 4.40 [207 x 207 x 112]
WA080806GSCG	\$70.00		8.13 x 8.13 x 6.40 [207 x 207 x 163]
WA081004GSCG	\$73.00		8.13 x 10.13 x 4.40 [207 x 257 x 112]
WA101004GSCG	\$80.00		10.13 x 10.13 x 4.40 [257 x 257 x 112]
WA101006GSCG	\$89.00		10.13 x 10.13 x 6.40 [257 x 257 x 163]
WA101206GSCG	\$101.00		10.13 x 12.13 x 6.40 [257 x 308 x 163]
WA121204GSCG	\$106.00		12.13 x 12.13 x 4.40 [308 x 308 x 112]
WA121206GSCG	\$111.00		12.13 x 12.13 x 6.40 [308 x 308 x 163]
WA121606GSCG	\$116.00		12.13 x 16.13 x 6.40 [308 x 410 x 163]
WA121608GSCG	\$120.00		12.13 x 16.13 x 8.40 [308 x 410 x 213]
WA161606GSCG	\$125.00		16.13 x 16.13 x 6.40 [410 x 410 x 163]
WA161608GSCG	\$129.00		16.13 x 16.13 x 8.40 [410 x 410 x 213]
WA181806GSCG	\$130.00		18.13 x 18.13 x 6.40 [461 x 461 x 163]
WA202008GSCG	\$200.00		12/12
WA202408GSCG	\$228.00	20.13 x 24.13 x 8.40 [511 x 613 x 213]	
WA242408GSCG	\$258.00	24.12 x 24.13 x 8.40 [613 x 613 x 213]	
WA303012GSCG	\$614.00	30.25 x 30.25 x 12.41 [768 x 768 x 315]	
WA363612GSCG	\$634.00	36.25 x 36.25 x 12.41 [921 x 921 x 315]	

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].

# NEMA 3, 4 and 4X Gasketed Screw Cover Stainless Steel



## Application

Designed for use as a wiring box, junction box, pull box and terminal box in many indoor or outdoor applications where dust or moisture is a problem.

## Construction

- Bodies and covers fabricated from 304 stainless steel.
- Seams are continuously welded and ground smooth
- Cover contains closed cell oil resistant neoprene gasket
- Enclosure comes with stainless steel cover screws which thread into sealed wells to prevent liquid, dust, etc., from entering into the box through the screw holes
- Ground stud located in door
- No holes, knockouts, or rear mounting holes

## Finish

- Cover and outside of enclosure have #3 intermediate polished finish

## Listings

- UL50, Type 3, 4 & 4X [UL File E23553]
- NEMA/EEMAC Type 3, 4 & 4X



FOR CURRENT LISTINGS, PLEASE SEE [WWW.AUTOMATIONDIRECT.COM](http://WWW.AUTOMATIONDIRECT.COM)



### Enclosure Shipping Schedule

Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------	-------------

Color indicates shipping lead time in business days.


### NEMA 3, 4 and 4X Gasketed Screw Cover - Stainless Steel

Stainless Steel	Price	Body/Door Steel Gauge	Enclosure Size HxWxD
WA060604GSCSS	\$118.00	14/14	6.13 x 6.13 x 4.32 [156 x 156 x 110]
WA060606GSCSS	\$168.00		6.13 x 6.13 x 6.32 [156 x 156 x 161]
WA060804GSCSS	\$134.00		6.13 x 8.13 x 4.32 [156 x 207 x 110]
WA060806GSCSS	\$141.00		6.13 x 8.13 x 6.32 [156 x 207 x 161]
WA080804GSCSS	\$218.00		8.13 x 8.13 x 4.32 [207 x 207 x 110]
WA080806GSCSS	\$175.00		8.13 x 8.13 x 6.32 [207 x 207 x 161]
WA081004GSCSS	\$189.00		8.13 x 10.13 x 4.32 [207 x 257 x 110]
WA101004GSCSS	\$204.00		10.13 x 10.13 x 4.32 [257 x 257 x 110]
WA101006GSCSS	\$229.00		10.13 x 10.13 x 6.32 [257 x 257 x 161]
WA101206GSCSS	\$253.00		10.13 x 12.13 x 6.32 [257 x 308 x 161]
WA121204GSCSS	\$277.00		12.13 x 12.13 x 4.32 [308 x 308 x 110]
WA121206GSCSS	\$296.00		12.13 x 12.13 x 6.32 [308 x 308 x 161]
WA121606GSCSS	\$322.00		12.13 x 16.13 x 6.32 [308 x 410 x 161]
WA121608GSCSS	\$331.00		12.13 x 16.13 x 8.32 [308 x 410 x 211]
WA161606GSCSS	\$340.00		16.13 x 16.13 x 6.32 [410 x 410 x 161]
WA161608GSCSS	\$377.00		16.13 x 16.13 x 8.32 [410 x 410 x 211]
WA181806GSCSS	\$414.00		18.13 x 18.13 x 6.32 [461 x 461 x 161]
WA202008GSCSS	\$450.00		20.13 x 20.13 x 8.32 [511 x 511 x 211]
WA202408GSCSS	\$452.00		20.13 x 24.13 x 8.32 [511 x 613 x 211]
WA242406GSCSS	\$456.00	24.12 x 24.13 x 6.32 [613 x 613 x 161]	
WA242408GSCSS	\$478.00	24.12 x 24.13 x 8.32 [613 x 613 x 211]	
WA303012GSCSS	\$888.00	12/12	30.25 x 30.25 x 12.35 [768 x 768 x 314]
WA363612GSCSS	\$1,143.00		36.25 x 36.25 x 12.35 [921 x 921 x 314]

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].

# NEMA 3, 4 and 4X Gasketed Screw Cover ANSI 61 Powder-Coated Steel, Galvanized Steel, and Stainless Steel

## Dimensions

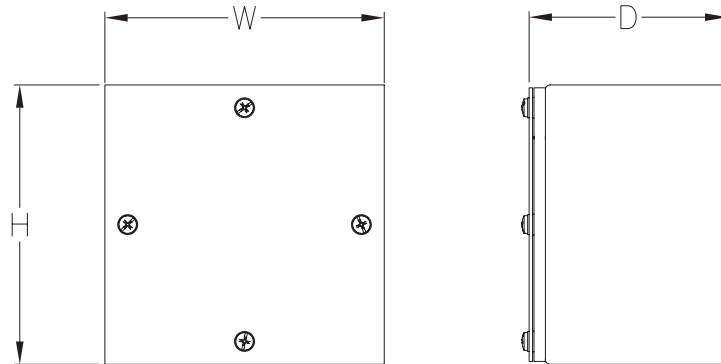

*See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.*