

# NEMA 3 and 4 Gasketed Screw Cover



## Application

Designed for use as a wiring box, junction box, pull box, and terminal box in many indoor or outdoor applications where dust or moisture is a problem.

## Construction

- Bodies and covers fabricated from 14 or 12 gauge carbon steel
- Seams are continuously welded and ground smooth
- Cover contains closed cell oil resistant neoprene gasket
- Enclosure comes with stainless steel cover screws which thread into sealed wells to prevent liquid, dust, etc., from entering into the enclosure through the screw holes
- Ground stud located in door
- No holes, knockouts, or rear mounting holes

## Finish

- ANSI 61 gray polyester powder inside and out

## Listings

- UL50, Types 3 & 4 [UL File E23553]
- CSA Certified Types 3 & 4 [CSA File LL66078]
- NEMA/EEMAC Types 3 & 4



| Enclosure Shipping Schedule                          |             |             |
|--|-------------|-------------|
| 1 - 7 days   | 1 - 10 days | 1 - 15 days |
| Color indicates shipping lead time in business days. |             |             |

| NEMA 3 and 4 Gasketed Screw Cover |          |  |   |
|-----------------------------------|----------|--|---|
| ANSI 61 Gray Light-Textured       | Price    | Body/Door Steel Gauge                  | Enclosure Size HxWxD                    |
| <b>WA060604GSC</b>                | \$47.50  | 14/14                                  | 6.13 x 6.13 x 4.36 [156 x 156 x 111]    |
| <b>WA060606GSC</b>                | \$48.00  |  | 6.13 x 6.13 x 6.36 [156 x 156 x 162]    |
| <b>WA060804GSC</b>                | \$49.50  |  | 6.13 x 8.13 x 4.36 [156 x 207 x 111]    |
| <b>WA060806GSC</b>                | \$53.00  |  | 6.13 x 8.13 x 6.36 [156 x 207 x 162]    |
| <b>WA080804GSC</b>                | \$58.00  |  | 8.13 x 8.13 x 4.36 [207 x 207 x 111]    |
| <b>WA080806GSC</b>                | \$61.00  |  | 8.13 x 8.13 x 6.36 [207 x 207 x 162]    |
| <b>WA081004GSC</b>                | \$63.00  |  | 8.13 x 10.13 x 4.36 [207 x 257 x 111]   |
| <b>WA101004GSC</b>                | \$69.00  |  | 10.13 x 10.13 x 4.36 [257 x 257 x 111]  |
| <b>WA101006GSC</b>                | \$76.00  |  | 10.13 x 10.13 x 6.36 [257 x 257 x 162]  |
| <b>WA101206GSC</b>                | \$87.00  |  | 10.13 x 12.13 x 6.36 [257 x 308 x 162]  |
| <b>WA121204GSC</b>                | \$91.00  |  | 12.13 x 12.13 x 4.36 [308 x 308 x 111]  |
| <b>WA121206GSC</b>                | \$95.00  |  | 12.13 x 12.13 x 6.36 [308 x 308 x 162]  |
| <b>WA121606GSC</b>                | \$100.00 |  | 12.13 x 16.13 x 6.36 [308 x 410 x 162]  |
| <b>WA121608GSC</b>                | \$103.00 |  | 12.13 x 16.13 x 8.36 [308 x 410 x 212]  |
| <b>WA161606GSC</b>                | \$107.00 |  | 16.13 x 16.13 x 6.36 [410 x 410 x 162]  |
| <b>WA161608GSC</b>                | \$111.00 |  | 16.13 x 16.13 x 8.36 [410 x 410 x 212]  |
| <b>WA181806GSC</b>                | \$112.00 |  | 18.13 x 18.13 x 6.36 [461 x 461 x 162]  |
| <b>WA202008GSC</b>                | \$174.00 |  | 20.13 x 20.13 x 8.36 [511 x 511 x 212]  |
| <b>WA202408GSC</b>                | \$197.00 | 20.13 x 24.13 x 8.36 [511 x 613 x 212] |   |
| <b>WA242408GSC</b>                | \$224.00 | 24.13 x 24.13 x 8.36 [613 x 613 x 212] |   |
| <b>WA303012GSC</b>                | \$530.00 | 12/12                                  | 30.25 x 30.25 x 12.41 [768 x 768 x 315] |
| <b>WA363612GSC</b>                | \$547.00 |  | 36.25 x 36.25 x 12.41 [921 x 921 x 315] |

**Notes: Subpanels must be ordered separately. Dimensions in inches [millimeters].**

# NEMA 3 and 4 Gasketed Screw Cover Galvanized Steel



## Application

Designed for use as a wiring box, junction box, pull box, and terminal box in many indoor or outdoor applications where dust or moisture is a problem.

## Construction

- Bodies and covers fabricated from G-90 grade galvanized steel.
- Seams are continuously welded and ground smooth
- Cover contains closed cell oil resistant neoprene gasket
- Enclosure comes with stainless steel cover screws which thread into sealed wells to prevent liquid, dust, etc., from entering into the enclosure through the screw holes
- Ground stud located in door
- Galvanized box welded corners protected by zinc-rich coating
- No holes, knockouts, or rear mounting holes

## Finish

- G-90 pregalvanized steel

## Listings

- UL50, Types 3 & 4 [UL File E23553]
- NEMA/EEMAC Types 3 & 4
- CSA Certified Types 3 & 4 [CSA File LL66078]



### Enclosure Shipping Schedule

1 - 7 days      1 - 10 days      1 - 15 days

Color indicates shipping lead time in business days.

| NEMA 3 and 4 Gasketed Screw Cover - Galvanized Steel |          |                       |   |
|--|----------|-----------------------|---|
| Galvanized   | Price    | Body/Door Steel Gauge | Enclosure Size HxWxD                    |
| WA060604GSCG   | \$47.50  | 14/14                 | 6.13 x 6.13 x 4.40 [156 x 156 x 112]    |
| WA060606GSCG   | \$48.00  |                       | 6.13 x 6.13 x 6.40 [156 x 156 x 163]    |
| WA060804GSCG   | \$50.00  |                       | 6.13 x 8.13 x 4.40 [156 x 207 x 112]    |
| WA060806GSCG   | \$53.00  |                       | 6.13 x 8.13 x 6.40 [156 x 207 x 163]    |
| WA080804GSCG   | \$58.00  |                       | 8.13 x 8.13 x 4.40 [207 x 207 x 112]    |
| WA080806GSCG   | \$61.00  |                       | 8.13 x 8.13 x 6.40 [207 x 207 x 163]    |
| WA081004GSCG   | \$63.00  |                       | 8.13 x 10.13 x 4.40 [207 x 257 x 112]   |
| WA101004GSCG   | \$69.00  |                       | 10.13 x 10.13 x 4.40 [257 x 257 x 112]  |
| WA101006GSCG   | \$77.00  |                       | 10.13 x 10.13 x 6.40 [257 x 257 x 163]  |
| WA101206GSCG   | \$87.00  |                       | 10.13 x 12.13 x 6.40 [257 x 308 x 163]  |
| WA121204GSCG   | \$91.00  | 14/14                 | 12.13 x 12.13 x 4.40 [308 x 308 x 112]  |
| WA121206GSCG   | \$96.00  |                       | 12.13 x 12.13 x 6.40 [308 x 308 x 163]  |
| WA121606GSCG   | \$100.00 |                       | 12.13 x 16.13 x 6.40 [308 x 410 x 163]  |
| WA121608GSCG   | \$103.00 |                       | 12.13 x 16.13 x 8.40 [308 x 410 x 213]  |
| WA161606GSCG   | \$107.00 |                       | 16.13 x 16.13 x 6.40 [410 x 410 x 163]  |
| WA161608GSCG   | \$112.00 |                       | 16.13 x 16.13 x 8.40 [410 x 410 x 213]  |
| WA181806GSCG   | \$112.00 |                       | 18.13 x 18.13 x 6.40 [461 x 461 x 163]  |
| WA202008GSCG   | \$173.00 |                       | 20.13 x 20.13 x 8.40 [511 x 511 x 213]  |
| WA202408GSCG   | \$196.00 |                       | 20.13 x 24.13 x 8.40 [511 x 613 x 213]  |
| WA242408GSCG   | \$223.00 |                       | 24.12 x 24.13 x 8.40 [613 x 613 x 213]  |
| WA303012GSCG   | \$530.00 | 12/12                 | 30.25 x 30.25 x 12.41 [768 x 768 x 315] |
| WA363612GSCG   | \$547.00 |                       | 36.25 x 36.25 x 12.41 [921 x 921 x 315] |

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].

# NEMA 3, 4 and 4X Gasketed Screw Cover Stainless Steel



## Application

Designed for use as a wiring box, junction box, pull box, and terminal box in many indoor or outdoor applications where dust or moisture is a problem.

## Construction

- Bodies and covers fabricated from 304 stainless steel.
- Seams are continuously welded and ground smooth
- Cover contains closed cell oil resistant neoprene gasket
- Enclosure comes with stainless steel cover screws which thread into sealed wells to prevent liquid, dust, etc., from entering into the box through the screw holes
- Ground stud located in door
- No holes, knockouts, or rear mounting holes

## Finish

- Cover and outside of enclosure have #3 intermediate polished finish

## Listings

- UL50, Type 3, 4 & 4X [UL File E23553]
- CSA Certified Types 3 & 4 [CSA File LL66078]
- NEMA/EEMAC Type 3, 4 & 4X



| Enclosure Shipping Schedule                          |             |
|--|-------------|
| 1 - 10 days  | 1 - 15 days |
| Color indicates shipping lead time in business days. |             |


| NEMA 3, 4 and 4X Gasketed Screw Cover - Stainless Steel |          |  |   |
|---|----------|--|---|
| Stainless Steel   | Price    | Body/Door Steel Gauge                  | Enclosure Size HxWxD                    |
| WA060604GSCSS   | \$96.00  | 14/14                                  | 6.13 x 6.13 x 4.32 [156 x 156 x 110]    |
| WA060606GSCSS   | \$109.00 |  | 6.13 x 6.13 x 6.32 [156 x 156 x 161]    |
| WA060804GSCSS   | \$104.00 |  | 6.13 x 8.13 x 4.32 [156 x 207 x 110]    |
| WA060806GSCSS   | \$117.00 |  | 6.13 x 8.13 x 6.32 [156 x 207 x 161]    |
| WA080804GSCSS   | \$109.00 |  | 8.13 x 8.13 x 4.32 [207 x 207 x 110]    |
| WA080806GSCSS   | \$122.00 |  | 8.13 x 8.13 x 6.32 [207 x 207 x 161]    |
| WA081004GSCSS   | \$114.00 |  | 8.13 x 10.13 x 4.32 [2037 x 257 x 110]  |
| WA101004GSCSS   | \$118.00 |  | 10.13 x 10.13 x 4.32 [257 x 257 x 110]  |
| WA101006GSCSS   | \$134.00 |  | 10.13 x 10.13 x 6.32 [257 x 257 x 161]  |
| WA101206GSCSS   | \$139.00 |  | 10.13 x 12.13 x 6.32 [257 x 308 x 161]  |
| WA121204GSCSS   | \$129.00 |  | 12.13 x 12.13 x 4.32 [308 x 308 x 110]  |
| WA121206GSCSS   | \$144.00 |  | 12.13 x 12.13 x 6.32 [308 x 308 x 161]  |
| WA121606GSCSS   | \$163.00 |  | 12.13 x 16.13 x 6.32 [308 x 410 x 161]  |
| WA121608GSCSS   | \$206.00 |  | 12.13 x 16.13 x 8.32 [308 x 410 x 211]  |
| WA161606GSCSS   | \$216.00 |  | 16.13 x 16.13 x 6.32 [410 x 410 x 161]  |
| WA161608GSCSS   | \$237.00 |  | 16.13 x 16.13 x 8.32 [410 x 410 x 211]  |
| WA181806GSCSS   | \$231.00 |  | 18.13 x 18.13 x 6.32 [461 x 461 x 161]  |
| WA202008GSCSS   | \$291.00 |  | 20.13 x 20.13 x 8.32 [511 x 511 x 211]  |
| WA202408GSCSS   | \$299.00 |  | 20.13 x 24.13 x 8.32 [511 x 613 x 211]  |
| WA242406GSCSS   | \$296.00 |  | 24.12 x 24.13 x 6.32 [613 x 613 x 161]  |
| WA242408GSCSS   | \$330.00 | 24.12 x 24.13 x 8.32 [613 x 613 x 211] |   |
| WA303012GSCSS   | \$769.00 | 12/12                                  | 30.25 x 30.25 x 12.35 [768 x 768 x 314] |
| WA363612GSCSS   | \$949.00 |  | 36.25 x 36.25 x 12.35 [921 x 921 x 314] |

**Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].**

# NEMA 3, 4 and 4X Gasketed Screw Cover ANSI 61 Powder-Coated Steel, Galvanized Steel, and Stainless Steel



## Dimensions

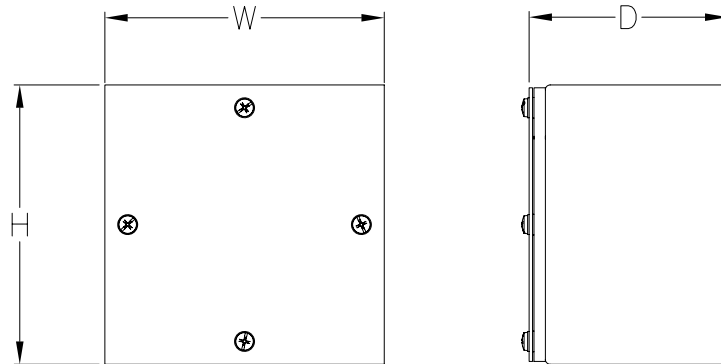

*See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.*