


# Ultimate Series NEMA 3R, 4, 12 and 13 Single-Door Wall Mount with Removable Gland Plate

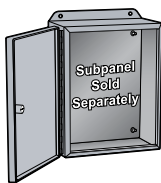

**N412121206CGP**



## Applications

Designed to house and protect electrical and electronic components from harsh, dirty environments. Features a removable gland plate on the bottom of the enclosure. The fully gasketed plate can be removed for easy drilling and hole tapping without disturbing the integrity of the enclosure. For use in installations where dust, dirt, water or other contaminants are present. Streamlined styling, flush latching, and an attractive, durable finish complement any high-tech electronic equipment. Removable, interchangeable doors feature concealed hinges. 1/4-turn semi-flush latch holds door securely closed.

## Construction

- Bodies, doors and gland plates fabricated from carbon steel
- Polyurethane poured-in-place gasket
- Collar studs provided for mounting optional subpanels

- Grounding provisions provided
- Continuous welded seams
- Concealed hinges
- Optional subpanels must be ordered separately
- Mounting holes in rear of enclosure body
- 1/4-turn semi-flush latch
- [Uses N41214 series latches](#)

## Finish

- ANSI 61 gray light-textured polyester powder coat, interior and exterior

## Listings

- cULus File E64791
- UL 508A, Type 3R, 4, 12, and 13
- Meets NEMA/EEMAC Type 3R, 4, 12 and 13 requirements
- N412MFK mounting feet are required to maintain UL external mounting requirements



FOR CURRENT LISTINGS, PLEASE SEE WWW.AUTOMATIONDIRECT.COM

Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.


Ultimate Series NEMA 3R, 4, 12 and 13 Single-Door Wall Mount with Removable Gland Plate						
Part Number	Price	Enclosure Size HxWxD	Painted Steel Subpanel	Galvanized Subpanel	304 Stainless Steel	Swing-Out Panel
N412121206CGP	\$230.00	12.20 x 12.00 x 6.92 [310 x 305 x 176]	NP1212C	NP1212CG	-	HFWNSP1212C
N412161206CGP	\$245.00	16.20 x 12.00 x 6.92 [411 x 305 x 176]	NP1612C	NP1612CG	NP1612SSC	HFWNSP1612C
N412161606CGP	\$264.00	16.20 x 16.00 x 6.92 [411 x 406 x 176]	NP1616C	NP1616CG	NP1616SSC	HFWNSP1616C
N412161608CGP	\$278.00	16.20 x 16.00 x 8.92 [411 x 406 x 227]	NP1616C	NP1616CG	NP1616SSC	HFWNSP1616C
N412201606CGP	\$283.00	20.20 x 16.00 x 6.92 [513 x 406 x 176]	NP2016C	NP2016CG	NP2016SSC	HFWNSP2016C
N412201608CGP	\$298.00	20.20 x 16.00 x 8.92 [513 x 406 x 227]	NP2016C	NP2016CG	NP2016SSC	HFWNSP2016C
N412202008CGP	\$323.00	20.20 x 20.00 x 8.92 [513 x 508 x 227]	NP2020C	NP2020CG	NP2020SSC	HFWNSP2020C
N412242408CGP	\$374.00	24.20 x 24.00 x 8.92 [615 x 610 x 227]	NP2424C	NP2424CG	NP2424SSC	HFWNSP2424C
N412242410CGP	\$389.00	24.20 x 24.00 x 10.92 [615 x 610 x 277]	NP2424C	NP2424CG	NP2424SSC	HFWNSP2424C
N412242412CGP	\$416.00	24.20 x 24.00 x 12.92 [615 x 610 x 328]	NP2424C	NP2424CG	NP2424SSC	HFWNSP2424C
N412302408CGP	\$416.00	30.20 x 24.00 x 8.92 [767 x 610 x 227]	NP2424C	NP3024CG	NP3024SSC	HFWNSP3024C
N412302410CGP	\$432.00	30.20 x 24.00 x 10.92 [767 x 610 x 277]	NP3024C	NP3024CG	NP3024SSC	HFWNSP3024C
N412302412CGP	\$462.00	30.20 x 24.00 x 12.92 [767 x 610 x 328]	NP3024C	NP3024CG	NP3024SSC	HFWNSP3024C
N412362408CGP	\$457.00	36.20 x 24.00 x 8.92 [919 x 610 x 227]	NP3024C	NP3624CG	NP3624SSC	HFWNSP3624C
N412362410CGP	\$480.00	36.20 x 24.00 x 10.92 [919 x 610 x 277]	NP3624C	NP3624CG	NP3624SSC	HFWNSP3624C
N412362412CGP	\$523.00	36.20 x 24.00 x 12.92 [919 x 610 x 328]	NP3624C	NP3624CG	NP3624SSC	HFWNSP3624C
N412363012CGP	\$570.00	36.20 x 30.00 x 12.92 [919 x 762 x 328]	NP3630C	NP3630CG	NP3630SSC	HFWNSP3630C
N412363612CGP	\$632.00	36.20 x 36.00 x 12.92 [919 x 914 x 328]	NP3636C	NP3630CG	NP3636SSC	HFWNSP3636C

Note: Subpanels must be ordered separately.  
 Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawings.

# Ultimate Series NEMA 3R, 4, 12 and 13 Single-Door Wall Mount with Removable Gland Plate



## Dimensions

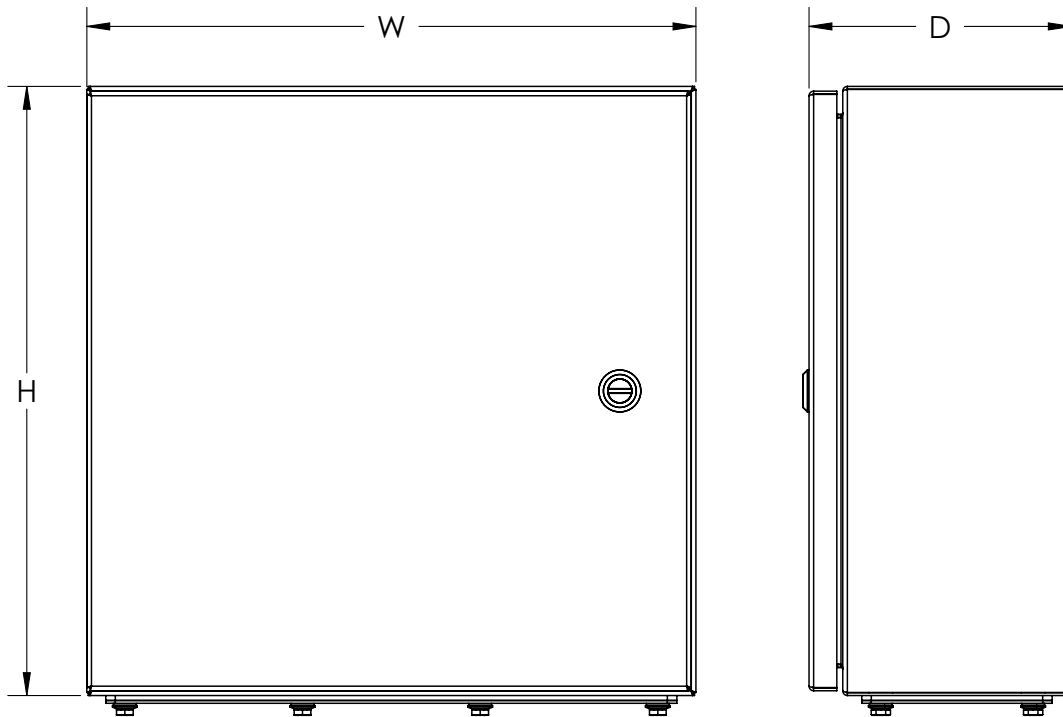

*See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.*