


Ultimate Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Double-Door Wall Mount

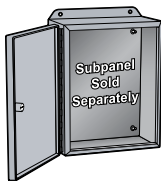

N412D243608SSC



Application

Removable, interchangeable doors feature concealed hinges. Removable center post provides easy access to components and for installing subpanels. Designed for applications where dirt, dust, oil or water are present.

Construction

- 304 stainless steel construction
- Continuous welded seams
- Polyurethane poured-in-place gasket
- Concealed hinges
- Removable center post
- Grounding studs welded to doors and body
- Collar studs for mounting optional subpanels
- 3-point keylocking/padlocking handle included
- [Uses WAL4 series handles](#)

Finish

- #3 intermediate polished

Listings

- NEMA 3R, 4, 4X, 12, and 13
- UL508A, Type 3R, 4, 4X, 12 and 13
- cULus File E64791
- IEC 60529, IP66
- N412MFKSS mounting feet are required to maintain UL external mounting requirements



FOR CURRENT LISTINGS, PLEASE SEE WWW.AUTOMATIONDIRECT.COM

Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 -10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.


Ultimate Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Double-Door Wall Mount					
Part Number	Price	Enclosure Size HxWxD	Painted Steel Subpanel	Galvanized Subpanel	304 Stainless Steel
N412D243608SSC	\$2,618.00	24.00 x 36.00 x 8.92 [610 x 914 x 227]	NP3624C	NP3624CG	NP3624SSC
N412D244208SSC	\$2,662.00	24.00 x 42.00 x 8.92 [610 x 1067 x 227]	NP4224C	-	-
N412D244808SSC	\$2,706.00	24.00 x 48.00 x 8.92 [610 x 1219 x 227]	NP4824C	NP4824CG	-
N412D304210SSC	\$2,773.00	30.00 x 42.00 x 10.92 [762 x 1067 x 277]	NP4230C	-	-
N412D304810SSC	\$2,828.00	30.00 x 48.00 x 10.92 [762 x 1219 x 277]	NP4830C	-	-
N412D306010SSC	\$2,937.00	30.00 x 60.00 x 10.92 [762 x 1524 x 277]	NP6030C	-	-
N412D364212SSC	\$2,915.00	36.00 x 42.00 x 12.92 [914 x 1067 x 328]	NP4236C	NP4236CG	NP4236SSC
N412D364812SSC	\$2,980.00	36.00 x 48.00 x 12.92 [914 x 1219 x 328]	NP4836C	NP4836CG	NP4836SSC
N412D366012SSC	\$3,111.00	36.00 x 60.00 x 12.92 [914 x 1524 x 328]	NP6036C	NP6036CG	NP6036SSC
N412D424212SSC	\$3,014.00	42.00 x 42.00 x 12.92 [1067 x 1067 x 328]	NP4242C	-	-
N412D424812SSC	\$3,170.00	42.00 x 48.00 x 12.92 [1067 x 1219 x 328]	NP4842C	-	-
N412D426012SSC	\$3,329.00	42.00 x 60.00 x 12.92 [1067 x 1524 x 328]	NP6042C	-	-
N412D484812SSC	\$3,267.00	48.00 x 48.00 x 12.92 [1219 x 1219 x 328]	NP4848C	-	-

Note: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.

Ultimate Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Double-Door Wall Mount



Dimensions

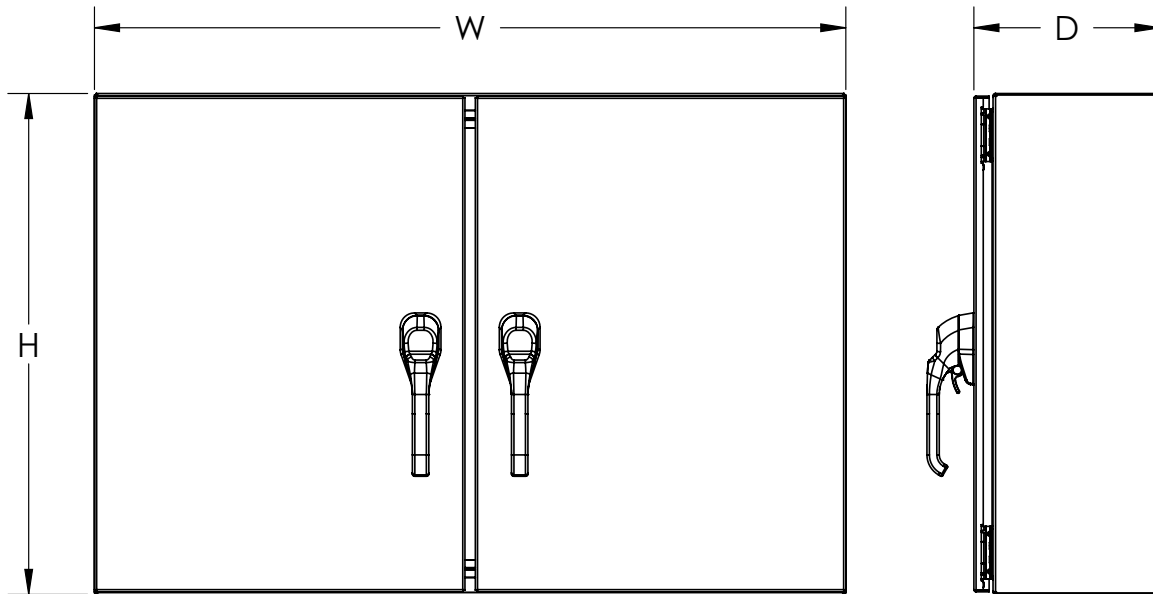

See our website: www.AutomationDirect.com for complete engineering drawings.