


Ultimate Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Two-Door Wall-Mount

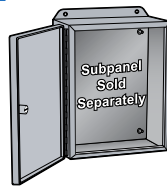

N412D244208SSC



Application

Removable, interchangeable doors feature concealed hinges. Removable center post provides easy access to components and for installing subpanels. Designed for applications where dirt, dust, oil or water are present.

Construction

304 stainless steel Construction

- Continuous welded seams
- Polyurethane poured-in-place gasket
- Concealed hinges
- Removable center post
- Grounding studs welded to doors and body
- Collar studs for mounting optional subpanels
- 3-point keylocking/padlocking handle included
- Uses WAL4 series handles

Finish

- #3 intermediate polished

Listings

- NEMA 3R, 4, 4X, 12, and 13
- UL508A, Type 3R, 4, 4X, 12, and 13
- cULus File E64791
- IEC 60529, IP66
- N412MFKSS mounting feet are required to maintain UL external mounting requirements



Note: For current listings, please see www.automationdirect.com

Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

Ultimate Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Two-Door Wall-Mount

Part Number	Price	Enclosure Size HxWxD	Painted Steel Subpanel	304 Stainless Steel
N412D244208SSC	\$3,512.00	24.00 x 42.00 x 8.92 [610 x 1067 x 227]	NP4224C	—
N412D244808SSC	\$3,570.00	24.00 x 48.00 x 8.92 [610 x 1219 x 227]	NP4824C	—
N412D304210SSC	\$3,378.00	30.00 x 42.00 x 10.92 [762 x 1067 x 277]	NP4230C	—
N412D304810SSC	\$3,553.00	30.00 x 48.00 x 10.92 [762 x 1219 x 277]	NP4830C	—
N412D306010SSC	\$3,691.00	30.00 x 60.00 x 10.92 [762 x 1524 x 277]	NP6030C	—
N412D364212SSC	\$3,584.00	36.00 x 42.00 x 12.92 [914 x 1067 x 328]	NP4236C	NP4236SSC
N412D364812SSC	\$3,745.00	36.00 x 48.00 x 12.92 [914 x 1219 x 328]	NP4836C	NP4836SSC
N412D424212SSC	\$3,672.00	42.00 x 42.00 x 12.92 [1067 x 1067 x 328]	NP4242C	—
N412D424812SSC	\$3,984.00	42.00 x 48.00 x 12.92 [1067 x 1219 x 328]	NP4842C	—
N412D426012SSC	\$4,184.00	42.00 x 60.00 x 12.92 [1067 x 1524 x 328]	NP6042C	—
N412D484812SSC	\$3,799.00	48.00 x 48.00 x 12.92 [1219 x 1219 x 328]	NP4848C	—

Note: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.

Ultimate Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Two-Door Wall-Mount



Dimensions

