


# KwikHinge™ Series NEMA 3R, 4, 4X, and 12 Freestanding Stainless Steel Single- and Two-Door

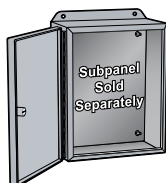

WRD603624SSFSN4



## Application

Designed to house and protect electrical and electronic controls, components and instruments in typical industrial environments. Enclosures protect equipment from dust, dirt, and water. These enclosures are used in machine tool applications for housing motor starters, drives, contactors, PLCs, as well as a wide variety of other electrical and electronic equipment. The addition of 19 in [483 mm] rack-mounted accessories make these enclosures ideal for providing rugged protection for sensitive rack-mounted components in harsh industrial environments.

## Construction

- Bodies and doors fabricated from stainless steel
- KwikHinge™ heavy-duty 316 stainless steel sliding hinge pins
- Continuous welded seams, ground smooth
- Doors opens 170°
- Doors sealed with Polyurethane poured-in-place gasket
- Heavy-duty removable lifting eyes
- Grounding provisions provided
- Optional subpanels must be ordered separately
- Uni-strut mounting channels welded horizontally to interior body sides to allow subpanels to be positioned in enclosure. Optional swing, half, full panels and rack angles can be mounted anywhere along the uni-strut channel
- 3-point keylocking/padlocking handle included
- Uses WAL4 series handles and WAEMK4A replacement key

## Finish

- #3 intermediate polished

## Listings

- cULus File E64791
- IEC 60529, IP66
- UL 508A, 3R, 4, 4X, and 12
- Meets NEMA/EEMAC 3R, 4, 4X, and 12 requirements



Note: For current listings, please see [www.automationdirect.com](http://www.automationdirect.com)



# KwikHinge™ Series NEMA 3R, 4, 4X, and 12 Freestanding Stainless Steel Single- and Two-Door



## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.


## KwikHinge™ Series NEMA 3R, 4, 4X, and 12 Freestanding Stainless Steel Single- and Two-Door

Part Number	Price	Enclosure Size HxWxD	Number of Hinges
<i>Single-Door</i>			
<b>WRD603624SSFSN4</b>	\$7,765.00	60.06 x 36.06 x 24.06 [1526 x 916 x 611]	3
<b>WRD722418SSFSN4</b>	\$6,494.00	72.06 x 24.06 x 18.06 [1830 x 611 x 459]	4
<b>WRD723024SSFSN4</b>	\$7,951.00	72.06 x 30.06 x 24.06 [1830 x 764 x 611]	4
<b>WRD723618SSFSN4</b>	\$7,858.00	72.06 x 36.06 x 18.06 [1830 x 916 x 459]	4
<b>WRD723630SSFSN4</b>	\$9,495.00	72.06 x 36.06 x 30.06 [1830 x 916 x 764]	4
<b>WRD902420SSFSN4</b>	\$7,738.00	90.06 x 24.06 x 20.06 [2288 x 611 x 510]	5
<b>WRD903636SSFSN4</b>	\$11,966.00	90.06 x 36.06 x 36.06 [2288 x 916 x 916]	5
Note: Subpanels must be ordered separately. Dimensions in inches [millimeters]. Letters in table correspond to letters on dimensional drawings.			

# KwikHinge™ Series NEMA 3R, 4, 4X, and 12 Freestanding Stainless Steel Single- and Two-Door



## Dimensions

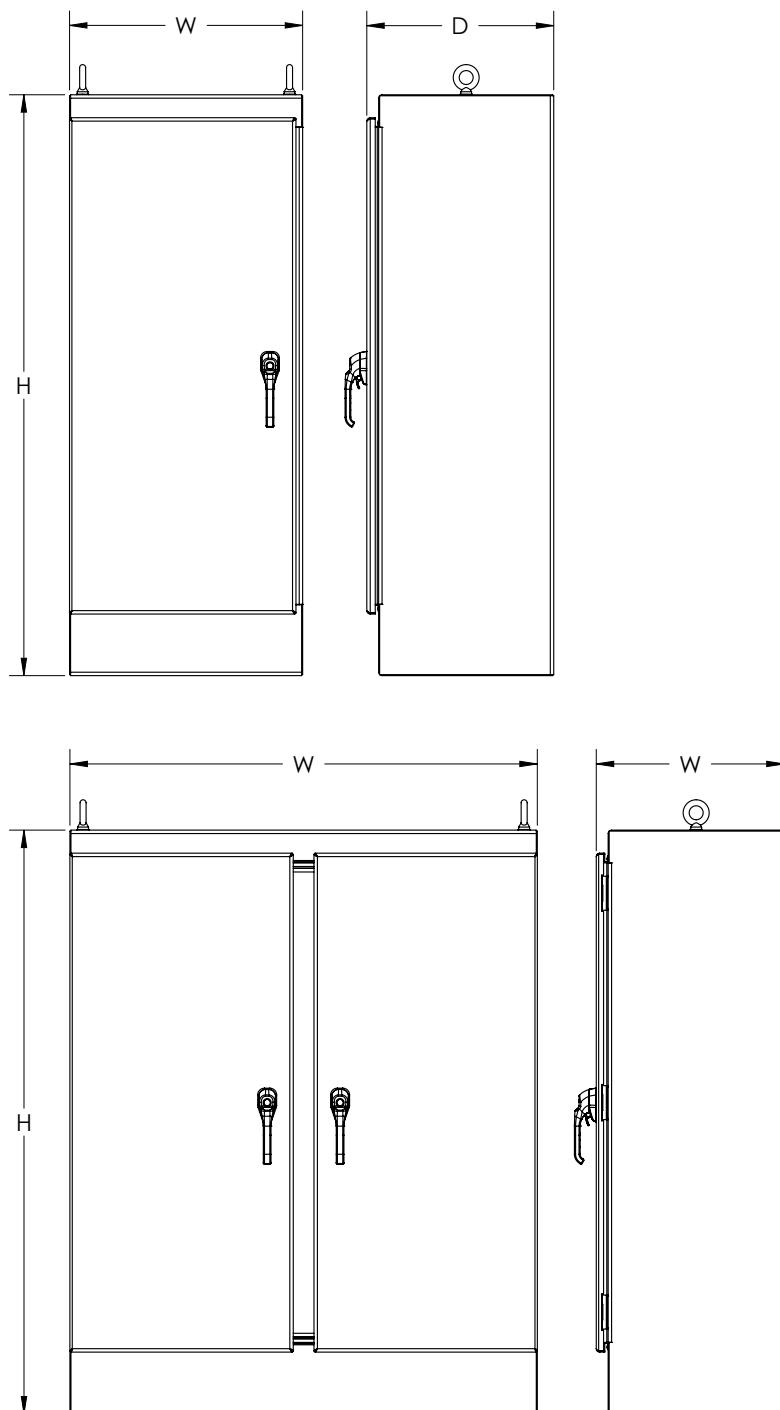

# KwikHinge™ Series NEMA 3R, 4, 4X, and 12 Freestanding Stainless Steel Single- and Two-Door



## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## Standard Subpanels

Enclosures	Full Height Subpanels		Half Height Subpanels	
	Painted Steel	Galvanized	Painted Steel	Galvanized
WRD603624SSFSN4	<u>WA60P36F1</u>	<u>WA60P36F1G</u>	<u>WA60P36F2</u>	<u>WA60P36F2G</u>
WRD722418SSFSN4	<u>WA72P24F1</u>	<u>WA72P24F1G</u>	—	—
WRD723024SSFSN4	<u>WA72P30F1</u>	<u>WA72P30F1G</u>	—	—
WRD723618SSFSN4	<u>WA72P36F1</u>	<u>WA72P36F1G</u>	—	—
WRD723630SSFSN4	<u>WA72P36F1</u>	<u>WA72P36F1G</u>	—	—
WRD902420SSFSN4	<u>WA90P24F1</u>	<u>WA90P24F1G</u>	—	—
WRD903636SSFSN4	<u>WA90P36F1</u>	<u>WA90P36F1G</u>	—	—

# Side-Mount Panels and Swing-Out Racks for KwikHinge™ Series Freestanding Stainless Steel Single-Door



## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## Side-Mount Panels

Enclosures	Side-Mount Panels	
	Painted Steel	
<b>WRD722418SSFSN4</b>	<b>WA72SMP14</b>	
<b>WRD723024SSFSN4</b>	<b>WA72SMP14</b>	<b>WA72SMP20</b>
<b>WRD723618SSFSN4</b>	<b>WA72SMP14</b>	
<b>WRD723630SSFSN4</b>	<b>WA72SMP14</b>	<b>WA72SMP20</b>