

# Ultimate Series NEMA 4, 4x, 12 and 13 Stainless Steel Single-Door Wall Mount



## Applications

The Wiegmann N412-SS stainless steel series, with its streamlined design, is a perfect fit for mounting electrical or high-tech electronic equipment in a variety of indoor and outdoor settings. It is typically used in the following areas where corrosion-resistant protection is needed: food processing plants, pharmaceutical manufacturing facilities, petrochemical plants, pulp and paper processing, and waste water treatment facilities.



## Construction

- Bodies and doors fabricated from 14 or 16 gauge type 304 or 316L stainless steel
- Doors are sealed with poured-in-place polyurethane gasket
- Concealed hinges
- Increased tub openings to accommodate larger size [optional] subpanels
- Collar studs for mounting optional subpanels
- Grounding provisions provided
- Optional subpanels must be ordered separately
- Swing-out panel kits WAJCDFK and WANADFK will not work with these enclosures.
- Doors are interchangeable and easily removable [open to 90° to remove door]
- 1/4 turn semi-flush oil tight latches are supplied to hold door securely closed
- Mounting holes in rear of enclosure
- Optional N412MFKSS mounting foot kit is required to maintain the NEMA Types 4, 4X, 12 and 13 ratings. Mounting foot kit must be ordered separately.
- [Uses N41214 SS series latches](#)

## Finish

- All exterior surfaces have a smooth grained finish
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized and stainless subpanels are a conductive finish [unpainted]

## Listings

- UL 508, Types 4, 4X, 12, and 13 [UL file E64791]
- Meets NEMA/EEMAC Types 4, 4X, 12, and 13 requirements
- Wall mounting brackets required to maintain UL/CSA external mounting requirements



FOR CURRENT LISTINGS, PLEASE SEE [WWW.AUTOMATIONDIRECT.COM](http://WWW.AUTOMATIONDIRECT.COM)

Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Ultimate Series NEMA 4, 4x, 12 and 13 Stainless Steel Single-Door Wall Mount									
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Steel Gauge	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel	Swing-Out Panel
N412121206SSC	\$472.00	N412121206SSAC	\$803.00	12.00 x 12.00 x 6.92 [305 x 305 x 176]	16	NP1212C	-	NP1212CG	HFWNSP1212C
N412161206SSC	\$517.00	N412161206SSAC	\$847.00	16.00 x 12.00 x 6.92 [406 x 305 x 176]	16	NP1612C	NP1612SSC	NP1612CG	HFWNSP1612C
N412161208SSC	\$545.00	N412161208SSAC	\$998.00	16.00 x 12.00 x 8.92 [406 x 305 x 227]	16	NP1612C	NP1612SSC	NP1612CG	HFWNSP1612C
N412161210SSC	\$567.00	N412161210SSAC	\$879.00	16.00 x 12.00 x 10.92 [406 x 305 x 277]	16	NP1612C	NP1612SSC	NP1612CG	HFWNSP1612C
N412161606SSC	\$573.00	N412161606SSAC	\$1,030.00	16.00 x 16.00 x 6.92 [406 x 406 x 176]	16	NP1616C	NP1616SSC	NP1616CG	HFWNSP1616C
N412161608SSC	\$621.00	N412161608SSAC	\$1,212.00	16.00 x 16.00 x 8.92 [406 x 406 x 227]	16	NP1616C	NP1616SSC	NP1616CG	HFWNSP1616C
N412161610SSC	\$646.00	N412161610SSAC	\$1,001.00	16.00 x 16.00 x 10.92 [406 x 406 x 277]	16	NP1616C	NP1616SSC	NP1616CG	HFWNSP1616C
N412162008SSC	\$694.00	N412162008SSAC	\$1,106.00	16.00 x 20.00 x 8.92 [406 x 508 x 227]	16	NP2016C	NP2016SSC	NP2016CG	HFWNSP1620C
N412162010SSC	\$722.00	N412162010SSAC	\$1,118.00	16.00 x 20.00 x 10.92 [406 x 508 x 277]	16	NP2016C	NP2016SSC	NP2016CG	HFWNSP1620C
N412201606SSC	\$647.00	N412201606SSAC	\$963.00	20.00 x 16.00 x 6.92 [508 x 406 x 176]	16	NP2016C	NP2016SSC	NP2016CG	HFWNSP2016C

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

# Ultimate Series NEMA 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount



Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Ultimate Series NEMA 4, 4x, 12 and 13 Stainless Steel Single-Door Wall Mount – [cont.]									
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Steel Gauge	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel	Swing-Out Panel
<b>N412201608SSC</b>	\$674.00	<b>N412201608SSAC</b>	\$1,106.00	20.00 x 16.00 x 8.92 [508 x 406 x 227]	16	<b>NP2016C</b>	<b>NP2016SSC</b>	<b>NP2016CG</b>	<b>HFWNSP2016C</b>
<b>N412201610SSC</b>	\$701.00	<b>N412201610SSAC</b>	\$1,086.00	20.00 x 16.00 x 10.92 [508 x 406 x 277]	16	<b>NP2016C</b>	<b>NP2016SSC</b>	<b>NP2016CG</b>	<b>HFWNSP2016C</b>
<b>N412202006SSC</b>	\$715.00	<b>N412202006SSAC</b>	\$1,028.00	20.00 x 20.00 x 6.92 [508 x 508 x 176]	16	<b>NP2020C</b>	<b>NP2020SSC</b>	<b>NP2020CG</b>	<b>HFWNSP2020C</b>
<b>N412202008SSC</b>	\$746.00	<b>N412202008SSAC</b>	\$1,289.00	20.00 x 20.00 x 8.92 [508 x 508 x 227]	16	<b>NP2020C</b>	<b>NP2020SSC</b>	<b>NP2020CG</b>	<b>HFWNSP2020C</b>
<b>N412202010SSC</b>	\$783.00	<b>N412202010SSAC</b>	\$1,213.00	20.00 x 20.00 x 10.92 [508 x 508 x 277]	16	<b>NP2020C</b>	<b>NP2020SSC</b>	<b>NP2020CG</b>	<b>HFWNSP2020C</b>
<b>N412202012SSC</b>	\$850.00	<b>N412202012SSAC</b>	\$1,525.00	20.00 x 20.00 x 12.92 [508 x 508 x 328]	16	<b>NP2020C</b>	<b>NP2020SSC</b>	<b>NP2020CG</b>	<b>HFWNSP2020C</b>
<b>N412241608SSC</b>	\$735.00	<b>N412241608SSAC</b>	\$1,249.00	24.00 x 16.00 x 8.92 [610 x 406 x 227]	16	<b>NP2416C</b>	<b>NP2416SSC</b>	<b>NP2416CG</b>	<b>HFWNSP2416C</b>
<b>N412241610SSC</b>	\$772.00	<b>N412241610SSAC</b>	\$1,196.00	24.00 x 16.00 x 10.92 [610 x 406 x 277]	16	<b>NP2416C</b>	<b>NP2416SSC</b>	<b>NP2416CG</b>	<b>HFWNSP2416C</b>
<b>N412242008SSC</b>	\$816.00	<b>N412242008SSAC</b>	\$1,339.00	24.00 x 20.00 x 8.92 [610 x 508 x 227]	16	<b>NP2420C</b>	<b>NP2420SSC</b>	<b>NP2420CG</b>	<b>HFWNSP2420C</b>
<b>N412242010SSC</b>	\$857.00	<b>N412242010SSAC</b>	\$1,328.00	24.00 x 20.00 x 10.92 [610 x 508 x 277]	16	<b>NP2420C</b>	<b>NP2420SSC</b>	<b>NP2420CG</b>	<b>HFWNSP2420C</b>
<b>N412242408SSC</b>	\$898.00	<b>N412242408SSAC</b>	\$1,472.00	24.00 x 24.00 x 8.92 [610 x 610 x 227]	14	<b>NP2424C</b>	<b>NP2424SSC</b>	<b>NP2424CG</b>	<b>HFWNSP2424C</b>
<b>N412242410SSC</b>	\$970.00	<b>N412242410SSAC</b>	\$1,503.00	24.00 x 24.00 x 10.92 [610 x 610 x 277]	14	<b>NP2424C</b>	<b>NP2424SSC</b>	<b>NP2424CG</b>	<b>HFWNSP2424C</b>
<b>N412242412SSC</b>	\$1,070.00	<b>N412242412SSAC</b>	\$1,778.00	24.00 x 24.00 x 12.92 [610 x 610 x 328]	14	<b>NP2424C</b>	<b>NP2424SSC</b>	<b>NP2424CG</b>	<b>HFWNSP2424C</b>
<b>N412302408SSC</b>	\$1,021.00	<b>N412302408SSAC</b>	\$1,671.00	30.00 x 24.00 x 8.92 [762 x 610 x 227]	14	<b>NP3024C</b>	<b>NP3024SSC</b>	<b>NP3024CG</b>	<b>HFWNSP3024C</b>
<b>N412302410SSC</b>	\$1,092.00	<b>N412302410SSAC</b>	\$1,692.00	30.00 x 24.00 x 10.92 [762 x 610 x 277]	14	<b>NP3024C</b>	<b>NP3024SSC</b>	<b>NP3024CG</b>	<b>HFWNSP3024C</b>
<b>N412302412SSC</b>	\$1,168.00	<b>N412302412SSAC</b>	\$1,896.00	30.00 x 24.00 x 12.92 [762 x 610 x 328]	14	<b>NP3024C</b>	<b>NP3024SSC</b>	<b>NP3024CG</b>	<b>HFWNSP3024C</b>
<b>N412303008SSC</b>	\$1,199.00	<b>N412303008SSAC</b>	\$2,030.00	30.00 x 30.00 x 8.92 [762 x 762 x 227]	14	<b>NP3030C</b>	<b>NP3030SSC</b>	<b>NP3030CG</b>	<b>HFWNSP3030C</b>
<b>N412303010SSC</b>	\$1,283.00	<b>N412303010SSAC</b>	\$1,988.00	30.00 x 30.00 x 10.92 [762 x 762 x 277]	14	<b>NP3030C</b>	<b>NP3030SSC</b>	<b>NP3030CG</b>	<b>HFWNSP3030C</b>
<b>N412362408SSC</b>	\$1,176.00	<b>N412362408SSAC</b>	\$1,973.00	36.00 x 24.00 x 8.92 [914 x 610 x 227]	14	<b>NP3624C</b>	<b>NP3624SSC</b>	<b>NP3624CG</b>	<b>HFWNSP3624C</b>
<b>N412362410SSC</b>	\$1,234.00	<b>N412362410SSAC</b>	\$1,913.00	36.00 x 24.00 x 10.92 [914 x 610 x 277]	14	<b>NP3624C</b>	<b>NP3624SSC</b>	<b>NP3624CG</b>	<b>HFWNSP3624C</b>

Notes: Subpanels must be ordered separately.  
 Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawings.

# Ultimate Series NEMA 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount




Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Ultimate Series NEMA 4, 4x, 12 and 13 Stainless Steel Single-Door Wall Mount – [cont.]									
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Steel Gauge	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel	Swing-Out Panel
<b>N412362412SSC</b>	\$1,280.00	<b>N412362412SSAC</b>	\$2,030.00	36.00 x 24.00 x 12.92 [914 x 610 x 328]	14	<b>NP3624C</b>	<b>NP3624SSC</b>	<b>NP3624CG</b>	<b>HFWNSP3624C</b>
<b>N412363008SSC</b>	\$1,348.00	<b>N412363008SSAC</b>	\$2,145.00	36.00 x 30.00 x 8.92 [914 x 762 x 227]	14	<b>NP3630C</b>	<b>NP3630SSC</b>	<b>NP3630CG</b>	<b>HFWNSP3630C</b>
<b>N412363010SSC</b>	\$1,443.00	<b>N412363010SSAC</b>	\$2,235.00	36.00 x 30.00 x 10.92 [914 x 762 x 277]	14	<b>NP3630C</b>	<b>NP3630SSC</b>	<b>NP3630CG</b>	<b>HFWNSP3630C</b>
<b>N412363012SSC</b>	\$1,530.00	<b>N412363012SSAC</b>	\$2,417.00	36.00 x 30.00 x 12.92 [914 x 762 x 328]	14	<b>NP3630C</b>	<b>NP3630SSC</b>	<b>NP3630CG</b>	<b>HFWNSP3630C</b>
<b>N412363610SSC</b>	\$1,544.00	<b>N412363610SSAC</b>	\$2,392.00	36.00 x 36.00 x 10.92 [914 x 914 x 277]	14	<b>NP3636C</b>	<b>NP3636SSC</b>	<b>NP3636CG</b>	<b>HFWNSP3636C</b>
<b>N412363612SSC</b>	\$1,660.00	<b>N412363612SSAC</b>	\$2,890.00	36.00 x 36.00 x 12.92 [914 x 914 x 328]	14	<b>NP3636C</b>	<b>NP3636SSC</b>	<b>NP3636CG</b>	<b>HFWNSP3636C</b>
<b>N412423610SSC</b>	\$1,732.00	<b>N412423610SSAC</b>	\$2,683.00	42.00 x 36.00 x 10.92 [1067 x 914 x 277]	14	<b>NP4236C</b>	<b>NP4236SSC</b>	<b>NP4236CG</b>	-
<b>N412423612SSC</b>	\$1,842.00	<b>N412423612SSAC</b>	\$3,201.00	42.00 x 36.00 x 12.92 [1067 x 914 x 328]	14	<b>NP4236C</b>	<b>NP4236SSC</b>	<b>NP4236CG</b>	-
<b>N412483610SSC</b>	\$1,884.00	<b>N412483610SSAC</b>	\$2,919.00	48.00 x 36.00 x 10.92 [1219 x 914 x 277]	14	<b>NP4836C</b>	<b>NP4836SSC</b>	<b>NP4836CG</b>	-
<b>N412483612SSC</b>	\$2,026.00	<b>N412483612SSAC</b>	\$3,526.00	48.00 x 36.00 x 12.92 [1219 x 914 x 328]	14	<b>NP4836C</b>	<b>NP4836SSC</b>	<b>NP4836CG</b>	-
<b>N412603610SSC</b>	\$2,133.00	<b>N412603610SSAC</b>	\$3,304.00	60.00 x 36.00 x 10.92 [1524 x 914 x 277]	14	<b>NP6036C</b>	<b>NP6036SSC</b>	<b>NP6036CG</b>	-
<b>N412603612SSC</b>	\$2,293.00	<b>N412603612SSAC</b>	\$4,162.00	60.00 x 36.00 x 12.92 [1524 x 914 x 328]	14	<b>NP6036C</b>	<b>NP6036SSC</b>	<b>NP6036CG</b>	-

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

## Dimensions

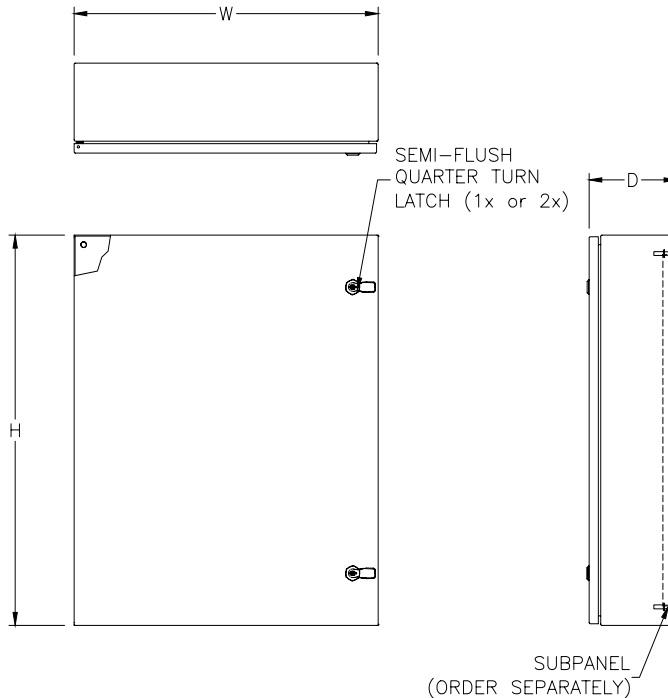

### NOTES:

- ENCLOSURES INCLUDE A 3-POINT LATCH WHEN H=40" OR MORE.
- TWO HINGES PROVIDED WHEN H=36". THREE HINGES PROVIDED WHEN H=36" OR GREATER. FOUR HINGES PROVIDED WHEN H=48" OR GREATER.
- ENCLOSURES SMALLER THAN 24"x24" ONLY HAVE ONE LATCH.

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Enclosure Subpanels



## Subpanels for Ultimate Series Wall Mount Enclosures


Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Subpanels for Ultimate Series Wall Mount Enclosures							
Painted Steel	Price	Galvanized	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size HxW
NP1212C	\$12.50	NP1212CG	\$10.50	-	-	12 x 12	10.20 x 10.20 [259 x 259]
NP1612C	\$13.50	NP1612CG	\$13.50	NP1612SSC	\$70.00	16 x 12	14.20 x 10.20 [361 x 259]
NP1616C	\$32.50	NP1616CG	\$32.50	NP1616SSC	\$85.00	16 x 16	14.20 x 14.20 [361 x 361]
NP2016C	\$39.00	NP2016CG	\$39.00	NP2016SSC	\$103.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
NP2020C	\$47.00	NP2020CG	\$47.00	NP2020SSC	\$133.00	20 x 20	18.20 x 18.20 [462 x 462]
NP2416C	\$45.00	NP2416CG	\$45.00	NP2416SSC	\$128.00	24 x 16	22.20 x 14.20 [564 x 361]
NP2420C	\$45.00	NP2420CG	\$61.00	NP2420SSC	\$162.00	24 x 20	22.20 x 18.20 [564 x 462]
NP2424C	\$70.00	NP2424CG	\$70.00	NP2424SSC	\$188.00	24 x 24	22.20 x 22.20 [564 x 564]
NP3020C	\$73.00	NP3020CG	\$73.00	-	-	30 x 20	28.20 x 18.20 [716 x 462]
NP3024C	\$84.00	NP3024CG	\$73.00	NP3024SSC	\$228.00	30 x 24	28.20 x 22.20 [716 x 564]
NP3030C	\$119.00	NP3030CG	\$119.00	NP3030SSC	\$337.00	30 x 30	28.20 x 28.20 [716 x 716]
NP3624C	\$101.00	NP3624CG	\$101.00	NP3624SSC	\$288.00	24 x 36 36 x 24	34.20 x 22.20 [869 x 564]
NP3630C	\$135.00	NP3630CG	\$135.00	NP3630SSC	\$357.00	36 x 30	34.20 x 28.20 [869 x 716]
NP3636C	\$158.00	NP3636CG	\$158.00	NP3636SSC	\$431.00	36 x 36	34.20 x 34.20 [869 x 869]
NP4224C	\$116.00	-	-	-	-	24 x 42	40.20  in x 22.20  in [1021 x 564]
NP4024C	\$121.00	NP4024CG	\$121.00	-	-	40 x 24	38.20 x 22.20 [970 x 564]
NP4242C	\$215.00	-	-	-	-	42 x 42	40.20  in x 40.20  in [1021 x 1021]
NP4230C	\$181.00	-	-	-	-	30 x 42 42 x 32	40.20 x 28.20 [1021 x 716]
NP4236C	\$181.00	NP4236CG	\$181.00	NP4236SSC	\$503.00	36 x 42 42 x 36	40.20 x 34.20 [1021 x 869]
NP4824C	\$131.00	NP4824CG	\$131.00	-	-	24 x 48 48 x 24	46.20 x 22.20 [1173 x 564]
NP4830C	\$173.00	-	-	-	-	30 x 48	46.20  in x 28.20  in [1173 x 716]
NP4842C	\$289.00	-	-	-	-	42 x 48	46.20  in x 40.20  in [1173 x 1021]
NP4836C	\$205.00	NP4836CG	\$205.00	NP4836SSC	\$545.00	36 x 48 48 x 36	46.20 x 34.20 [1173 x 869]
NP4848C	\$322.00	-	-	-	-	48 x 48	46.20  in x 46.20  in [1173 x 1173]
NP6030C	\$212.00	-	-	-	-	30 x 60	58.20  in x 28.20  in [1478 x 716]
NP6036C	\$252.00	NP6036CG	\$252.00	NP6036SSC	\$719.00	36 x 30 60 x 36	58.20 x 34.20 [1478 x 869]
NP6042C	\$299.00	-	-	-	-	42 x 60	58.20  in x 40.20  in [1478 x 1021]

Notes: Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawing.  
Disconnect enclosures will be up to 2 inches [51mm] wider than width dimensions in this table.

# Swing-Out Panels for Ultimate Series Enclosures

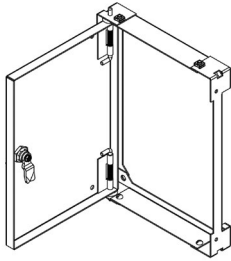

For N412 Ultimate Series Wall Mount Enclosures except N412-1PTC, -3PTC, -SS1PTC, -SS3PTC, -SSA1PTC, and -SSA3PTC

- Maximum swing 107 degrees
- Convenient access to sub enclosure is provided via 1/4 turn pull-tab
- On solid doors, the clearance from the swing panel face to the interior door face is 1-1/4", and 1" on window doors (when the door is closed)
- The kit includes the swing panel, brackets and hardware necessary for a tub flange install. Swing out panels meet Type 1 with enclosure door open
- Painted steel subpanels are painted white polyester powder over phosphated surfaces
- Fabricated from 1/4 gauge steel
- Mounting hardware is furnished with each panel

**Notes:** HFWNSPxxxxC swing-out panels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Swing-out panel HFWNSP1212C will not fit enclosures N41212126 or N412121206SS.

Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.


Swing-Out Panels for Ultimate Series Enclosures				
Part Number	Price	Panel Size CxE	Overall Dimensions HxW	Enclosure Nominal Size
HFWNSP1212C	\$103.00	9.75 x 9.75 [248 x 248]	10.50 x 10.62 [267 x 270]	12 x 12
HFWNSP1612C	\$107.00	13.75 x 9.75 [349 x 248]	14.50 x 10.62 [368 x 270]	16 x 12
HFWNSP1616C	\$113.00	13.75 x 13.75 [349 x 349]	14.50 x 14.62 [368 x 37]	16 x 16
HFWNSP1620C	\$119.00	13.75 x 17.75 [349 x 451]	14.50 x 18.62 [368 x 473]	16 x 20
HFWNSP2016C	\$119.00	17.75 x 13.75 [451 x 349]	18.50 x 14.62 [470 x 371]	20 x 16
HFWNSP2020C	\$126.00	17.75 x 17.75 [451 x 451]	18.50 x 18.62 [ 470 x 473]	20 x 20
HFWNSP2024C	\$133.00	17.75 x 21.75 [451 x 552]	18.50 x 22.62 [470 x 575]	20 x 24
HFWNSP2416C	\$125.00	21.75 x 13.75 [552 x 349]	22.50 x 14.62 [572 x 371]	24 x 16
HFWNSP2420C	\$133.00	21.75 x 17.75 [552 x 451]	22.50 x 18.62 [572 x 473]	24 x 20
HFWNSP2424C	\$142.00	21.75 x 21.75 [552 x 552]	22.50 x 22.62 [572 x 575]	24 x 24
HFWNSP3020C	\$144.00	27.75 x 17.75 [705 x 451]	28.50 x 18.62 [724 x 473]	30 x 20
HFWNSP3024C	\$155.00	27.75 x 21.75 [705 x 552]	28.50 x 22.62 [724 x 575]	30 x 24
HFWNSP3030C	\$171.00	27.75 x 27.75 [705 x 705]	28.50 x 28.62 [724 x 727]	30 x 30
HFWNSP3624C	\$168.00	33.75 x 21.75 [857 x 552]	34.50 x 22.62 [876 x 575]	36 x 24
HFWNSP3630C	\$187.00	33.75 x 27.75 [857 x 705]	34.50 x 28.62 [876 x 727]	36 x 30
HFWNSP3636C	\$206.00	33.75 x 33.75 [857 x 857]	34.50 x 34.62 [876 x 879]	36 x 36

**Notes:** Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawings.  
 If used in a two-door enclosure, a center panel support must be ordered.

## Dimensions

in [mm]

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

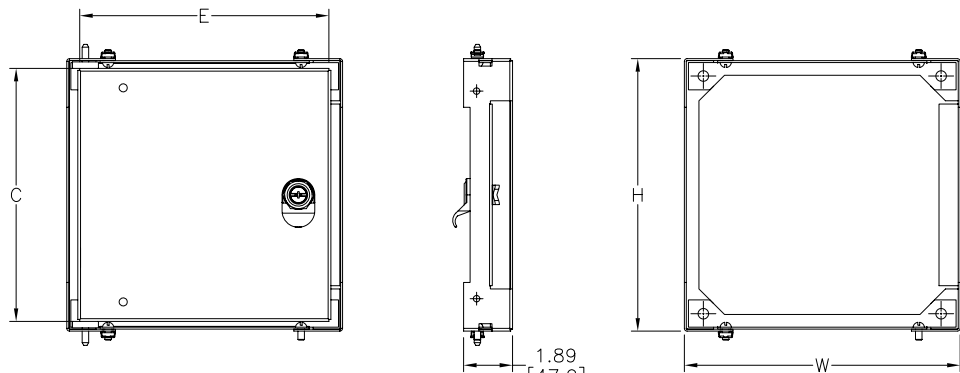

DOOR REMOVED

Enclosure Subpanels tENC-332

# Enclosure Accessories - Miscellaneous



## Strip Gasket



Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Strip Gasket	Price	Description	Wt. [oz]
<b>WGAS51634</b>	\$15.25	Wiegmann strip gasket, replacement, self-adhesive, microcell urethane foam, 5/16 inch thick x 3/4 inch wide x 10 ft long roll. For gasket replacement on Wiegmann wall-mount NEMA 12, 4 & 4X enclosures.	7
<b>WGAS3834</b>	\$15.50	Wiegmann strip gasket, replacement, self-adhesive, closed cell sponge rubber, 3/8 inch thick x 3/4 inch wide x 10 ft long roll. For gasket replacement on Wiegmann floor-mount and freestanding NEMA 12, 4 & 4X enclosures.	7



## Locking Protective Cover


### Features

- Packaged multi-purpose protective cover
- Locking door
- Weather and UV resistant (UL 94-HB)
- IP 20 Protection Class
- Includes mounting screws

Locking Protective Cover	Description	Price
<b>086110-00</b>	Stego multi-purpose protective cover with locking door, weather and UV resistant (UL 94-HB), IP20 protection class. Includes mounting screws and keys.	\$41.00



### Dimensions in [mm]

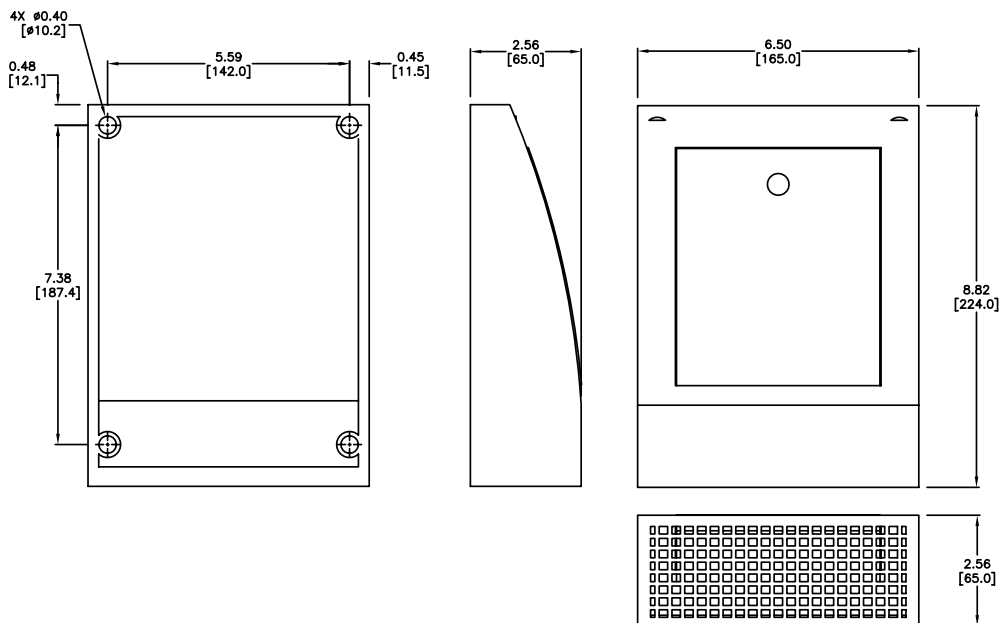

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.