

NEMA 4, 4X and 12 Stainless Steel Two-Door Floor Mount with 3-Point Handle



Application

Designed to house electrical and electronic controls, components and instruments in wet corrosive environments. Typical applications for these enclosures include dairies, breweries, waste water, coastal, food processing and/or activities that may require hose down. Enclosures are designed for outdoor applications.

Construction

- Bodies, doors and floor stand feet are fabricated from 12/10 gauge 304 or 316L stainless steel
- Continuously welded seams ground smooth
- Body stiffeners added for extra strength
- Rolled lip around three sides of door and along top of enclosure's opening excludes liquids and contaminants from entering
- 3-point 316L SS padlocking handles
- Heavy gauge continuous hinges are provided to secure doors
- Doors are removable by pulling stainless steel continuous hinge pin
- Removable print pocket is provided
- Standard 12" high floor kits are welded to bottom of enclosure
- Heavy duty removable lifting eyes

- Collar studs for mounting optional subpanels
- Easily removable center post permits easy panel installations
- Doors are sealed with poured-in-place gasket
- Grounding provisions provided
- **Uses WAL3 SS series handles**

Finish

Exterior: smooth-grained finish

Listings

- UL 508, Types 4, 4X, and 12 [UL Files E64791]
- CSA Certified, Types 4, 4X & 12 [CSA File LL66078]
- NEMA/EEMAC Types 4, 4X, and 12



FOR CURRENT LISTINGS, PLEASE SEE WWW.AUTOMATIONDIRECT.COM

Enclosure Shipping Schedule

Same day	1 - 7 days	1 -10 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------

Color indicates shipping lead time in business days.


NEMA 4, 4X and 12 Stainless Steel Two-Door Floor Mount Enclosures with 3-Point Handle

304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD [not incl. 12" legs]	Painted Steel Subpanel	Galvanized Subpanel
SSN4D6248123PT	\$6,278.00	SSN4D6248123PTA	\$7,150.00	62.06 x 48.06 x 12.06 [1576 x 1221 x 306]	NPDD6048	NPDD6048G
SSN4D6248183PT	\$6,584.00	SSN4D6248183PTA	\$7,908.00	62.06 x 48.06 x 18.06 [1576 x 1221 x 459]	NPDD6048	NPDD6048G
SSN4D6260123PT	\$7,040.00	SSN4D6260123PTA	\$8,022.00	62.06 x 60.06 x 12.06 [1576 x 1526 x 306]	NPDD6060	NPDD6060G
SSN4D7460123PT	\$8,028.00	SSN4D7460123PTA	\$9,635.00	74.06 x 60.06 x 12.06 [1881 x 1526 x 306]	NPDD7260	NPDD7260G
SSN4D7472123PT	\$8,676.00	SSN4D7472123PTA	\$9,891.00	74.06 x 72.06 x 12.06 [1881 x 1830 x 306]	NPDD7272	—
SSN4D7472243PT	\$11,059.00	SSN4D7472243PTA	\$12,594.00	74.06 x 72.06 x 24.06 [1881 x 1830 x 611]	NPDD7272	—

Notes: Subpanels must be ordered separately.
 Dimensions in inches [millimeters].
 Letters in table correspond to letters on dimensional drawings.

NEMA 4, 4X and 12 Stainless Steel Two-Door Floor Mount with 3-Point Handle

Dimensions in [mm]

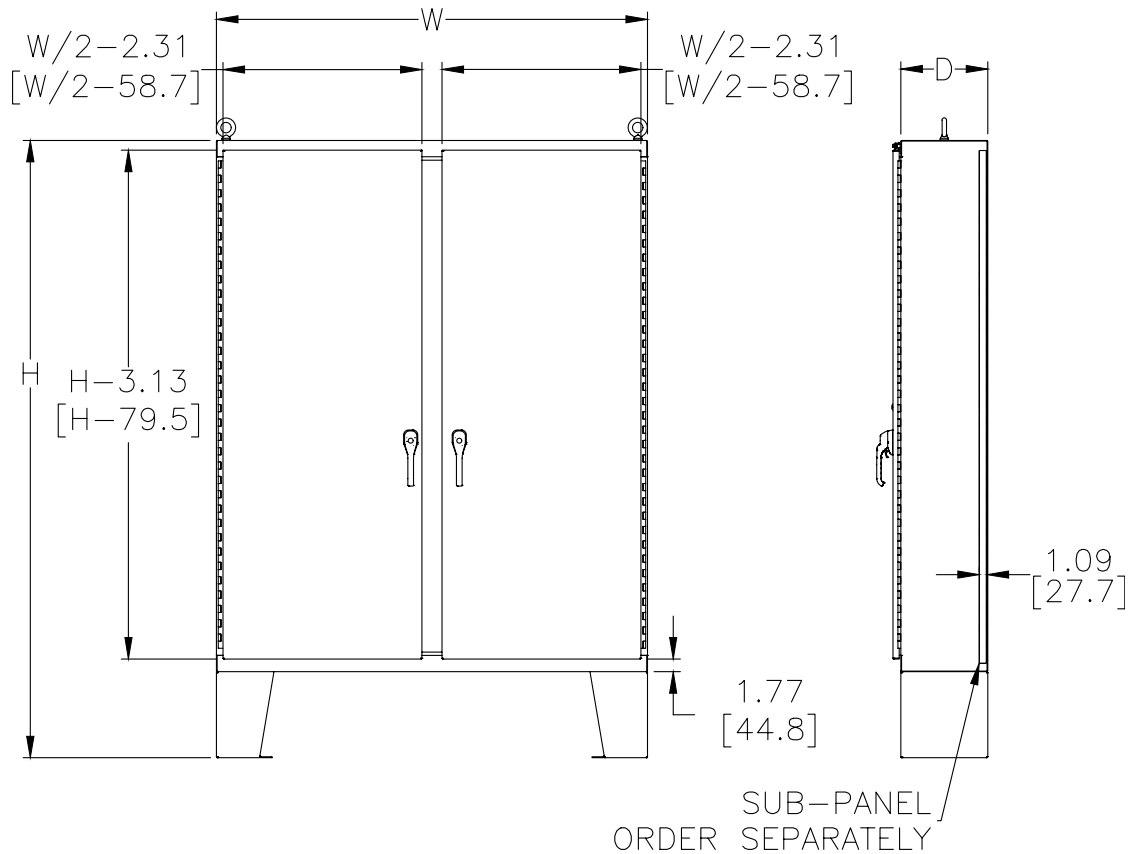

See our website: www.AutomationDirect.com for complete engineering drawings.

Enclosure Subpanels



Subpanels for Double-door Floor Mount Enclosures

- Subpanels are fabricated from 10 gauge carbon steel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Subpanels are used in NEMA 12 double-door floor mount enclosures and some double-door wall mount enclosures



Enclosure Shipping Schedule				
Same day	1 - 7 days	1 -10 days	1 - 15 days	1 - 20 days


Color indicates shipping lead time in business days.

Subpanels for Double-door Floor Mount Enclosures					
Painted Steel	Price	Galvanized	Price	Nominal Enclosure Size HxW*	Subpanel Size AxB
NPDD4242	\$173.00	NPDD4242G	\$173.00	42 x 42	39.00 x 39.00 [991 x 991]
NPDD4260	\$254.00	NPDD4260G	\$254.00	42 x 60	38.00 x 56.00 [965 x 1422]
NPDD4842	\$197.00	NPDD4842G	\$197.00	48 x 42	45.00 x 39.00 [1143 x 991]
NPDD4848	\$236.00	NPDD4848G	\$236.00	48 x 48	44.00 x 44.00 [1118 x 1118]
NPDD5442	\$210.00	NPDD5442G	\$210.00	54 x 42	50.00 x 38.00 [1270 x 965]
NPDD6048	\$286.00	NPDD6048G	\$286.00	60 x 48	44.00 x 56.00 [1118 x 1422]
NPDD6060	\$353.00	NPDD6060G	\$353.00	60 x 60	56.00 x 56.00 [1422 x 1422]
NPDD7260	\$420.00	NPDD7260G	\$420.00	72 x 60	56.00 x 68.00 [1422 x 1727]
NPDD7272	\$502.00	—		72 x 72	68.00 x 68.00 [1727 x 1727]

Notes: Dimensions in inches [millimeters].
 Letters in table correspond to letters on dimensional drawing.
 *Some floor mount enclosures may be up to 2 inches [51mm] taller than height listed in this table.
 Disconnect enclosures will be up to 2 inches [51 mm] wider than width dimensions listed in this table.

Dimensions

in [mm]

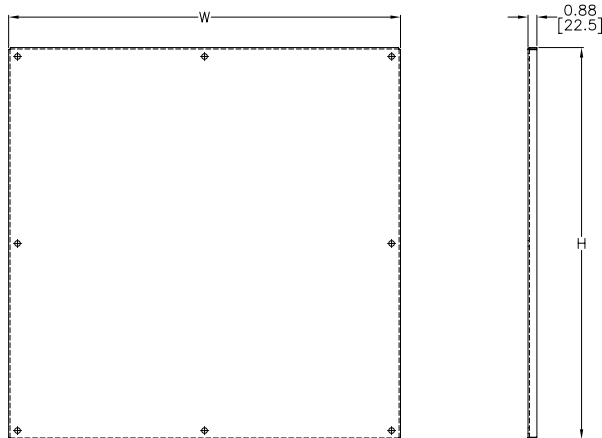

See our website: www.AutomationDirect.com for complete engineering drawings.