

NEMA 4, 4X and 12 Stainless Steel Two-Door Wall Mount with 3-Point Handle



Applications

SSN4WF Series is intended for use in housing electrical and electronic controls, instruments, components, and associated wiring. These enclosures incorporate double-hinged doors which provide convenient access. Designed for outdoor use in protecting components from dust, dirt, oil, and water.



Construction

- Bodies and doors fabricated from 14 gauge 304 stainless steel
- Continuously welded seams ground smooth
- Rolled lip around all sides of enclosure opening is provided to exclude liquids and contaminants
- Two independent doors with removable center post
- 3-point 316L SS padlocking handles
- Doors are removable by pulling heavy gauge stainless continuous hinge pin
- Doors are sealed with a poured-in-place polyurethane gasket
- Collar studs are provided for mounting optional subpanels
- External mounting feet are provided for mounting
- Grounding provisions provided
- Removable print pocket is provided
- **Uses WAL3 SS series handles**

Finish

- Smooth-grained stainless steel finish

Listings

- UL 508 Listed, Types 12, 4, 4X [UL Files E64791]
- NEMA/EEMAC Type 12, 4, 4x



FOR CURRENT LISTINGS, PLEASE SEE WWW.AUTOMATIONDIRECT.COM

Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days


Color indicates shipping lead time in business days.

NEMA 4, 4X and 12 Stainless Steel Two-Door Wall Mount Enclosures with 3-Point Handle						
Part Number	Price	Enclosure Size HxWxD	Painted Subpanel	Stainless Steel Subpanel	Galvanized Subpanel	Perforated Subpanel
SSN4244208WF3PT	\$2,383.00	24.00 x 42.00 x 9.04 [610 x 1067 x 230]	NP4224	-	NP4224G	-
SSN4244808WF3PT	\$2,566.00	24.00 x 48.00 x 9.04 [610 x 1219 x 230]	NP4824	-	NP4824G	-
SSN4304210WF3PT	\$2,786.00	30.00 x 42.00 x 11.04 [762 x 1067 x 280]	NP4230	NP4230SS	NP4230G	NP4230PP
SSN4304810WF3PT	\$2,998.00	30.00 x 48.00 x 11.04 [762 x 1219 x 280]	NP4830	-	NP4830G	-
SSN4306010WF3PT	\$3,409.00	30.00 x 60.00 x 11.04 [762 x 1524 x 280]	NP6030	-	NP6030G	-
SSN4364212WF3PT	\$3,227.00	36.00 x 42.00 x 13.04 [914 x 1067 x 331]	NP4236	NP4236SS	NP4236G	NP4236PP
SSN4364812WF3PT	\$3,501.00	36.00 x 48.00 x 13.04 [914 x 1219 x 331]	NP4836	NP4836SS	NP4836G	NP4836PP
SSN4366012WF3PT	\$3,996.00	36.00 x 60.00 x 13.04 [914 x 1524 x 331]	NP6036	NP6036SS	NP6036G	NP6036PP
SSN4424212WF3PT	\$3,546.00	42.00 x 42.00 x 13.04 [1067 x 1067 x 331]	NPDD4242	-	NPDD4242G	-
SSN4424812WF3PT	\$3,831.00	42.00 x 48.00 x 13.04 [1067 x 1219 x 331]	NPDD4842	-	NPDD4842G	-
SSN4426012WF3PT	\$4,498.00	42.00 x 60.00 x 13.04 [1067 x 1524 x 331]	NPDD4260	-	NPDD4260G	-
SSN4484812WF3PT	\$4,169.00	48.00 x 48.00 x 13.04 [1219 x 1219 x 331]	NPDD4848	-	NPDD4848G	-

NEMA 4, 4X and 12 Stainless Steel Two-Door Wall Mount with 3-Point Handle



Dimensions

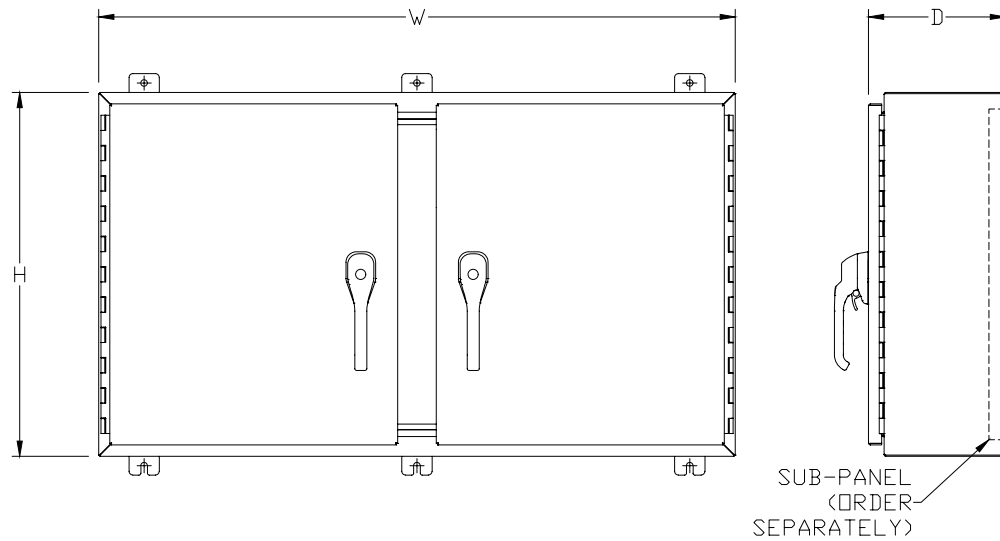

See our website: www.AutomationDirect.com for complete engineering drawings.

Enclosure Subpanels



Subpanels for Ultimate Series Wall Mount Enclosures

Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Subpanels for Ultimate Series Wall Mount Enclosures							
Painted Steel	Price	Galvanized	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size HxW
NP1212C	\$12.50	NP1212CG	\$10.50	–	–	12 x 12	10.20 x 10.20 [259 x 259]
NP1612C	\$13.50	NP1612CG	\$13.50	NP1612SSC	\$70.00	16 x 12	14.20 x 10.20 [361 x 259]
NP1616C	\$32.50	NP1616CG	\$32.50	NP1616SSC	\$85.00	16 x 16	14.20 x 14.20 [361 x 361]
NP2016C	\$39.00	NP2016CG	\$39.00	NP2016SSC	\$103.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
NP2020C	\$47.00	NP2020CG	\$47.00	NP2020SSC	\$133.00	20 x 20	18.20 x 18.20 [462 x 462]
NP2416C	\$45.00	NP2416CG	\$45.00	NP2416SSC	\$128.00	24 x 16	22.20 x 14.20 [564 x 361]
NP2420C	\$45.00	NP2420CG	\$61.00	NP2420SSC	\$162.00	24 x 20	22.20 x 18.20 [564 x 462]
NP2424C	\$70.00	NP2424CG	\$70.00	NP2424SSC	\$188.00	24 x 24	22.20 x 22.20 [564 x 564]
NP3020C	\$73.00	NP3020CG	\$73.00	–	–	30 x 20	28.20 x 18.20 [716 x 462]
NP3024C	\$84.00	NP3024CG	\$73.00	NP3024SSC	\$228.00	30 x 24	28.20 x 22.20 [716 x 564]
NP3030C	\$119.00	NP3030CG	\$119.00	NP3030SSC	\$337.00	30 x 30	28.20 x 28.20 [716 x 716]
NP3624C	\$101.00	NP3624CG	\$101.00	NP3624SSC	\$288.00	24 x 36 36 x 24	34.20 x 22.20 [869 x 564]
NP3630C	\$135.00	NP3630CG	\$135.00	NP3630SSC	\$357.00	36 x 30	34.20 x 28.20 [869 x 716]
NP3636C	\$158.00	NP3636CG	\$158.00	NP3636SSC	\$431.00	36 x 36	34.20 x 34.20 [869 x 869]
NP4224C	\$116.00	–	–	–	–	24 x 42	40.20 in x 22.20 in [1021 x 564]
NP4024C	\$121.00	NP4024CG	\$121.00	–	–	40 x 24	38.20 x 22.20 [970 x 564]
NP4242C	\$215.00	–	–	–	–	42 x 42	40.20 in x 40.20 in [1021 x 1021]
NP4230C	\$181.00	–	–	–	–	30 x 42 42 x 32	40.20 x 28.20 [1021 x 716]
NP4236C	\$181.00	NP4236CG	\$181.00	NP4236SSC	\$503.00	36 x 42 42 x 36	40.20 x 34.20 [1021 x 869]
NP4824C	\$131.00	NP4824CG	\$131.00	–	–	24 x 48 48 x 24	46.20 x 22.20 [1173 x 564]
NP4830C	\$173.00	–	–	–	–	30 x 48	46.20 in x 28.20 in [1173 x 716]
NP4842C	\$289.00	–	–	–	–	42 x 48	46.20 in x 40.20 in [1173 x 1021]
NP4836C	\$205.00	NP4836CG	\$205.00	NP4836SSC	\$545.00	36 x 48 48 x 36	46.20 x 34.20 [1173 x 869]
NP4848C	\$322.00	–	–	–	–	48 x 48	46.20 in x 46.20 in [1173 x 1173]
NP6030C	\$212.00	–	–	–	–	30 x 60	58.20 in x 28.20 in [1478 x 716]
NP6036C	\$252.00	NP6036CG	\$252.00	NP6036SSC	\$719.00	36 x 30 60 x 36	58.20 x 34.20 [1478 x 869]
NP6042C	\$299.00	–	–	–	–	42 x 60	58.20 in x 40.20 in [1478 x 1021]

Notes: Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawing.
Disconnect enclosures will be up to 2 inches [51mm] wider than width dimensions in this table.