

NEMA 4, 4X and 12 Stainless Steel Two-Door Wall Mount with 3-Point Handle



Application

SSN4WF Series is intended for use in housing electrical and electronic controls, instruments, components, and associated wiring. These enclosures incorporate double-hinged doors which provide convenient access. Designed for outdoor use in protecting components from dust, dirt, oil, and water.

Construction

- Bodies and doors fabricated from 14 gauge 304 stainless steel
- Continuously welded seams ground smooth
- Rolled lip around all sides of enclosure opening is provided to exclude liquids and contaminants
- Two independent doors with removable center post
- 3-point 316L SS padlocking handles
- Doors are removable by pulling heavy gauge stainless continuous hinge pin
- Doors are sealed with a poured-in-place polyurethane gasket
- Collar studs are provided for mounting optional subpanels
- External mounting feet are provided for mounting
- Grounding provisions provided
- Removable print pocket is provided

Finish

Smooth-grained stainless steel finish

Listings

- UL 508 Listed, Types 12, 4, 4X [UL Files E64791]
- CSA Certified, Types 12, 4, 4X [CSA File LL66078]
- NEMA/EEMAC Type 12, 4, 4x



FOR CURRENT LISTINGS, PLEASE SEE
WWW.AUTOMATIONDIRECT.COM

Enclosure Shipping Schedule

Same day	1 - 7 days	1-10 days
----------	------------	-----------

Color indicates shipping lead time in business days.


NEMA 4, 4X and 12 Stainless Steel Two-Door Wall Mount Enclosures with 3-Point Handle

Part Number	Price	Enclosure Size HxWxD	Painted Subpanel	Stainless Steel Subpanel	Galvanized Subpanel	Perforated Subpanel
SSN4244208WF3PT	\$2,418.00	24x42x8 [610x1067x203]	NP4224	-	NP4224G	NP4224PP
SSN4244808WF3PT	\$2,604.00	24x48x8 [610x1219x203]	NP4824	-	NP4824G	NP4824PP
SSN4304210WF3PT	\$2,828.00	30x42x10 [762x1067x254]	NP4230	NP4230SS	NP4230G	NP4230PP
SSN4304810WF3PT	\$3,042.00	30x48x10 [762x1219x254]	NP4830	-	NP4830G	NP4830PP
SSN4306010WF3PT	\$3,460.00	30x60x10 [762x1524x254]	NP6030	-	NP6030G	NP6030PP
SSN4364212WF3PT	\$3,274.00	36x42x12 [914x1067x305]	NP4236	NP4236SS	NP4236G	NP4236PP
SSN4364812WF3PT	\$3,553.00	36x48x12 [914x1219x305]	NP4836	NP4836SS	NP4836G	NP4836PP
SSN4366012WF3PT	\$4,055.00	36x60x12 [914x1524x305]	NP6036	NP6036SS	NP6036G	NP6036PP
SSN4424212WF3PT	\$3,599.00	42x42x12 [1067x1067x305]	NPDD4242	-	NPDD4242G	NPDD4242PP
SSN4424812WF3PT	\$3,888.00	42x48x12 [1067x1219x305]	NPDD4842	-	NPDD4842G	NPDD4842PP
SSN4426012WF3PT	\$4,564.00	42x60x12 [1067x1524x305]	NPDD4260	-	NPDD4260G	NPDD4260PP
SSN4484812WF3PT	\$4,231.00	48x48x12 [1219x1219x305]	NPDD4848	-	NPDD4848G	NPDD4848PP

NEMA 4, 4X and 12 Stainless Steel Two-Door Wall Mount with 3-Point Handle

Dimensions

in [mm]

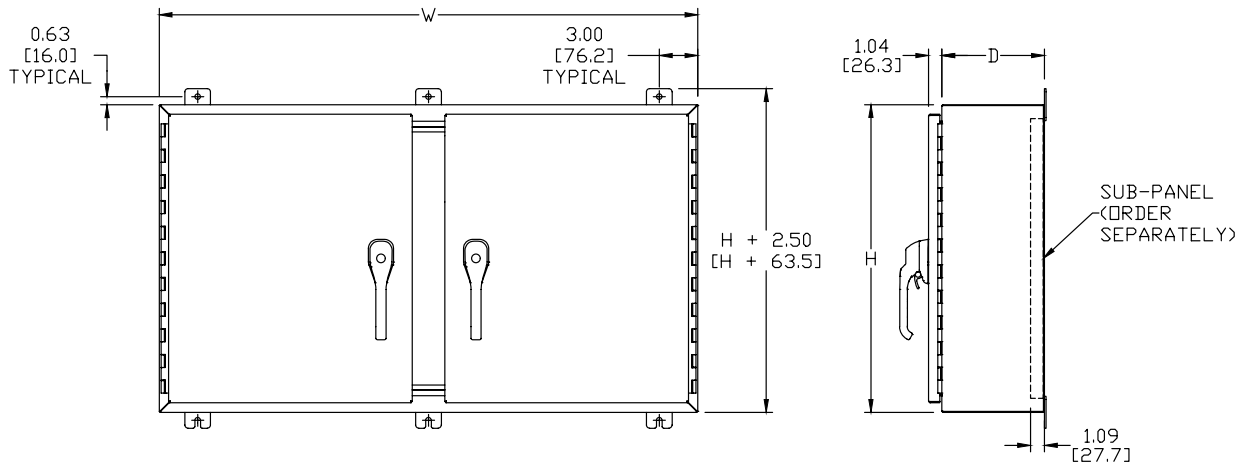

See our website: www.AutomationDirect.com for complete engineering drawings.

Enclosure Subpanels




Subpanels for Ultimate Series Wall Mount Enclosures

- 12 gauge steel
- Subpanels with dimensions 30" x 30" and larger are flanged on all sides. Smaller subpanels are flanged on two sides
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)



Dimensions in [mm]

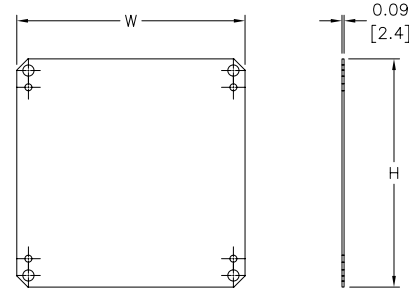

Panels listed fit all styles of N412 Ultimate Series wall mount enclosures, including slope top and disconnect enclosures.

NOTE: NPxxxxC subpanels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Subpanel NP1212C will not fit enclosures N412121206 or N412121206SS.

Enclosure Shipping Schedule	
Same day	1 - 7 days
Color indicates shipping lead time in business days.	

Subpanels for Ultimate Series Wall Mount Enclosures							
Painted Steel	Price	Galvanized	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size AxB
NP1212C	\$16.00	NP1212CG	\$16.00	—		12 x 12	10.20 x 10.20 [259 x 259]
NP1612C	\$19.50	NP1612CG	\$19.50	NP1612SSC	\$101.00	16 x 12	14.20 x 10.20 [361 x 259]
NP1616C	\$26.50	NP1616CG	\$26.50	NP1616SSC	\$70.00	16 x 16	14.20 x 14.20 [361 x 361]
NP2016C	\$26.50	NP2016CG	\$26.50	NP2016SSC	\$70.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
NP2020C	\$33.00	NP2020CG	\$33.00	NP2020SSC	\$93.00	20 x 20	18.20 x 18.20 [462 x 462]
NP2416C	\$37.00	NP2416CG	\$37.00	NP2416SSC	\$105.00	24 x 16	22.20 x 14.20 [564 x 361]
NP2420C	\$45.00	NP2420CG	\$45.00	NP2420SSC	\$119.00	24 x 20	22.20 x 18.20 [564 x 462]
NP2424C	\$47.50	NP2424CG	\$47.50	NP2424SSC	\$128.00	24 x 24	22.20 x 22.20 [564 x 564]
NP3020C	\$60.00	NP3020CG	\$60.00	—		30 x 20	28.20 x 18.20 [716 x 462]
NP3024C	\$57.00	NP3024CG	\$57.00	NP3024SSC	\$155.00	30 x 24	28.20 x 22.20 [716 x 564]
NP3030C	\$97.00	NP3030CG	\$97.00	NP3030SSC	\$276.00	30 x 30	28.20 x 28.20 [716 x 716]
NP3624C	\$75.00	NP3624CG	\$75.00	NP3624SSC	\$213.00	36 x 24	34.20 x 22.20 [869 x 564]
NP3630C	\$99.00	NP3630CG	\$99.00	NP3630SSC	\$263.00	36 x 30	34.20 x 28.20 [869 x 716]
NP3636C	\$117.00	NP3636CG	\$117.00	NP3636SSC	\$318.00	36 x 36	34.20 x 34.20 [869 x 869]
NP4024C	\$99.00	NP4024CG	\$99.00	—		40 x 24	38.20 x 22.20 [970 x 564]
NP4230C	\$126.00	—		—		42 x 32	40.20 x 28.20 [1021 x 716]
NP4236C	\$148.00	NP4236CG	\$148.00	NP4236SSC	\$411.00	42 x 36	40.20 x 34.20 [1021 x 869]
NP4824C	\$107.00	NP4824CG	\$107.00	—		48 x 24	46.20 x 22.20 [1173 x 564]
NP4836C	\$168.00	NP4836CG	\$168.00	NP4836SSC	\$446.00	48 x 36	46.20 x 34.20 [1173 x 869]
NP6036C	\$188.00	NP6036CG	\$188.00	NP6036SSC	\$535.00	60 x 36	58.20 x 34.20 [1478 x 869]

Notes: Dimensions in inches [millimeters].
 Letters in table correspond to letters on dimensional drawing.
 *Disconnect enclosures will be up to 2 inches [51mm] wider than width dimensions in this table.