

NEMA 4, 4X and 12 Stainless Steel Single-Door Wall Mount with 1/4-turn Latch



Application

Provides unmatched protection for housing electrical components in highly corrosive environments. This enclosure is used for indoor and outdoor settings that are frequently wet or have constant exposure to water, other liquids, or contaminants.

Construction

- Fabricated from 16 gauge type 304 or 316L stainless steel
- Continuously welded seams ground smooth
- Closed cell oil-resistant neoprene gasket
- External mounting feet
- Weldnuts are provided for mounting optional subpanels securely
- Continuous hinge cover with a 1/4-turn semi-flush oil-tight latch
- Door removed by pulling stainless steel continuous hinge pin
- Grounding provisions provided
- Optional subpanels must be ordered separately
- **Uses N41214 series latches (requires reuse of existing latch cam)**

Finish

- Cover and outside of enclosure have a #3 intermediate polished finish

Listings

- UL 50 Listed, Types 4, 4X, and 12 [UL file E6924 and E470978]
- Meets NEMA/EEMAC Types 4, 4X and 12



FOR CURRENT LISTINGS, PLEASE SEE WWW.AUTOMATIONDIRECT.COM

Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 -10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.


NEMA 4, 4X and 12 Stainless Steel Single-Door Wall Mount 1/4-turn Latch							
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel
BN4060604CHQTSS	\$193.00	BN4060604CHQTSSA	\$250.00	6.31 x 6.31 x 4.75 [160 x 160 x 121]	P0606	P0606SS	P0606G
BN4080604CHQTSS	\$224.00	BN4080604CHQTSSA	\$291.00	8.31 x 6.31 x 4.75 [211 x 160 x 121]	P0806	P0806SS	P0806G
BN4100804CHQTSS	\$244.00	BN4100804CHQTSSA	\$317.00	10.31 x 8.31 x 4.75 [262 x 211 x 121]	P1008	P1008SS	P1008G
BN4100806CHQTSS	\$275.00	BN4100806CHQTSSA	\$357.00	10.31 x 8.31 x 6.75 [262 x 211 x 171]	P1008	P1008SS	P1008G
BN4121006CHQTSS	\$367.00	BN4121006CHQTSSA	\$477.00	12.31 x 10.31 x 6.75 [313 x 262 x 171]	P1210	P1210SS	P1210G
BN4121008CHQTSS	\$419.00	BN4121008CHQTSSA	\$545.00	12.31 x 10.31 x 8.75 [313 x 313 x 171]	P1210	P1210SS	P1210G
BN4121010CHQTSS	\$461.00	BN4121010CHQTSSA	\$461.00	12.31 x 10.31 x 10.75 [313 x 262 x 273]	P1210	P1210SS	P1210G
BN4121206CHQTSS	\$398.00	BN4121206CHQTSSA	\$517.00	12.31 x 12.31 x 6.75 [313 x 313 x 171]	P1212	P1212SS	P1212G
BN4121208CHQTSS	\$429.00	BN4121208CHQTSSA	\$558.00	12.31 x 12.31 x 8.75 [313 x 262 x 222]	P1212	P1212SS	P1212G
BN4121210CHQTSS	\$492.00	BN4121210CHQTSSA	\$492.00	12.31 x 12.31 x 10.75 [313 x 313 x 273]	P1212	P1212SS	P1212G
BN4141206CHQTSS	\$409.00	BN4141206CHQTSSA	\$531.00	14.31 x 12.31 x 6.75 [363 x 313 x 171]	P1412	P1412SS	P1412G
BN4141208CHQTSS	\$440.00	BN4141208CHQTSSA	\$572.00	14.31 x 12.31 x 8.75 [363 x 313 x 222]	P1412	P1412SS	P1412G
BN4161406CHQTSS	\$440.00	BN4161406CHQTSSA	\$572.00	16.31 x 14.31 x 6.75 [414 x 363 x 171]	P1614	P1614SS	P1614G
BN4161408CHQTSS	\$471.00	BN4161408CHQTSSA	\$612.00	16.31 x 14.31 x 8.75 [414 x 363 x 222]	P1614	P1614SS	P1614G

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.

NEMA 4, 4X and 12 Stainless Steel Single-Door Wall Mount with 1/4-turn Latch



Dimensions

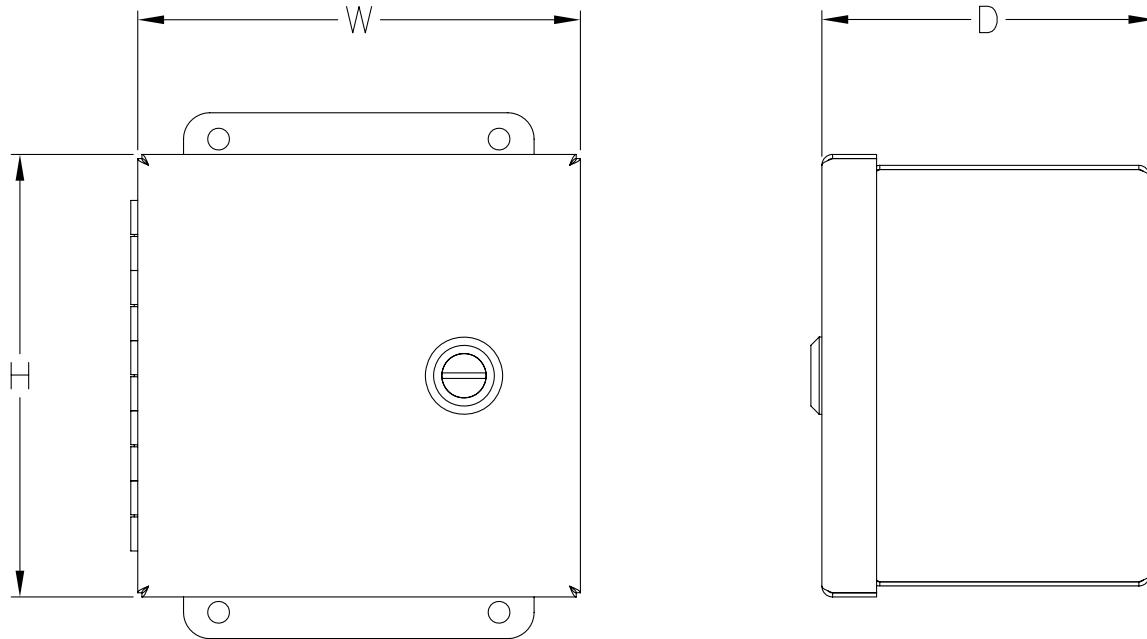

See our website: www.AutomationDirect.com for complete engineering drawings.

Enclosure Subpanels



Subpanels

Subpanels are not included with most enclosures and must be purchased separately.

The specifications table for each enclosure family list the part number of the subpanel that goes with each enclosure.

Subpanels for Small NEMA 12 (B) and NEMA 4 (BN4) Enclosures

- 14 gauge (painted, stainless, and galvanized)
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Subpanels fit the following enclosures: B, B_CH, BN4, BN4_CH, BN4_CHQT, BN4_SS, BN4_CHSS, BN4_CHSSA, BN4_CHQTSS, BN4_CHQTSSA ("_" refers to dimensions).



Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days


Color indicates shipping lead time in business days.

Subpanels for B and BN4 Enclosures							
Painted Steel	Price	304 Stainless Steel	Price	Galvanized	Price	Nominal Enclosure Size HxW	Subpanel Size AxB
P0604	\$4.00	P0604SS	\$13.50	P0604G	\$4.00	6 x 4	4.88 x 2.88 [124 x 73]
P0606	\$4.75	P0606SS	\$16.75	P0606G	\$4.75	6 x 6	4.88 x 4.88 [124 x 124]
P0806	\$5.50	P0806SS	\$19.75	P0806G	\$5.50	8 x 6	6.88 x 4.88 [175 x 124]
P0808	\$6.50	-	-	P0808G	\$6.50	8 x 8	6.88 x 6.88 [175 x 175]
P1008	\$7.00	P1008SS	\$28.50	P1008G	\$7.00	10 x 8	8.88 x 6.88 [226 x 175]
P1010	\$9.00	-	-	P1010G	\$9.00	10 x 10	8.88 x 8.88 [226 x 226]
P1206	\$7.00	-	-	P1206G	\$7.00	12 x 6	10.88 x 4.88 [276 x 124]
P1210	\$10.25	P1210SS	\$40.00	P1210G	\$10.25	12 x 10	10.88 x 8.88 [276 x 226]
P1212	\$12.00	P1212SS	\$47.00	P1212G	\$12.00	12 x 12	10.88 x 10.88 [276 x 276]
P1408	\$9.75	-	-	P1408G	\$9.75	14 x 8	12.88 x 6.88 [327 x 175]
P1412	\$13.25	P1412SS	\$54.00	P1412G	\$13.25	14 x 12	12.88 x 10.88 [327 x 276]
P1610	\$13.00	-	-	P1610G	\$13.00	16 x 10	14.88 x 8.88 [378 x 226]
P1614	\$17.75	P1614SS	\$71.00	P1614G	\$17.75	16 x 14	14.88 x 12.88 [378 x 327]

Notes: Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawing.

Dimensions

in [mm]

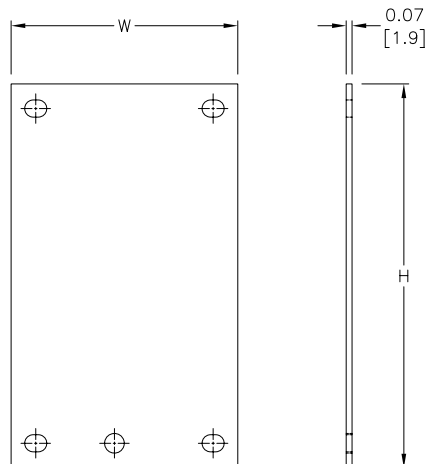

See our website: www.AutomationDirect.com for complete engineering drawings.