

# NEMA 4, 4X and 12 Stainless Steel Single-Door Wall Mount with 1/4-turn Latch



## Application

Provides unmatched protection for housing electrical components in highly corrosive environments. This enclosure is used for indoor and outdoor settings that are frequently wet or have constant exposure to water, other liquids, or contaminants.

## Finish

- Cover and outside of enclosure have a #3 intermediate polished finish

## Listings

- UL 50 Listed, Types 4, 4X, and 12 [UL file E6924 and E470978]
- CSA Certified, Types 4 and 12 [CSA file LL66078]
- Meets NEMA/EEMAC Types 4, 4X and 12



## Construction

- Fabricated from 16 gauge type 304 or 316L stainless steel
- Continuously welded seams ground smooth
- Closed cell oil-resistant neoprene gasket
- External mounting feet
- Weldnuts are provided for mounting optional subpanels securely
- Continuous hinge cover with a 1/4-turn semi-flush oil-tight latch
- Door removed by pulling stainless steel continuous hinge pin
- Grounding provisions provided
- Optional subpanels must be ordered separately
- **Uses N41214 series latches (requires reuse of existing latch cam)**

### Enclosure Shipping Schedule

Same day	1 - 7 days	1 - 10 days
----------	------------	-------------

Color indicates shipping lead time in business days.

### NEMA 4, 4X and 12 Stainless Steel Single-Door Wall Mount 1/4-turn Latch


304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel
<b>BN4060604CHQTSS</b>	\$112.00	<b>BN4060604CHQTSSA</b>	\$122.00	6.31 x 6.31 x 4.75 [160 x 160 x 121]	<b>P0606</b>	<b>P0606SS</b>	<b>P0606G</b>
<b>BN4080604CHQTSS</b>	\$117.00	<b>BN4080604CHQTSSA</b>	\$127.00	8.31 x 6.31 x 4.75 [211 x 160 x 121]	<b>P0806</b>	<b>P0806SS</b>	<b>P0806G</b>
<b>BN4100804CHQTSS</b>	\$126.00	<b>BN4100804CHQTSSA</b>	\$142.00	10.31 x 8.31 x 4.75 [262 x 211 x 121]	<b>P1008</b>	<b>P1008SS</b>	<b>P1008G</b>
<b>BN4100806CHQTSS</b>	\$137.00	<b>BN4100806CHQTSSA</b>	\$156.00	10.31 x 8.31 x 6.75 [262 x 211 x 171]	<b>P1008</b>	<b>P1008SS</b>	<b>P1008G</b>
<b>BN4121006CHQTSS</b>	\$149.00	<b>BN4121006CHQTSSA</b>	\$166.00	12.31 x 10.31 x 6.75 [313 x 262 x 171]	<b>P1210</b>	<b>P1210SS</b>	<b>P1210G</b>
<b>BN4121008CHQTSS</b>	\$223.00	<b>BN4121008CHQTSSA</b>	\$243.00	12.31 x 10.31 x 8.75 [313 x 313 x 171]	<b>P1210</b>	<b>P1210SS</b>	<b>P1210G</b>
<b>BN4121010CHQTSS</b>	\$256.00	<b>BN4121010CHQTSSA</b>	\$256.00	12.31 x 10.31 x 10.75 [313 x 262 x 273]	<b>P1210</b>	<b>P1210SS</b>	<b>P1210G</b>
<b>BN4121206CHQTSS</b>	\$155.00	<b>BN4121206CHQTSSA</b>	\$174.00	12.31 x 12.31 x 6.75 [313 x 313 x 171]	<b>P1212</b>	<b>P1212SS</b>	<b>P1212G</b>
<b>BN4121208CHQTSS</b>	\$229.00	<b>BN4121208CHQTSSA</b>	\$252.00	12.31 x 12.31 x 8.75 [313 x 262 x 222]	<b>P1212</b>	<b>P1212SS</b>	<b>P1212G</b>
<b>BN4121210CHQTSS</b>	\$263.00	<b>BN4121210CHQTSSA</b>	\$263.00	12.31 x 12.31 x 10.75 [313 x 313 x 273]	<b>P1212</b>	<b>P1212SS</b>	<b>P1212G</b>
<b>BN4141206CHQTSS</b>	\$161.00	<b>BN4141206CHQTSSA</b>	\$185.00	14.31 x 12.31 x 6.75 [363 x 313 x 171]	<b>P1412</b>	<b>P1412SS</b>	<b>P1412G</b>
<b>BN4141208CHQTSS</b>	\$237.00	<b>BN4141208CHQTSSA</b>	\$263.00	14.31 x 12.31 x 8.75 [363 x 313 x 222]	<b>P1412</b>	<b>P1412SS</b>	<b>P1412G</b>
<b>BN4161406CHQTSS</b>	\$175.00	<b>BN4161406CHQTSSA</b>	\$199.00	16.31 x 14.31 x 6.75 [414 x 363 x 171]	<b>P1614</b>	<b>P1614SS</b>	<b>P1614G</b>
<b>BN4161408CHQTSS</b>	\$254.00	<b>BN4161408CHQTSSA</b>	\$284.00	16.31 x 14.31 x 8.75 [414 x 363 x 222]	<b>P1614</b>	<b>P1614SS</b>	<b>P1614G</b>

Notes: Subpanels must be ordered separately.  
 Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawings.

# NEMA 4, 4X and 12 Stainless Steel Single-Door Wall Mount with 1/4-turn Latch



## Dimensions

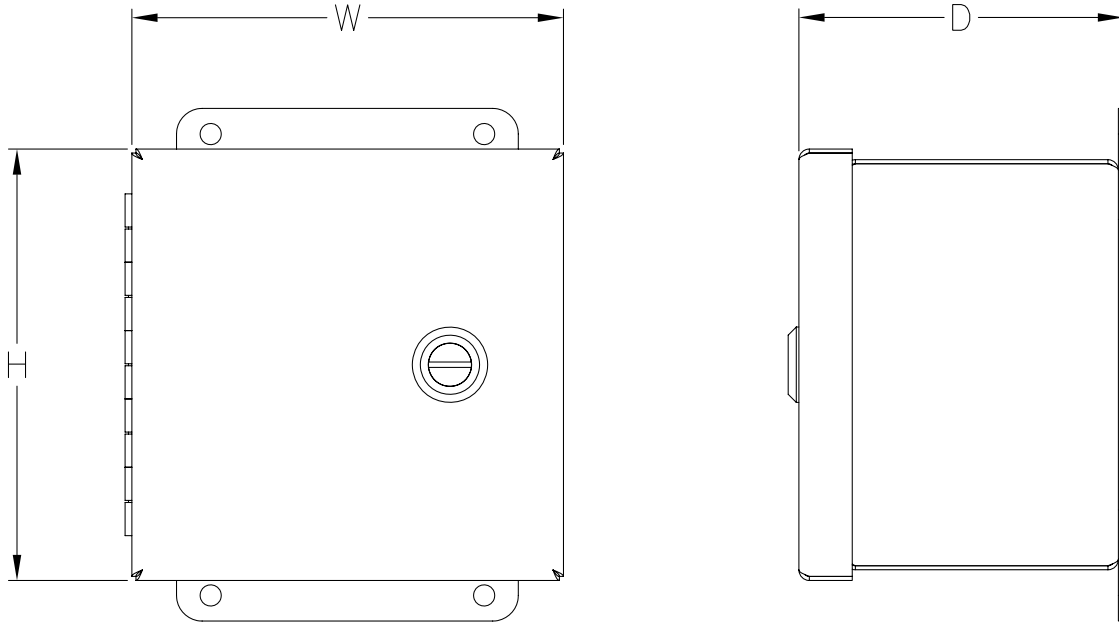

*See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.*

# Enclosure Subpanels



## Subpanels

Subpanels are not included with most enclosures and must be purchased separately. The specifications table for each enclosure family lists the part number of the subpanel that goes with each enclosure.

## Subpanels for Small NEMA 12 (B) and NEMA 4 (BN4) Enclosures

- 14 gauge (painted, stainless, and galvanized)
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Subpanels fit the following enclosures: B, B\_CH, BN4, BN4\_CH, BN4\_CHQT, BN4\_SS, BN4\_CHSS, BN4\_CHSSA, BN4\_CHQTSS, BN4\_CHQTSSA ("\_" refers to dimensions).




Subpanels for B and BN4 Enclosures							
Painted Steel	Price	304 Stainless Steel	Price	Galvanized	Price	Nominal Enclosure Size HxW	Subpanel Size AxB
P0604	\$3.00	P0604SS	\$10.75	P0604G	\$3.00	6 x 4	4.88 x 2.88 [124 x 73]
P0606	\$3.25	P0606SS	\$13.25	P0606G	\$3.25	6 x 6	4.88 x 4.88 [124 x 124]
P0806	\$4.00	P0806SS	\$15.50	P0806G	\$4.00	8 x 6	6.88 x 4.88 [175 x 124]
P0808	\$4.75	-		P0808G	\$4.75	8 x 8	6.88 x 6.88 [175 x 175]
P1008	\$5.25	P1008SS	\$22.50	P1008G	\$5.25	10 x 8	8.88 x 6.88 [226 x 175]
P1010	\$7.25	-		P1010G	\$7.25	10 x 10	8.88 x 8.88 [226 x 226]
P1206	\$5.75	-		P1206G	\$5.75	12 x 6	10.88 x 4.88 [276 x 124]
P1210	\$7.50	P1210SS	\$30.00	P1210G	\$7.50	12 x 10	10.88 x 8.88 [276 x 226]
P1212	\$9.00	P1212SS	\$37.50	P1212G	\$9.00	12 x 12	10.88 x 10.88 [276 x 276]
P1408	\$8.00	-		P1408G	\$8.00	14 x 8	12.88 x 6.88 [327 x 175]
P1412	\$9.75	P1412SS	\$43.00	P1412G	\$9.75	14 x 12	12.88 x 10.88 [327 x 276]
P1610	\$10.75	-		P1610G	\$10.75	16 x 10	14.88 x 8.88 [378 x 226]
P1614	\$12.00	P1614SS	\$57.00	P1614G	\$12.00	16 x 14	14.88 x 12.88 [378 x 327]

*Notes: Dimensions in inches [millimeters]. Letters in table correspond to letters on dimensional drawing.*

### Dimensions

in [mm]

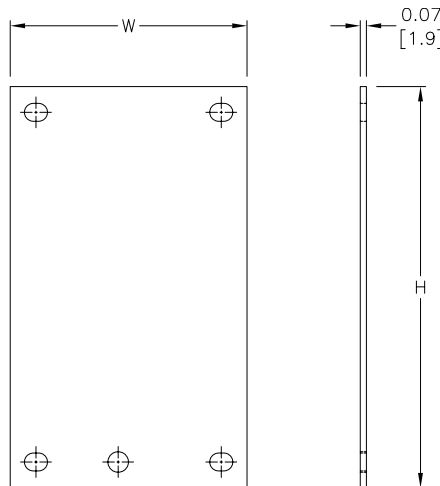

Enclosure Shipping Schedule	
Same day	1 - 7 days
Color indicates shipping lead time in business days.	

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.