

NEMA 3, 4 and 12 Single-Door Freestanding



Applications

Designed to house electrical and electronic controls, terminals and instruments in areas that are regularly hosed down or are otherwise very wet. Also suitable for outdoor applications.

Construction

- Bodies and doors fabricated from 12 gauge steel
- Continuously welded seams ground smooth
- Poured-in-place polyurethane gasket
- “Uni-strut” mounting channels are welded horizontally to interior body sides [top, bottom and center]
- Optional swing, half, full and rack panels can be mounted anywhere along “uni-strut” channel
- Rolled lip around three sides of door and along top of enclosure’s opening excludes liquids and contaminants from entering
- Quick and easy-to-operate stainless steel door clamps around three sides of doors
- Heavy-gauge continuous hinge with stainless steel hinge pin
- Doors are removable by pulling stainless steel continuous hinge pin

- Hasp and staple are provided for padlocking
- Heavy duty removable lifting eyes
- Grounding provisions provided

Finish

ANSI-61 gray polyester powder light texture inside and out over phosphatized surfaces

Listings

- UL 508, Types 3, 4, & 12 [UL File E64791]
- CSA Certified, Types 3,4 & 12 [CSA File LL66078]
- NEMA/EEMAC Types 3,4,& 12



FOR CURRENT LISTINGS,
PLEASE SEE WWW.AUTOMATIONDIRECT.COM

Enclosure Shipping Schedule

1 - 7 days

1 -10 days

Color indicates shipping lead time in business days.

NEMA 3, 4 and 12 Single-Door Freestanding Enclosures

Part Number	Price	Enclosure Size HxWxD
N4S722518FS	\$1,486.00	72.12x25.12x18.12 [1832x638x460]
N4S723124FS	\$1,815.00	72.12x31.12x24.12 [1832x790x613]
N4S723724FS	\$1,978.00	72.12x37.12x24.12 [1832x943x613]

Note: Subpanels must be ordered separately. Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.

Standard Subpanels

Enclosures	Full Height		Half Height	
	Painted Steel	Galvanized	Painted Steel	Galvanized
N4S722518FS	WA72P24F1	WA72P24F1G	WA72P24F2	WA72P24F2G
N4S723124FS	WA72P30F1	WA72P30F1G	WA72P30F2	WA72P30F2G
N4S723724FS	WA72P36F1	WA72P36F1G	WA72P36F2	WA72P36F2G

NEMA 3, 4 and 12 Single-Door Freestanding

Enclosure Shipping Schedule

1 - 7 days

1 -10 days


Color indicates shipping lead time in business days.

Swing-Out Panels				
Enclosures	Full Height		Half Height	
	Painted Steel	Galvanized	Painted Steel	Galvanized
N4S722518FS	WA72SP24F3	WA72SP24F3G	WA72SP24F4	WA72SP24F4G
N4S723124FS	WA72SP30F3	WA72SP30F3G	WA72SP30F4	WA72SP30F4G
N4S723724FS	WA72SP36F3	WA72SP36F3G	WA72SP36F4	WA72SP36F4G

Side Mount Panels			Swing-Out Rack
Enclosures	Painted Steel	Galvanized	
N4S722518FS	WA72SMP14	WA72SMP14G	-
N4S723124FS	WA72SMP14, WA72SMP20	WA72SMP14G, WA72SMP20G	WA7230SOF19
N4S723724FS	WA72SMP14, WA72SMP20	WA72SMP14G, WA72SMP20G	WA7236SOF19

Dimensions

in [mm]

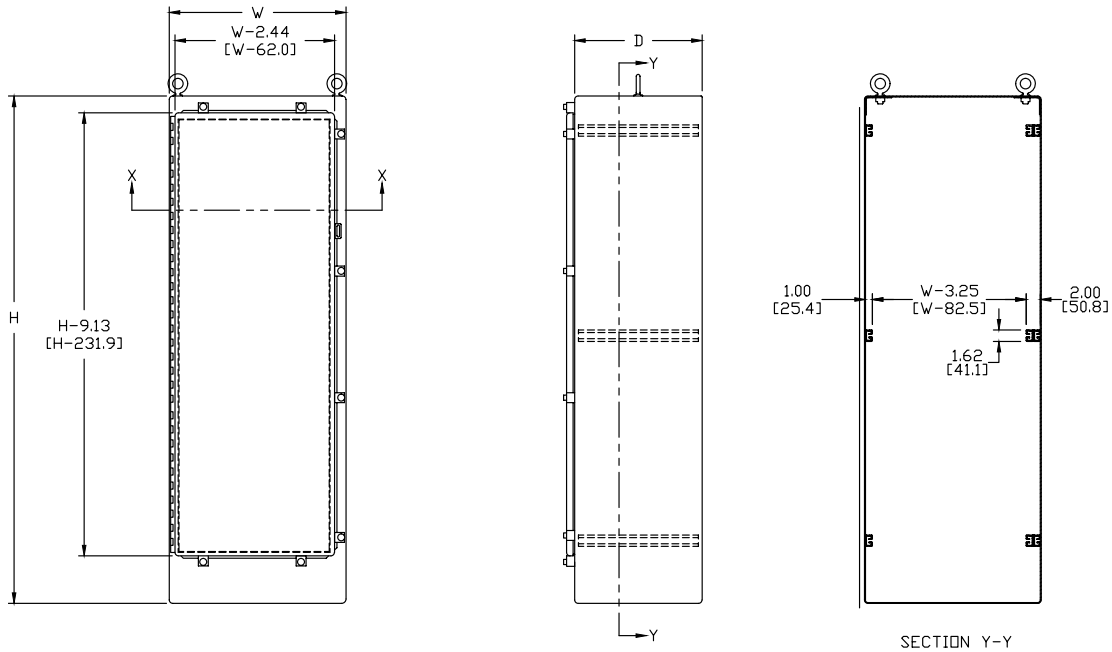


See our website: www.AutomationDirect.com for complete engineering drawings.

WA-F1/F2 Panels for Single-Door Freestanding Enclosures



Description

- Panels for single-door single-access and single-door dual-access, freestanding NEMA 12, and freestanding NEMA 4 enclosures
- Can be positioned anywhere along horizontal depth-wise mounting channels
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- May be used in two-door enclosures along with other freestanding accessories

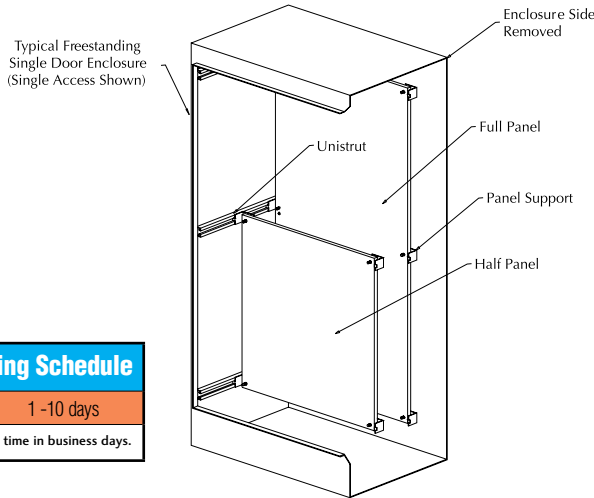


Enclosure Shipping Schedule	
1 - 7 days	1 -10 days
Color indicates shipping lead time in business days.	

Painted Steel	Price	Galvanized	Price	Steel Gauge	Panel Size AxB	Subpanel Type
WA60P24F1	\$220.00	WA60P24F1G	\$220.00	12	48x20 [1219x508]	Full
WA60P24F2	\$146.00	WA60P24F2G	\$146.00	10	24.88x20 [632x508]	Half
WA60P36F1	\$284.00	WA60P36F1G	\$284.00	12	48x32 [1219x813]	Full
WA60P36F2	\$179.00	WA60P36F2G	\$179.00	12	24.88x32 [632x813]	Half
WA72P24F1	\$246.00	WA72P24F1G	\$246.00	12	60x20 [1524x508]	Full
WA72P24F2	\$158.00	WA72P24F2G	\$158.00	12	30.88x20 [784x508]	Half
WA72P30F1	\$286.00	WA72P30F1G	\$286.00	12	60x26 [1524x660]	Full
WA72P30F2	\$179.00	WA72P30F2G	\$179.00	10	30.88x26 [784x660]	Half
WA72P36F1	\$326.00	WA72P36F1G	\$326.00	12	60x32 [1524x813]	Full
WA72P36F2	\$199.00	WA72P36F2G	\$199.00	12	30.88x32 [784x813]	Half
WA90P24F1	\$286.00	WA90P24F1G	\$286.00	12	78x20 [1981x508]	Full
WA90P24F2	\$179.00	WA90P24F2G	\$179.00	10	39.88x20 [1013x508]	Half
WA90P36F1	\$383.00	WA90P36F1G	\$383.00	12	78x32 [1981x813]	Full
WA90P36F2	\$231.00	WA90P36F2G	\$231.00	10	39.88x32 [1013x813]	Half

Note: Dimensions in inches [millimeters]. If used in a two-door enclosure, a center panel support must be ordered. Suffix F1= full panel, F2 = half panel


Dimensions

in [mm]

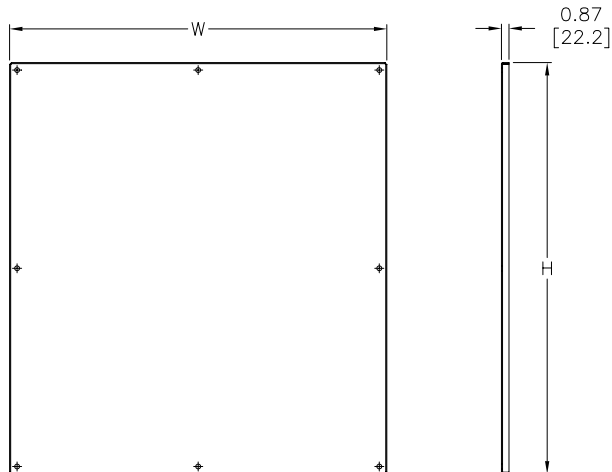

See our website: www.AutomationDirect.com for complete engineering drawings.

WA-SMP Series Side-Mount Panels for Freestanding Enclosures

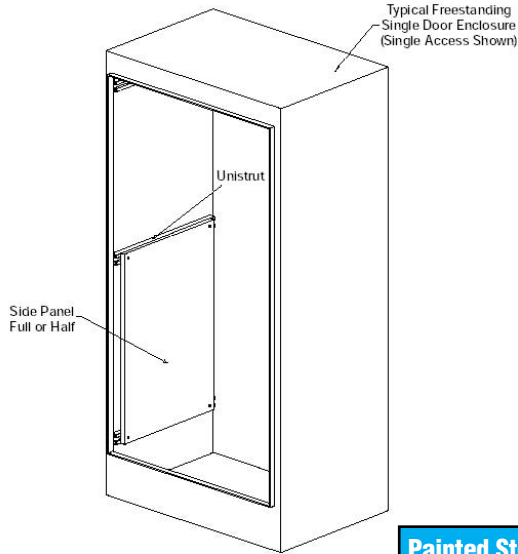

Description

- Panels for freestanding NEMA 4 and freestanding NEMA 12 enclosures
- Panels are fabricated from 12 gauge steel
- They provide extra mounting space on the sides of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels attach securely to mounting channels

Enclosure Shipping Schedule

1 - 7 days	1 -10 days
------------	------------


Color indicates shipping lead time in business days.

Painted Steel	Price	Galvanized	Price	Panel Size AxB
WA60SMP14	\$133.00	WA60SMP14G	\$133.00	48x14 [1219x356]
WA72SMP14	\$151.00	WA72SMP14G	\$151.00	60x14 [1524x356]
WA72SMP20	\$185.00	WA72SMP20G	\$185.00	60x20 [1524x508]
WA90SMP14	\$217.00	WA90SMP14G	\$217.00	78x14 [1981x356]
WA90SMP20	\$227.00	WA90SMP20G	\$227.00	78x20 [1981x508]

Note: Dimensions in inches [millimeters]


Dimensions

in [mm]

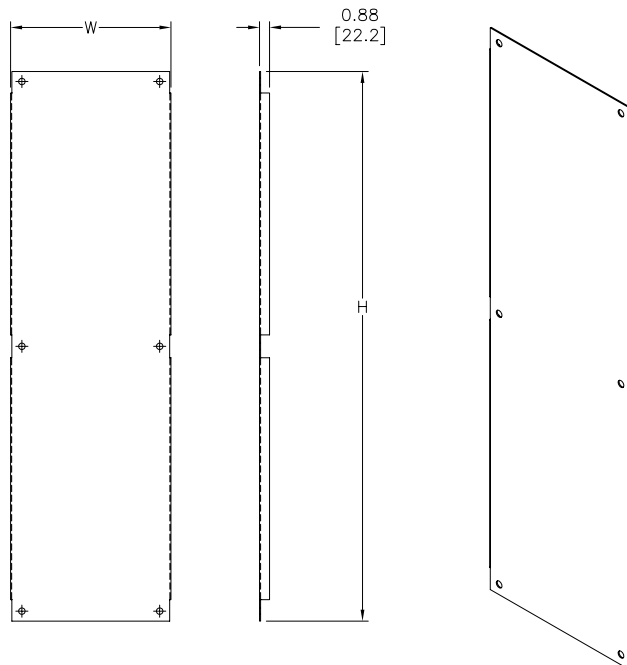

See our website: www.AutomationDirect.com for complete engineering drawings.

WASP-F3/F4 Series Accessory Swing-Out Panels For Freestanding Enclosures

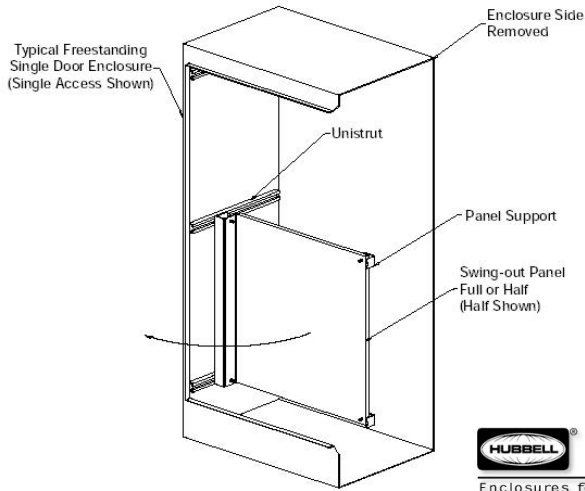

Description

- Panels for freestanding NEMA 12 enclosures and freestanding NEMA 4 enclosures
- Full-height and half-height swing-out panels are available
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting can be on either side of the enclosure
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- May be used in two-door enclosures along with other freestanding accessories
- Fabricated from 12 gauge steel
- Mounting hardware is furnished with each panel




Enclosure Shipping Schedule	
1 - 7 days	1 -10 days
Color indicates shipping lead time in business days.	

Painted Steel	Price	Galvanized	Price	Panel Size AxB	Subpanel Type
WA60SP24F3	\$355.00	WA60SP24F3G	\$355.00	48x19 [1219x483]	Full
WA60SP24F4	\$250.00	WA60SP24F4G	\$250.00	24.88x19 [632x483]	Half
WA60SP36F3	\$437.00	WA60SP36F3G	\$437.00	48x31 [1219x787]	Full
WA60SP36F4	\$290.00	WA60SP36F4G	\$290.00	24.88x31 [632x787]	Half
WA72SP24F3	\$430.00	WA72SP24F3G	\$430.00	60x19 [1524x483]	Full
WA72SP24F4	\$292.00	WA72SP24F4G	\$292.00	30.88x19 [784x483]	Half
WA72SP30F3	\$499.00	WA72SP30F3G	\$499.00	60x25 [1524x635]	Full
WA72SP30F4	\$330.00	WA72SP30F4G	\$330.00	30.88x25 [784x635]	Half
WA72SP36F3	\$568.00	WA72SP36F3G	\$568.00	60x31 [1524x787]	Full
WA72SP36F4	\$368.00	WA72SP36F4G	\$368.00	30.88x31 [784x787]	Half
WA90SP36F3	\$674.00	WA90SP36F3G	\$674.00	78x31 [1981x787]	Full
WA90SP36F4	\$425.00	WA90SP36F4G	\$425.00	39.88x31 [1013x787]	Half

Note: Dimensions in inches [millimeters]. Note 1: If used in a two-door enclosure, a center panel support must be ordered.
 Note 2: Suffix F3 =full panel, F4 =half panel

Dimensions

in [mm]

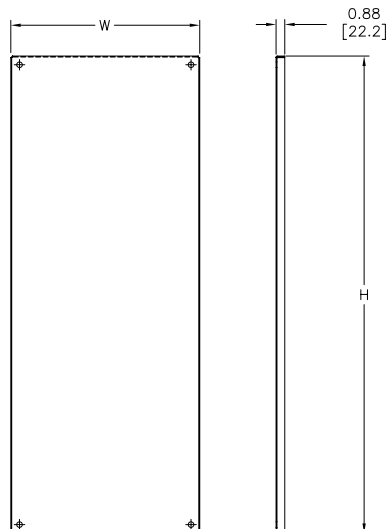

See our website: www.AutomationDirect.com for complete engineering drawings.