

NEMA 1, 3R, 3RX Stainless Steel Screw Cover without Knockouts



Applications

Designed for use as wiring boxes and junction boxes, these enclosures provide protection against rain, sleet and snow in outdoor applications, or against dripping water indoors. Can also be used in corrosive environments.

Construction

- Body and cover fabricated from 304 stainless steel.
- Slip-on reversible cover is securely fastened with screws located along the bottom edge.
- Mounting holes are located on back of enclosure.
- Drip shield top and smooth seamless sides and front.
- No gasketing is required.
- Hasp for padlocking or meter seal is provided except as noted.

Finish

- Exterior surfaces have a No. 3 intermediate polished finish.

Listings

- UL 50, Types 1, 3R, 3RX [UL file E23553]
- CSA Certified, Type 1, 3R, 3RX [CSA file LL66078]
- NEMA/EEMAC Type 1, 3R, and 3RX



Note 1: For removal of cover, move downward, then outward. 4x4x4 only has 2 mounting holes centered horizontally. 4x6x4 only has 2 mounting holes centered vertically.

Note 2: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.

NEMA 1, 3R, 3RX Stainless Steel Screw Cover without Knockouts			
Part Number	Price	Enclosure Size H x W x D	Steel Gauge
RSC040404NKSS*	\$60.00	4.06 x 4.30 x 4.41 [103 x 109 x 112]	16
RSC040604NKSS*	\$79.00	6.06 x 4.30 x 4.41 [154 x 109 x 112]	
RSC060604NKSS	\$81.00	6.06 x 6.30 x 4.41 [154 x 160 x 112]	
RSC060606NKSS	\$84.00	6.06 x 6.30 x 6.41 [154 x 160 x 163]	
RSC060804NKSS	\$91.00	8.06 x 6.30 x 4.41 [205 x 160 x 112]	
RSC060806NKSS	\$93.00	8.06 x 6.30 x 6.41 [205 x 160 x 163]	
RSC080804NKSS	\$100.00	8.06 x 8.30 x 4.41 [205 x 211 x 112]	
RSC080806NKSS	\$106.00	8.06 x 8.30 x 6.41 [205 x 211 x 163]	
RSC081004NKSS	\$102.00	10.06 x 8.30 x 4.41 [256 x 211 x 112]	
RSC081006NKSS	\$120.00	10.06 x 8.30 x 6.41 [256 x 211 x 163]	
RSC081206NKSS	\$133.00	12.06 x 8.30 x 6.41 [306 x 211 x 163]	
RSC101004NKSS	\$116.00	10.06 x 10.30 x 4.41 [256 x 262 x 112]	
RSC101006NKSS	\$136.00	10.06 x 10.30 x 6.41 [256 x 262 x 163]	
RSC101204NKSS	\$132.00	12.06 x 10.30 x 4.41 [306 x 262 x 112]	
RSC101206NKSS	\$152.00	12.06 x 10.30 x 6.41 [306 x 262 x 163]	
RSC121204NKSS	\$146.00	12.06 x 12.30 x 4.41 [306 x 312 x 112]	
RSC121206NKSS	\$170.00	12.06 x 12.30 x 6.41 [306 x 312 x 163]	
RSC121208NKSS	\$196.00	12.06 x 12.30 x 8.41 [306 x 312 x 214]	
RSC121210NKSS	\$215.00	12.06 x 12.30 x 10.41 [306 x 312 x 264]	
RSC121504NKSS	\$168.00	15.06 x 12.30 x 4.41 [383 x 312 x 112]	
RSC121506NKSS	\$195.00	15.06 x 12.30 x 6.41 [383 x 312 x 163]	
RSC121806NKSS	\$243.00	18.06 x 12.30 x 6.41 [459 x 312 x 163]	
RSC121808NKSS	\$254.00	18.06 x 12.30 x 8.41 [459 x 312 x 214]	
RSC151806NKSS	\$285.00	18.06 x 15.30 x 6.41 [459 x 389 x 163]	
RSC151808NKSS	\$308.00	18.06 x 15.30 x 8.41 [459 x 389 x 214]	
RSC161610NKSS	\$314.00	16.06 x 16.30 x 10.41 [408 x 414 x 264]	
RSC181804NKSS	\$299.00	18.06 x 18.30 x 4.41 [459 x 465 x 112]	
RSC181806NKSS	\$343.00	18.06 x 18.30 x 6.41 [459 x 465 x 163]	
RSC181808NKSS	\$383.00	18.06 x 18.30 x 8.41 [459 x 465 x 214]	
RSC182406NKSS	\$433.00	24.06 x 18.30 x 6.41 [611 x 465 x 163]	
RSC182408NKSS	\$478.00	24.06 x 18.30 x 8.41 [611 x 465 x 214]	
RSC202408NKSS	\$510.00	24.06 x 20.30 x 8.41 [611 x 516 x 214]	
RSC242406NKSS	\$513.00	24.07 x 24.36 x 6.47 [611 x 619 x 164]	
RSC242408NKSS	\$578.00	24.07 x 24.36 x 8.47 [611 x 619 x 215]	
RSC242412NKSS	\$686.00	24.07 x 24.36 x 12.47 [611 x 619 x 317]	
RSC242416NKSS	\$1,005.00	24.07 x 24.36 x 16.47 [611 x 619 x 418]	
RSC243008NKSS	\$1,005.00	30.07 x 24.36 x 8.47 [764 x 619 x 215]	
RSC243612NKSS	\$1,055.00	36.07 x 24.36 x 12.47 [916 x 619 x 317]	
RSC303012NKSS	\$1,246.00	30.10 x 30.57 x 12.56 [765 x 776 x 319]	
RSC303016NKSS	\$1,286.00	30.10 x 30.57 x 16.56 [765 x 776 x 421]	
RSC303612NKSS	\$1,295.00	36.10 x 30.57 x 12.56 [917 x 776 x 319]	
RSC363612NKSS	\$1,803.00	36.10 x 36.57 x 12.56 [917 x 929 x 319]	
RSC363616NKSS	\$2,208.00	36.10 x 36.57 x 16.56 [917 x 929 x 421]	
RSC364816NKSS	\$2,281.00	48.10 x 36.57 x 16.56 [1222 x 929 x 421]	



Dimensions in inches [millimeters]
*No hasp or meter seal.

Enclosure Shipping Schedule

1 - 15 days

Color indicates shipping lead time in business days.

NEMA 1, 3R, 3RX Stainless Steel Screw Cover without Knockouts

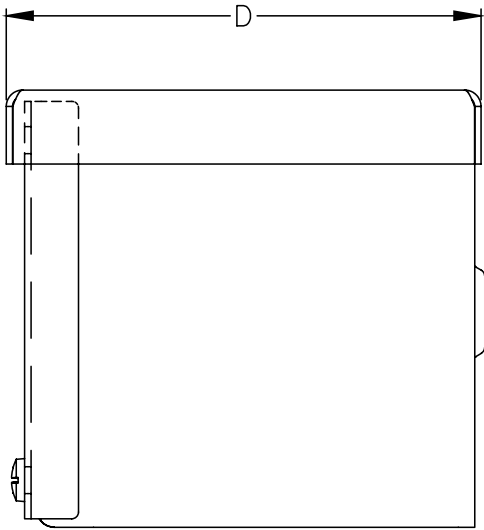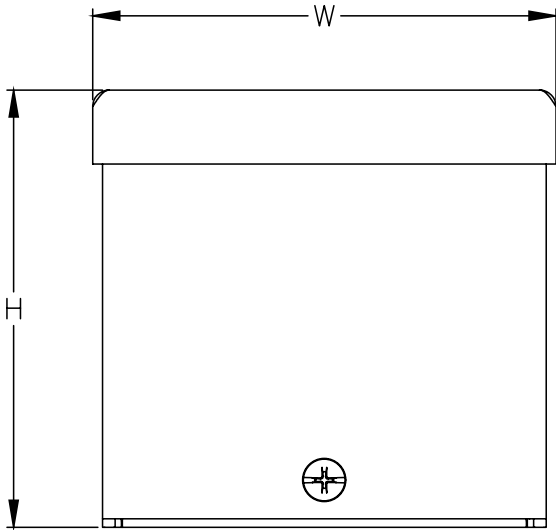

See our website: www.AutomationDirect.com for complete engineering drawings.

Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.

Grounding Kit		
Part Number	Description	Price
WGNDKT	Grounding Kit	\$1.25
Field grounding kit includes necessary parts to properly ground enclosure		