



# Pneumatic Modular Air Pilot Valves – BVS Series



**BVS Single Air Pilot**




**BVS Double Air Pilot**

NITRA pneumatic BVS series modular piloted valves are body ported 4-port (4-way) valves. Models are single pilot, spring return or double pilot operated.


## Features

- Body ported 4-port (4-way) spool valves
- 1/4" or 6mm push-to-connect inlet/outlet ports
- 5/32" (4mm) push-to-connect pilot ports
- Flow coefficient (Cv) 0.8
- 2-position
- 2-year warranty

## Valve Symbols

 

**Diagram A**

 

**Diagram B**


BVS 4-Way Air Pilot Specifications				
Model	BVS-425-1P	BVS-46M-1P	BVS-425-2P	BVS-46M-2P
Price	\$31.00	\$31.00	\$34.00	\$34.00
Weight (lbs)	0.13			
Acting	Spool (2-Position), spring return		Spool (2-Position), double air pilot	
Diagram	A		B	
Port Size	(1) 1/4" inlet (2) 1/4" outlet (1) 1/4" exhaust (1) 5/32" (4mm) pilot	(1) 6mm inlet (2) 6mm outlet (1) 6mm exhaust (1) 5/32" (4mm) pilot	(1) 1/4" inlet (2) 1/4" outlet (1) 1/4" exhaust (2) 5/32" (4mm) pilot	(1) 6mm inlet (2) 6mm outlet (1) 6mm exhaust (2) 5/32" (4mm) pilot
Orifice Size	0.2" [5.0 mm] (Cv = 0.8)			
Fluid	Air or Inert Gas (to be filtered by 40µ filter element)			
Min. / Max. Pressure	30psi (2bar) - 120psi (8.3 bar)			
Vacuum	Air pilot models can be used in vacuum applications with external air signal to pilot ports.			
Body	Glass Reinforced Thermoplastic			
Expected Life	20,000,000 cycles at max 3 cycles/second			
Temperature - Operation and Storage	0-120°F (-18-49°C)			
Lubrication	Not Required			
Protection	IP 65			




# Pneumatic Modular Air Pilot Valves – BVS Series

## Dimensions

inches [mm]

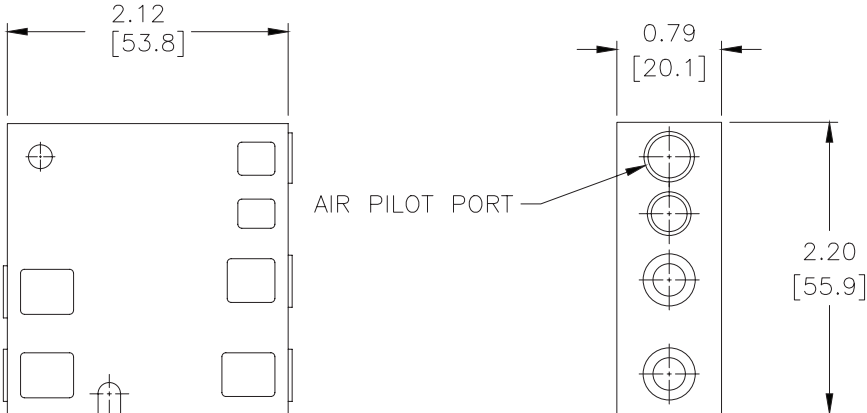

**BVS Single Air Pilot**

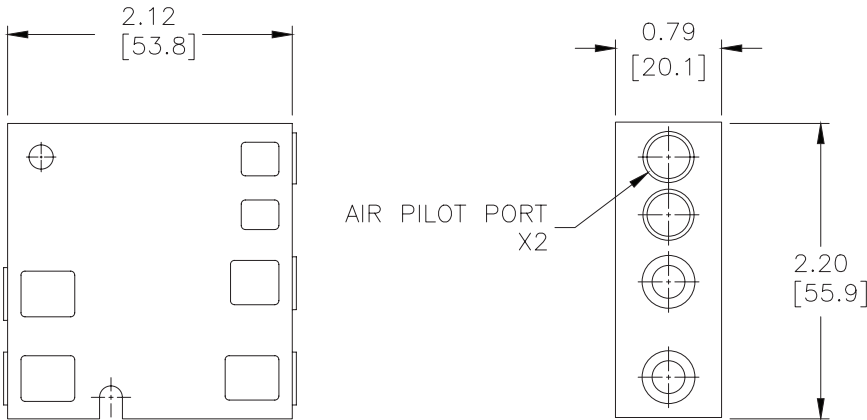

**BVS Double Air Pilot**

See our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete Engineering drawings.




# Manifolds for Modular Solenoid Valves – BVM-4 Series



**BVM - 2-Station**



**BVM - 3-Station**

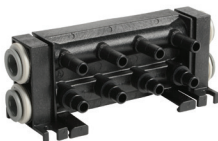

**BVM - 4-Station**

NITRA pneumatic BVM-4 series modular manifolds simplify the mounting of BVS-4 series solenoid valves. Made of sturdy glass reinforced thermoplastic with DIN rail mounting clips included, they are available in 2, 3 and 4-station models. Push-to-connect inlet and outlet ports allow quick and easy tubing connections.




### Features

- No tools required to install/remove valves
- 2, 3 or 4-station manifolds available
- 3/8" or 10mm tube inlets and outlets
- 35 mm DIN rail mounting clips included
- 2-year warranty

BVM Series Manifolds						
Part No.	Stations	Inlet	Outlet	Dimension "A" in [mm]	Price	Weight (lbs)
<b>BVM-4225</b>	2	3/8"	3/8"	2.71 [68.9]	\$22.00	0.3
<b>BVM-426M</b>	2	10mm	10mm		\$22.00	0.3
<b>BVM-4325</b>	3	3/8"	3/8"	3.54 [89.9]	\$24.00	0.3
<b>BVM-436M</b>	3	10mm	10mm		\$24.00	0.3
<b>BVM-4425</b>	4	3/8"	3/8"	4.37 [110.9]	\$26.00	0.3
<b>BVM-446M</b>	4	10mm	10mm		\$26.00	0.3

### Dimensions inches [mm]

#### 2-Station Manifold

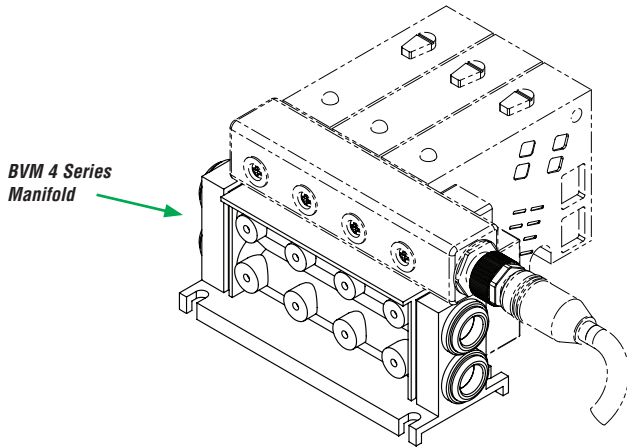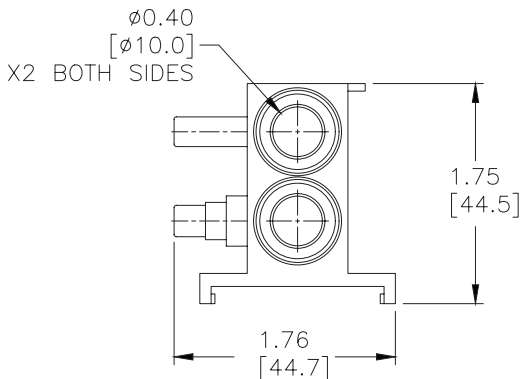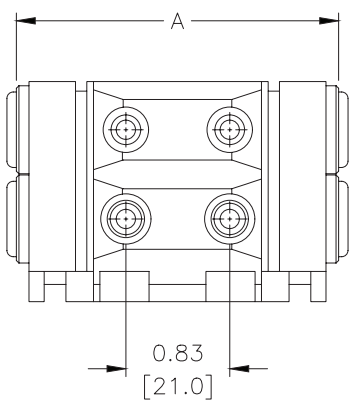

See our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete Engineering drawings.