



# Quick-Disconnect Fittings

**NITRA** pneumatic quick-disconnect hose couplings allow easy changing of tools or hose connections. Couplers and plugs are sold separately. Industrial Interchange, ARO210 and Truflate plugs are available in steel and chrome-plated steel. Couplers are available in Industrial Interchange manual or automatic and universal automatic. Safety couplers bleed off air pressure downstream before disconnecting.



## Features

- Plugs and couplers for 1/4 and 3/8 inch hose sizes
- Male and female NPT threaded
- Thread sealant supplied on all male fittings
- Maximum pressure of 250 psi, including safety coupler fittings

NITRA™ Quick-Disconnect 1/4 in. I.D. Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<a href="#"><u>HC14-14F-A</u></a>	\$7.75	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<a href="#"><u>HC14-38F-A</u></a>	\$8.25	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<a href="#"><u>HC14-14M-A</u></a>	\$7.75	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<a href="#"><u>HC14-38M-A</u></a>	\$8.00	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
<a href="#"><u>HC14-14F-B</u></a>	\$15.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<a href="#"><u>HC14-38F-B</u></a>	\$15.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<a href="#"><u>HC14-14M-B</u></a>	\$15.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<a href="#"><u>HC14-38M-B</u></a>	\$15.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
<a href="#"><u>HC14-14F-C</u></a>	\$20.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<a href="#"><u>HC14-38F-C</u></a>	\$20.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<a href="#"><u>HC14-14M-C</u></a>	\$20.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<a href="#"><u>HC14-38M-C</u></a>	\$20.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2




**HC14-38F-A**



**HC14-38F-B**



**HC14-14M-C**

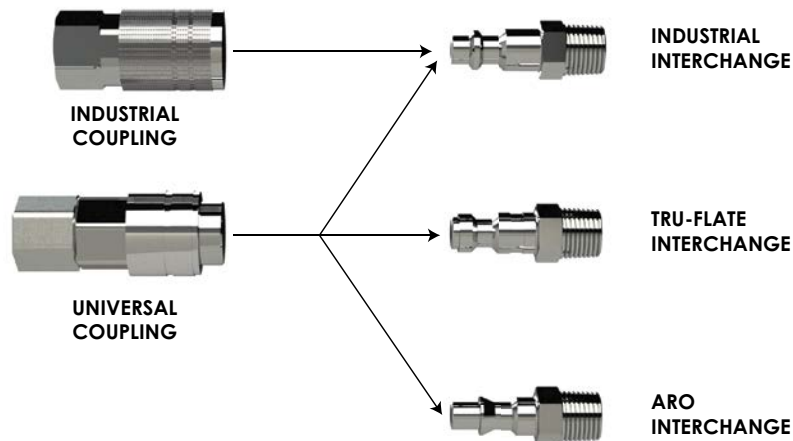



# Quick-Disconnect Fittings

**HCP14-14F-J****HCP14-14M-K****HCP14-14M-L****HCP14-14F-M**

NITRA™ Quick-Disconnect 1/4 in. I.D. Plug Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<a href="#"><u>HCP14-14F-J</u></a>	\$1.50	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<a href="#"><u>HCP14-38F-J</u></a>	\$3.00	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<a href="#"><u>HCP14-14M-J</u></a>	\$1.50	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<a href="#"><u>HCP14-38M-J</u></a>	\$2.50	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<a href="#"><u>HCP14-14F-K</u></a>	\$2.25	Quick-disconnect plug, ARO 210, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<a href="#"><u>HCP14-14M-K</u></a>	\$2.00	Quick-disconnect plug, ARO 210, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<a href="#"><u>HCP14-14F-L</u></a>	\$2.00	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<a href="#"><u>HCP14-14M-L</u></a>	\$1.50	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<a href="#"><u>HCP14-38M-L</u></a>	\$2.75	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<a href="#"><u>HCP14-14F-M</u></a>	\$2.75	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<a href="#"><u>HCP14-38F-M</u></a>	\$4.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<a href="#"><u>HCP14-14M-M</u></a>	\$2.75	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<a href="#"><u>HCP14-38M-M</u></a>	\$2.75	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1

**HC38-14F-A****HC38-14M-A****HC38-14M-B**

NITRA™ Quick-Disconnect 3/8 in. I.D. Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<a href="#"><u>HC38-14F-A</u></a>	\$11.50	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.3
<a href="#"><u>HC38-38F-A</u></a>	\$11.50	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.3
<a href="#"><u>HC38-12F-A</u></a>	\$12.50	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.3
<a href="#"><u>HC38-14M-A</u></a>	\$10.50	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.3
<a href="#"><u>HC38-38M-A</u></a>	\$12.00	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.3
<a href="#"><u>HC38-12M-A</u></a>	\$15.00	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.3
<a href="#"><u>HC38-14F-B</u></a>	\$16.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<a href="#"><u>HC38-38F-B</u></a>	\$16.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<a href="#"><u>HC38-14M-B</u></a>	\$16.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<a href="#"><u>HC38-38M-B</u></a>	\$16.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
<a href="#"><u>HC38-12M-B</u></a>	\$21.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.2



# Quick-Disconnect Fittings

**HCP38-14M-J****HCP38-14F-M**

<b>NITRA™ Quick-Disconnect 3/8 in. I.D. Plug Fittings Cont'd</b>				
<b>Part No.</b>	<b>Price</b>	<b>Description</b>	<b>Parts Per Pkg</b>	<b>Weight (lbs)</b>
<b><u>HCP38-14F-J</u></b>	\$2.50	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<b><u>HCP38-38F-J</u></b>	\$3.75	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<b><u>HCP38-14M-J</u></b>	\$4.00	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<b><u>HCP38-38M-J</u></b>	\$4.25	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<b><u>HCP38-14F-M</u></b>	\$3.75	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<b><u>HCP38-38F-M</u></b>	\$4.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<b><u>HCP38-12F-M</u></b>	\$6.00	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.2
<b><u>HCP38-14M-M</u></b>	\$3.75	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<b><u>HCP38-38M-M</u></b>	\$3.75	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<b><u>HCP38-12M-M</u></b>	\$5.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.1