



Quick-Disconnect Fittings

NITRA pneumatic quick-disconnect hose couplings allow easy changing of tools or hose connections. Couplers and plugs are sold separately. Industrial Interchange, ARO210 and Truflate plugs are available in steel and chrome-plated steel. Couplers are available in Industrial Interchange manual or automatic and universal automatic. Safety couplers bleed off air pressure downstream before disconnecting.

Features

- Plugs and couplers for 1/4 and 3/8 inch hose sizes
- Male and female NPT threaded
- Thread sealant supplied on all male fittings
- Maximum pressure of 250 psi, including safety coupler fittings



HC14-38F-A




HC14-38F-B



HC14-14M-C

NITRA™ Quick-Disconnect 1/4 in. I.D. Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HC14-14F-A	\$5.25	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
HC14-38F-A	\$5.75	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
HC14-14M-A	\$5.25	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
HC14-38M-A	\$5.50	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
HC14-14F-B	\$10.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
HC14-38F-B	\$10.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
HC14-14M-B	\$10.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
HC14-38M-B	\$10.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
HC14-14F-C	\$13.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
HC14-38F-C	\$13.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
HC14-14M-C	\$13.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
HC14-38M-C	\$13.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2

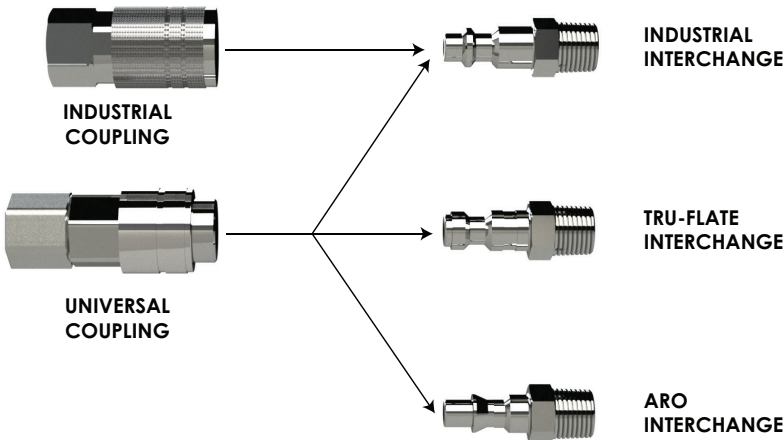



Quick-Disconnect Fittings



HCP14-14F-J



HCP14-14M-K



HCP14-14M-L



HCP14-14F-M

NITRA™ Quick-Disconnect 1/4 in. I.D. Plug Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HCP14-14F-J	\$1.25	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP14-38F-J	\$2.25	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
HCP14-14M-J	\$1.25	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP14-38M-J	\$2.00	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
HCP14-14F-K	\$1.75	Quick-disconnect plug, ARO 210, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP14-14M-K	\$1.50	Quick-disconnect plug, ARO 210, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP14-14F-L	\$1.50	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP14-38F-L	\$2.25	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
HCP14-14M-L	\$1.25	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP14-38M-L	\$2.25	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
HCP14-14F-M	\$2.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP14-38F-M	\$3.00	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
HCP14-14M-M	\$2.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP14-38M-M	\$2.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1



HC38-14F-A



HC38-14M-A



HC38-14M-B

NITRA™ Quick-Disconnect 3/8 in. I.D. Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HC38-14F-A	\$7.50	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.3
HC38-38F-A	\$7.50	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.3
HC38-12F-A	\$8.25	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.3
HC38-14M-A	\$6.75	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.3
HC38-38M-A	\$8.00	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.3
HC38-12M-A	\$10.00	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.3
HC38-14F-B	\$11.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
HC38-38F-B	\$11.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
HC38-12F-B	\$13.50	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.2
HC38-14M-B	\$11.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
HC38-38M-B	\$11.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
HC38-12M-B	\$13.50	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.2



Quick-Disconnect Fittings



HCP38-14M-J



HCP38-14F-M



HC14-14M-D

NITRA™ Quick-Disconnect 3/8 in. I.D. Plug Fittings Cont'd				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HCP38-14F-J	\$2.00	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP38-38F-J	\$2.50	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
HCP38-14M-J	\$2.75	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP38-38M-J	\$3.00	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
HCP38-14F-M	\$2.50	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP38-38F-M	\$3.00	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
HCP38-12F-M	\$4.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.2
HCP38-14M-M	\$2.50	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP38-38M-M	\$2.50	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
HCP38-12M-M	\$3.75	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.1

NITRA™ Quick-Disconnect 1/4 in. I.D. Safety Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HC14-14M-D	\$16.50	Quick-disconnect automatic safety coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.3
HC14-14F-D	No Match!	Quick-disconnect automatic safety coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.3