



# Quick-Disconnect Fittings

**NITRA** pneumatic quick-disconnect hose couplings allow easy changing of tools or hose connections. Couplers and plugs are sold separately. Industrial Interchange, ARO210 and Truflate plugs are available in steel and chrome-plated steel. Couplers are available in Industrial Interchange manual or automatic and universal automatic. Safety couplers bleed off air pressure downstream before disconnecting.

## Features

- Plugs and couplers for 1/4 and 3/8 inch hose sizes
- Male and female NPT threaded
- Thread sealant supplied on all male fittings
- Maximum pressure of 250 psi, including safety coupler fittings



**HC14-38F-A**




**HC14-38F-B**



**HC14-14M-C**

NITRA™ Quick-Disconnect 1/4 in. I.D. Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<b>HC14-14F-A</b>	\$5.25	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<b>HC14-38F-A</b>	\$5.75	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<b>HC14-14M-A</b>	\$5.25	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<b>HC14-38M-A</b>	\$5.50	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
<b>HC14-14F-B</b>	\$10.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<b>HC14-38F-B</b>	\$10.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<b>HC14-14M-B</b>	\$10.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<b>HC14-38M-B</b>	\$10.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
<b>HC14-14F-C</b>	\$13.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<b>HC14-38F-C</b>	\$13.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<b>HC14-14M-C</b>	\$13.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<b>HC14-38M-C</b>	\$13.00	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2

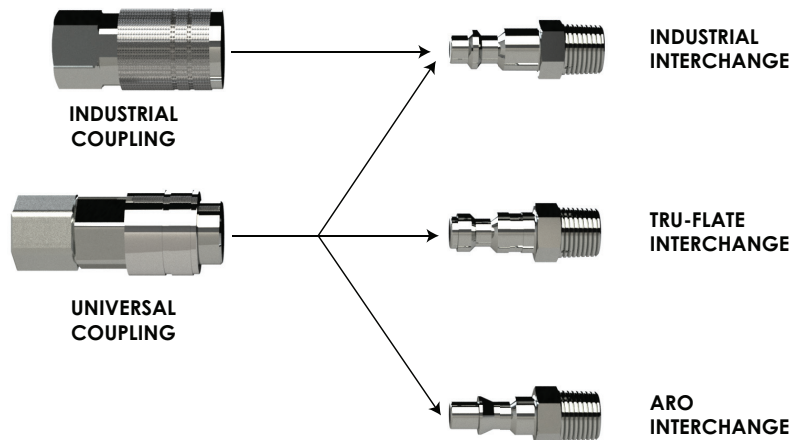



# Quick-Disconnect Fittings



**HCP14-14F-J**



**HCP14-14M-K**



**HCP14-14M-L**



**HCP14-14F-M**

NITRA™ Quick-Disconnect 1/4 in. I.D. Plug Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<b>HCP14-14F-J</b>	\$1.25	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<b>HCP14-38F-J</b>	\$2.25	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<b>HCP14-14M-J</b>	\$1.25	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<b>HCP14-38M-J</b>	\$2.00	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<b>HCP14-14F-K</b>	\$1.75	Quick-disconnect plug, ARO 210, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<b>HCP14-14M-K</b>	\$1.50	Quick-disconnect plug, ARO 210, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<b>HCP14-14F-L</b>	\$1.50	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<b>HCP14-38F-L</b>	\$2.25	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<b>HCP14-14M-L</b>	\$1.25	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<b>HCP14-38M-L</b>	\$2.25	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<b>HCP14-14F-M</b>	\$2.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<b>HCP14-38F-M</b>	\$3.00	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<b>HCP14-14M-M</b>	\$2.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<b>HCP14-38M-M</b>	\$2.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1



**HC38-14F-A**



**HC38-14M-A**



**HC38-14M-B**

NITRA™ Quick-Disconnect 3/8 in. I.D. Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<b>HC38-14F-A</b>	\$7.50	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.3
<b>HC38-38F-A</b>	\$7.50	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.3
<b>HC38-12F-A</b>	\$8.25	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.3
<b>HC38-14M-A</b>	\$6.75	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.3
<b>HC38-38M-A</b>	\$8.00	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.3
<b>HC38-12M-A</b>	\$10.00	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.3
<b>HC38-14F-B</b>	\$11.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<b>HC38-38F-B</b>	\$11.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<b>HC38-12F-B</b>	\$13.50	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.2
<b>HC38-14M-B</b>	\$11.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<b>HC38-38M-B</b>	\$11.00	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
<b>HC38-12M-B</b>	\$13.50	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.2



# Quick-Disconnect Fittings



**HCP38-14M-J**



**HCP38-14F-M**



**HC14-14M-D**

<b>NITRA™ Quick-Disconnect 3/8 in. I.D. Plug Fittings Cont'd</b>				
<b>Part No.</b>	<b>Price</b>	<b>Description</b>	<b>Parts Per Pkg</b>	<b>Weight (lbs)</b>
<b>HCP38-14F-J</b>	\$2.00	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<b>HCP38-38F-J</b>	\$2.50	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<b>HCP38-14M-J</b>	\$2.75	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<b>HCP38-38M-J</b>	\$3.00	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<b>HCP38-14F-M</b>	\$2.50	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<b>HCP38-38F-M</b>	\$3.00	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<b>HCP38-12F-M</b>	\$4.25	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.2
<b>HCP38-14M-M</b>	\$2.50	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<b>HCP38-38M-M</b>	\$2.50	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<b>HCP38-12M-M</b>	\$3.75	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.1

<b>NITRA™ Quick-Disconnect 1/4 in. I.D. Safety Coupler Fittings</b>				
<b>Part No.</b>	<b>Price</b>	<b>Description</b>	<b>Parts Per Pkg</b>	<b>Weight (lbs)</b>
<b>HC14-14M-D</b>	\$16.50	Quick-disconnect automatic safety coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.3
<b>HC14-14F-D</b>	\$16.50	Quick-disconnect automatic safety coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.3