




Quick-Disconnect Swivel Fittings

Features

- Two independent-rotation points allow a full 360° circular rotation and 45° angled rotation for better swivel action vs. traditional swivel fittings
- Prevents kinking of and strain on the supply line
- Lightweight, streamlined design
- Chrome-plated steel construction for long service life
- Thread sealant supplied on all male fittings
- Maximum pressure of 145 psi

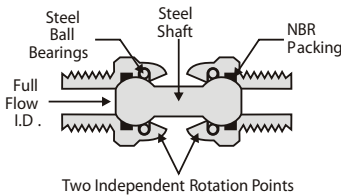

45° Swivel Design



HS14F-14M

NITRA™ 1/4 in. NPT Swivel Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HS14F-14M	\$26.00	Swivel fitting, chrome plated steel, 1/4 inch female NPT and 1/4 inch male NPT threaded connections	1	0.2



HSP38-14M-S

NITRA™ Quick-Disconnect Plug to NPT Swivel Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HSP14-14M-S	\$27.00	Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch industrial interchange plug and 1/4 inch male NPT threaded connection	1	0.2
HSP38-14M-S	\$27.00	Quick-disconnect swivel fitting, chrome plated steel, 3/8 inch industrial interchange plug and 1/4 inch male NPT threaded connection	1	0.2
HSP38-38M-S	\$30.00	Quick-disconnect swivel fitting, chrome plated steel, 3/8 inch industrial interchange plug and 3/8 inch male NPT threaded connection	1	0.2
HSP14-14M-T	\$30.00	Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch ARO 210 plug and 1/4 inch male NPT threaded connection	1	0.1
HSP14-14M-U	\$30.00	Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch Truflate plug and 1/4 inch male NPT threaded connection	1	0.1