




Pneumatic Stem Adapters and Special Purpose Fitting Accessories

NITRA pneumatic stem adapters are used to easily connect push-to-connect fittings to a threaded port. They are made of nickel-plated brass. Five adapters per package.

Features


- Works with push-to-connect fittings
- Nickel-plated brass
- Two-year warranty

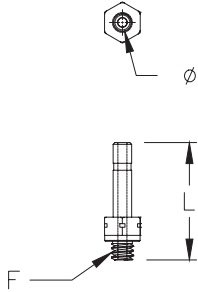

| NITRA® Stem Adapters | | | | | | | |
|---|--------|----------------------------|------|-----------|------|----------------------|---------------|
| Inch Sizes - dimensions in inches (in.) | | | | | | | |
| Part No. | Price | Tube Size | ø | F | L | Package Weight (lbs) | Qty. per pack |
| SA532-10N | \$3.25 | 5/32 in. [4mm] x 10/32 UNF | 5/32 | 10/32 UNF | 0.99 | 0.1 | 5 |
| SA532-18N | \$3.50 | 5/32 in. [4mm] x 1/8 NPT | 5/32 | 1/8 NPT | 1.09 | 0.1 | 5 |
| SA532-14N | \$5.00 | 5/32 in. [4mm] x 1/4 NPT | 5/32 | 1/4 NPT | 1.19 | 0.2 | 5 |
| SA14-10N | \$4.50 | 1/4 in. x 10/32 UNF | 1/4 | 10/32 UNF | 1.01 | 0.1 | 5 |
| SA14-18N | \$3.25 | 1/4 in. x 1/8 NPT | 1/4 | 1/8 NPT | 1.11 | 0.1 | 5 |
| SA14-14N | \$3.50 | 1/4 in. x 1/4 NPT | 1/4 | 1/4 NPT | 1.20 | 0.2 | 5 |
| SA14-38N | \$4.00 | 1/4 in. x 3/8 NPT | 1/4 | 3/8 NPT | 1.31 | 0.3 | 5 |
| SA516-18N | \$3.25 | 5/16 in. [8mm] x 1/8 NPT | 5/16 | 1/8 NPT | 1.15 | 0.1 | 5 |
| SA516-14N | \$3.50 | 5/16 in. [8mm] x 1/4 NPT | 5/16 | 1/4 NPT | 1.24 | 0.2 | 5 |
| SA516-38N | \$5.50 | 5/16 in. [8mm] x 3/8 NPT | 5/16 | 3/8 NPT | 1.35 | 0.3 | 5 |

See our website www.AutomationDirect.com for complete Engineering drawings.

Special Purpose Fitting Accessories

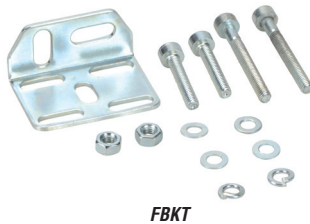

FBKT



TU14


| NITRA® Special Purpose Pneumatic Fitting Accessories | | | |
|--|--------|--|--------------|
| Part No. | Price | Description | Weight (lbs) |
| FBKT | \$2.25 | NITRA pneumatic mounting bracket, fits all push-to-connect fittings, plated steel. Screws supplied with bracket are for mounting one fitting only. | 0.1 |
| TU14 | \$3.00 | NITRA pneumatic U-tube, polyamide, 1/4 inch, works with push-to-connect fittings | 0.1 |
| TU516 | \$3.00 | NITRA pneumatic U-tube, polyamide, 5/16 inch [8mm], works with push-to-connect fittings | 0.1 |



Special Purpose Push-to-Connect Pneumatic Fittings

NITRA pneumatic inline fittings are special purpose products mounted inline with pneumatic circuits. With these small, highly efficient components it is possible to perform many pneumatic functions at any point in a circuit.

- Ultra-modular
- Components can be connected in parallel
- Push-to-Connect: No tools required!
- Made of lightweight technopolymer
- Stem adapters connect push-to-connect fittings to NPT ports

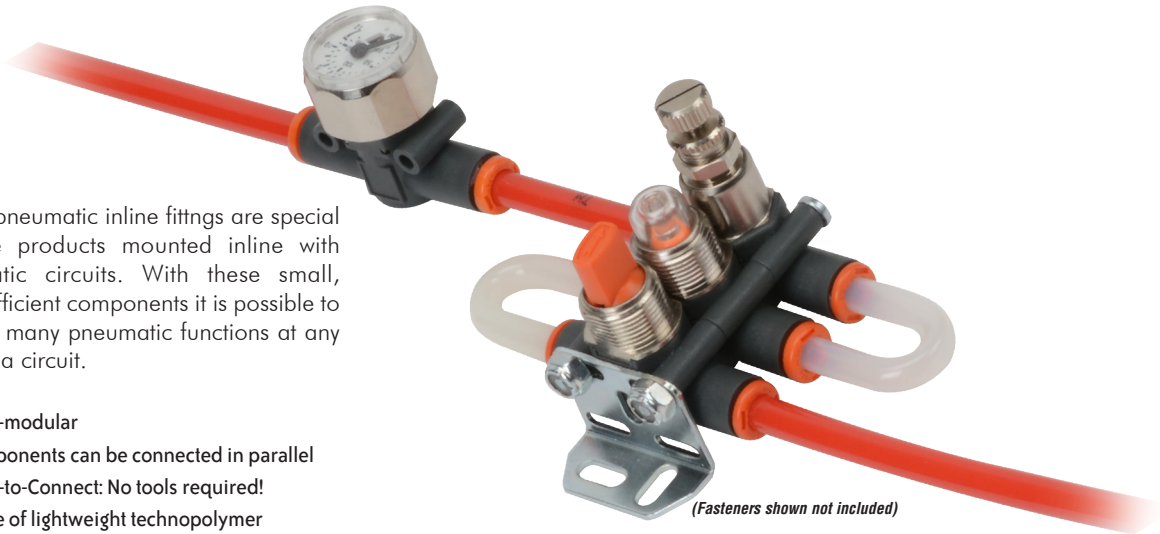

(Fasteners shown not included)



INLINE PRESSURE REGULATORS
from \$20.25



INLINE PRESSURE GAUGES
from \$17.75



INLINE PRESSURE INDICATORS
from \$11.75



INLINE MANUAL SHUTOFF VALVES
from \$11.25



INLINE QUICK EXHAUST VALVES
from \$8.75



STEM ADAPTERS
from \$3.25