



1/4" NPT Stainless Steel Manifolds



MRS-2CB

NITRA stainless steel manifolds


- 303 Stainless Steel
- Maximum input pressure of 3500 psi
- Made in the USA



| NITRA® 1/4" NPT Stainless Steel Manifolds | | | | | |
|---|--|--------------|---------------|--------------|---------|
| Part No. | Description | A | Parts Per Pkg | Weight (lbs) | Price |
| MRS-2CB | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 2 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 1.75 [44.5] | 1 | 0.4 | \$49.00 |
| MRS-3CB | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 3 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 2.50 [63.0] | 1 | 0.5 | \$54.00 |
| MRS-4CB | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 4 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 3.25 [82.6] | 1 | 0.7 | \$58.00 |
| MRS-5CB | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 5 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 4.00 [101.6] | 1 | 0.9 | \$61.00 |
| MRS-6CB | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 6 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 4.75 [120.7] | 1 | 1.1 | \$64.00 |
| MRS-7CB | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 7 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 5.50 [139.7] | 1 | 1.2 | \$68.00 |
| MRS-8CB | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 8 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 6.25 [158.8] | 1 | 1.4 | \$73.00 |
| MRS-9CB | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 9 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 7.00 [177.8] | 1 | 1.6 | \$78.00 |
| MRS-10CB | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 10 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 7.75 [196.9] | 1 | 1.7 | \$84.00 |

Dimensions

inches [mm]

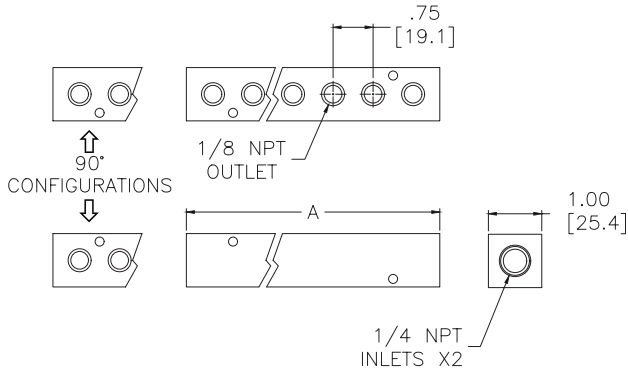

See our website www.AutomationDirect.com for complete Engineering drawings.



3/8" NPT Stainless Steel Manifolds



MRS-2DC


- NITRA** stainless steel manifolds
- 303 Stainless Steel
 - Maximum input pressure of 3500 psi
 - Made in the USA



| NITRA® 3/8" NPT Stainless Steel Manifolds | | | | | |
|---|--|--------------|---------------|--------------|----------|
| Part No. | Description | A | Parts Per Pkg | Weight (lbs) | Price |
| MRS-2DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 2 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 2.13 [54.1] | 1 | 0.7 | \$58.00 |
| MRS-3DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 3 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 3.00 [76.2] | 1 | 1.0 | \$64.00 |
| MRS-4DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 4 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 3.88 [98.6] | 1 | 1.3 | \$69.00 |
| MRS-5DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 5 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 4.75 [120.7] | 1 | 1.6 | \$77.00 |
| MRS-6DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 6 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 5.63 [143.0] | 1 | 1.9 | \$84.00 |
| MRS-7DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 7 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 6.50 [165.1] | 1 | 2.2 | \$91.00 |
| MRS-8DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 8 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 7.38 [187.5] | 1 | 2.5 | \$99.00 |
| MRS-9DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 9 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 8.25 [209.6] | 1 | 2.8 | \$105.00 |
| MRS-10DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 10 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 9.13 [231.9] | 1 | 3.1 | \$114.00 |

Dimensions

inches [mm]

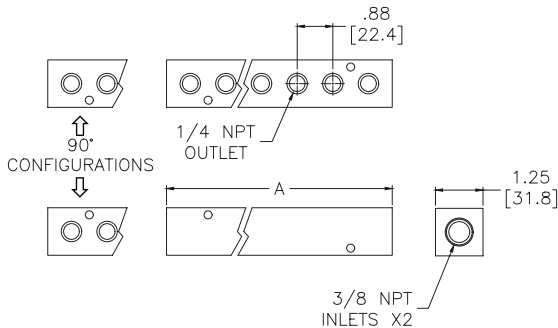

See our website www.AutomationDirect.com for complete Engineering drawings.