

Enclosures Subpanels



Subpanels for NEMA 1, 12, 4 and 4X wall mount enclosures and WC9 NEMA 12 operator consoles

- 12 gauge steel
- Subpanels with any side over 17" have 3/4" flange on all sides
- Subpanels are painted white polyester powder

Panels listed fit the following enclosures:


- NEMA 1 large (NIC)
- NEMA 12 large (JIC)
- NEMA 12 single door wall mount
- NEMA 12 two door wall mount
- NEMA 12 single door flush wall mount
- NEMA 4 (N) and 4X (SSN) single door wall mount
- NEMA 12 operator consoles (WC9)

NOTE: Use NPxxxx subpanels in NEMA 1, NEMA 4 and 4X, and NEMA 12 enclosures only. Do NOT use NPxxxx subpanels in NEMA 4/12 enclosures with a C suffix.



| Enclosure Shipping Schedule | | |
|---|------------|------------|
| Same day | 1 - 7 days | 1 -10 days |
| Color indicates shipping lead time in business days | | |

| Part Number | Price | Enclosure Size HxW | Subpanel Size AxB |
|-------------|------------|--------------------|-------------------|
| NP1212 | <---> | 12x12 (305x305) | 9x9 (229x229) |
| NP1224 | <---> | 12x24 (305x610) | 9x21 (229x533) |
| NP1612 | <---> | 16x12 (406x305) | 13x9 (330x229) |
| NP1616 | <---> | 16x16 (406x406) | 13x13 (330x330) |
| NP2012 | <---> | 20x12 (508x305) | 17x9 (432x229) |
| NP2016 | <---> | 20x16 (508x406) | 17x13 (432x330) |
| NP2020 | <---> | 20x20 (508x508) | 17x17 (432x432) |
| NP2412 | Use NP1224 | | 21x9 (533x229) |
| NP2416 | <---> | 24x16 (610x406) | 21x13 (533x330) |
| NP2420 | <---> | 24x20 (610x508) | 21x17 (533x432) |
| NP2424 | <---> | 24x24 (610x610) | 21x21 (533x533) |
| NP3016 | <---> | 30x16 (762x406) | 27x13 (686x330) |
| NP3020 | <---> | 30x20 (762x508) | 27x17 (686x432) |
| NP3024 | <---> | 30x24 (762x610) | 27x21 (686x533) |
| NP3030 | <---> | 30x30 (762x762) | 27x27 (686x686) |
| NP3624 | <---> | 36x24 (914x610) | 33x21 (838x533) |
| NP3630 | <---> | 36x30 (914x762) | 33x27 (838x686) |
| NP3636 | <---> | 36x36 (914x914) | 33x33 (838x838) |
| NP4024 | <---> | 40x24 (1016x610) | 37x21 (940x533) |
| NP4224 | <---> | 42x24 (1067x610) | 39x21 (991x533) |
| NP4230 | <---> | 42x30 (1067x762) | 39x27 (991x686) |
| NP4236 | <---> | 42x36 (1067x914) | 39x33 (991x838) |
| NP4824 | <---> | 48x24 (1219x610) | 45x21 (1143x533) |
| NP4830 | <---> | 48x30 (1219x762) | 45x27 (1143x686) |
| NP4836 | <---> | 48x36 (1219x914) | 45x33 (1143x838) |
| NP6030 | <---> | 60x30 (1527x762) | 57x27 (1448x686) |
| NP6036 | <---> | 60x36 (1527x914) | 57x33 (1448x838) |
| NP7230 | <---> | 72x30 (1832x762) | 69x27 (1753x686) |
| NP7236 | <---> | 72x36 (1832x914) | 69x33 (1753x838) |

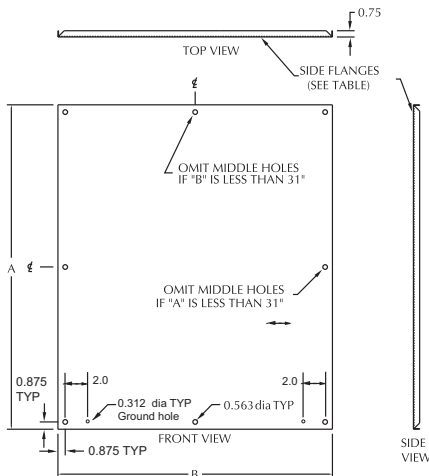

Note: Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawing.