

19-Inch Rack Cabinets



Multi-use racks providing numerous options for equipment rack mounting. Ideal for securing rack mount equipment in spaces where room for a traditional rack or cabinet is limited or not available. The modular design includes a body with numerous accessory options to suit your unique application.

Features

- 19 in [483 mm] mounting rail slots allow for adjustable depth rails and/or optional fan installation.
- Mounting rails are easily removed for non-rack mounting equipment.
- Starter pack of CAGKIT1032-10 screws and cage nuts included with 3U units or CAGKIT1032-50 screws and cage nuts included with 6U and 9U units.
- Removable cover panel for ease of equipment installation.
- Includes four cutouts perfect for mounting over an electrical receptacle and/or for cable entry.
- Interior cable management lances.
- Removable plastic handles for side mounting storage.
- Optional surface mounted doors with 1/4-turn lock and end cap available.



Construction

- Cabinet frame, removable cover and doors constructed from 16-gauge steel.
- Square hole 19 in [483 mm] mounting rails are constructed from 12-gauge steel, include rack unit indicators, and are finished in smooth black powder coat.
- Suggested load ratings:
 - Wall-Mount (Rack-Mounted) up to 150 lb [68 kg].
 - Wall-Mount (Rails removed) up to 50 lb [22 kg].
 - Ceiling/ Under Desk Mount up to 150 lb [68 kg].
 - Freestanding (with or without casters) up to 800 lb [362 kg].
- Grounding studs provided on frame as well as on side panels and doors.
- Include punched square holes with 10-32 cage nuts and screws.

Listings

- TAA compliant for GSA Schedule purchases.
- RoHS



19-Inch Rack Cabinets				
Part Number	Price	Rack Units	Overall Size HxWxD	Drawing Link
SDC243U17BK		3U	6.25 x 24.00 x 17.50 [159 x 610 x 445]	PDF
SDC243U24BK		3U	6.25 x 24.00 x 24.50 [159 x 610 x 622]	PDF
SDC243U31BK		3U	6.25 x 24.00 x 31.50 [159 x 610 x 800]	PDF
SDC243U36BK		3U	6.25 x 24.00 x 36.00 [159 x 610 x 914]	PDF
SDC246U17BK		6U	11.50 x 24.00 x 17.50 [292 x 610 x 445]	PDF
SDC246U24BK		6U	11.50 x 24.00 x 24.50 [292 x 610 x 622]	PDF
SDC246U31BK		6U	11.50 x 24.00 x 31.50 [292 x 610 x 800]	PDF
SDC246U36BK		6U	11.50 x 24.00 x 36.00 [292 x 610 x 914]	PDF
SDC249U17BK		9U	16.75 x 24.00 x 17.50 [425 x 610 x 445]	PDF
SDC249U24BK		9U	16.75 x 24.00 x 24.50 [425 x 610 x 622]	PDF
SDC249U31BK		9U	16.75 x 24.00 x 31.50 [425 x 610 x 800]	PDF
SDC249U36BK		9U	16.75 x 24.00 x 36.00 [425 x 610 x 914]	PDF

Note: Dimensions in inches [millimeters].

19-Inch Rack Cabinets

Accessories




Solid Cabinet Doors

Part Number	Price	Rack Units	Drawing Link
SDC3USD		3U	PDF
SDC6USD		6U	PDF
SDC9USD		9U	PDF



Vented Cabinet Doors

Part Number	Price	Rack Units	Drawing Link
SDC3UVD		3U	PDF
SDC6UVD		6U	PDF
SDC9UVD		9U	PDF

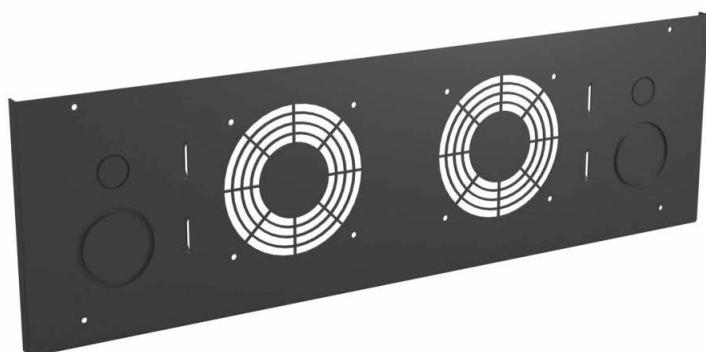

Fan Cover Panels

Part Number	Price	Rack Units	Drawing Link
SDC3UCFP		3U	PDF
SDC6UCFP		6U	PDF
SDC9UCFP		9U	PDF

Compatible with fans [DNFK1AC120](#) and [DNFK2AC120](#)