

# Flanged Steel Panels for 19-Inch Racks



## Application

Install in unused 19 in [483 mm] wide rack space to improve both cooling efficiency and prevent air recirculation.

## Features

- Fits standard EIA compliant rails.

## Construction

- Constructed of 16-gauge steel.
- Finished in smooth powder coat.

## Listings

- TAA compliant for GSA Schedule purchases.
- RoHS



**Flanged Steel Panels for 19-Inch Racks**

| <i>Gloss Black</i>                  | <i>Matte Black</i>                 | <i>RAL7035 Gray</i>                 | <i>ANSI 61 Gray</i>                 | <i>Price</i> | <i>Rack Units</i> | <i>Panel Height</i> | <i>Drawing Link</i>        |
|-------------------------------------|------------------------------------|-------------------------------------|-------------------------------------|--------------|-------------------|---------------------|----------------------------|
| <a href="#"><u>PBFS19000BK2</u></a> | <a href="#"><u>PBFS19000BK</u></a> | —                                   | —                                   |              | 1/2U              | 0.90 [23]           | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBFS19001BK2</u></a> | <a href="#"><u>PBFS19001BK</u></a> | <a href="#"><u>PBFS19001LG2</u></a> | <a href="#"><u>PBFS19001GY2</u></a> |              | 1U                | 1.75 [44]           | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBFS19003BK2</u></a> | <a href="#"><u>PBFS19003BK</u></a> | <a href="#"><u>PBFS19003LG2</u></a> | <a href="#"><u>PBFS19003GY2</u></a> |              | 2U                | 3.50 [89]           | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBFS19005BK2</u></a> | <a href="#"><u>PBFS19005BK</u></a> | <a href="#"><u>PBFS19005LG2</u></a> | <a href="#"><u>PBFS19005GY2</u></a> |              | 3U                | 5.25 [133]          | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBFS19007BK2</u></a> | <a href="#"><u>PBFS19007BK</u></a> | <a href="#"><u>PBFS19007LG2</u></a> | <a href="#"><u>PBFS19007GY2</u></a> |              | 4U                | 7.00 [178]          | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBFS19008BK2</u></a> | —                                  | <a href="#"><u>PBFS19008LG2</u></a> | <a href="#"><u>PBFS19008GY2</u></a> |              | 5U                | 8.75 [222]          | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBFS19010BK2</u></a> | —                                  | <a href="#"><u>PBFS19010LG2</u></a> | <a href="#"><u>PBFS19010GY2</u></a> |              | 6U                | 10.50 [267]         | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBFS19012BK2</u></a> | —                                  | <a href="#"><u>PBFS19012LG2</u></a> | <a href="#"><u>PBFS19012GY2</u></a> |              | 7U                | 12.25 [311]         | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBFS19014BK2</u></a> | —                                  | <a href="#"><u>PBFS19014LG2</u></a> | <a href="#"><u>PBFS19014GY2</u></a> |              | 8U                | 14.00 [356]         | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBFS19015BK2</u></a> | —                                  | <a href="#"><u>PBFS19015LG2</u></a> | <a href="#"><u>PBFS19015GY2</u></a> |              | 9U                | 15.75 [400]         | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBFS19017BK2</u></a> | —                                  | <a href="#"><u>PBFS19017LG2</u></a> | <a href="#"><u>PBFS19017GY2</u></a> |              | 10U               | 17.50 [445]         | <a href="#"><u>PDF</u></a> |

Note: Dimensions in inches [millimeters].

# Flat Steel Panels for 19-Inch Racks


**HAMMOND  
MANUFACTURING®**

## Application

Install in unused 19 in [483 mm] wide rack space to improve both cooling efficiency and prevent air recirculation.

## Features


- Fits standard EIA compliant rails.

## Construction

- Constructed of 14-gauge steel.
- Finished in smooth powder coat.

## Listings

- TAA compliant for GSA Schedule purchases.
- RoHS

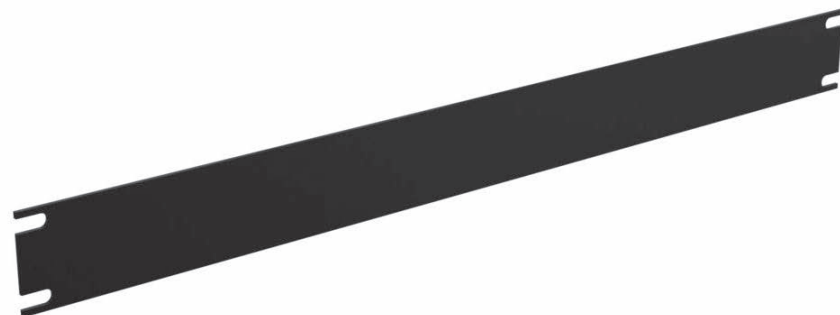

| Flat Steel Panels for 19-Inch Racks |                                    |                                     |                                     |              |                   |                     |                            |
|-------------------------------------|------------------------------------|-------------------------------------|-------------------------------------|--------------|-------------------|---------------------|----------------------------|
| <i>Gloss Black</i>                  | <i>Matte Black</i>                 | <i>RAL7035 Gray</i>                 | <i>ANSI 61 Gray</i>                 | <i>Price</i> | <i>Rack Units</i> | <i>Panel Height</i> | <i>Drawing Link</i>        |
| <a href="#"><u>PBPS19001BK2</u></a> | <a href="#"><u>PBPS19001BK</u></a> | <a href="#"><u>PBPS19001LG2</u></a> | <a href="#"><u>PBPS19001GY2</u></a> |              | 1U                | 1.75 [44]           | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBPS19003BK2</u></a> | <a href="#"><u>PBPS19003BK</u></a> | <a href="#"><u>PBPS19003LG2</u></a> | <a href="#"><u>PBPS19003GY2</u></a> |              | 2U                | 3.50 [89]           | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBPS19005BK2</u></a> | <a href="#"><u>PBPS19005BK</u></a> | <a href="#"><u>PBPS19005LG2</u></a> | <a href="#"><u>PBPS19005GY2</u></a> |              | 3U                | 5.25 [133]          | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBPS19007BK2</u></a> | <a href="#"><u>PBPS19007BK</u></a> | <a href="#"><u>PBPS19007LG2</u></a> | <a href="#"><u>PBPS19007GY2</u></a> |              | 4U                | 7.00 [178]          | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBPS19008BK2</u></a> | —                                  | <a href="#"><u>PBPS19008LG2</u></a> | <a href="#"><u>PBPS19008GY2</u></a> |              | 5U                | 8.75 [222]          | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBPS19010BK2</u></a> | —                                  | <a href="#"><u>PBPS19010LG2</u></a> | <a href="#"><u>PBPS19010GY2</u></a> |              | 6U                | 10.50 [267]         | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBPS19012BK2</u></a> | —                                  | <a href="#"><u>PBPS19012LG2</u></a> | <a href="#"><u>PBPS19012GY2</u></a> |              | 7U                | 12.25 [311]         | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBPS19014BK2</u></a> | —                                  | <a href="#"><u>PBPS19014LG2</u></a> | —                                   |              | 8U                | 14.00 [356]         | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBPS19015BK2</u></a> | —                                  | <a href="#"><u>PBPS19015LG2</u></a> | —                                   |              | 9U                | 15.75 [400]         | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>PBPS19017BK2</u></a> | —                                  | <a href="#"><u>PBPS19017LG2</u></a> | —                                   |              | 10U               | 17.50 [445]         | <a href="#"><u>PDF</u></a> |

Note: Dimensions in inches [millimeters].