

Perforated Steel Panels for 19-Inch Racks



Application

Install in unused 19 in [483 mm] wide rack space to improve both cooling efficiency and allow 25% air recirculation.

Features


- Fits standard EIA compliant rails.
- Allows 25% airflow through panel.

Construction

- Constructed of 16-gauge steel.
- Finished in smooth powder coat.

Listings

- TAA compliant for GSA Schedule purchases.
- RoHS

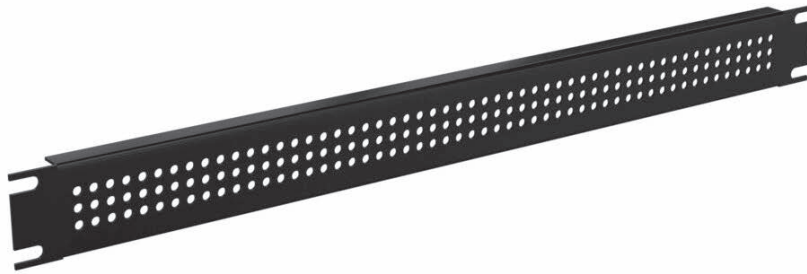

Perforated Steel Panels for 19-Inch Racks

<i>Gloss Black</i>	<i>RAL7035 Gray</i>	<i>Price</i>	<i>Rack Units</i>	<i>Panel Height</i>	<i>Drawing Link</i>
<u>PPFS19001BK2</u>	<u>PPFS19001LG2</u>		1U	1.75 [44]	<u>PDF</u>
<u>PPFS19003BK2</u>	<u>PPFS19003LG2</u>		2U	3.50 [89]	<u>PDF</u>
<u>PPFS19005BK2</u>	<u>PPFS19005LG2</u>		3U	5.25 [133]	<u>PDF</u>
<u>PPFS19007BK2</u>	<u>PPFS19007LG2</u>		4U	7.00 [178]	<u>PDF</u>
<u>PPFS19008BK2</u>	<u>PPFS19008LG2</u>		5U	8.75 [222]	<u>PDF</u>
<u>PPFS19010BK2</u>	<u>PPFS19010LG2</u>		6U	10.50 [267]	<u>PDF</u>

Note: Dimensions in inches [millimeters].