


Rack Rail Reducer Panels

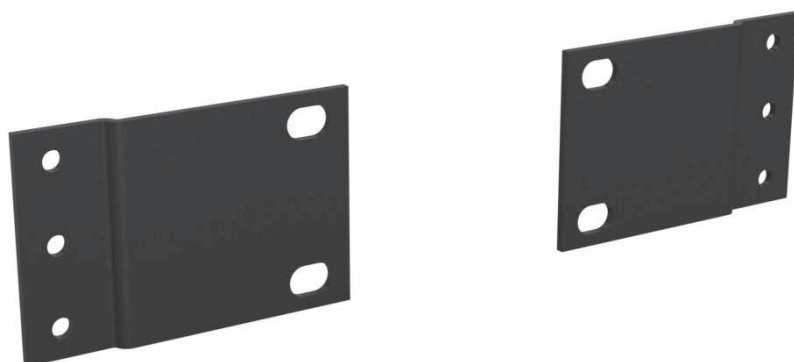

Features

- Sold in pairs.
- Round punched hole or tapped 12-24 for 19 in [483 mm] mounting.
- Converts standard 23 in [584 mm] or 24 in [610 mm] rack mounting rails to 19 in [483 mm] rack mounting.

Construction

- Constructed from 14-gauge steel.
- Side of rail folded for rear support or accessory mounting.

Listings

- TAA Compliant for GSA Schedule purchases.
- EIA compliant
- RoHS



24-Inch Rack Rail Reducer Panels

<i>Glossy Black</i>	<i>RAL7035 Gray</i>	<i>Price</i>	<i>Rack Units</i>	<i>Height</i>	<i>Drawing Link</i>
<u>PBAS19001BK2</u>	<u>PBAS19001LG2</u>		1U	1.75 [44]	<u>PDF</u>
<u>PBAS19003BK2</u>	<u>PBAS19003LG2</u>		2U	3.50 [89]	<u>PDF</u>
<u>PBAS19005BK2</u>	<u>PBAS19005LG2</u>		3U	5.25 [133]	<u>PDF</u>
<u>PBAS19007BK2</u>	<u>PBAS19007LG2</u>		4U	7.00 [178]	<u>PDF</u>
<u>PBAS19008BK2</u>	<u>PBAS19008LG2</u>		5U	8.75 [222]	<u>PDF</u>
<u>PBAS19010BK2</u>	<u>PBAS19010LG2</u>		6U	10.50 [267]	<u>PDF</u>
<u>PBAS19012BK2</u>	<u>PBAS19012LG2</u>		7U	12.25 [311]	<u>PDF</u>
<u>PBAS19014BK2</u>	<u>PBAS19014LG2</u>		8U	14.00 [356]	<u>PDF</u>

Note: Dimensions in inches [millimeters].

23-Inch Rack Rail Reducer Panels

<i>Part Number</i>	<i>Price</i>	<i>Rack Units</i>	<i>Height</i>	<i>Drawing Link</i>
<u>PA2319001BK1</u>		1U	1.75 [44]	<u>PDF</u>
<u>PA2319003BK1</u>		2U	3.50 [89]	<u>PDF</u>
<u>PA2319005BK1</u>		3U	5.25 [133]	<u>PDF</u>
<u>PA2319008BK1</u>		5U	8.75 [222]	<u>PDF</u>

Note: Dimensions in inches [millimeters].