


Rack Rails

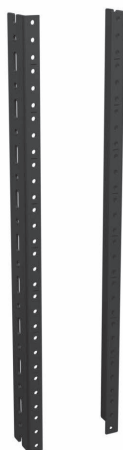

Features

- Sold in pairs.
- Drilled and tapped 10-32 holes.
 - Rack mounting hardware sold separately.
- Rails come included with rack unit indicator.
- Rails can be used for 19 in [483 mm], 23 in [584 mm], and 24 in [610 mm] rack mounting applications.
- Also compatible with RB-2PW wall rack and 24 in [610 mm] wide HWC wall cabinet.



Construction

- Constructed from 12-gauge steel.
- Side of rail folded for rear support or accessory mounting.
- Finished in smooth black powder coat.

Listings

- TAA Compliant for GSA Schedule purchases.
- TIA compliant
- EIA compliant
- RoHS



Rack Rails				
Part Number	Price	Rack Units	Height	Drawing Link
URR2U		2U	3.50 [89]	PDF
URR3U		3U	5.25 [133]	PDF
URR4U		4U	7.00 [178]	PDF
URR6U		6U	10.50 [267]	PDF
URR8U		8U	14.00 [356]	PDF
URR10U		10U	17.50 [445]	PDF
URR12U		12U	21.00 [533]	PDF
URR14U		14U	24.50 [622]	PDF
URR16U		16U	21.00 [533]	PDF
URR18U		18U	31.50 [800]	PDF
URR21U		21U	36.75 [933]	PDF
URR24U		24U	42.00 [1067]	PDF
URR27U		27U	47.25 [1200]	PDF
URR36U		36U	63.00 [1600]	PDF
URR45U		45U	78.75 [2000]	PDF
Note: Dimensions in inches [millimeters].				