

# NEMA 12 and 13 Single-Door Wall-Mount



## Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments.
- Provides some protection from falling dirt, dust, oil, and water.

## Construction


- Formed 14-gauge steel bodies and doors.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Door and body stiffeners are provided in the larger enclosures for extra rigidity.
- 14-gauge welded mounting brackets
- Formed lip on door and enclosure exclude flowing liquids and contaminants.
- Continuously hinged door may be removed by pulling the hinge pin.
- Door is secured with easily operated stainless steel clamps.
- Provision for padlocking.
- Oil-resistant gaskets are permanently secured.
- A removable 12-gauge subpanel is included.
- Collar studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.
- A literature pocket is provided for the inside of the door.

## Finish

- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating on the inside and outside.
- Removable subpanel is finished in white RAL9003 powder coating.

## Listings

- UL 508A Type 12 and 13 [UL File E65324]
- CSA Type 12 and 13 [CSA File LR21001]
- Complies with
  - NEMA Type 12 and 13
  - IEC 60529, IP54

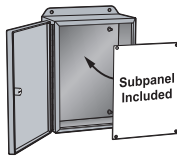

## NEMA 12 and 13 Single-Door Wall-Mount

| Part Number             | Price | Enclosure Size HxWxD                    | Subpanels               |                           |                         |                         |                            | Size HxW                  | Drawing Link        |
|-------------------------|-------|-----------------------------------------|-------------------------|---------------------------|-------------------------|-------------------------|----------------------------|---------------------------|---------------------|
|                         |       |                                         | Painted (included)      | Perforated                | Aluminum                | Galvanized              | Stainless                  |                           |                     |
| <a href="#">1418A6</a>  |       | 12.00 x 24.00 x 7.20 [305 x 610 x 183]  | <a href="#">18P2109</a> | —                         | —                       | <a href="#">18G2109</a> | —                          | 21.00 x 9.00 [533 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418A8</a>  |       | 12.00 x 24.00 x 9.20 [305 x 610 x 234]  | <a href="#">18P2109</a> | —                         | —                       | <a href="#">18G2109</a> | —                          | 21.00 x 9.00 [533 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418B6</a>  |       | 16.00 x 12.00 x 7.20 [406 x 305 x 183]  | <a href="#">18P1309</a> | <a href="#">18P1309PP</a> | <a href="#">18A1309</a> | <a href="#">18G1309</a> | <a href="#">18P1309S16</a> | 13.00 x 9.00 [330 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418B8</a>  |       | 16.00 x 12.00 x 9.20 [406 x 305 x 234]  | <a href="#">18P1309</a> | <a href="#">18P1309PP</a> | <a href="#">18A1309</a> | <a href="#">18G1309</a> | <a href="#">18P1309S16</a> | 13.00 x 9.00 [330 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418B10</a> |       | 16.00 x 12.00 x 11.20 [406 x 305 x 284] | <a href="#">18P1309</a> | <a href="#">18P1309PP</a> | <a href="#">18A1309</a> | <a href="#">18G1309</a> | <a href="#">18P1309S16</a> | 13.00 x 9.00 [330 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418G6</a>  |       | 16.00 x 16.00 x 7.20 [406 x 406 x 183]  | <a href="#">18P1313</a> | <a href="#">18P1313PP</a> | <a href="#">18A1313</a> | <a href="#">18G1313</a> | <a href="#">18P1313S16</a> | 13.00 x 13.00 [330 x 330] | <a href="#">PDF</a> |
| <a href="#">1418G8</a>  |       | 16.00 x 16.00 x 9.20 [406 x 406 x 234]  | <a href="#">18P1313</a> | <a href="#">18P1313PP</a> | <a href="#">18A1313</a> | <a href="#">18G1313</a> | <a href="#">18P1313S16</a> | 13.00 x 13.00 [330 x 330] | <a href="#">PDF</a> |
| <a href="#">1418CR6</a> |       | 16.00 x 20.00 x 7.20 [406 x 508 x 183]  | <a href="#">18P1713</a> | <a href="#">18P1713PP</a> | —                       | <a href="#">18G1713</a> | <a href="#">18P1713S16</a> | 17.00 x 13.00 [432 x 330] | <a href="#">PDF</a> |
| <a href="#">1418CR8</a> |       | 16.00 x 20.00 x 9.20 [406 x 508 x 234]  | <a href="#">18P1713</a> | <a href="#">18P1713PP</a> | —                       | <a href="#">18G1713</a> | <a href="#">18P1713S16</a> | 17.00 x 13.00 [432 x 330] | <a href="#">PDF</a> |
| <a href="#">1418CA6</a> |       | 20.00 x 12.00 x 7.20 [508 x 305 x 183]  | <a href="#">18P1709</a> | —                         | —                       | <a href="#">18G1709</a> | —                          | 17.00 x 9.00 [432 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418CA8</a> |       | 20.00 x 12.00 x 9.20 [508 x 305 x 234]  | <a href="#">18P1709</a> | —                         | —                       | <a href="#">18G1709</a> | —                          | 17.00 x 9.00 [432 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418C6</a>  |       | 20.00 x 16.00 x 7.20 [508 x 406 x 183]  | <a href="#">18P1713</a> | <a href="#">18P1713PP</a> | —                       | <a href="#">18G1713</a> | <a href="#">18P1713S16</a> | 17.00 x 13.00 [432 x 330] | <a href="#">PDF</a> |
| <a href="#">1418C8</a>  |       | 20.00 x 16.00 x 9.20 [508 x 406 x 234]  | <a href="#">18P1713</a> | <a href="#">18P1713PP</a> | —                       | <a href="#">18G1713</a> | <a href="#">18P1713S16</a> | 17.00 x 13.00 [432 x 330] | <a href="#">PDF</a> |
| <a href="#">1418C10</a> |       | 20.00 x 16.00 x 11.20 [508 x 406 x 284] | <a href="#">18P1713</a> | <a href="#">18P1713PP</a> | —                       | <a href="#">18G1713</a> | <a href="#">18P1713S16</a> | 17.00 x 13.00 [432 x 330] | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

Table continued on next page

# NEMA 12 and 13 Single-Door Wall-Mount



Table continued from previous  
page

| NEMA 12 and 13 Single-Door Wall-Mount |       |                                         |                         |                           |                         |                         |                            |                           |                     |
|---------------------------------------|-------|-----------------------------------------|-------------------------|---------------------------|-------------------------|-------------------------|----------------------------|---------------------------|---------------------|
| Part Number                           | Price | Enclosure Size HxWxD                    | Subpanels               |                           |                         |                         |                            | Size HxW                  | Drawing Link        |
|                                       |       |                                         | Painted (included)      | Perforated                | Aluminum                | Galvanized              | Stainless                  |                           |                     |
| <a href="#">1418C12</a>               |       | 20.00 x 16.00 x 13.20 [508 x 406 x 335] | <a href="#">18P1713</a> | <a href="#">18P1713PP</a> | —                       | <a href="#">18G1713</a> | <a href="#">18P1713S16</a> | 17.00 x 13.00 [432 x 330] | <a href="#">PDF</a> |
| <a href="#">1418D6</a>                |       | 20.00 x 20.00 x 7.20 [508 x 508 x 183]  | <a href="#">18P1717</a> | <a href="#">18P1717PP</a> | <a href="#">18A1717</a> | <a href="#">18G1717</a> | <a href="#">18P1717S16</a> | 17.00 x 17.00 [432 x 432] | <a href="#">PDF</a> |
| <a href="#">1418D8</a>                |       | 20.00 x 20.00 x 9.20 [508 x 508 x 234]  | <a href="#">18P1717</a> | <a href="#">18P1717PP</a> | <a href="#">18A1717</a> | <a href="#">18G1717</a> | <a href="#">18P1717S16</a> | 17.00 x 17.00 [432 x 432] | <a href="#">PDF</a> |
| <a href="#">1418D10</a>               |       | 20.00 x 20.00 x 11.20 [508 x 508 x 284] | <a href="#">18P1717</a> | <a href="#">18P1717PP</a> | <a href="#">18A1717</a> | <a href="#">18G1717</a> | <a href="#">18P1717S16</a> | 17.00 x 17.00 [432 x 432] | <a href="#">PDF</a> |
| <a href="#">1418ER6</a>               |       | 20.00 x 24.00 x 7.20 [508 x 610 x 183]  | <a href="#">18P2117</a> | <a href="#">18P2117PP</a> | <a href="#">18A2117</a> | <a href="#">18G2117</a> | <a href="#">18P2117S16</a> | 21.00 x 17.00 [533 x 432] | <a href="#">PDF</a> |
| <a href="#">1418ER8</a>               |       | 20.00 x 24.00 x 9.20 [508 x 610 x 234]  | <a href="#">18P2117</a> | <a href="#">18P2117PP</a> | <a href="#">18A2117</a> | <a href="#">18G2117</a> | <a href="#">18P2117S16</a> | 21.00 x 17.00 [533 x 432] | <a href="#">PDF</a> |
| <a href="#">1418AR6</a>               |       | 24.00 x 12.00 x 7.20 [610 x 305 x 183]  | <a href="#">18P2109</a> | —                         | —                       | <a href="#">18G2109</a> | —                          | 21.00 x 9.00 [533 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418AR8</a>               |       | 24.00 x 12.00 x 9.20 [610 x 305 x 234]  | <a href="#">18P2109</a> | —                         | —                       | <a href="#">18G2109</a> | —                          | 21.00 x 9.00 [533 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418AR10</a>              |       | 24.00 x 12.00 x 11.20 [610 x 305 x 284] | <a href="#">18P2109</a> | —                         | —                       | <a href="#">18G2109</a> | —                          | 21.00 x 9.00 [533 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418H6</a>                |       | 24.00 x 16.00 x 7.20 [610 x 406 x 183]  | <a href="#">18P2113</a> | —                         | —                       | <a href="#">18G2113</a> | <a href="#">18P2113S16</a> | 21.00 x 13.00 [533 x 330] | <a href="#">PDF</a> |
| <a href="#">1418H8</a>                |       | 24.00 x 16.00 x 9.20 [610 x 406 x 234]  | <a href="#">18P2113</a> | —                         | —                       | <a href="#">18G2113</a> | <a href="#">18P2113S16</a> | 21.00 x 13.00 [533 x 330] | <a href="#">PDF</a> |
| <a href="#">1418E6</a>                |       | 24.00 x 20.00 x 7.20 [610 x 508 x 183]  | <a href="#">18P2117</a> | <a href="#">18P2117PP</a> | <a href="#">18A2117</a> | <a href="#">18G2117</a> | <a href="#">18P2117S16</a> | 21.00 x 17.00 [533 x 432] | <a href="#">PDF</a> |
| <a href="#">1418E8</a>                |       | 24.00 x 20.00 x 9.20 [610 x 508 x 234]  | <a href="#">18P2117</a> | <a href="#">18P2117PP</a> | <a href="#">18A2117</a> | <a href="#">18G2117</a> | <a href="#">18P2117S16</a> | 21.00 x 17.00 [533 x 432] | <a href="#">PDF</a> |
| <a href="#">1418E10</a>               |       | 24.00 x 20.00 x 11.20 [610 x 508 x 284] | <a href="#">18P2117</a> | <a href="#">18P2117PP</a> | <a href="#">18A2117</a> | <a href="#">18G2117</a> | <a href="#">18P2117S16</a> | 21.00 x 17.00 [533 x 432] | <a href="#">PDF</a> |
| <a href="#">1418E12</a>               |       | 24.00 x 20.00 x 13.20 [610 x 508 x 335] | <a href="#">18P2117</a> | <a href="#">18P2117PP</a> | <a href="#">18A2117</a> | <a href="#">18G2117</a> | <a href="#">18P2117S16</a> | 21.00 x 17.00 [533 x 432] | <a href="#">PDF</a> |
| <a href="#">1418E16</a>               |       | 24.00 x 20.00 x 17.20 [610 x 508 x 437] | <a href="#">18P2117</a> | <a href="#">18P2117PP</a> | <a href="#">18A2117</a> | <a href="#">18G2117</a> | <a href="#">18P2117S16</a> | 21.00 x 17.00 [533 x 432] | <a href="#">PDF</a> |
| <a href="#">1418J6</a>                |       | 24.00 x 24.00 x 7.20 [610 x 610 x 183]  | <a href="#">18P2121</a> | <a href="#">18P2121PP</a> | <a href="#">18A2121</a> | <a href="#">18G2121</a> | <a href="#">18P2121S16</a> | 21.00 x 21.00 [533 x 533] | <a href="#">PDF</a> |
| <a href="#">1418J8</a>                |       | 24.00 x 24.00 x 9.20 [610 x 610 x 234]  | <a href="#">18P2121</a> | <a href="#">18P2121PP</a> | <a href="#">18A2121</a> | <a href="#">18G2121</a> | <a href="#">18P2121S16</a> | 21.00 x 21.00 [533 x 533] | <a href="#">PDF</a> |
| <a href="#">1418J10</a>               |       | 24.00 x 24.00 x 11.20 [610 x 610 x 284] | <a href="#">18P2121</a> | <a href="#">18P2121PP</a> | <a href="#">18A2121</a> | <a href="#">18G2121</a> | <a href="#">18P2121S16</a> | 21.00 x 21.00 [533 x 533] | <a href="#">PDF</a> |
| <a href="#">1418J12</a>               |       | 24.00 x 24.00 x 13.20 [610 x 610 x 335] | <a href="#">18P2121</a> | <a href="#">18P2121PP</a> | <a href="#">18A2121</a> | <a href="#">18G2121</a> | <a href="#">18P2121S16</a> | 21.00 x 21.00 [533 x 533] | <a href="#">PDF</a> |
| <a href="#">1418J16</a>               |       | 24.00 x 24.00 x 17.20 [610 x 610 x 437] | <a href="#">18P2121</a> | <a href="#">18P2121PP</a> | <a href="#">18A2121</a> | <a href="#">18G2121</a> | <a href="#">18P2121S16</a> | 21.00 x 21.00 [533 x 533] | <a href="#">PDF</a> |
| <a href="#">1418KR8</a>               |       | 24.00 x 30.00 x 9.20 [610 x 762 x 234]  | <a href="#">18P2721</a> | <a href="#">18P2721PP</a> | <a href="#">18A2721</a> | <a href="#">18G2721</a> | <a href="#">18P2721S16</a> | 27.00 x 21.00 [686 x 533] | <a href="#">PDF</a> |
| <a href="#">1418KA8</a>               |       | 30.00 x 12.00 x 9.20 [762 x 305 x 234]  | <a href="#">18P2709</a> | —                         | —                       | <a href="#">18G2709</a> | —                          | 27.00 x 9.00 [686 x 229]  | <a href="#">PDF</a> |
| <a href="#">1418FG6</a>               |       | 30.00 x 16.00 x 7.20 [762 x 406 x 183]  | <a href="#">18P2713</a> | —                         | —                       | <a href="#">18G2713</a> | —                          | 27.00 x 13.00 [686 x 330] | <a href="#">PDF</a> |
| <a href="#">1418KG8</a>               |       | 30.00 x 16.00 x 9.20 [762 x 406 x 234]  | <a href="#">18P2713</a> | —                         | —                       | <a href="#">18G2713</a> | —                          | 27.00 x 13.00 [686 x 330] | <a href="#">PDF</a> |
| <a href="#">1418F6</a>                |       | 30.00 x 20.00 x 7.20 [762 x 508 x 183]  | <a href="#">18P2717</a> | —                         | —                       | <a href="#">18G2717</a> | <a href="#">18P2717S16</a> | 27.00 x 17.00 [686 x 432] | <a href="#">PDF</a> |
| <a href="#">1418F8</a>                |       | 30.00 x 20.00 x 9.20 [762 x 508 x 234]  | <a href="#">18P2717</a> | —                         | —                       | <a href="#">18G2717</a> | <a href="#">18P2717S16</a> | 27.00 x 17.00 [686 x 432] | <a href="#">PDF</a> |
| <a href="#">1418F10</a>               |       | 30.00 x 20.00 x 11.20 [762 x 508 x 284] | <a href="#">18P2717</a> | —                         | —                       | <a href="#">18G2717</a> | <a href="#">18P2717S16</a> | 27.00 x 17.00 [686 x 432] | <a href="#">PDF</a> |
| <a href="#">1418K6</a>                |       | 30.00 x 24.00 x 7.20 [762 x 610 x 183]  | <a href="#">18P2721</a> | <a href="#">18P2721PP</a> | <a href="#">18A2721</a> | <a href="#">18G2721</a> | <a href="#">18P2721S16</a> | 27.00 x 21.00 [686 x 533] | <a href="#">PDF</a> |
| <a href="#">1418K8</a>                |       | 30.00 x 24.00 x 9.20 [762 x 610 x 234]  | <a href="#">18P2721</a> | <a href="#">18P2721PP</a> | <a href="#">18A2721</a> | <a href="#">18G2721</a> | <a href="#">18P2721S16</a> | 27.00 x 21.00 [686 x 533] | <a href="#">PDF</a> |
| <a href="#">1418K10</a>               |       | 30.00 x 24.00 x 11.20 [762 x 610 x 284] | <a href="#">18P2721</a> | <a href="#">18P2721PP</a> | <a href="#">18A2721</a> | <a href="#">18G2721</a> | <a href="#">18P2721S16</a> | 27.00 x 21.00 [686 x 533] | <a href="#">PDF</a> |
| <a href="#">1418K12</a>               |       | 30.00 x 24.00 x 13.20 [762 x 610 x 335] | <a href="#">18P2721</a> | <a href="#">18P2721PP</a> | <a href="#">18A2721</a> | <a href="#">18G2721</a> | <a href="#">18P2721S16</a> | 27.00 x 21.00 [686 x 533] | <a href="#">PDF</a> |
| <a href="#">1418K16</a>               |       | 30.00 x 24.00 x 17.20 [762 x 610 x 437] | <a href="#">18P2721</a> | <a href="#">18P2721PP</a> | <a href="#">18A2721</a> | <a href="#">18G2721</a> | <a href="#">18P2721S16</a> | 27.00 x 21.00 [686 x 533] | <a href="#">PDF</a> |
| <a href="#">1418K20</a>               |       | 30.00 x 24.00 x 21.20 [762 x 610 x 538] | <a href="#">18P2721</a> | <a href="#">18P2721PP</a> | <a href="#">18A2721</a> | <a href="#">18G2721</a> | <a href="#">18P2721S16</a> | 27.00 x 21.00 [686 x 533] | <a href="#">PDF</a> |
| <a href="#">1418K24</a>               |       | 30.00 x 24.00 x 25.20 [762 x 610 x 640] | <a href="#">18P2721</a> | <a href="#">18P2721PP</a> | <a href="#">18A2721</a> | <a href="#">18G2721</a> | <a href="#">18P2721S16</a> | 27.00 x 21.00 [686 x 533] | <a href="#">PDF</a> |
| <a href="#">1418KK8</a>               |       | 30.00 x 30.00 x 9.20 [762 x 762 x 234]  | <a href="#">18P2727</a> | <a href="#">18P2727PP</a> | —                       | <a href="#">18G2727</a> | <a href="#">18P2727S16</a> | 27.00 x 27.00 [686 x 686] | <a href="#">PDF</a> |
| <a href="#">1418KK12</a>              |       | 30.00 x 30.00 x 13.20 [762 x 762 x 335] | <a href="#">18P2727</a> | <a href="#">18P2727PP</a> | —                       | <a href="#">18G2727</a> | <a href="#">18P2727S16</a> | 27.00 x 27.00 [686 x 686] | <a href="#">PDF</a> |
| <a href="#">1418MR8</a>               |       | 30.00 x 36.00 x 9.20 [762 x 914 x 234]  | <a href="#">18P3327</a> | <a href="#">18P3327PP</a> | <a href="#">18A3327</a> | <a href="#">18G3327</a> | <a href="#">18P3327S16</a> | 33.00 x 27.00 [838 x 686] | <a href="#">PDF</a> |
| <a href="#">1418L6</a>                |       | 36.00 x 24.00 x 7.20 [914 x 610 x 183]  | <a href="#">18P3321</a> | <a href="#">18P3327PP</a> | <a href="#">18A3321</a> | <a href="#">18G3321</a> | <a href="#">18P3321S16</a> | 33.00 x 21.00 [838 x 533] | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

Table continued on next page

# NEMA 12 and 13 Single-Door Wall-Mount



Table continued from previous  
page

| NEMA 12 and 13 Single-Door Wall-Mount |       |                                          |                         |                           |                         |                         |                            |                            |                     |
|---------------------------------------|-------|------------------------------------------|-------------------------|---------------------------|-------------------------|-------------------------|----------------------------|----------------------------|---------------------|
| Part Number                           | Price | Enclosure Size HxWxD                     | Subpanels               |                           |                         |                         |                            | Size HxW                   | Drawing Link        |
|                                       |       |                                          | Painted (included)      | Perforated                | Aluminum                | Galvanized              | Stainless                  |                            |                     |
| <a href="#">1418L8</a>                |       | 36.00 x 24.00 x 9.20 [914 x 610 x 234]   | <a href="#">18P3321</a> | <a href="#">18P3321PP</a> | <a href="#">18A3321</a> | <a href="#">18G3321</a> | <a href="#">18P3321S16</a> | 33.00 x 21.00 [838 x 533]  | <a href="#">PDF</a> |
| <a href="#">1418L10</a>               |       | 36.00 x 24.00 x 11.20 [914 x 610 x 284]  | <a href="#">18P3321</a> | <a href="#">18P3321PP</a> | <a href="#">18A3321</a> | <a href="#">18G3321</a> | <a href="#">18P3321S16</a> | 33.00 x 21.00 [838 x 533]  | <a href="#">PDF</a> |
| <a href="#">1418L12</a>               |       | 36.00 x 24.00 x 13.20 [914 x 610 x 335]  | <a href="#">18P3321</a> | <a href="#">18P3321PP</a> | <a href="#">18A3321</a> | <a href="#">18G3321</a> | <a href="#">18P3321S16</a> | 33.00 x 21.00 [838 x 533]  | <a href="#">PDF</a> |
| <a href="#">1418M6</a>                |       | 36.00 x 30.00 x 7.20 [914 x 762 x 183]   | <a href="#">18P3327</a> | <a href="#">18P3327PP</a> | <a href="#">18A3327</a> | <a href="#">18G3327</a> | <a href="#">18P3327S16</a> | 33.00 x 27.00 [838 x 686]  | <a href="#">PDF</a> |
| <a href="#">1418M8</a>                |       | 36.00 x 30.00 x 9.20 [914 x 762 x 234]   | <a href="#">18P3327</a> | <a href="#">18P3327PP</a> | <a href="#">18A3327</a> | <a href="#">18G3327</a> | <a href="#">18P3327S16</a> | 33.00 x 27.00 [838 x 686]  | <a href="#">PDF</a> |
| <a href="#">1418M10</a>               |       | 36.00 x 30.00 x 11.20 [914 x 762 x 284]  | <a href="#">18P3327</a> | <a href="#">18P3327PP</a> | <a href="#">18A3327</a> | <a href="#">18G3327</a> | <a href="#">18P3327S16</a> | 33.00 x 27.00 [838 x 686]  | <a href="#">PDF</a> |
| <a href="#">1418M12</a>               |       | 36.00 x 30.00 x 13.20 [914 x 762 x 335]  | <a href="#">18P3327</a> | <a href="#">18P3327PP</a> | <a href="#">18A3327</a> | <a href="#">18G3327</a> | <a href="#">18P3327S16</a> | 33.00 x 27.00 [838 x 686]  | <a href="#">PDF</a> |
| <a href="#">1418M16</a>               |       | 36.00 x 30.00 x 17.20 [914 x 762 x 437]  | <a href="#">18P3327</a> | <a href="#">18P3327PP</a> | <a href="#">18A3327</a> | <a href="#">18G3327</a> | <a href="#">18P3327S16</a> | 33.00 x 27.00 [838 x 686]  | <a href="#">PDF</a> |
| <a href="#">1418M20</a>               |       | 36.00 x 30.00 x 21.20 [914 x 762 x 538]  | <a href="#">18P3327</a> | <a href="#">18P3327PP</a> | <a href="#">18A3327</a> | <a href="#">18G3327</a> | <a href="#">18P3327S16</a> | 33.00 x 27.00 [838 x 686]  | <a href="#">PDF</a> |
| <a href="#">1418LL8</a>               |       | 36.00 x 36.00 x 9.20 [914 x 914 x 234]   | <a href="#">18P3333</a> | <a href="#">18P3333PP</a> | —                       | <a href="#">18G3333</a> | <a href="#">18P3333S16</a> | 33.00 x 33.00 [838 x 838]  | <a href="#">PDF</a> |
| <a href="#">1418LL12</a>              |       | 36.00 x 36.00 x 13.20 [914 x 914 x 335]  | <a href="#">18P3333</a> | <a href="#">18P3333PP</a> | —                       | <a href="#">18G3333</a> | <a href="#">18P3333S16</a> | 33.00 x 33.00 [838 x 838]  | <a href="#">PDF</a> |
| <a href="#">1418N8</a>                |       | 42.00 x 24.00 x 9.20 [1067 x 610 x 234]  | <a href="#">18P3921</a> | —                         | —                       | <a href="#">18G3921</a> | —                          | 39.00 x 21.00 [991 x 533]  | <a href="#">PDF</a> |
| <a href="#">1418O8</a>                |       | 42.00 x 30.00 x 9.20 [1067 x 762 x 234]  | <a href="#">18P3927</a> | —                         | —                       | <a href="#">18G3927</a> | <a href="#">18P3927S16</a> | 39.00 x 27.00 [991 x 686]  | <a href="#">PDF</a> |
| <a href="#">1418O10</a>               |       | 42.00 x 30.00 x 11.20 [1067 x 762 x 284] | <a href="#">18P3927</a> | —                         | —                       | <a href="#">18G3927</a> | <a href="#">18P3927S16</a> | 39.00 x 27.00 [991 x 686]  | <a href="#">PDF</a> |
| <a href="#">1418O12</a>               |       | 42.00 x 30.00 x 13.20 [1067 x 762 x 335] | <a href="#">18P3927</a> | —                         | —                       | <a href="#">18G3927</a> | <a href="#">18P3927S16</a> | 39.00 x 27.00 [991 x 686]  | <a href="#">PDF</a> |
| <a href="#">1418P8</a>                |       | 42.00 x 36.00 x 9.20 [1067 x 914 x 234]  | <a href="#">18P3933</a> | —                         | —                       | <a href="#">18G3933</a> | —                          | 39.00 x 33.00 [991 x 838]  | <a href="#">PDF</a> |
| <a href="#">1418P10</a>               |       | 42.00 x 36.00 x 11.20 [1067 x 914 x 284] | <a href="#">18P3933</a> | —                         | —                       | <a href="#">18G3933</a> | —                          | 39.00 x 33.00 [991 x 838]  | <a href="#">PDF</a> |
| <a href="#">1418P12</a>               |       | 42.00 x 36.00 x 13.20 [1067 x 914 x 335] | <a href="#">18P3933</a> | —                         | —                       | <a href="#">18G3933</a> | —                          | 39.00 x 33.00 [991 x 838]  | <a href="#">PDF</a> |
| <a href="#">1418P16</a>               |       | 42.00 x 36.00 x 17.20 [1067 x 914 x 437] | <a href="#">18P3933</a> | —                         | —                       | <a href="#">18G3933</a> | —                          | 39.00 x 33.00 [991 x 838]  | <a href="#">PDF</a> |
| <a href="#">1418Q8</a>                |       | 48.00 x 24.00 x 9.20 [1219 x 610 x 234]  | <a href="#">18P4521</a> | —                         | —                       | <a href="#">18G4521</a> | —                          | 45.00 x 21.00 [1143 x 533] | <a href="#">PDF</a> |
| <a href="#">1418R8</a>                |       | 48.00 x 30.00 x 9.20 [1219 x 762 x 234]  | <a href="#">18P4527</a> | —                         | —                       | <a href="#">18G4527</a> | —                          | 45.00 x 27.00 [1143 x 686] | <a href="#">PDF</a> |
| <a href="#">1418R10</a>               |       | 48.00 x 30.00 x 11.20 [1219 x 762 x 284] | <a href="#">18P4527</a> | —                         | —                       | <a href="#">18G4527</a> | —                          | 45.00 x 27.00 [1143 x 686] | <a href="#">PDF</a> |
| <a href="#">1418S8</a>                |       | 48.00 x 36.00 x 9.20 [1219 x 914 x 234]  | <a href="#">18P4533</a> | —                         | <a href="#">18A4533</a> | <a href="#">18G4533</a> | <a href="#">18P4533S16</a> | 45.00 x 33.00 [1143 x 838] | <a href="#">PDF</a> |
| <a href="#">1418S10</a>               |       | 48.00 x 36.00 x 11.20 [1219 x 914 x 284] | <a href="#">18P4533</a> | —                         | <a href="#">18A4533</a> | <a href="#">18G4533</a> | <a href="#">18P4533S16</a> | 45.00 x 33.00 [1143 x 838] | <a href="#">PDF</a> |
| <a href="#">1418S12</a>               |       | 48.00 x 36.00 x 13.20 [1219 x 914 x 335] | <a href="#">18P4533</a> | —                         | <a href="#">18A4533</a> | <a href="#">18G4533</a> | <a href="#">18P4533S16</a> | 45.00 x 33.00 [1143 x 838] | <a href="#">PDF</a> |
| <a href="#">1418S16</a>               |       | 48.00 x 36.00 x 17.20 [1219 x 914 x 437] | <a href="#">18P4533</a> | —                         | <a href="#">18A4533</a> | <a href="#">18G4533</a> | <a href="#">18P4533S16</a> | 45.00 x 33.00 [1143 x 838] | <a href="#">PDF</a> |
| <a href="#">1418S20</a>               |       | 48.00 x 36.00 x 21.20 [1219 x 914 x 538] | <a href="#">18P4533</a> | —                         | <a href="#">18A4533</a> | <a href="#">18G4533</a> | <a href="#">18P4533S16</a> | 45.00 x 33.00 [1143 x 838] | <a href="#">PDF</a> |
| <a href="#">1418T8</a>                |       | 60.00 x 36.00 x 9.20 [1524 x 914 x 234]  | <a href="#">18P4533</a> | —                         | <a href="#">18A5733</a> | <a href="#">18G5733</a> | <a href="#">18P4533S16</a> | 45.00 x 33.00 [1143 x 838] | <a href="#">PDF</a> |
| <a href="#">1418T10</a>               |       | 60.00 x 36.00 x 11.20 [1524 x 914 x 284] | <a href="#">18P5733</a> | —                         | <a href="#">18A5733</a> | <a href="#">18G5733</a> | <a href="#">18P5733S16</a> | 57.00 x 33.00 [1448 x 838] | <a href="#">PDF</a> |
| <a href="#">1418T12</a>               |       | 60.00 x 36.00 x 13.20 [1524 x 914 x 335] | <a href="#">18P5733</a> | —                         | <a href="#">18A5733</a> | <a href="#">18G5733</a> | <a href="#">18P5733S16</a> | 57.00 x 33.00 [1448 x 838] | <a href="#">PDF</a> |
| <a href="#">1418T16</a>               |       | 60.00 x 36.00 x 17.20 [1524 x 914 x 437] | <a href="#">18P5733</a> | —                         | <a href="#">18A5733</a> | <a href="#">18G5733</a> | <a href="#">18P5733S16</a> | 57.00 x 33.00 [1448 x 838] | <a href="#">PDF</a> |
| <a href="#">1418T20</a>               |       | 60.00 x 36.00 x 21.20 [1524 x 914 x 538] | <a href="#">18P5733</a> | —                         | <a href="#">18A5733</a> | <a href="#">18G5733</a> | <a href="#">18P5733S16</a> | 57.00 x 33.00 [1448 x 838] | <a href="#">PDF</a> |
| <a href="#">1418U12</a>               |       | 72.00 x 30.00 x 13.20 [1829 x 762 x 335] | <a href="#">18P6927</a> | —                         | —                       | <a href="#">18G6927</a> | —                          | 69.00 x 27.00 [1753 x 686] | <a href="#">PDF</a> |
| <a href="#">1418U16</a>               |       | 72.00 x 30.00 x 17.20 [1829 x 762 x 437] | <a href="#">18P6927</a> | —                         | —                       | <a href="#">18G6927</a> | —                          | 69.00 x 27.00 [1753 x 686] | <a href="#">PDF</a> |
| <a href="#">1418U20</a>               |       | 72.00 x 30.00 x 21.20 [1829 x 762 x 538] | <a href="#">18P6927</a> | —                         | —                       | <a href="#">18G6927</a> | —                          | 69.00 x 27.00 [1753 x 686] | <a href="#">PDF</a> |
| <a href="#">1418U24</a>               |       | 72.00 x 30.00 x 25.20 [1829 x 762 x 640] | <a href="#">18P6927</a> | —                         | —                       | <a href="#">18G6927</a> | —                          | 69.00 x 27.00 [1753 x 686] | <a href="#">PDF</a> |
| <a href="#">1418V12</a>               |       | 72.00 x 36.00 x 13.20 [1829 x 914 x 335] | <a href="#">18P6933</a> | —                         | —                       | <a href="#">18G6933</a> | —                          | 69.00 x 33.00 [1753 x 838] | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

# NEMA 12 and 13 Single-Door Wall-Mount



## Dimensions

