

Non-Metallic Enclosures – Slim Line Series

Slim Line Junction Box with Lift-off Opaque Cover



HW-N4X1144

Construction

- Hot compression molded fiberglass reinforced thermoset polyester
- Poured polyurethane seamless gasket provides watertight dust-tight environmental seal
- NEMA 4X rating
- UV resistant
- Workable material cuts, drills, punches and saws with ease and accuracy
- Four recessed captive stainless steel screws
- 300 Series stainless steel used on all external hardware
- Optional mounting feet available
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Rounded edges, minimal protrusions or exposed pocket areas for accumulation of dust or debris
- Non-corrosive in chemical exposure

- Rated watertight and submersible for long periods
- High impact resistance
- Non-conductive double insulated material
- Lift-off cover with four cover screws
- Smooth surface, no color variations, swirls or color pockets, no voids
- Color: Gray

Listings


- UL/cUL 50/508, Types 1, 3, 4X, 6P, 12
- UL File E64791
- CSA Standard C22.2 File 222873 Types 1, 3, 4x, 6P, 12
- NEMA Standard 250 Types 1, 3, 4x, 6P, 12
- Temperature Range: -40°F to 250°F (-40°C to 120°C)
- Flammability Rating: UL94-5V
- Non-flame propagating



Slim Line Junction Box with Opaque Cover and Four Screws										
Part Number	Price	Enclosure Overall Size HxWxD	Enclosure Inside AxBxC	I	J	K	L	M	N	Wt.
HW-N4X332*	<-->	3.72 x 3.63 x 2.95 (95 x 92 x 75)	3.13 x 3.03 x 2.70 (79 x 77 x 69)	0 (flat cover)	0 (flat cover)	2.31 (59)	2.75 (70)	1.59 (40)	2.03 (52)	1 lb
HW-N4X532*	<-->	5.97 x 3.63 x 3.14 (152 x 92 x 80)	5.38 x 3.03 x 2.87 (137 x 77 x 73)	4.72 (120)	2.38 (60)	4.56 (116)	2.75 (70)	3.84 (98)	2.03 (52)	1 lb
HW-N4X644	<-->	6.63 x 3.81 x 3.89 (168 x 97 x 99)	6.00 x 3.19 x 3.63 (153 x 81 x 92)	5.31 (135)	2.50 (64)	4.88 (124)	2.94 (75)	4.13 (105)	2.19 (56)	2 lbs
HW-N4X832*	<-->	8.41 x 3.63 x 3.14 (214 x 92 x 80)	7.82 x 3.03 x 2.87 (199 x 77 x 73)	7.16 (182)	2.38 (60)	7.00 (178)	2.75 (70)	6.28 (160)	2.03 (52)	2 lbs
HW-N4X844	<-->	8.88 x 3.81 x 3.89 (225 x 97 x 99)	8.26 x 3.19 x 3.63 (210 x 81 x 92)	7.56 (192)	2.50 (64)	7.13 (181)	2.94 (75)	6.38 (162)	2.19 (56)	2 lbs
HW-N4X932*	<-->	9.35 x 3.63 x 3.14 (237 x 92 x 80)	8.75 x 3.03 x 2.87 (222 x 77 x 73)	8.10 (206)	2.38 (60)	7.94 (202)	2.75 (70)	7.22 (183)	2.03 (52)	2 lbs
HW-N4X1144	<-->	11.13 x 3.81 x 3.89 (283 x 97 x 99)	10.51 x 3.19 x 3.63 (267 x 81 x 92)	9.81 (249)	2.50 (64)	9.37 (238)	2.94 (75)	8.63 (219)	2.19 (56)	2 lbs
HW-N4X1432*	<-->	13.78 x 3.63 x 3.14 (350 x 92 x 80)	13.19 x 3.03 x 2.87 (335 x 77 x 73)	12.53 (318)	2.38 (60)	12.37 (314)	2.75 (70)	11.66 (296)	2.03 (52)	2 lbs
HW-N4X1732*	<-->	17.35 x 3.63 x 3.14 (441 x 92 x 80)	16.75 x 3.03 x 2.87 (426 x 77 x 73)	16.10 (409)	2.50 (64)	15.94 (405)	2.75 (70)	15.22 (387)	2.03 (52)	3 lbs

Note: No Subpanel required. Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawings.
 Mounting foot kit (HW-N4XMTGFTKIT) must be ordered separately.
 *Mounting foot kit not available for these sizes.

Dimensions

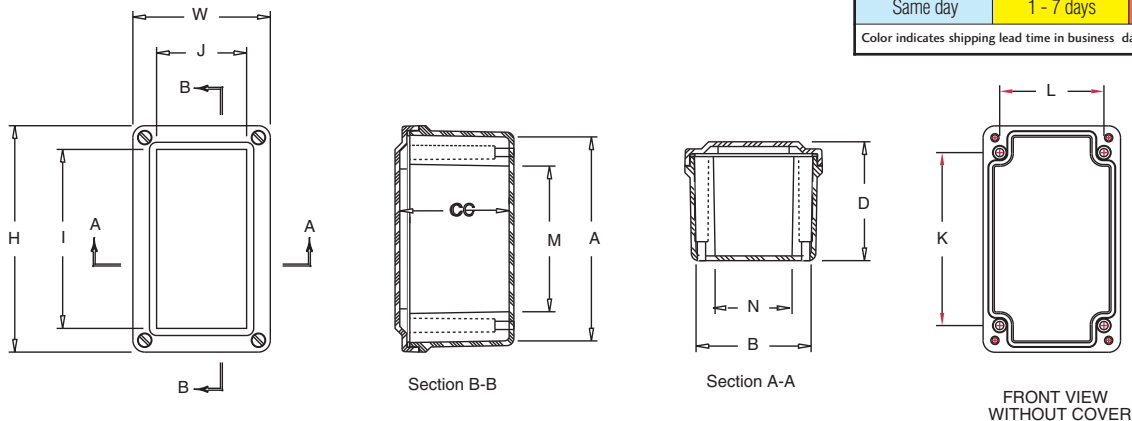

Enclosure Shipping Schedule		
Same day	1 - 7 days	1 - 14 days

Color indicates shipping lead time in business days.

Non-Metallic Enclosures – Slim Line Series

Slim Line Junction Box with Lift-off Opaque Cover



HW-N4X763SC

Construction

- Hot compression molded fiberglass reinforced thermoset polyester
 - Poured polyurethane seamless gasket provides watertight dust-tight environmental seal
 - NEMA 4X rating
 - UV resistant
 - Workable material cuts, drills, punches and saws with ease and accuracy
 - Four recessed captive stainless steel screws
 - 300 Series stainless steel used on all external hardware
 - Optional mounting feet available
 - Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
 - Rounded edges, minimal protrusions or exposed pocket areas for accumulation of dust or debris
 - Non-corrosive in chemical exposure
 - Rated watertight and submersible for long periods
 - High impact resistance
- Non-conductive double insulated material
 - Lift-off cover with four cover screws
 - Smooth surface, no color variations, swirls or color pockets, no voids
 - Optional carbon steel back panel available
 - Color: Gray

Listings


- UL/cUL 50/508, Types 1, 3, 4X, 6P, 12
- UL File E64791
- CSA Standard C22.2 File 222873 Types 1, 3, 4x, 6P, 12
- NEMA Standard 250 Types 1, 3, 4x, 6P, 12
- Temperature Range: -40°F to 250°F (-40°C to 120°C)
- Flammability Rating: UL94-5V
- Non-flame propagating



Slim Line Series Junction Box with Opaque Lift-off Cover and Four Screws											
Part Number	Price	Enclosure Overall Size HxWxD	Enclosure Inside AxBxC	Wt.	Carbon Steel Subpanel*	Mounting ExF	J	K	L	M	N
HW-N4X763SC	<--->	7.63 x 6.63 x 3.19 (194 x 168 x 81)	6.90 x 5.90 x 2.88 (175 x 150 x 73)	3 lbs.	HW-MP706CS	5.37 x 5.63 (137 x 143)	2.48 (63)	5.37 (137)	4.25 (108)	4.52 (115)	4.9 (124)
HW-N4X963SC	<--->	9.87 x 6.63 x 3.19 (251 x 168 x 81)	9.15 x 5.90 x 2.88 (232 x 150 x 73)	3 lbs.	HW-MP906CS	7.62 x 5.63 (194 x 143)	2.48 (63)	7.62 (194)	4.25 (108)	6.77 (172)	4.9 (124)

**Note: Subpanels must be ordered separately. Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawings. Mounting foot kit (HW-N4XMTGFTKIT) must be ordered separately.*

Dimensions

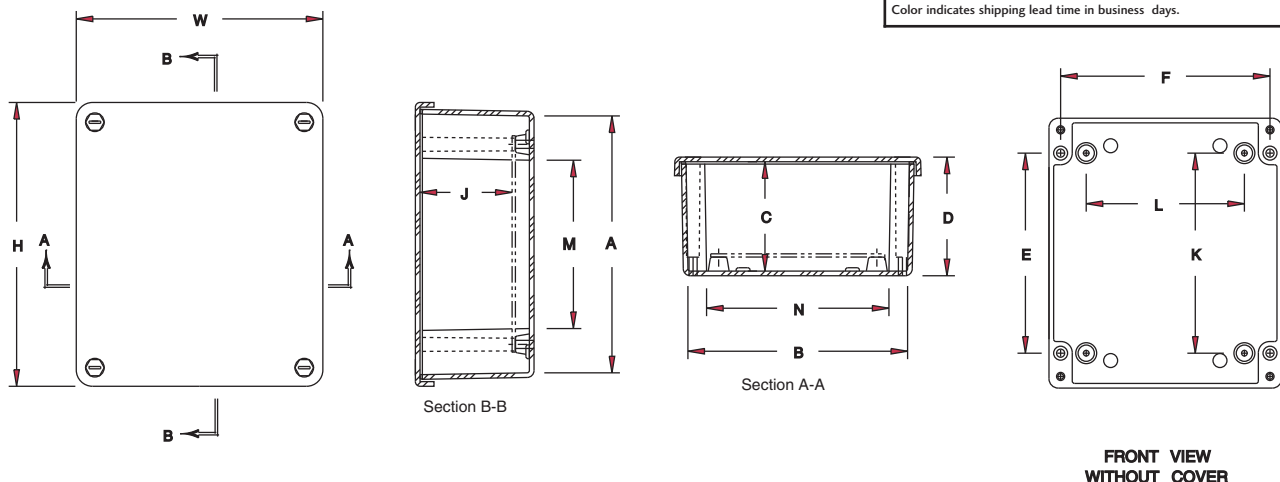

Enclosure Shipping Schedule		
Same day	1 - 7 days	1 - 14 days
Color indicates shipping lead time in business days.		